



EuropeanHome



gas  
fireplaces



timelessly clean & modern



# INDEX

**H Series**  
single | corner | see-through |  
3-sided | peninsula .....6-13

**G Series**  
linear gas burner .....14-15

**Gas Stones**  
modern gas log .....16-17

**About**..... 18

All models are designed and  
manufactured in the U.S.A. 

“Quality is the pride  
of workmanship”

– W. Edward Deming





designed by R+B Design Architecture, built by Wadleigh and Associates



## H Series

---

This vent-free gas fireplace features a contemporary, trimless, open front style and is designed with simplicity in mind. The increasing desirability of vent-free gas fireplaces can be summed up by the following:

1. **Zero Clearance:** The term “zero clearance” means that this type of fireplace can be installed very close to combustible materials like walls and furniture. This feature provides flexibility in placement and design.
2. **Vent-Free Technology:** Vent-free fireplaces do not require a chimney or flue. This simplifies the installation process and makes it more affordable compared to traditional fireplaces, which often require extensive venting systems.
3. **High Efficiency:** Vent-free gas fireplaces are known for their high efficiency. Since there’s no chimney or flue, heat is retained within the room,

making the fireplace 99% efficient. This can lead to cost savings on your gas utility bills.

4. **Versatile Placement:** Because vent-free fireplaces don’t need outside venting, you have more options for where to install them. They can be placed in various rooms throughout your home, including condos and small homes, without the need for extensive construction work.

The combination of ease of installation, energy efficiency, and contemporary style has made H Series vent-free fireplaces a popular choice in the market.

Above

**H Series Single-Sided**  
Smith Campus Center  
at Harvard University, MA

# SPECIFICATIONS

MODEL	H SERIES
Gas Type	Natural Gas (only)
Flame Adjustment	Yes
Vented Available	No
Vent-Free Available	Yes
Vented Flue Dimensions	N/A
Heat Output	25,000 - 37,500 BTU/hr (NG)
Efficiency	99% (Vent-Free)
Thermostatic Remote Control	Yes
Interior Options	Satin Black (Standard), Black Enamel or Concrete Style
Electronic Ignition	Yes
Certifications	ANSI Z21.11.2

**H Series Single-Sided**  
installer: Fireside Distributors, FL  
builder: Hedrick Brothers, FL



# H Series: Design Options

---

## 1. UNIT SIZE OPTIONS



42"







60"



72"

## 2. CONFIGURATIONS

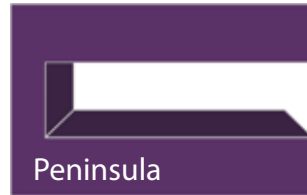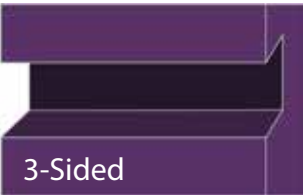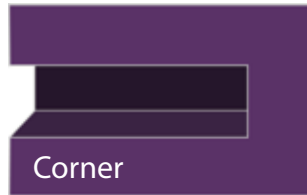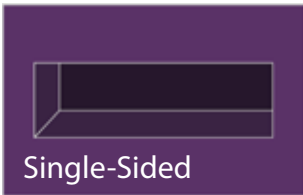

## 3. INTERIOR OPTIONS



Satin Black (Standard)



Concrete Style



Black Enamel



## 4. FIRE MEDIA



Pacific Blue Glass



Clear Glass



Amber Glass



Black Glass



Cobalt Blue Glass



Carrara Pebbles

## H Series Peninsula

*Installed by  
American Fireplace & BBQ Dist., MI*





HVF-42 [ Single-Sided ]  
*Pictured with optional Concrete Style interior.*  
*Millennium Tower - Boston, MA*



HVF-60 [ Corner Style ]  
*Pictured with Satin Black interior.*




HVF-60 [ See-Through ]  
*Featured on HGTV's Love It or List It.*  
*P.S. They Loved It!*  
*Private Residence - Durham, NC*

# H Series


## SINGLE-SIDED: DIMENSIONS (in.)

	HVF-42	HVF-60	HVF-72
A	42	60	72
B	18	18	18
C	18	18	18
D	37 1/2	37 1/2	37 1/2
E	38	49	59

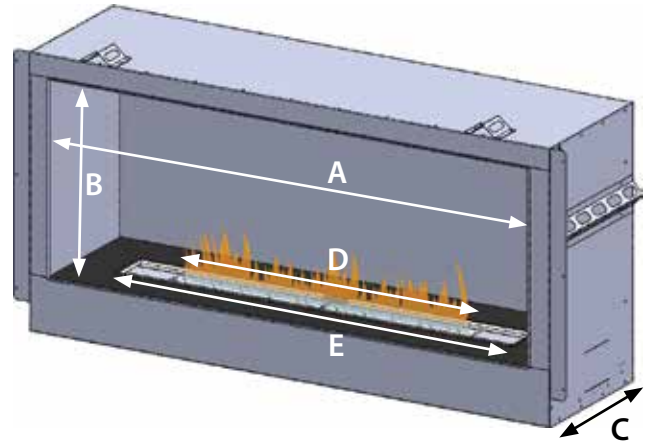


## CORNER STYLE: DIMENSIONS (in.)

	HVF-42-C	HVF-60-C	HVF-72-C
A	44 1/2	62 3/4	74 1/2
B	18	18	18
C	18	18	18
D	37 1/2	37 1/2	37 1/2
E	38	49	59

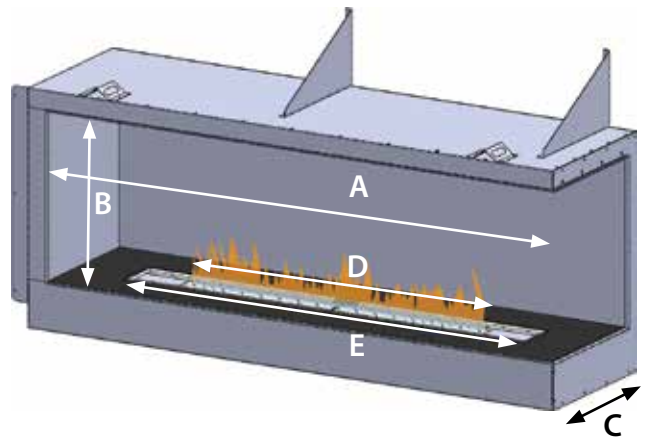

## SEE-THROUGH: DIMENSIONS (in.)

	HVF-42-ST	HVF-60-ST	HVF-72-ST
A	42	60	72
B	18	18	18
C	18	18	18
D	37 1/2	37 1/2	37 1/2
E	38	49	59

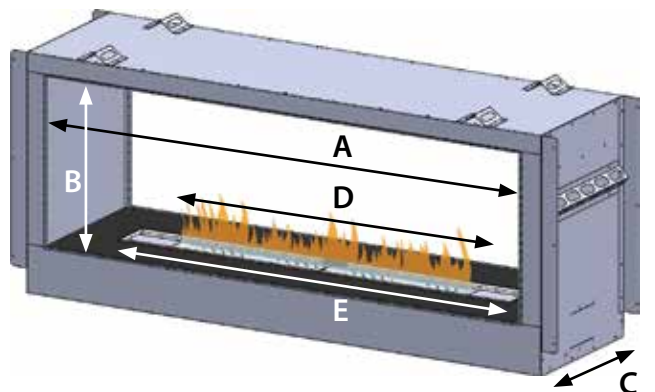

Available in three lengths:  
42", 60", and 72"

## H SERIES CONFIGURATIONS, Continued



HVF-42 [ 3-Sided ]

*The St. Gregory Hotel - Washington, D.C*

*Installed by Day or Night Home & Hearth Services LLC - Elkridge, MD*




HVF-72 [ Peninsula ]

# H Series


## 3-SIDED: DIMENSIONS (in.)

	HVF-42-3S	HVF-60-3S	HVF-72-3S
A	46 3/4	59 7/8	71 7/8
B	18	18	18
C	18	18	18
D	37 1/2	37 1/2	37 1/2
E	38	49	59

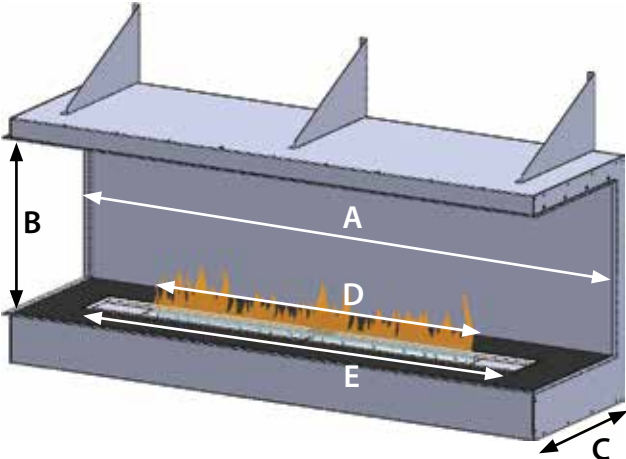

## PENINSULA: DIMENSIONS (in.)

	HVF-42-P	HVF-60-P	HVF-72-P
A	44 1/2	62 3/4	74 1/2
B	18	18	18
C	18	18	18
D	37 1/2	37 1/2	37 1/2
E	38	49	59

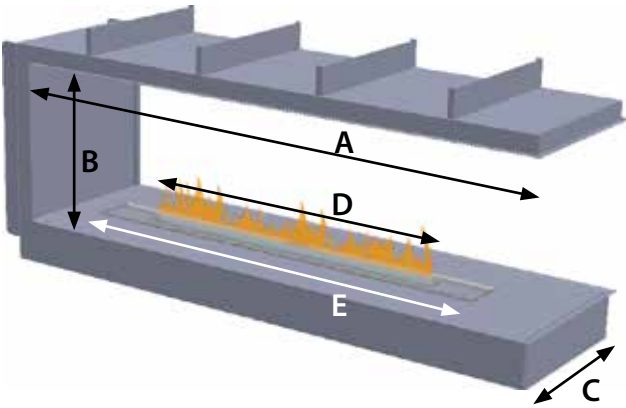

Optional enamel interior enhances the flames



*G Series 42" installed by Texas Draft Co., TX*

## G Series

---

Looking for a custom design? The G Series linear gas burner provides a simple way to achieve the look of a custom fireplace with the flexibility of an approved dual listed vented and vent-free natural gas burner. This burner can be used in an existing fireplace or in a listed firebox project.

The G Series is available in three sizes as a drop in burner (shown above) or with the optional burner cover (shown below). The optional cover is useful for floor level installation because it hides away the controls and burner structure to provide a clean, modern aesthetic.



G Series  
with optional cover



*Installed by Embers Fireplaces, NJ*

# SPECIFICATIONS

MODEL	G SERIES
Gas Type	Natural Gas (only)
Flame Adjustment	Yes
Vented Available	Yes
Vent-Free Available	Yes
Vented Flue Dimensions	8" Diameter or 50 in. <sup>2</sup> Flue Diameter (Vented) N/A (Vent-Free)
Heat Output	25,000 - 37,500 BTU/hr (NG)
Efficiency	85% (Vented) - 99% (Vent-Free)
Thermostatic Remote Control	Yes
Interior Options	N/A
Electronic Ignition	Yes
Certifications	ANSI Z21.11.2 ANSI Z.21.60 CSA 2.26

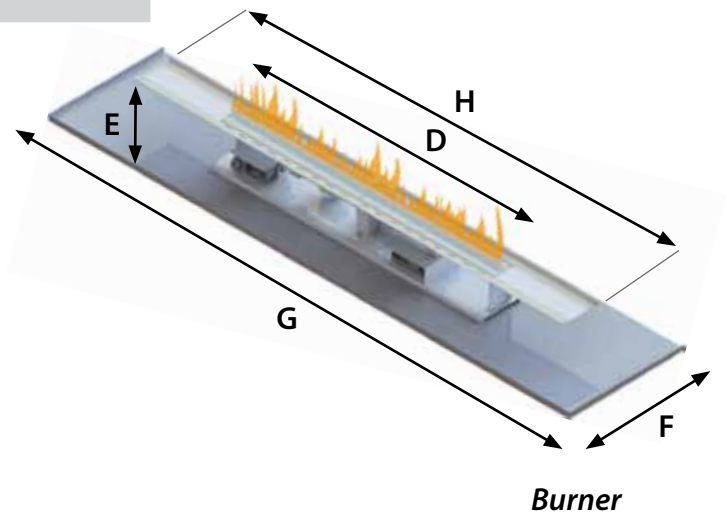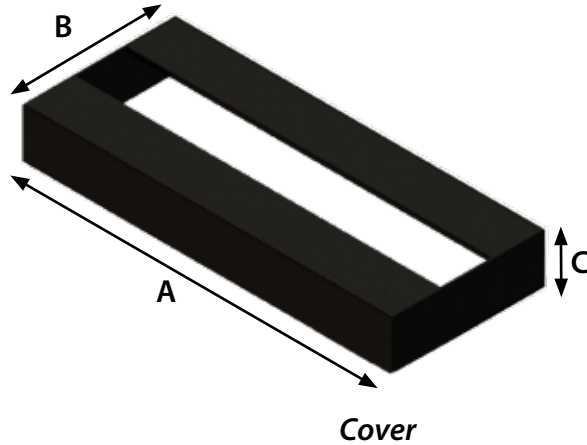

## DIMENSIONS (in.)

	GVF-42	GVF-60	GVF-72
A	39 1/8	60	72
B	16 1/4	16 1/4	16 1/4
C	5 5/16	5 5/16	5 5/16
D	38 1/2	38 1/2	38 1/2
E	5 5/16	5 5/16	5 5/16
F	16 1/4	16 1/4	16 1/4
G	39	60	72
H	38 1/2	49 1/4	59 1/4

## FIRE MEDIA



Pacific Blue Glass



Clear Glass



Amber Glass



Black Glass



Cobalt Blue Glass



Carrara Pebbles



*Add a modern touch to a vintage look*

## Gas Stones

---

For use in a wood burning fireplace or vent-free firebox, our Gas Stones eliminate the “log” look of traditional gas log sets and fireplace inserts. Clean, contemporary and thoroughly modern. If you are looking for a modern alternative to gas logs, this is it. This minimalist design will provide you with a

calming, uncluttered presence in your fireplace for years to come.

Beautiful stones and driftwood crafted from fireproof ceramic sit atop a steel cover fully concealing the gas burner and controls. The burner cover is available in white or black.



24" or 30" Burner Covers available in White or Black




# SPECIFICATIONS

MODEL	GAS STONES
Gas Type	Natural Gas or Propane (Vented) Natural Gas (Vent-Free)
Flame Adjustment	Yes
Vented Available	Yes
Vent-Free Available	Yes
Vented Flue Dimensions	Existing Chimney (Vented) N/A (Vent Free)
Heat Output	27,000 - 42,000 BTU/hr (NG) Vented 27,000 - 43,500 BTU/hr (LP) Vented 27,000 - 39,000 BTU/hr (NG) Vent-Free
Efficiency	32% (NG), 39% (LP) Vented 99% (NG) Vent-Free
Thermostatic Remote Control	No (Vented) Yes (Vent-Free)
Exterior Options	Black or White Steel Cover
Electronic Ignition	Yes
Certifications	ANSI Z21.60b (Vented) CSA 2.26b (Vented) CGA 2.17-M911 (Vented)  ANSI Z21.11.2 (Vent-Free)

## DIMENSIONS (in.)

	Gas Stones 24 in.	Gas Stones 30 in.
A	24	30
B	6 ¾	6 ¾
C	12	12
D	17 ⅞	17 ⅞
E	5 ⅜	5 ⅜

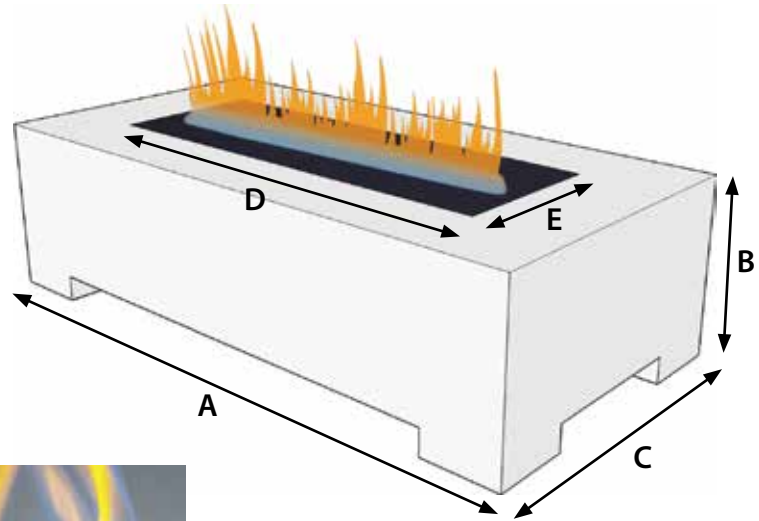

## FIRE MEDIA



Beach Stones\*



Dover Stones

\* Vent-Free models only support Beach Stones fire media.



## H Series See-Through

*Taula House (TX)  
Designed by M Gooden Design  
Photography by Parrish Ruiz de Velasco*

# About Us

At *European Home*, beautiful design drives everything we do. Founder, Holly Markham, evolved her business into fireplaces by embarking on study and research. Because of that dedication we now design and manufacture the highest quality modern fireplaces. From the materials we use, to the efficiency standards we hold, to the skilled hands and innovative minds behind every product – **every detail is considered completely.**

All European Home gas fireplaces are manufactured in the United States and are certified for use in North America.\* In addition, European Home is the exclusive importer of the European brands Flamerite Fires and Focus. These brands hail from the UK and France respectively.

*\*Some restrictions apply for vent-free products. Check your local guidelines.*



H Series  
Single-Sided  
[oldsilvershed.com](http://oldsilvershed.com)



H Series  
Peninsula  
*(with optional safety screens)*  
Installed by  
Metro House of Fire, GA



G Series  
Custom Burner  
Installed by  
Embers Fireplaces, NJ



*Installer: Fireside Distributors, FL  
Builder: Hedrick Brothers, FL*

*H Series Single-Sided*

Available Locally Through:



Or Find Your Local Dealer Today:



**EuropeanHome**  
[www.europeanhome.com](http://www.europeanhome.com)  
[info@europeanhome.com](mailto:info@europeanhome.com)

