

Framery O

The original soundproof
office phone booth

07/2023



Framery O is the ideal space to take ad-hoc phone calls and join video meetings without disturbing the office. Featuring world-class soundproofing and echo-free acoustics, you can comfortably talk in private without compromising sound quality. And automatic ventilation makes Framery O a comfortable working environment for one.

Framery O – The original soundproof office phone booth



Framery O Quick Call

The Quick Call Package includes the basic features of a single-person pod that are needed for having a private phone call without disturbing your colleagues. In addition to superior sound insulation, it has a white high-pressure laminated table, acoustic interior felt, anti-static carpet, occupancy sensor, LED lighting and power outlet. Seat not included.



Framery O Standard

The Standard Package expands the use of a single-person pod to also include heads-down work. In addition to the core features of Framery O, it includes a fixed height-adjustable Tovi stool and power source with USB-C+A outlets.



Framery O Color

The Color Package lets you select from all of the color options available for Framery O – making it an affordable way to fully personalize the pod. Select the color of the table, seat fabric, exterior covers, door and door frame.

Framery O / Furniture



HEIGHT-ADJUSTABLE SEAT ensures that the stool accommodates all users. The height can be adjusted vertically between 68.5–81.5 cm / 26.8–31.9 in. The stool is attached to the pod with a robust fixing plate making it stable and durable. The color of the seat can be customized.



REGULAR TABLE is designed to provide space for a laptop, a notebook and a mobile charging your devices while working or taking part in a call. Table size: 13 x 70 x 28.5cm / 5.1 x 27.5 x 11.2in (height, width, depth). Table height from floor: 102.5 cm / 39.6 in.



WIDE TABLE is designed to provide space for a laptop, a notebook and a mobile charging your devices while working or taking part in a call. Table size: 12 x 75 x 30 cm / 4.7 x 29.5 x 11.8in (height, width, depth). Table height from floor: 102.5 cm / 39.6 in.

Framery O / Colors

EXTERIOR

	White (Standard) RAL 9016 Glossy
	White RAL 9016 Ultramatt
	Black RAL 9005 Ultramatt
	Gray S7500-N Ultramatt
	Navy S 7020 - R90B Ultramatt
	Sand S 2010 - Y20R Ultramatt
	Powder Blue 3421-R86B Ultramatt
	Winter Moss S 7010-G10Y Ultramatt
	Blush 2728-R01B Ultramatt

INTERIOR

	Light Gray Felt (Standard)
--	----------------------------

CARPET

	Light Gray (Standard) Ex-dono Quartet #393330 Fletco Carpets
--	--

FRAME

	White (Standard) F6463 Formica
	Black F2253 Formica

TABLE

	White (Standard) White laminate
	Black Black Laminate with anti-fingerprint surface

SEATING FABRIC

	Light Gray (Standard) Remix 3 #123 Kvadrat
	Grape Select #61190 Gabriel
	Rose Select #65117 Gabriel
	Green Selected #68209 Gabriel
	Antimicrobial Highland Graphite 954 Panaz
	Graphite Select #60051 Gabriel
	Dark Blue Select #66144 Gabriel
	Powder Blue Select #67098 Gabriel
	Beige Select #61184 Gabriel
	Mustard Select #62098 Gabriel

Framery O / Optional Functionalities



COPPER-PLATED DOOR HANDLE helps to prevent the spread of viruses. According to a study by Centers for Disease Control and Prevention (CDC), viruses disintegrate quicker after landing on copper surfaces than on plastic or stainless steel surfaces.



WIRELESS CHARGER allows you to charge your phone fast and wire-free inside our pods. The charger itself is located underneath the table, with a sticker on top of the table indicating where to place your phone to charge. Available for Wide table.



POWER OPTIONS includes outlets with or without two charging USB-C+A sockets and a LAN cable lead-through.



MOVABILITY KIT allows you to easily relocate your Framery O without disassembly. This kit includes six castors to make it easier to move the pod.



SELF-CLOSING HINGES can be used to limit the opening of doors and to make sure that they are not blocking passageways. Available in black and white.



SMART LOCK COMPATIBLE is a kit of parts that allows selected smart locks and key locks to be installed in Framery O.



ELECTROMECHANICAL CODE LOCK handle can be used to limit access to a pod only for users with a number code.



LAN CABLE 7 m.

Framery O

TECHNICAL SPECIFICATIONS



Size	EXTERIOR 221 × 100 × 100 cm / 87 × 39.4 × 39.4 in (h, w, d). With castors (comes with movability kit) extra 2cm / 0.8 in in height. INTERIOR 200 × 80 × 95 cm / 78.7 × 31.5 × 37.4 in (h, w, d). DOORWAY 200 × 80 cm / 78.7 × 31.5 in (h, w).
Weight	320 kg / 705 lb.
Ventilation Space	Min. recommended space for air to circulate: <ul style="list-style-type: none"> • Sides: 5 cm / 1.9 in. • Above: 15 cm / 5.9 in.
Acoustics	30dB (Speech level reduction according to ISO-23351-1 testing method).
Airflow	Total airflow is 21.5 l/s, 45 CFM (77.4 m ³ /h). On standby mode the fans are working on 25 % of the maximum power.
Lighting	LED-Light 4000 K and 300 lux.
Exterior materials	EXTERIOR Painted sheet metal. GLASS Sound control laminated glass (4 + 4 mm / 0.16 + 0.16 in). FRAME Formica laminate on birch plywood with varnish trim.
Interior materials	SOLID WALLS AND ROOF A sandwich element of sheet metal, birch plywood, recycled acoustic foam and acoustic felt. FLOOR An anti-static and stain resistant low loop pile carpet. TABLE Formica laminate on birch plywood with varnish trim.
	Power cord can be led out of the bottom corner of the pod. The cord length outside the pods is 4.5 m / 176.4 in.

POWER

Power consumption	WHILE IN USE 13W on standard configuration. Standard configuration: <ul style="list-style-type: none"> • LED lights: 10W. • Fans in total: 3.1W. STANDBY MODE 0.8W. Input 100–240 VAC, 8.0 A, 50–60 Hz.
Outlets	REGULAR TABLE OUTLETS Power socket. Optional LAN. WIDE TABLE OUTLETS Power socket, USB-A+C. Optional LAN.
Output values	Output AC (power socket) 100–240VAC, 6.6A, 50–60 Hz. Output USB (TUF) charging. Maximum combined output of 5 A at 5 VDC (25 W) dBm.

All electric components can be changed if there is a malfunction. Power consumption is a constant value that is determined by the power usage of the pods' internal components (electric unit, motion detector, light and fans). Framery's products can be plugged into a wall socket. The pods have their own power supplies that give 24 V DC to the lights and 12 V DC to the fans. The lights and fans are operated by a motion detector. Inside the pods, there are country-specific power outlets for charging mobile devices.

DIMENSIONS

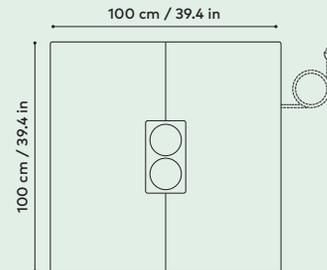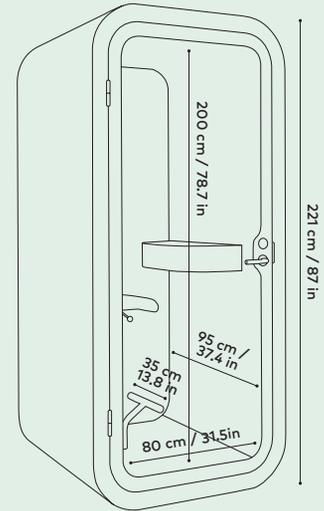

Framery O is UL GREENGUARD certified



Framery O shipped in North America is UL 962 listed