

LIGHTING
COLLECTION



FRITZ HANSEN

EXTRAORDINARY DESIGN SINCE 1872

Welcome to a world of design, craftsmanship and beauty. Here, you'll find more than 150 years of Danish design tradition and collaborations with visionary architects, designers and artists from around the world.

Welcome to Fritz Hansen.



Since 1872, Fritz Hansen has been crafting extraordinary design that transforms the everyday into something special. By continuously pushing the boundaries of design and craftsmanship we shape the world for those who wish to be inspired, intrigued and surprised.

A PASSION FOR LIGHTING DESIGN

Fritz Hansen has a passion for lighting. This passion for extraordinary lighting design drives us to create pendants, wall lamps, table lamps and floor lamps that make interior spaces come alive.

In this catalogue, you will find an array of lighting from extraordinary designers from around the world, produced with the high quality material and precise attention to detail that are synonymous with Fritz Hansen's name.

We hope you enjoy this catalogue. If you have any questions, our local sales representatives are at your service.

For more information, visit fritzhanzen.com

KAISER idell™ (6631-T Luxus) by Christian Dell in brass and matt black is a strong pairing of reflective warmth and cool darkness.

A PEARL OF LIGHT

Clam™



Clam™ Ø550 pendant, designed by Ahm & Lund shown together with PK54™, PK54A™ and PK9™ by Poul Kjærholm.

Mouth-blown opal glass and brushed brass come together – and move apart – to create elegant, adjustable and atmospheric lighting for dining and

living spaces. Equally elegant open as it is closed, the perfectly balanced design elevates any room with its considered combination of form and ambience.



Caravaggio™ (P2) in Warm Silk.

NEW NORDIC DINING

The eye-catching Caravaggio™ pendant was launched in 2005 and instantaneously gained status as a design icon. With its simple, elegant and recognisable shape it has set the standard as a new classic in lighting design.



The elegant Caravaggio™ pendant by Cecilie Manz together Superellipse™ table by Piet Hein and Bruno Mathsson and Drop™ chair designed by Arne Jacobsen.

KAISER idell™



KAISER idell™ (6580-F Luxus) floor lamp by Christian Dell in white by an **Alphabet™ Sofa** by Piero Lissoni.

KAISER idell™ (6722-P)
in Soft Ochre, Smooth Slate
and Russet Red.



BAUHAUS INSPIRED

All KAISER idell™ lighting is characterised by Christian Dell's ability to create elegant design with the basic hallmarks of Modernism: geometric shapes. The entire lighting design series, while diverse in its expressions, is united by its Bauhaus origin, timelessness and clever details.



An elegant **KAISER idell™** (6718-W) wall lamp in Easy Grey, designed by Christian Dell, pair perfectly with an **AJ Trolley** side table designed by Arne Jacobsen.



KAISER idell™ (6556-T) table lamp in Easy Grey.

FOREVER MODERN

From 1922 to 1925, Christian Dell worked as a foreman of the metal workshop at the Bauhaus in Weimar where he developed a highly innovative and pioneering style of design.

In 1926, Dell began sketching lamps. His first catalogue was launched in 1936, and the table lamp model 6631-T Luxus appeared for the first time, becoming the undisputed top model of the **KAISER idell™** series.

Ever since, it has been considered a symbol of Germanic design, exquisite choice of materials, and precise engineering.

The **KAISER idell™** (6631-P) pendant in black is slim, and practical – perfect over the small dining table or a shelf.



Maluma™



COLOUR COMPLETE

Pleasant interior lighting shapes mood, improves productivity and conserves energy. Fritz Hansen's collection of timeless lighting design focuses on overall impact: turned on or left off, indoor lighting should be beautiful.



ROOM FOR IMAGINATION





The **Cross-Plex™** (T-500) by Bodil Kjær fuses clean cuts, straight lines and a bright opal, plexiglass shade.

Cross-Plex™



Cross-Plex™ (T-300) lamp designed by Bodil Kjær.

REFINED FUNCTIONALITY

The Danish architect Bodil Kjær's Cross-Plex™ lamp was designed in 1961, expressing an elegance and simplicity that was far ahead of her time. With a base constructed like a puzzle, the design has the perfect bit of space for a cord to ascend through the centre of the lamp.



TIMELESS SILHOUETTE

The simple, timeless Caravaggio™ pendant by Cecilie Manz consists of a metal shade with soft, feminine lines held by a metal suspension. The textile cable is particularly well integrated into the design and gives the lamp its finishing touch. The lamp casts a concentrated, downward light whilst also illuminating both the suspension and the cable through a hole at the top of the lamp. The shade is designed to prevent glare and provide beautiful, well balanced light.

Caravaggio™ (P2) pendants in Grey25 by Danish designer Cecilie Manz, shown with Series 7™ chairs in Pale Rose designed by Arne Jacobsen, a Superellipse™ table, and Louise Candleholders.

Concert™



Black **Concert™** P3 pendant by Jørn Utzon, shown over the **Essay™** table by Cecilie Manz together with **Series 7™** chairs by Arne Jacobsen. On the table is an **Ikebana** vase.

ARCHITECTURAL ELEGANCE

Concert™ is the result of Utzon's life-long fascination with architecture and light. The masterful design nods to the contoured shapes of his architectural achievements, which include the Sydney Opera House.

Concert profiles beauty and function in equal measure, making it the ideal centrepiece for modern living and dining spaces alike.



The multi-layered **Concert™** P3 pendant showcases Jørn Utzon's architectural language.



Orient™



Orient™ (P3) lighting by Jo Hammerborg over an Essay™ table by Cecilie Manz with leather Series 7™ chairs by Arne Jacobsen.

LUXURY LIVES ON

The Orient™ pendant was created by Jo Hammerborg in 1963 and relaunched by Fritz Hansen in 2013. The fitting elegantly conceals a low energy light source and ensures a soft, pleasant light without any glare.

The shade is hand spun in a wooden mould, a feature that underlines the original, organic shape and true craftsmanship of this beautiful pendant design.



Orient™ (P3) pendant in aluminium and oak.

BRIGHT IDEAS



PM-02

The **PM-02** table lamp by Paul McCobb channels a minimalist expression with a decidedly Scandinavian feel.



KAISER idell™

The **KAISER idell™** (6556-T) by Christian Dell is a slim, elegant and functional design classic.

Night Owl™

Rich in personality, the **Night Owl™** by Nicholai Wiig Hansen is perfect for a cosy corner.



KAISER idell™

The **KAISER idell™** (6631-T Luxus) by Christian Dell boasts an iconic expression in white.



AQ01™

The **AQ01™** desk light by Anne Qvist brings understated elegance to the workspace.



Cross-Plex™

The **Cross-Plex™** (T-500) by Bodil Kjær features an illuminated opal shade and a simple, sophisticated form.



Caravaggio™ Read

Caravaggio™ Read can fit into kitchens, living rooms or bedrooms. The timeless design by Cecilie Manz has a rotating neck and flexible head to adjust lighting for reading, cooking or mood.





Orient™

Orient™ (P2) pendant by Jo Hammerborg
in black and rosewood.

HAMMERBORG DESIGNS

Danish designer Jo Hammerborg was a visionary for shape and sculptural lighting. Hammerborg's Orient™ and Silhuet™ pendant designs display his signature simplicity and daring expression in a variety of finishes.

Silhuet™



Polished brass Silhuet™ pendant by Jo Hammerborg.

ELEGANT ILLUMINATION



The **PM-02** in brass.

The PM-02 table lamp by legendary American designer Paul McCobb emits diffused light from hand-blown, opal glass to create a warm, atmospheric glow.

Calabash™



Calabash™ lighting by Komplot Design shown with Analog™ table by Jaime Hayon, Ant™ chairs by Arne Jacobsen and the Moon Eye vase set.



ORGANIC SIMPLICITY

The Calabash™ pendants designed by Komplot Design are inspired by the simple and harmonious form of the calabash pumpkin. Made of aluminium and finished with chrome or textured coating, the pendants balance form and function, and technology with craftsmanship.

Turned on or left off, the distinct design has strong presence by combining convex and concave shapes – mirroring the room in Silver or Gold, and standing strong in Black Meteor or Grey Meteor with a confident, sculptural quality.



The **Suspence™** pendant (P1.5) in light grey brings cool colour into a warm, pastel-hued room.

SUSPENDED IN AIR

In the making of the **Suspence™** lamp series, the designers GamFratesi sought to translate movement into a physical shape: a water droplet suspended in air. The final form appears as an uninterrupted whole, enhanced by its monochrome expression and natural, soft curve. An infinity diffuser at the base of the lamp concentrates the light, prevents glare, and creates an elegant optical illusion.



A **Suspence™** pendant by GamFratesi over a **Circular™** table and **Grand Prix™** chairs in True Yellow, both designed by Arne Jacobsen.



AQ01™ table lamp by Anne Qvist sitting on an **Pluralis™** table designed by Kasper Salto with **Oxford™** chairs designed by Arne Jacobsen.

FUNCTIONAL ELEGANCE

The AQ01™ offers a fresh take on the classic architect's desk light. Distinguished by its delicate lines and matt finish, the light offers a refined elegance and genius utility. Technology allows springs to be hidden within the design and AQ01's shade to be switched on and off, or dimmed up and down, with the touch of a hand on the lamp's shade.



The **AQ01™** desk light by Anne Qvist brings understated elegance to the workspace.

PRODUCTS

Here is everything you need to know about Fritz Hansen's lighting collection with designs listed alphabetically. Visit [fritzhanzen.com](https://www.fritzhanzen.com) for details specific to each country.

AQ01™

Design: Anne Qvist, 2017

The AQ01™ offers a fresh take on the classic architect's desk light. Distinguished by its delicate lines and matt finish, the light offers a refined elegance and genius utility. Technology allows springs to be hidden within the design and AQ01's shade to be switched on and off, or dimmed up and down, with the touch of a hand on the lamp's shade.

Isolation class: Class II
IP rating: IP20
Certification: CE, UL [†]
Energy label: A++



Category: Table lamp

Dimensions:
Height: 44 cm / 17.3 in
Width: 45 cm / 17.7 in

Cord specifications:
Length: 2,5 m
Colour: White/Black/Blue
Material: PVC

Materials:
Shade/Base: Aluminium
Diffuser: Polycarbonate (PC)

Weight: 0,5 kg

Light source: LED (Build in)

Features: Tilttable, Swivel, Dimmable

Colours:



White Black Blue



Category: Table lamp (Plug-in)

Dimensions:
Height: 45.3 cm / 17.8 in
Width: 45 cm / 17.7 in

Cord specifications:
Length: 2,5 m
Colour: White/Black/Blue
Material: PVC

Materials:
Shade/Base: Aluminium
Diffuser: Polycarbonate (PC)

Weight: 0,5 kg

Light source: LED (Build in)

Features: Tilttable, Swivel, Dimmable

Colours:



White Black Blue



Category: Wall lamp

Dimensions:
Height: 48.3 cm / 17.8 in
Width: 45 cm / 17.7 in

Cord specifications:
Length: 2,5 m
Colour: White/Black/Blue
Material: PVC

Materials:
Shade/Base: Aluminium
Diffuser: Polycarbonate (PC)

Weight: 0,5 kg

Light source: LED (Build in)

Features: Tilttable, Swivel, Dimmable

Colours:



White Black Blue

AVION™

Design: Iskos-Berlin, 2012

The Avion™ is inspired by a childhood fascination with aircraft - in particular, Zeppelin airships gliding across the sky. The pendant's large, oval-like shape has a playful expression, and emits a soft and diffused light that contributes to the natural atmosphere of any room.

Isolation class: Class II
IP rating: IP20
Certification: CE



Category: Pendant

Dimensions:
Height: 34.2 cm / 13.5 in
Width: 85 cm / 33.5 in

Cord specifications:
Length: 6 m
Colour: White
Material: PVC w. wire

Materials:
Polyethylene (PE)

Weight: 4,9 kg

Socket:
2x E27 max 100W

Colours:



 
Opal

CALABASH™


Design: Komplot Design, 2010

Calabash™ pendants are inspired by the simple and harmonious form of the calabash pumpkin. Made of aluminium and finished with chrome or textured coating, Calabash pendants are an example of authentic craftsmanship. Turned on or left off, its distinct design has strong presence by combining convex and concave shapes – mirroring the room or manifesting that reflection with sculptural quality.

Isolation class: Class II
IP rating: IP20
Certification: CE, UL ⚡, PSE ⚡
Canopy: Black



 Category: Pendant
Model: P1
Dimensions:
Height: 21 cm / 8.3 in
Diameter: 15.8 cm / 6.2 in
Cord specifications:
Length: 3 m
Colour: Black
Material: Textile
Materials:
Aluminium
Weight: 0,5-0,6 kg
Socket: E27 max 30W



Category: Pendant
Model: P2
Dimensions:
Height: 30.5 cm / 12 in
Diameter: 22.4 cm / 8.8 in
Cord specifications:
Length: 3 m
Colour: Black
Material: Textile
Materials:
Aluminium
Weight: 0,8-0,9 kg
Socket: E27 max 46W



Category: Pendant
Model: P3
Dimensions:
Height: 48.4 cm / 19 in
Diameter: 34 cm / 13.4 in
Cord specifications:
Length: 6 m
Colour: Black
Material: Textile
Materials:
Aluminium
Weight: 1,7 kg
Socket: E27 max 100W



CARAVAGGIO™


Design: Cecilie Manz, 2005

Caravaggio™ lighting have gained the status of design icons. Designed by Cecilie Manz, Caravaggio upscales a timeless silhouette with a fresh, modern expression.


Isolation class: Class II (P0-P3)
IP rating: IP20
Certification: CB, CE, UL ⚡, PSE ⚡
Canopy: White or Black



Category: Pendant
Model: PO LED
Dimensions:
Height: 14.5 cm / 5.7 in
Diameter: 11 cm / 4.3 in
Cord specifications:
Length: 3 m
Colour: Silver grey
Material: Textile
Materials:
Shade: Handblown glass
Suspension: Steel
Weight: 0,4 kg

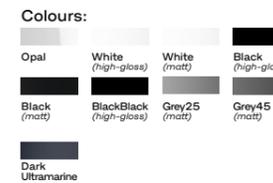

Category: Pendant
Model: P1
Dimensions:
Height: 21.6 cm / 8.5 in
Diameter: 16.5 cm / 6.4 in
Cord specifications:
Length: 3 m
Colour: Varies w. shade colour
Material: Textile
Materials:
Shade: Steel or Handblown glass
Suspension: Steel/Aluminium
Weight: 1,0 kg / 2.5 kg (glass)
Socket: E27 max 46W

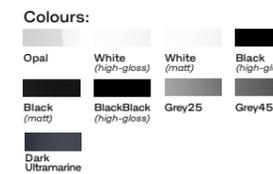

Category: Pendant
Model: P2
Dimensions:
Height: 33.7 cm / 13.2 in
Diameter: 25.8 cm / 10.1 in
Cord specifications:
Length: 3 m
Colour: Varies w. shade colour
Material: Textile (Opal version with wire)
Materials:
Shade: Steel or Handblown glass
Suspension: Steel/Aluminium
Weight: 1,0 kg / 2,0 kg (Glass)
Socket: E27 max 100W




Category: Pendant
Model: P3
Dimensions:
Height: 51.6 cm / 20.3 in
Diameter: 40 cm / 15.7 in
Cord specifications:
Length: 6 m
Colour: Varies w. shade colour
Material: Textile (Opal version with wire)
Materials:
Shade: Aluminium or Handblown glass
Suspension: Steel/Aluminium
Diffuser: Polycarbonate (PC)
Weight: 2,3 kg / 4,7 kg (Glass)
Socket: E27 max 100W

CARAVAGGIO™ READ

Design: Cecilie Manz, 2005

The Caravaggio™ has gained the status of a design icon. Designed by Cecilie Manz, the shades upscale a timeless silhouette with a fresh, modern expression. A rotating arm and flexible neck make this design adjustable for a variety of settings and tasks.

Isolation class: Class II
IP rating: IP20
Certification: CE

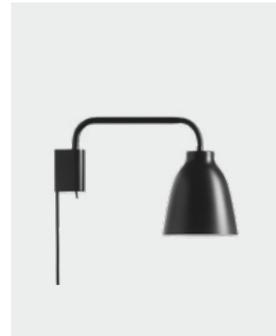

Category: Wall lamp

Dimensions:
Height: 20.6 cm / 8.1 in
Diameter: 35 cm / 13.7 in

Cord specifications:
Length: 1,5 m
Colour: Varies w. shade colour
Material: PVC

Materials:
Shade: Steel/Glass
Base: Die-cast zinc alloy
Weight: 1,1 kg / 1,6 kg (Glass)
Socket: E27 max 46W

Features: Tilttable, Swivel

Colours:



CLAM™

Design: Ahm & Lund, 2019

Like a seashell hides its pearl, the Clam™ pendant opens to reveal its light. Inspired by nature and designed by Ahm & Lund, this award-winning pendant is acknowledged for both its remarkable form and the ambiance it creates with diffused light. With beautiful, mouth-blown glass and brass details, the Clam™ pendant by Ahm & Lund is a new classic within lighting excellence.

Isolation class: Class I
IP rating: IP20
Certification: CE, CB, UL



Colours:



Category: Pendant

Model: Ø440

Dimensions:
Height: 52,2 cm / 20.5"
Width: 44 cm / 17.3"
Depth: 44 cm / 17.3"

Cord specifications:
Length: 6 m / 236.2"
Material: Textile with wire
Colour: Black

Materials:
Shade: Opal glass (Each shade is individually made and variations in surface thickness and texture, including air bubbles, may occur).
Canopy: Brass (untreated). Please note that brass will patinate.

Weight: : 6,5 kg / 14.3 lb



Colours:



Category: Pendant

Model: Ø550

Dimensions:
Height: 54 cm / 21.3"
Width: 55 cm / 21.7"
Depth: 55 cm / 21.7"

Cord specifications:
Length: 6 m / 236.2"
Material: Textile with wire
Colour: Black

Materials:
Shade: Opal glass (Each shade is individually made and variations in surface thickness and texture, including air bubbles, may occur).
Canopy: Brass (untreated). Please note that brass will patinate.

Weight: 9 kg / 19.8 lb



CONCERT™

Design: Jørn Utzon, 2005

The world-famous Concert™ is a Danish design staple. The unique shade configuration is visually characteristic of Utzon's design ethos and is reminiscent of his greatest work, the Sydney Opera House. The pendant's diffuser is handcrafted using triple-layered opal blown glass and provides a pleasant, even light, making it the perfect centrepiece to any living space or meeting space.



Category: Pendant
Model: P1
Dimensions:
Height: 16,6 cm / 7.5 in
Diameter: 32 cm / 12.5 in
Cord specifications:
Length: 3 m
Colour: White, Black
Material: Textile
Materials:
Shade: Steel
Suspension: Glass (frosted)
Weight: 2,5 kg
Socket: E27 max 75W

Colours:



White Black



Category: Pendant
Model: P3
Dimensions:
Height: 32 cm / 12.5 in
Diameter: 55 cm / 21.6 in
Cord specifications:
Length: 6 m
Colour: White, Black
Material: Textile w. wire
Materials:
Shade: Steel
Suspension: Glass (frosted)
Weight: 9,0 kg
Socket: E27 max 150W

Colours:



White Black

CROSS-PLEX™

Design: Bodil Kjær, 1961

Shaped like a cross in plexiglass, the Cross-Plex is a simple yet refined table lamp with a natural ability to lift the ambience of any space. Seen from its profile, the lamp resembles a miniature building with its translucent shade like an illuminated roof.

Isolation class: Class II
IP rating: IP20
Certification: CE



Category: Table lamp
Model: T-300
Dimensions:
Height: 30 cm / 11.8 in
Width: 40 cm / 15.8 in
Cord specifications:
Length: 3 m
Colour: Black
Material: Textile
Materials:
Shade: Opal acrylic
Base: Clear acrylic
Weight: 1,9 kg
Socket: E27 max 70W

Colours:



Opal/
Clear



Category: Table lamp
Model: T-500
Dimensions:
Height: 50 cm / 19.7 in
Width: 20 cm / 7.9 in
Cord specifications:
Length: 3 m
Colour: Black
Material: Textile
Materials:
Shade: Opal acrylic
Base: Clear acrylic
Weight: 1,8 kg
Socket: E27 max 70W

Colours:



Opal/
Clear

↗ For details specific to Japan, see Product Fact Sheets on www.fritzhanzen.com



KAISER idell™

Design: Christian Dell, 1931

 

The renowned KAISER idell™ lamp is characterised by Christian Dell's ability to create elegant design with the basic hallmarks of Modernism: geometric shapes. Today, the KAISER idell is widely recognised as a symbol of noble Bauhaus design, exquisite choice of material, and precise engineering.

Isolation class: Class II
IP rating: IP20
Certification: CE, PSE ↗, UL ↗
Canopy: Chrome, brass




* Available with Brass elements

Category: Pendant
Model: 6722-P
Dimensions:
Height: 15.5 cm / 6.1 in
Diameter: 14.5 cm / 5.7 in
Cord specifications:
Length: 3 m
Colour: Black
Material: Textile
Materials:
Shade: Steel (High-gloss, Matte)
Elements: Chrome-plated brass, Brass
Weight: 0,6 kg
Socket: E27 max 40W

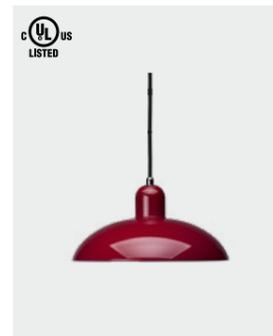

 Category: Pendant
Model: 6631-P
Dimensions:
Height: 13.5 cm / 5.3 in
Diameter: 28.5 cm / 11.2 in
Cord specifications:
Length: 3 m
Colour: Black
Material: Textile
Materials:
Steel/Chrome-plated brass
Weight: 0,8 kg
Socket: E27 max 60W




* Available with Brass elements

Category: Wall lamp
Model: 6718-W
Dimensions:
Height (base): 14.8 cm / 5.8 in
Diameter (shade): 16.4 cm / 6.5 in
Width: 47-89 cm / 18.5-35 in
Cord specifications:
Length: 2 m
Colour: Black, White
Material: Textile
Materials:
Shade/Base: Steel (High-gloss, Matte)
Elements: Chrome-plated brass, Brass
Weight: 1,8 kg
Socket: E27 max 60W
Features: Stretchable, Swivel




* Available with Brass or standard Chrome elements

 Category: Table lamp
Model: 6631-T Luxus
Dimensions:
Height: 42.5 cm / 16.7 in
Diameter (shade): 28.5 cm / 11.2 in
Diameter (base): 19.4 cm / 7.6 in
Cord specifications:
Length: 2 m
Colour: Black
Material: Textile
Materials:
Shade/Base: Steel (High-gloss, Matte)
Elements: Chrome-plated brass, Brass
Weight: 3,8 kg
Socket: E27 max 60W
Features: Tilttable




* Available with Brass elements

 Category: Table lamp
Model: 6556-T
Dimensions:
Height: 47 cm / 18.5 in
Diameter (shade): 21.5 cm / 8.5 in
Diameter (base): 18.5 cm / 7.3 in
Cord specifications:
Length: 2 m
Colour: Black
Material: Textile
Materials:
Shade/Base: Steel (High-gloss, Matte)
Elements: Chrome-plated brass, Brass
Weight: 2,4 kg
Socket: E27 max 60W
Features: Tilttable



 Category: Floor lamp
Model: 6580-F Luxus
Dimensions:
Height: 125-135 cm / 49.2-53.1 in
Diameter (shade): 21.5 cm / 8.5 in
Diameter (base): 22.5 cm / 8.9 in
Cord specifications:
Length: 2 m
Colour: Black
Material: Textile
Materials:
Steel/Chrome-plated brass
Weight: 6,5 kg
Socket: E27 max 60W
Features: Height adjustable, Swivel



* Available with Brass elements

Category: Floor lamp
Model: 6556-F
Dimensions:
Height: 125 cm / 49.2 in
Diameter (shade): 21.5 cm / 8.5 in
Diameter (base): 22.5 cm / 8.9 in
Cord specifications:
Length: 2 m
Colour: Black
Material: Textile
Materials:
Shade/Base: Steel (High-gloss, Matte)
Elements: Chrome-plated brass, Brass
Weight: 5,2 kg
Socket: E27 max 60W
Features: Tilttable

MALUMA™

Design: Fumie Shibata , 2021

Maluma™ pendant adds soft colour to a room whether it is on or off and keeps its colour when turned on. It gives both soft ambient light and functional downlight from its open bottom.

Isolation class: Class II
IP rating: IP20
Certification: CB, CE
Canopy: Black(Moss, Plum), White(Rose)



Category: Pendant
Model: H350
Dimensions:
Height: 35 cm / 13.8"
Diameter: 23,5 cm / 9.3"
Cord specifications:
Length: 3 m
Colour: Black(Moss, Plum), Grey25(Rose)
Material: Textile
Materials:
Shade: Frosted coloured glass
Suspension: Anodized aluminium
Weight: 0.5 kg
Socket: E27 max 75W

Colours:



NIGHT OWL™

Design: Nikolai Wiig Hansen, 2015

The Night Owl™ table lamp was born out of a desire to create a uniquely Nordic wash of light; warm, cosy and informal. Distinctive in form and appearance, the base and oval shade merge seamlessly together to form one single unit. Its personality is a unique addition to any space.

Isolation class: Class II
IP rating: IP20
Certification: CE, PSE ↗



Category: Table lamp
Dimensions:
Height: 23.9 cm / 9.4 in
Diameter: 23.5 cm / 9.2 in
Cord specifications:
Length: 2 m
Colour: Black
Material: Textile
Materials:
Shade: PVC
Base: Aluminium or Ash
Diffuser: Polycarbonate (PC)
Weight: 1,2 kg / 1,3 kg (Ash)
Socket: E27 max 15W

Colours:




ORIENT™

Design: Jo Hammerborg, 1963

The Orient™ pendant is an ode to fine craftsmanship. The lampshade is hand spun in a wooden mould - a feature that underlines its original, organic shape. The fitting elegantly conceals the light source and ensures a soft, pleasant light without any glare.


Isolation class: Class II
IP rating: IP20
Certification: CB, CE, PSE, UL
Canopy: Black

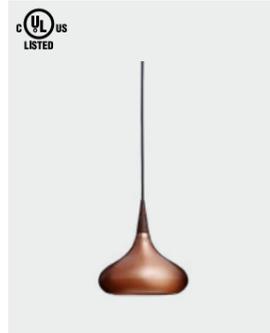

Category: Pendant
Model: P1
Dimensions:
Height: 24.5 cm / 9.6 in
Diameter: 22.5 cm / 8.8 in
Cord specifications:
Length: 3 m
Colour: Black/Grey
Material: Textile
Materials:
Copper/Rosewood
Aluminium/Oak
Black lacquered aluminium/
Rosewood
Weight: 1,1 / 0,7 / 0,6 kg
Socket: E27 max 60W



 Category: Pendant
Model: P2
Dimensions:
Height: 37 cm / 14.5 in
Diameter: 34 cm / 13.3 in
Cord specifications:
Length: 3 m
Colour: Black/Grey
Material: Textile
Materials:
Copper/Rosewood
Aluminium/Oak
Black lacquered aluminium/
Rosewood
Weight: 2,1 / 1,1 / 1,0 kg
Socket: E27 max 75W



Category: Pendant
Model: P3
Dimensions:
Height: 54 cm / 21.2 in
Diameter: 50 cm / 19.6 in
Cord specifications:
Length: 6 m
Colour: Black/Grey
Material: Textile
Materials:
Aluminium/Oak
Black lacquered aluminium/
Rosewood
Weight: 5 kg
Socket: E27 max 100W



PM-02

Design: Paul McCobb, 1950

Proving that simple can be beautiful, the thoughtful, practical PM-02 table lamp design emits diffused light from its hand-blown opal glass shade to create a warm, atmospheric glow. The three-legged base in solid untreated brass or black lacquered steel provides an elegant contrast to the cylindrical shade.

Isolation class: Class II
IP rating: IP20
Certification: CE, UL



Category: Table lamp
Dimensions:
Height: 31.4 cm / 12.3 in
Diameter: 13.6 cm / 5.3 in
Cord specifications:
Length: 2,5 m
Colour: Black
Material: Textile
Materials:
Shade: Opal glass
Base: Black lacquered steel/
Brass (untreated)
Weight: 1,8 kg
Socket: E27 max 60W



SILHUET™

Design: Jo Hammerborg, 1977

The beautiful Silhuet™ pendant is characterized by soft – almost hypnotising – lines and warm brass. Fritz Hansen reissued the Silhuet™ design in celebration of the Danish designer Jo Hammerborg's 100th anniversary. In homage, Hammerborg's signature and a 100-year tag are inscribed inside every pendant.

Isolation class: Class II
IP rating: IP20
Certification: CE, PSE ↗
Canopy: Black




Category: Pendant
Model: P2
Dimensions:
Height: 32.8 cm / 12.9 in
Diameter: 29.5 cm / 11.6 in
Cord specifications:
Length: 3 m
Colour: Black
Material: Textile
Materials:
Brass (untreated)
Weight: 1,0 kg
Socket:
E27 max 75W

Colours:



Brushed brass Polished brass

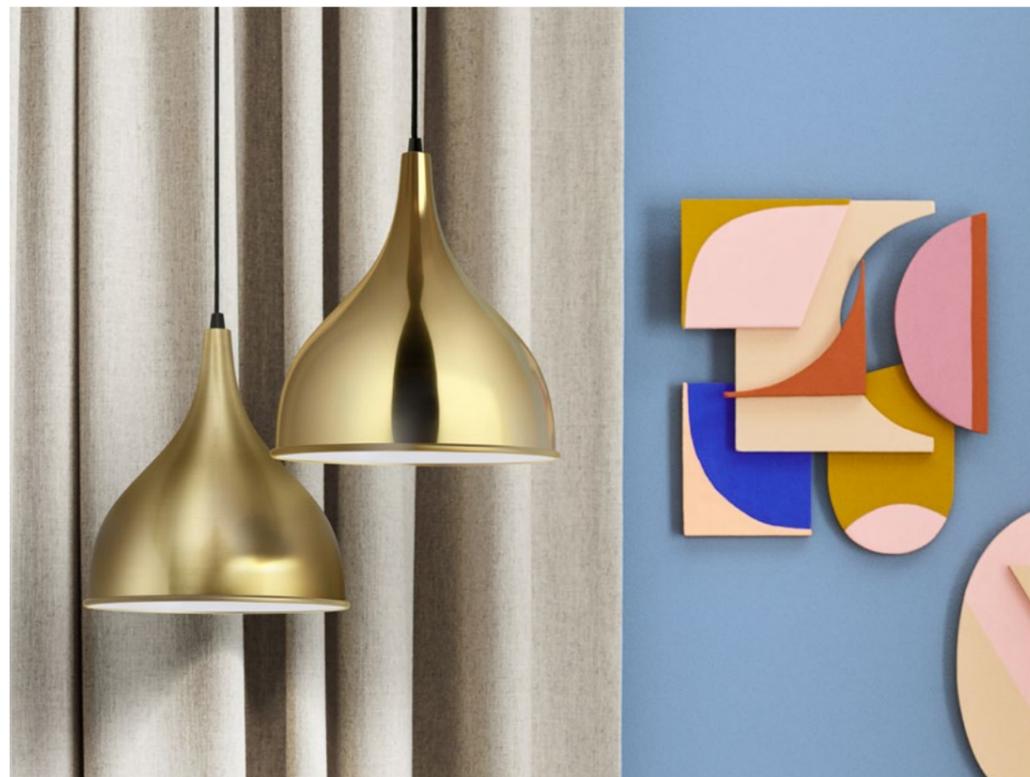

SUSPENCE™

Design: GamFratesi, 2013

In the making of the Suspence™ lamp series, the designers sought to translate movement into a physical shape: a water droplet suspended in air. The final form appears as an uninterrupted whole, enhanced by its monochrome expression and natural soft curve.

Isolation class: Class II
IP rating: IP20
Certification: CB, CE, PSE, UL
Canopy: Black or White



Category: Pendant
Model: P1
Dimensions:
Height: 22.5 cm / 8.8 in
Diameter: 24 cm / 9.4 in
Cord specifications:
Length: 3 m
Colour: Varies w. shade colour
Material: PVC
Materials:
Shade: Aluminium/Polished copper
Diffuser: Polycarbonate (PC)
Weight: 1,0 kg / 1,4 kg (Copper)
Socket: E27 max 53W

Colours:



White Black Light Grey Copper



Category: Pendant
Model: P1.5
Dimensions:
Height: 29.8 cm / 11.7 in
Diameter: 32 cm / 12.6 in
Cord specifications:
Length: 3 m
Colour: Varies w. shade colour
Material: PVC
Materials:
Shade: Aluminium
Diffuser: Polycarbonate (PC)
Weight: 1,3 kg
Socket: E27 max 53W

Colours:



Light Grey Powder Burgundy Pale Pearl



Category: Pendant
Model: P2
Dimensions:
Height: 36 cm / 14.2 in
Diameter: 38.5 cm / 15.1 in
Cord specifications:
Length: 3 m
Colour: Varies w. shade colour
Material: PVC (w. wire for Copper)
Materials:
Shade: Aluminium/Polished copper
Diffuser: Polycarbonate (PC)
Weight: 1,7 kg / 2,7 kg (Copper)
Socket: E27 max 100W

Colours:



White Black Light Grey Copper



PRODUCT LOCATOR

AQ01™ (28, 40, 44)

Avion™ (17, 45)

Calabash™ (36, 46)

Caravaggio™ (8, 20, 47)

Caravaggio™ Read (30, 48)

Clam™ (6, 49)

Concert™ (22, 50)

Cross-Plex™ (18, 29, 51)

KAISER idell™ (5, 10, 12, 28, 29, 52, 53)

Maluma™ (14, 54)

Night Owl™ (24, 29, 55)

Orient™ (26, 32, 56)

PM-02 (28, 34, 57)

Silhuet™ (33, 58)

Suspence™ (38, 59)



HEADQUARTERS

FRITZ HANSEN A/S
Allerødvej 8
3450 Allerød
Denmark
Tel: +45 48 17 23 00

GET IN TOUCH

SALES - ASIA & OCEANIA
customerserviceasia@fritzhanzen.com
Tel: +81 3 3400 3316

SALES - EUROPE
salesupport@fritzhanzen.com
Tel: +45 70 80 70 90

SALES - NORTH AMERICA
info@fritzhanzen.com
Tel: +001 212 219 3226

PRESS - GLOBAL
press@fritzhanzen.com
Tel: +45 25 19 07 03

LEARN MORE

NEWSLETTER
Sign up at:
fritzhanzen.com/newsletter

DOWNLOADS
Find 2D & 3D files, imagery,
product facts and much more at:
downloads.fritzhanzen.com

INSTAGRAM
[@fritzhanzen](https://www.instagram.com/fritzhanzen)

PINTEREST
Fritz Hansen™

FACEBOOK
Fritz Hansen

LINKEDIN
Fritz Hansen

FRITZHANSEN.COM