

MEETING OWL 3

See and hear it all in 360°

The Meeting Owl 3 is our all-in-one 360° camera, mic, and speaker device. It sits at the center of the table and captures a panoramic view of the room, as well as a face-to-face view of active speakers, to make hybrid meetings engaging and immersive.

Learn More

REMOTE VIEW



Seamless automatic camera-switching

360-degree view of the room

Auto-focus on active speakers for face-to-face discussion

Outfit any workspace with our endlessly flexible ecosystem


8 omnidirectional volume-equalizing smart mics

360° panoramic fisheye lens

Plug-and-play compatibility with all video conferencing platforms

360° tri-speaker

Option to extend audio range by 8' (2.5m) with add-on **Expansion Mic**

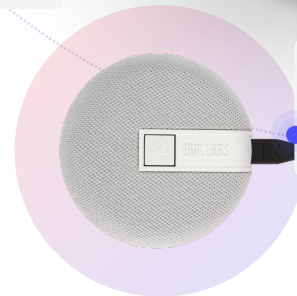

Give everyone a seat at the table

The Meeting Owl leverages the Owl Intelligence System™ to auto-focus on whoever is speaking to capture a face-to-face view of in-room participants alongside a 360° panoramic view of the room.

Meet the award-winning Meeting Owl

[Learn More](#)

IN ROOM
EXPERIENCE



Outfit any space

Wirelessly pair with the Owl Bar or a second Meeting Owl for collaboration in larger spaces



MEETING OWL 3 + OWL BAR



MEETING OWL 3 + MEETING OWL 3

Meeting Owl[®] 3 Specifications

MEETING OWL 3
MTW300-1000
OWL LABS[®]

OVERVIEW

Camera	Microphone	Speaker	Connection
Single custom-designed 360° panoramic fisheye camera to eliminate image distortion Shows optional 360° panoramic view of the room and face-to-face view that auto-focuses on whoever is speaking Output Resolution: 1080p HD Video Range: 10' (3m) Field of View: 360°	8 omni-directional beamforming smart mics Smart mics equalize speaker volume to amplify quiet voices Audio Pickup Radius: 18' (5.5m) Option to connect to Expansion Mic to extend audio range by 8' (2.5m)	Three built-in speakers for 360° coverage and clear in-room sound Speaker Output Level: 80 db SPL	Plug and play connection to host computer via USB-C Option to pair with the Owl Bar and the Whiteboard Owl via Bluetooth Option to connect to the Expansion Mic
Processing Power	Dimensions	Power Supply	Warranty
Qualcomm [®] Snapdragon™ 605 processor	Dimensions: 4.4" W x 4.4" D x 10.72" H (111mm W x 111mm D x 272mm H) Weight: 2.61lb (1.2kg)	AC Input: 100-240V Line cord: Specific to region	2-year warranty Option to extend warranty to 3 years with Owl Care

USAGE

Software	Compatibility	Management	Security
AI-powered Owl Intelligence System™ to intelligently focus on whoever is speaking Intelligently autofocuses on the active speaker using vision, voice, and motion Options for presenter enhancement, digital whiteboarding capabilities, and different camera controls to customize your meeting experience	Plug and play connection to host computer via USB-C Certified for Microsoft Teams Compatible with virtually all web-based video conferencing platforms, including Zoom, Google Meet, Slack, Webex, and many more Extend range by pairing with the Owl Bar, another Meeting Owl, or add-on Expansion Mic	Meeting Owl App: <ul style="list-style-type: none">Desktop: Mac and WindowsMobile: iOS and AndroidTablet: iPad Required for first-time setup and adjusting settings during meetings The Nest : Manage your fleet of Owls through our web-based portal	Meeting Owl 3 does not record any video or audio content Video and audio are streamed to the host computer via USB-C connection Full security and privacy details

SETUP

Setup	What's Included
Placement: 3' (1m) from the in-room TV or monitor and within 18' (5.5m) of in-room participants Setup Options: Center of the table, tripod-mounted, or ceiling-mounted	<ul style="list-style-type: none">Meeting Owl 3Power adapter and line cordUSB-C to USB-C cableSetup GuideTable Card + Owl holder

