

PEDESTRIAN

PRODUCTS PORTFOLIO



AS **AUTOMATIC**
SYSTEMS

Access controlled...
Future secured



Scan the page
to see more
reference
pictures



SECURITY ENTRANCE LANES

SLIMLANE SERIES - AESTHETICS & SECURITY

Featuring a streamlined design, SlimLane's double swing door security entrance lanes combine high throughput (opening time < 1 sec.) with advanced user protection while providing a minimal footprint.

SLIMLANE - 2 DOORS

SLIMLANE 940-940SC

STANDARD LANE

- ♦ Passage width: 600 mm (from 550 to 725 mm)
- ♦ Obstacle heights: 900/1200/1500/1700 mm
- ♦ Footprint (W x L): 1000 x 1640 mm/1000 x 1274 mm (SC)



* picture with trolley detection, side glass and end-post extensions (EP)

SLIMLANE 950-950SC

WIDE LANE

- ♦ Passage width: 550 mm (from 550 to 600 mm)
- ♦ Obstacle heights: 900/1200/1500/1700 mm
- ♦ Footprint (W x L): 1300 x 1640 mm/1300 x 1274 mm (SC)



SLIMLANE 950EW

EXTRA-WIDE LANE

- ♦ Passage width: 1200/1400 mm
- ♦ Obstacle heights: 900 mm
- ♦ Footprint (W x L): 1600 x 1640 mm




SERVICELANE

SERVICE LANE


- ♦ Passage width: 900 mm
- ♦ Obstacle heights: 1000/1200 mm
- ♦ Footprint (W x L): same dimensions as intermediate cabinets 940/950/944




CONFIGURATION EXAMPLES

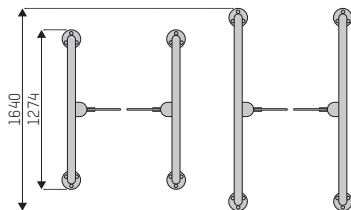


SLIMLANE 940SC
SLIMLANE 940

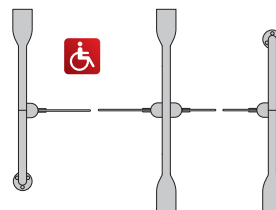

SLIMLANE 950EP + 940EP
WITH END-POSTS

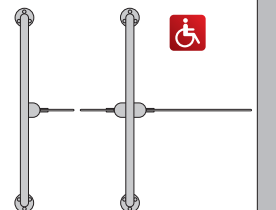

SLIMLANE 940 +
SERVICELANE

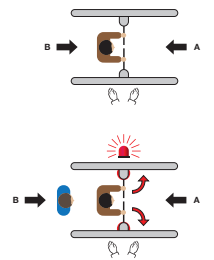

FAIL-SAFE

SECURITY ENTRANCE LANES

SLIMLANE SERIES - GREATER MODULARITY

A compelling product offering:

- ◆ standard or short cabinets
- ◆ standard or wide lanes with end-post extensions (EP)
- ◆ 1 or 2 doors
- ◆ low or high obstacles
- ◆ 2 operating modes - Securi-safe or Egress

SLIMLANE - 1 DOOR

SLIMLANE 944-944SC

COMPACT LANE

- ◆ Passage width: 550 mm (from 550 to 600 mm)
- ◆ Obstacle heights: 900/1200/1500/1700 mm
- ◆ Footprint (W x L): 857 x 1640 mm / 857 x 1274 mm (SC)



* picture with end-post extension (EP)

SLIMLANE 945-945SC TWIN

DUAL COMPACT LANE

- ◆ Passage width: 900 mm (from 725 to 950 mm)
- ◆ Obstacle heights: 900/1200/1500/1700 mm
- ◆ Footprint (W x L): 1300 x 1640 mm / 1565 x 1274 mm (SC)




SLIMLANE 950+944+944

WITH END-POST EXTENSIONS (EP)

- ◆ Installation example with maximum throughput and minimum footprint
- ◆ Footprint (W x L): 2719 x 1450 mm (1 wide lane + 2 standard lanes)



CONFIGURATION EXAMPLES

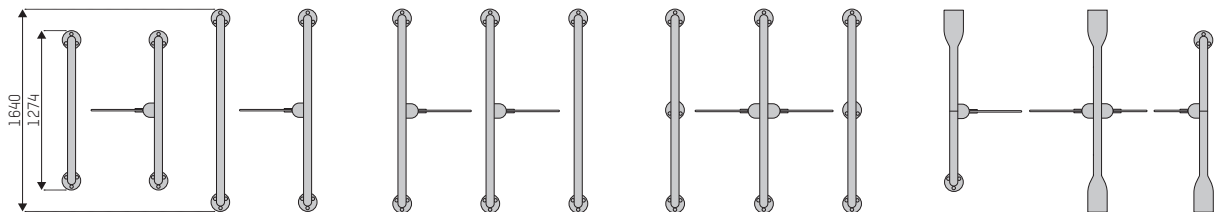

SLIMLANE 944SC
SLIMLANE 944

DOUBLE LANE
SLIMLANE 944

SLIMLANE
945 TWIN

TRIPLE LANE SLIMLANE 944
WITH END-POSTS (EP)



SECURITY ENTRANCE LANES

SMARTLANE SERIES

The elegant and discreet design of the SmartLane range of high security, bidirectional speed gates (opening time < 1 sec.), blends seamlessly into any type of architecture. SmartLane is available in multiple possible configurations, including extensions options, open or closed, one-way or double.

SMARTLANE 2900

STANDARD LANE

- ◆ Passage width: 600 mm
- ◆ Obstacle heights: 1000/1200/1500/1700/1800/1900/2000 mm
- ◆ Footprint (W x L): 1200 x 1200 mm



SMARTLANE 2910

WIDE LANE

- ◆ Passage width: 900 mm
- ◆ Obstacle heights: 1000/1200/1500/1700/1800/1900/2000mm
- ◆ Footprint (W x L): 1800 x 1200 mm



OPEN EXTENSION



DOUBLE OPEN EXTENSION




CLOSED EXTENSION



DOUBLE CLOSED EXTENSION



CONFIGURATION EXAMPLES

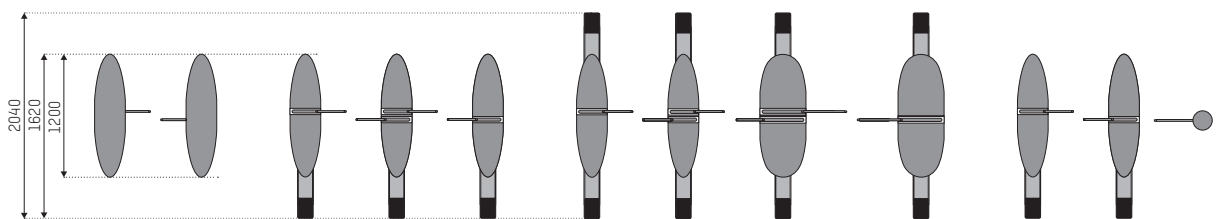

SL 2900

SL 2900 EXTENSION

SL 2900 & SL 2910
DOUBLE EXTENSION

SL 2900 EXTENSION
& ACCESSLANE



Scan the page
to see more
reference
pictures



reddot winner 2021

SECURITY ENTRANCE LANES

FIRSTLANE SERIES

FirstLane double swing door security turnstiles provide a high bi-directional flow and safety without compromise. With its modern and stylish design, FirstLane is perfectly suited to any type of architecture. Its exclusive detection system ensures precise user tracking for maximum safety and security. FirstLane combines high throughput with state-of-the-art detection.

FIRSTLANE

- ◆ Passage width: 600/900 mm
- ◆ Obstacle height: 910 mm
- ◆ Footprint (W x L): 990 x 1300 mm/1290 x 1300 mm



STANDARD LANE



WIDE LANE


SWING GATES

ACCESSLANE SERIES

Bidirectional swing gates can be used alone or in conjunction with others products such as SmartLane, TriLane, SlimLane. They can be installed discretely and aesthetically in the entrance areal of buildings.

ACCESSLANE 933

- ◆ Passage width: 900 mm
- ◆ Obstacle heights: 900/1000/1200 mm
- ◆ Footprint (W x L): 1000 x 220 mm

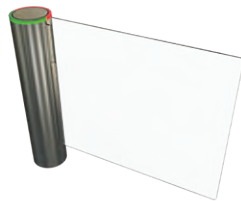


ACCESSLANE 934


- ◆ Passage width: 900 mm
- ◆ Obstacle heights: 1500/1700/1800/1900 mm
- ◆ Footprint (W x L): 1535 x 220 mm



CONFIGURATION
EXAMPLES

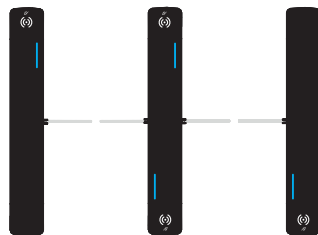

STANDARD DOUBLE LANE FIRSTLANE

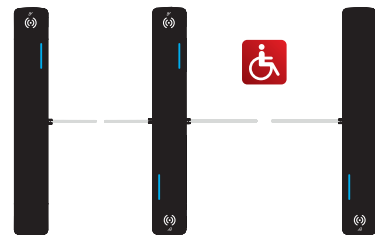

STANDARD AND WIDE FIRSTLANE
LANE COMBINATION

TRIPOD TURNSTILES

TRILANE SERIES

Bidirectional TriLane tripod turnstiles are robust products for sites with heavy use. They can function equally well indoors and outdoors.



TL1 STANDARD



TL1 STAINLESS STEEL



TL2 STANDARD



TL2 HYBRID



TL2 STAINLESS STEEL

TRILANE TL 1

TRIPOD TURNSTILE

- ◆ Passage width: 550 mm
- ◆ Footprint (W x L): 849 x 400 mm

TRILANE TL 2

TRIPOD TURNSTILE

- ◆ Passage width: 550 mm
- ◆ Footprint (W x L): 745 x 1300 mm

FULL-HEIGHT TURNSTILES

TRS SERIES

Mainly used to lock down the perimeter of enclosed outdoor sites, our bidirectional full-height turnstiles ensure single-user throughput and are extremely weather-resistant.

TRS 370

3-SECTIONS FULL-HEIGHT TURNSTILE

- ◆ Single passage
- ◆ Passage width: 640 mm



TRS 371

4-SECTIONS FULL-HEIGHT TURNSTILE

- ◆ Single passage
- ◆ Passage width: 560 mm



TRS 372

3-SECTIONS FULL-HEIGHT TURNSTILE

- ◆ Double passage
- ◆ Passage width: 2 x 640 mm



TRS 373

4-SECTIONS FULL-HEIGHT TURNSTILE

- ◆ Double passage
- ◆ Passage width: 2 x 560 mm



TRS PMR

SECURITY DOOR DESIGNED FOR PERSONS WITH REDUCED MOBILITY (PRM)

- ◆ It can be fully integrated with the TRS37x range for side-by-side or remote installation
- ◆ The bidirectional door is available in motorized or manual version
- ◆ Passage width: 1050 mm





SECURITY DOORS

CLEARLOCK SERIES

ClearLock automatic security booths are cylindrical doors that provide very strict access control, specially adapted to sensitive sites.



1. Passage widths: between 580 and 900 mm
2. Single passage detection
3. Metal detection

4. Bullet-proof glass EN1063 (*)
5. Force-entry resistance EN1627-1630/ LPS1175 SRI-2-3 (*)
6. Intrinsic mechanical opening (*)

REVLOCK SERIES

RevLock automatic revolving security doors are designed to provide high-security access control with high throughput.

REVLOCK 60X-614
 REVOLVING DOORS
 WITH WEIGHT DETECTION

1. Doors with 3 or 4 sections
2. External diameters: 1800/2000/2300 mm (*)
3. Single passage detection



REVLOCK 60XT
 REVOLVING DOORS
 WITH 3D VIDEO DETECTION

4. Bullet-proof glass EN1063 (*)
5. Forced-entry resistance EN1627-1630 (*)
6. Night doors and folding doors (*)



INTERLOCK SERIES

InterLock rectangular security booths are equipped with flat glass doors, providing access control that is particularly recommended for public sites.

INTERLOCK 67X
 AUTOMATIC SECURITY BOOTHS
 WITH FLAT DOORS

1. Passage widths: 700 or 900 mm
2. Single passage detection
3. Metal Detection




INTERLOCK 68X
 MANUAL SECURITY BOOTHS
 WITH FLAT DOORS

4. Single or double passage (*)
5. Bullet-proof glass EN1063 (*)
6. Intrinsic mechanical opening (*)




(*) depending on the model


CONFIGURATION
EXAMPLES

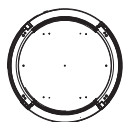


CLEARLOCK 63X

 


CLEARLOCK 64X

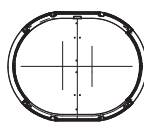

CLEARLOCK 656

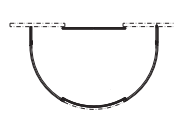

CLEARLOCK 660

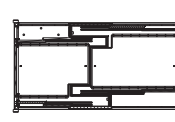

INTERLOCK 674



REVLOCK 60X



► FIND THE PEDESTRIAN PRODUCT FOR YOUR NEEDS

	PASSAGES/MINUTE (1)	MOBILITY IMPAIRED	PASSAGE WIDTH (mm)	OBSTACLE HEIGHT (mm)	FOOTPRINT	MOVEMENT			ACTIVATION		AESTHETICS		AUTOMATIC OPENING IN CASE OF EMERGENCY
					SINGLE LANE (mmxmm)	RETRACTABLE	SWING	ROTATING	MOTORISED	MANUAL	CONTEMPORARY	CLASSIC	
SECURITY ENTRANCE LANES													
SlimLane 940	60		575-725	900-1700	1000 x 1640		<1s		◆		◆		◆*
SlimLane 950		♿	725-950		1300x1640		<1s		◆		◆		◆*
SlimLane 950EW	50	♿	1200-1400	900	1600x1640		1.2s		◆		◆		◆*
SlimLane 944	60		525-600	900-1700	857x1640		1s		◆		◆		◆*
SlimLane 945 Twin	2x60		2 x 525-600		1565x1640		1s		◆		◆		◆*
SlimLane 940SC	60		575-725	900-1700	1000x1274 (2)		<1s		◆		◆		◆*
SlimLane 950SC		♿	725-950		1300x1274 (2)		<1s		◆		◆		◆*
SlimLane 944SC	60		525-600	900-1700	857 x 1274 (2)		1s		◆		◆		◆*
SlimLane 945SC Twin	2x60		2 x 525-600		1565x1274 (2)		1s		◆		◆		◆*
FirstLane	60	♿	600/900	910	990 x 1300 / 1290 x 1300		<1s		◆		◆		◆ (3)
SmartLane 2900			600	1000-2000	1200x1200		<1s		◆		◆		◆
SmartLane 2910	60		900		1800x1200		<1s		◆		◆		◆
SWING GATES													
ServiceLane	20	♿		1000-1200			4s		◆		◆		◆
AccessLane 933		♿	900	900-1200	1000 x 220		4s		◆		◆		
AccessLane 934	20	♿		1500-1900	1535 x 220		6s		◆		◆		
TRIPOD TURNSTILES													
TriLane TL 1			550	760	849 x 400			◆		◆		◆	◆
TriLane TL 2	20				745 x 1300				◆		◆		◆
FULL-HEIGHT TURNSTILES													
TRS 370	20		640		1540 x 1370			◆		◆		◆	
TRS 371	20		560	2290	1540 x 1529			◆		◆		◆	
TRS 372	2x20		2 x 640		2400 x 1370			◆		◆		◆	
TRS 373	2x20		2 x 560	2290	2400x1370			◆		◆		◆	
TRS PMR	20	♿	1050	2296	1400x991			◆		◆		◆	

Legend: * Option / (1) varies with access control systems / (2) L = 1450 mm with 1 end-post / L = 1625 mm with 2 end-posts / (3) on power supply



► FIND THE SECURITY DOOR FOR YOUR NEEDS



PASSAGES / MINUTE ⁽¹⁾	PASSAGE WIDTH (mm)	HEIGHT (mm)		DIMENSION (mm)		NO. OF DOORS	MOVEMENT			ACTIVATION		DETECTION		
		EXTERIOR	INTERIOR	OUTER	INNER		SWING	ROTATING	SLIDING	MOTORISED	MANUAL	FLOOR WEIGHING	SUSPENDED WEIGHING	TIME OF FLIGHT (TOF)

AUTOMATIC ROUND SECURITY BOOTHS

ClearLock 635	6	580	2350	2074	Ø 1052	Ø 832	2			◆	◆		◆				
ClearLock 636		650			Ø 1152	Ø 949				◆	◆		◆				
ClearLock 637	5	900	2350	2074	Ø 1500	Ø 1292	2			◆	◆		◆				◆
ClearLock 638	6						4			◆	◆		◆				◆
ClearLock 639	5	900	2300	2025	Ø 1750	Ø 1536	2			◆	◆		◆		◆		◆
ClearLock 639T			2575	2300						◆	◆		◆		◆		◆

AUTOMATIC SQUARE SECURITY BOOTHS

ClearLock 645	6	580	2360	1990	1050x1050	Ø 719	2			◆	◆			◆			
ClearLock 646		640			1150x1150	Ø 861				◆	◆			◆			

AUTOMATIC EXTENDED SECURITY BOOTHS

ClearLock 656	6	900	2400	2075	1485x1900	1305x1695	4			◆	◆		◆				◆
---------------	---	-----	------	------	-----------	-----------	---	--	--	---	---	--	---	--	--	--	---

AUTOMATIC SEMI-CIRCULAR SECURITY BOOTHS

ClearLock 660	6	900	2400	2125	1910x1250	1786x1058	4			◆	◆		◆				◆
ClearLock 664	1,5 s	812	2400	2045	1252x1000	1119x841	1			◆	◆		◆				

AUTOMATIC SECURITY BOOTHS WITH FLAT DOORS

InterLock 673	6	900	2350	2135	1600x1200	1542x820	4			◆	◆		◆				◆
InterLock 678					1600x1600	1542x1220	4			◆	◆		◆				◆
InterLock 674	2 x 6	700 + 900	2350	2135	2300x1200	(1016x820)+ (1216x820)	8			◆	◆		◆				◆

MANUAL SECURITY BOOTHS WITH FLAT SWING DOORS

InterLock 681		700	2300	2034	1050x1050	986x962	2	◆				◆	◆				
InterLock 682		900			1280x1050	1220x962	2	◆				◆	◆				
InterLock 680		950	2250	2100	1050x400	605x293	2	◆				◆	◆				

AUTOMATIC REVOLVING SECURITY DOORS

RevLock 603		1206			Ø 1970	913				◆	◆		◆				
RevLock 604	2 x 20 ⁽²⁾	1090	2300	2073	Ø 1810	829	4			◆	◆		◆				
RevLock 605		1479			Ø 2362	991				◆	◆		◆				
RevLock 614	1 x 15 ⁽²⁾	829	2300	2073	Ø 1810	829	3			◆	◆		◆				
RevLock 603T		1206			Ø 1970	913				◆	◆						◆
RevLock 604T	2 x 20 ⁽²⁾	1090	2505	2300	Ø 1810	829	4			◆	◆						◆
RevLock 605T		1479			Ø 2362	991				◆	◆						◆

SWING SECURITY DOORS

DoorLock 693		900-1200	2100-2350	2030-2280	1030-1330	900-1200	1	◆				◆					antipanic bar
DoorLock 694		920	2205	2115	1090	920	1	◆				◆					

(1) varies depending on the access control system / (2) Option

HEADQUARTERS - INTERNATIONAL SALES

AUTOMATIC SYSTEMS SA

Avenue Mercator 5 - 1300 Wavre
BELGIUM
T.: +32 (0)10 230 211
sales.asgroup@automatic-systems.com

LOCAL OFFICES AROUND THE WORLD

UNITED KINGDOM

T.: +44 (0)1604 65 42 10
E: sales.uk@automatic-systems.com

UNITED STATES

T.: +1 516 944 94 98
E: sales.nam@automatic-systems.com

CANADA

T.: +1 450 659 07 37
E: sales.nam@automatic-systems.com

FRANCE

T.: +33 (0)1 30 28 95 50 (Persan office)
T.: +33 (0)1 41 11 40 20 (Suresnes office)
E: sales.fr@automatic-systems.com

SPAIN

T.: +34 (0)93 478 77 55 (Barcelona office)
T.: +34 (0)91 659 07 66 (Madrid office)
E: sales.es@automatic-systems.com

GERMANY

T.: +49 2303 553 4040
E: sales.de@automatic-systems.com

**AUTOMATIC
SYSTEMS**

Access controlled...
Future secured



Scan the pages where you find the icon to discover exclusive content online



Visit our virtual showroom to discover the other Automatic Systems' products



Download our app to make augmented reality simulations with the main Automatic Systems products

