



Krugger
Reflections USA



2022-23

**MIRROR
PRICE BOOK**

TERMS AND CONDITIONS



PRICING: This retail price list supersedes all previous price lists. Prices and specifications are subject to change without prior notice.

PAYMENT TERMS: Net 30 days with prior approved credit application on file.

PAST DUE ACCOUNTS: All past due accounts are placed on credit hold. No orders will be processed until the account is brought current. Accounts continually past due will be changed to C.O.D. or the account may be closed.

KRUGGSafe PACKAGING All items are designed for easy and safe drop ship carrier methods.

ORDER SUBMISSION: Orders can be placed in a few ways listed and prioritized below:

Krugg Dealer Portal www.Krugg.us/Dealer-Login

Emailed to Orders@Krugg.us

Or Faxed 800 672 1914

All orders will be confirmed by email. (Faxed by request)

RETURNS

BUYER'S REMORSE: No restocking fee will be charged for returns that are requested 120 days from date of delivery. Original shipping charge will not be refunded; rather, a prepaid n/c return shipping label will be issued. Return claims must be accompanied with a picture of the product in good condition. If the packaging was lost or destroyed, the product must be repackaged as per UPS guidelines

DAMAGE CLAIMS:

Full credit or replacement must be requested no more than 30 days from day of delivery. Returns with proof of damage (photos must include packaging as well as the damaged item) are eligible for full refund or replacement.

KRUGG LIMITED LIFETIME WARRANTY

Subject to the terms and conditions specified herein, Krugg Reflections USA LLC, ("KRUGG") hereby extends a limited lifetime warranty (this "Limited Warranty") to original Purchasers (as defined below) of the Krugg LED Lighted Mirror (the "Product") with respect to certain specified structural components of the Product. Specifically, KRUGG, by this Limited Warranty, warrants that, for the durations specified herein, Products purchased directly from KRUGG or KRUGG's authorized retailers will be free of defects in the material and workmanship of the Product's electrical components, glass and mirrors, which defects would cause the Product to substantially fail to function when subject to normal use.

For full warranty information please visit us at <https://www.krugg.us/warranty/>

FLAT RATE SHIPPING OPTIONS

Phone: 347-794-9654

Fax: 800 672 1914



SKU	Shipping type
Icon 1830, Icon 2032, Icon 2424, Icon 2424 Round, Icon 2436, Icon 2430, Bijou 1520, Soho 2436, Sol 22, Sol 27, Sol 2030, Tudor 2030, Icon 2432ADA, Bijou 1530, Mod 1836, Mod 2136, Mod 2436	Small Mirrors
Tudor 2442, Sol 2240, Sol 30, Icon3636, Icon 2442, Soho 3636, Sol 32, Sol 2444, Mod 3636	Medium Mirrors
Icon 4824, Icon 4836, Icon 4242, Mod 4836, Soho 4836, Sol 42	Large
Icon 6030, Tudor 6030, Icon 5424, Icon 5436, Soho6030	X-Large
Icon 6636, Icon 7230, Icon 8430, EXL 9636, Icon 6036, Icon 7236	Oversize Mirrors

Shipping Type	Geographic Location	Standard Rate	Expediated 2nd Day
Small Medium	Continental USA (Continuous 48 states)	\$29.95	\$99.95
Medium Mirror	Continental USA (Continuous 48 states)	\$59.95	\$169.95
Large Mirror	Continental USA (Continuous 48 states)	\$79.95	\$219.95
X-Large	Continental USA (Continuous 48 states)	\$99.95	\$349.95
Oversize Mirror	Continental USA (Continuous 48 states)	\$149.95	N/A

For International Shipments Including Alaska, Hawaii and American Territories Please Call or Email for a Rate Quote

DROP SHIPPING

\$15 per order Fee Not Applicable to Gold and Platinum dealers

To prevent issues during delivery, drop shipping orders must include the customer’s full name, full address, and best contact phone number. If the customer cannot be reached by the carrier to schedule delivery or the delivery address is incorrect, the carrier will consider this shipment as undelivered and the shipment will come back to our facility. In this case, we will have to charge a 25% restocking fee up to a maximum of \$99, and the original shipping charge will not be credited back. If the order needs to be resent, we will charge the standard delivery fee on the new shipment.

ICON COLLECTION



Integrated Heating Element to Keep Mirror Fog Free


Bright LED Light (50000 Hours)

On/Off Dimmer Touch Sensor

KruggeReflect +

KruggeReflect+ Offer a perfectly clear and bright Reflection. It's beautiful turquoise color backing provides a natural looking glass eliminating black edging found on Inferior mirrors.


KruggeClear +

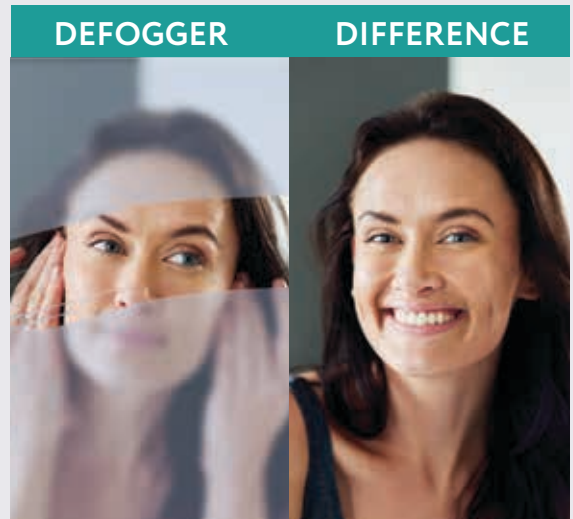

Good
Competitor



 BEST
KruggeReflect



Better
Competitor



ICON LED MIRROR



STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- Flexible (Vertical/Horizontal) Installation
- 5000 Kelvins Light Temp



	Product ID	List Price
	Icon 1830 18" x 30" LED Mirror CRI 90, 3000 Lumens	\$475
	Icon 2032 20" x 32" LED Mirror CRI 90, 3200 Lumens	\$565
	Icon 2430 24" x 30" LED Mirror CRI 90, 3400 Lumens	\$585
	Icon 2436 24" x 36" LED Mirror CRI 90, 3720 Lumens	\$655
	Icon 2442 24" x 42" LED Mirror CRI 90, 4000 Lumens	\$965


ICON LED MIRROR

STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- 5000 Kelvins Light Temp




Product ID	List Price
------------	------------

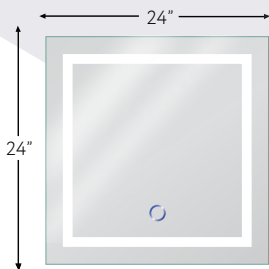


Icon 2424
24" x 24" LED Mirror
CRI 90, 3000 Lumens

\$631

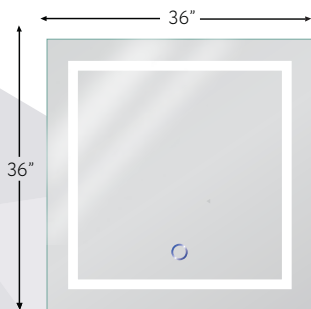

Icon 3636
36" x 36" LED Mirror
CRI 90, 4500 Lumens

\$973

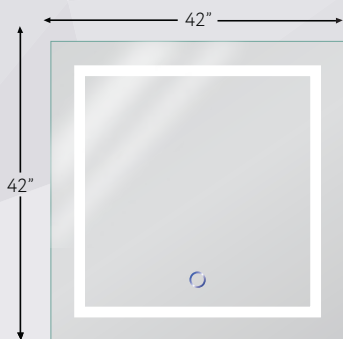

Icon 4242
42" x 42" LED Mirror
CRI 90 Lumens 6200

\$1,443

ICON LED MIRROR




STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- 5000 Kelvins Light Temp




Product ID	List Price
------------	------------

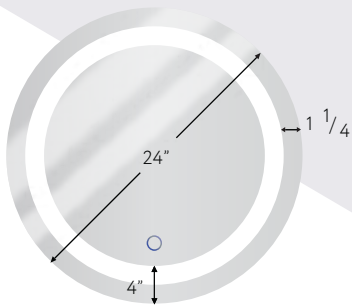

Icon 24 Round
24" x 24" LED Mirror
CRI 90, 2300 Lumens

\$631

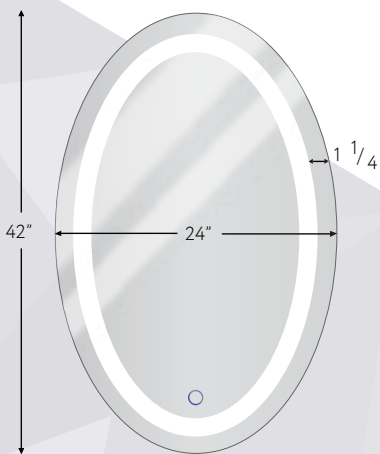

Icon 2442 Oval
24" x 42" LED Mirror
CRI 90, 3000 Lumens

\$850

ICON LED MIRROR

STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- Flexible (Vertical/Horizontal) Installation
- 5000 Kelvins Light Temp



Product ID	
	<p>Icon 4824 48" x 24" LED CRI90, Lumens 4480</p> <p>\$1,283</p>
	<p>Icon 4836 48" x 36" LED CRI90, Lumens 5800</p> <p>\$1,438</p>
	<p>Icon 5424 54" x 24" LED CRI90, Lumens 4850</p> <p>\$1,538</p>
	<p>Icon 5436 54" x 36" LED CRI90, Lumens 6350</p> <p>\$2,147</p>
	<p>Icon 6030 60" x 30" LED CRI90, Lumens 5620</p> <p>\$1,454</p>

ICON LED MIRROR



STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- Flexible (Vertical/Horizontal) Installation
- 5000 Kelvins Light Temp



	Product ID	List Price
	Icon 6036 60"x 36" LED CRI90, Lumens 6000	\$2,021
	Icon 6636 66"x 36" LED CRI90, Lumens 6360	\$2,247
	Icon 7230 72"x 30" LED CRI90, Lumens 6380	\$2,115
	Icon 7236 72"x 36" LED CRI90, Lumens 6900	\$2,703
	Icon 8430 84"x 30" LED CRI90, Lumens 7120	\$3,202

SOHO COLLECTION




- Integrated Heating Element to Keep Mirror Fog Free
- Bright LED Light (50000 Hours)
- On/Off Dimmer Touch Sensor

KruggReflect +

KruggReflect+ Offer a perfectly clear and bright Reflection. It's beautiful turquoise color backing provides a natural looking glass eliminating black edging found on Inferior mirrors.


KruggClear +

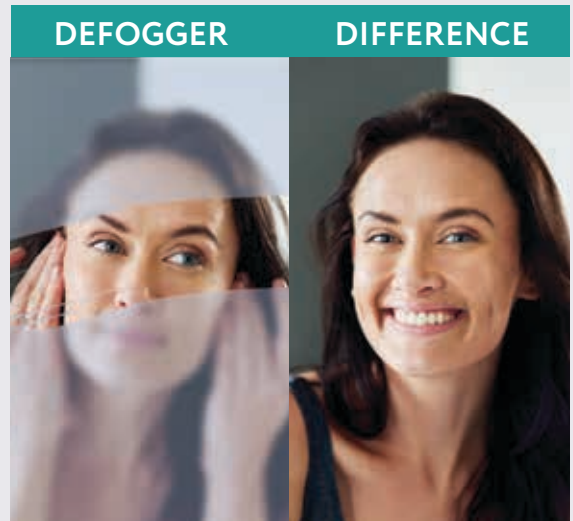

Good
Competitor



BEST
KruggReflect

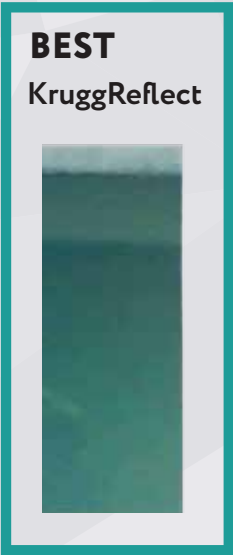

Better
Competitor



SOHO GOLD LED MIRRORS



STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- 5000 Kelvins Light Temp



	Product ID	List Price
	<p>Soho Gold 2436</p> <p>24" x 36" LED Mirror</p> <p>3720 Lumens</p>	<p>\$859</p>
	<p>Soho Gold 3636</p> <p>36" x 36" LED Mirror</p> <p>4500 Lumens</p>	<p>\$1,360</p>
	<p>Soho Gold 4836</p> <p>48" x 36" LED Mirror</p> <p>5800 Lumens</p>	<p>\$1,870</p>
	<p>Soho Gold 6030</p> <p>60" x 30" LED Mirror</p> <p>5620 Lumens</p>	<p>\$1,998</p>

SOHO BLACK LED MIRRORS




STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- 5000 Kelvins Light Temp




	Product ID	List Price
--	------------	------------

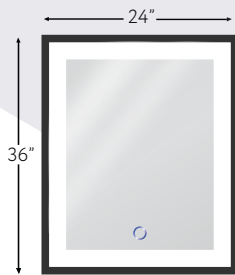


Soho Black 2436
 24" x 36" LED Mirror
 3720 Lumens

\$859

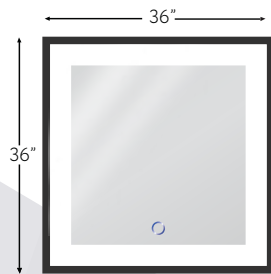


Soho Black 3636
 36" x 36" LED Mirror
 4500 Lumens

\$1,360

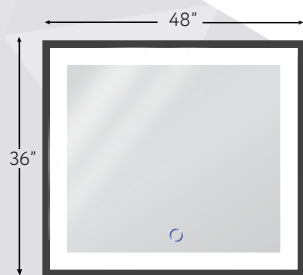

Soho Gold 4836
 48" x 36" LED Mirror
 5800 Lumens

\$1,870

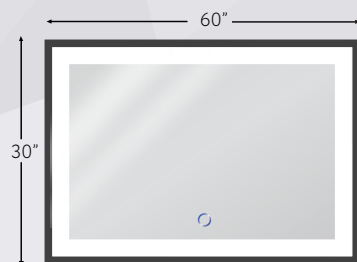

Soho Gold 6030
 60" x 30" LED Mirror
 5620 Lumens

\$1,998

SOHO BLACK LED MIRRORS



COMMERCIAL LED MIRROR



● Integrated Heating Element to Keep Mirror Fog Free

● Silver Backed -Copper Free Mirror


● 110V-277V compatible

● Works with outside Wall Switch or Dimmer

KruggReflect +

KruggReflect+ Offer a perfectly clear and bright Reflection. It's beautiful turquoise color backing provides a natural looking glass eliminating black edging found on Inferior mirrors.

KruggClear +

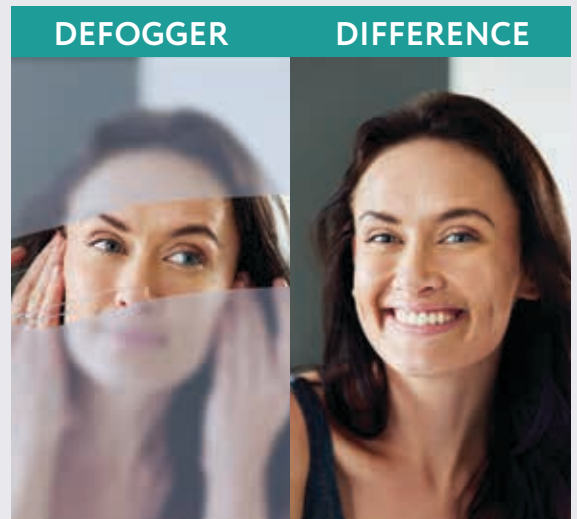

Good Competitor




BEST
KruggReflect



Better Competitor




COMMERCIAL LED MIRROR

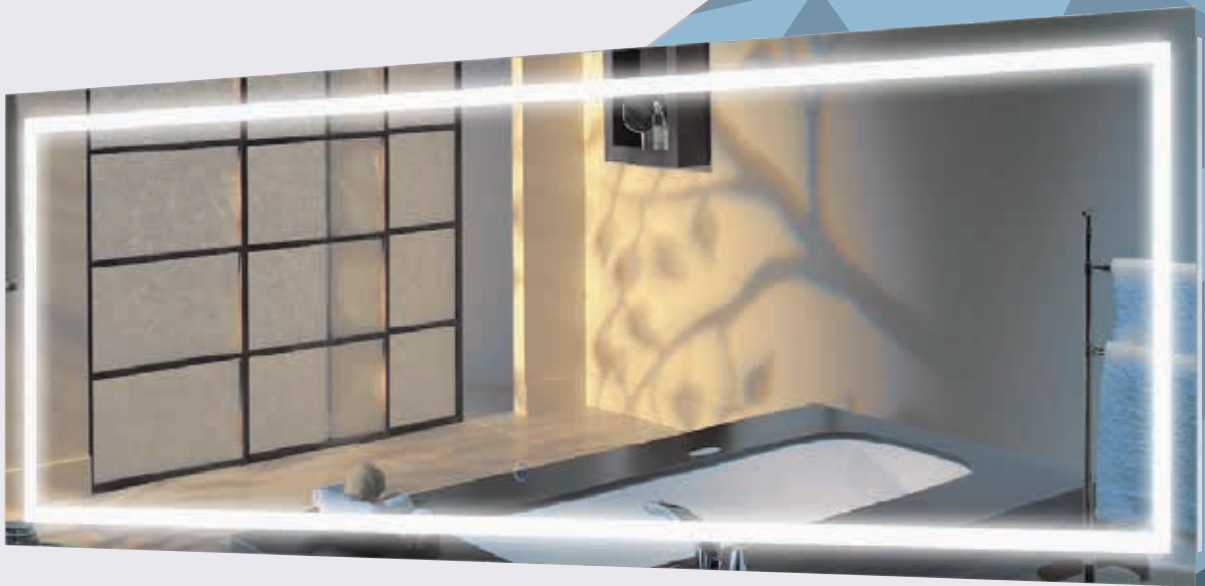

STANDARD FEATURES

- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade Silver Backed Glass
- Defogger Element Included
- Flexible (Vertical/Horizontal) Installation
- 110V-277V compatible
- Works with Outside Dimmer or Regular Switch
- 5000 Kelvins Light Temp

	Product ID	List Price
--	------------	------------

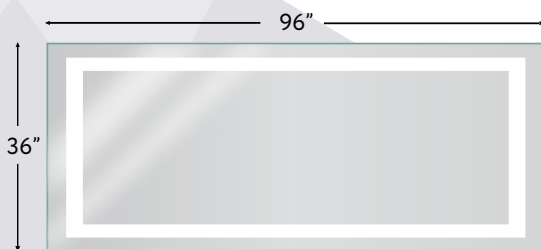

EXL 9636

\$5,500

96"x36" LED Mirror

CRI 90, Lumens 8450


FIXED TILT LED MIRROR

STANDARD FEATURES

- ADA compliant
- 4000 K Color Temp
- 50,000 Hours Lifspan of LED Light
- Commercial grade
- 5000 Kelvins Light Temp



Product ID	List Price
------------	------------

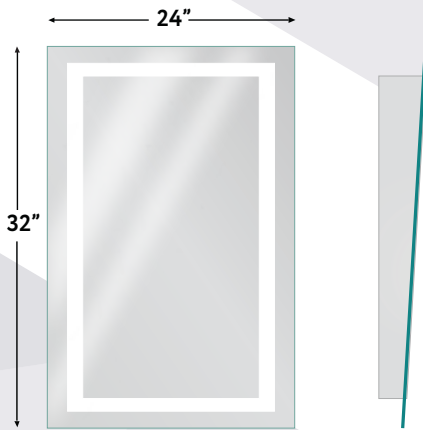

Icon 2432 ADA
24"x32" LED Mirror
CRI 90, 2200 Lumens

\$1,070

TUDOR COLLECTION



TUDOR COLLECTION




- Integrated Heating Element to Keep Mirror Fog Free
- Bright LED Light (50,000 Hours)
- On/Off Dimmer Touch Sensor

KruggReflect +

KruggReflect+ Offer a perfectly clear and bright Reflection. It's beautiful turquoise color backing provides a natural looking glass eliminating black edging found on Interior mirrors.

KruggClear +

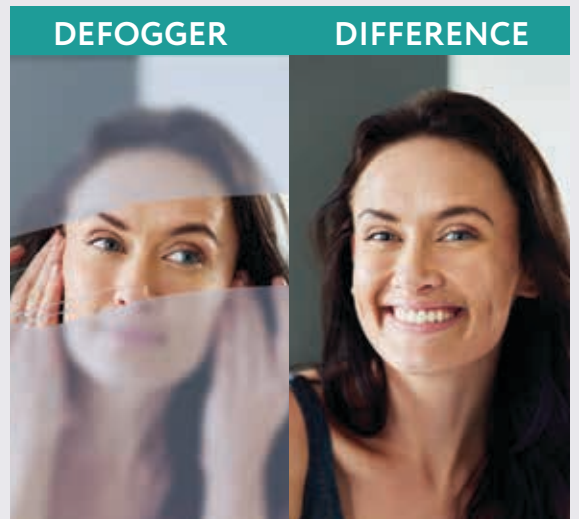

Good
Competitor



BEST
KruggReflect



Better
Competitor



TUDOR LED MIRROR



STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- Flexible (Vertical/Horizontal) Installation
- 5000 Kelvins Light Temp



	Product ID	List Price
	TUDOR 2030 20" x 30" LED Mirror CRI 90, 2950 Lumens	\$601
	TUDOR 2442 24" x 42" LED Mirror CRI 90, 3950 Lumens	\$948
	TUDOR 6030 60" x 30" LED Mirror CRI 90, 5420 Lumens	\$1,675

SOL COLLECTION




- Integrated Heating Element to Keep Mirror Fog Free
- Bright LED Light (50,000 Hours)
- On/Off Dimmer Touch Sensor

KruggReflect +

KruggReflect+ Offer a perfectly clear and bright Reflection. It's beautiful turquoise color backing provides a natural looking glass eliminating black edging found on Interior mirrors.

KruggClear +

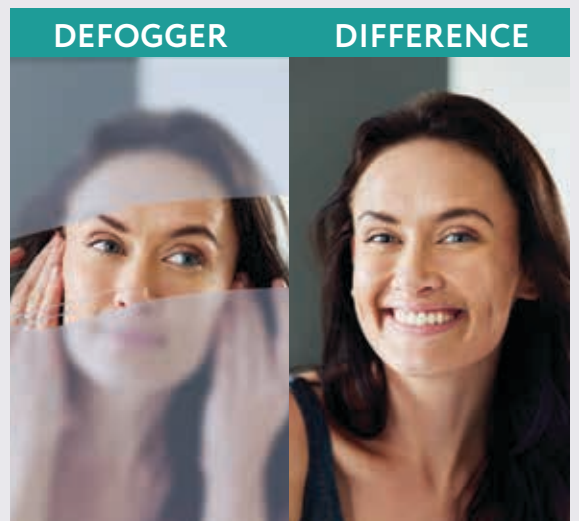

Good
Competitor



BEST
KruggReflect



Better
Competitor








SOL LED BACKLIT MIRRORS



STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- 5000 Kelvins Light Temp

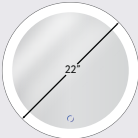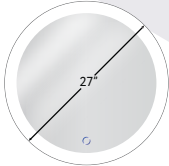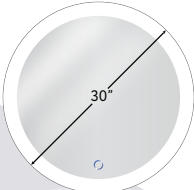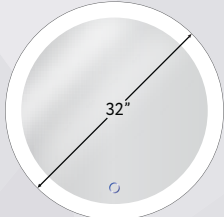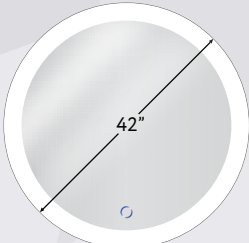


	Product ID	List Price
	SOL 22 22" Diameter, LED Mirror CRI 90, 2200 Lumens	\$441
	SOL 27 27" Diameter, LED Mirror CRI 90, 2600 Lumens	\$568
	SOL 30 30" Diameter, LED Mirror CRI 90, 2900 Lumens	\$888
	SOL 32 32" Diameter, LED Mirror CRI 90, 3100 Lumens	\$1,132
	SOL 42 42" Diameter, LED Mirror CRI 90, 4000 Lumens	\$1,350

BIJOU LED BACKLIT MIRRORS




STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- 5000 Kelvins Light Temp

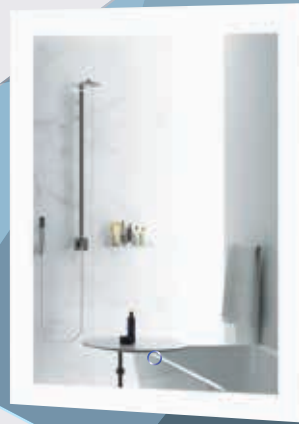


Product ID	List Price
------------	------------

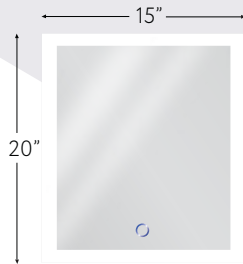

Bijou 1520
15" x 20" LED Mirror
CRI 90, 2100 Lumens

\$510

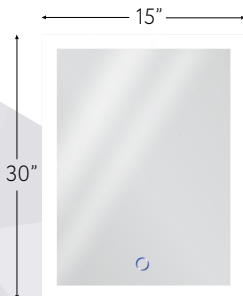

Bijou 1530
15" x 30" LED Mirror
CRI 90, 2400 Lumens

\$605

SOL LED MIRROR




STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- Flexible (Vertical/Horizontal) Installation
- 5000 Kelvins Light Temp




Product ID	List Price
------------	------------

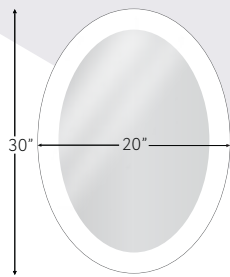


SOL 2030
 22" x 30" (Oval), LED Mirror
 CRI 90, 2600 Lumens

\$510

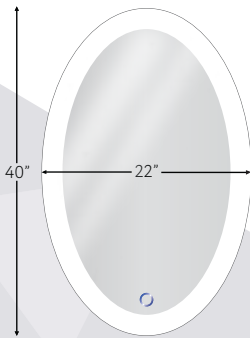

SOL 2240
 22" x 40" (Oval), LED Mirror
 CRI 90, 3300 Lumens


\$690

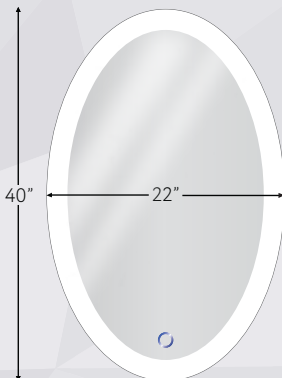

SOL 2444
 24" x 44" (Oval), LED Mirror
 CRI 90, 3700 Lumens

\$981

MODULAR LED MIRROR SYSTEM

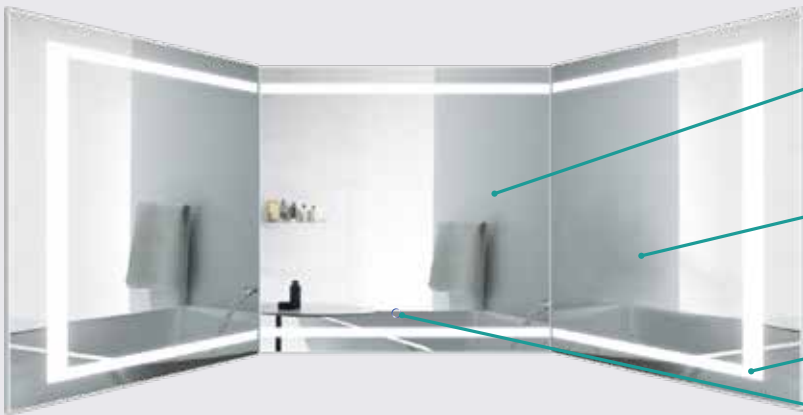


- Integrated Heating Element to Keep Mirror Fog Free
- Silver Backed -Copper Free Mirror
- 110V-277V compatible
- Works with outside Wall Switch or Dimmer

KruggReflect +

KruggReflect+ Offer a perfectly clear and bright Reflection. It's beautiful turquoise color backing provides a natural looking glass eliminating black edging found on Interior mirrors.

KruggClear +

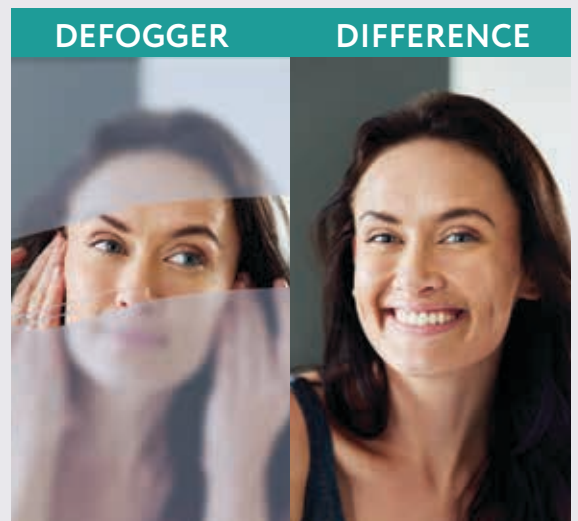

Good
Competitor



BEST
KruggReflect



Better
Competitor





PERFECT LIGHT


Eliminating the corner dark spots found in the many cheaper LED mirrors.

Krugg Bright⁺

CRI

Color Rendering describes how a light source makes the color of an object appear to the human eye, and how well the subtle variations in color shades are revealed.




Krugg Mirrors only use lights with a CRI of 90 or higher. Which is near perfect at color rendering and should be used for tasks requiring the most accurate color discrimination.

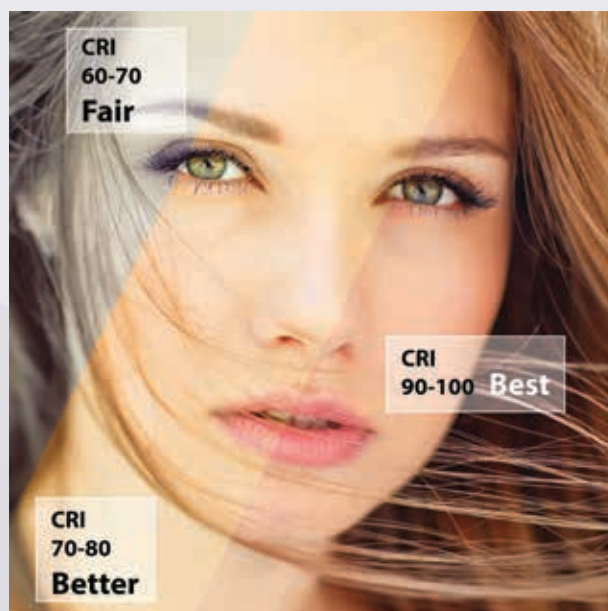

MODULAR LED MIRROR SYSTEM



Make any Size LED Mirror configuration, including single or double alcove.

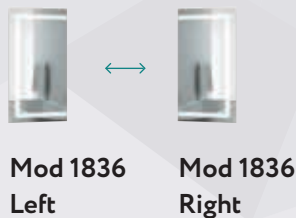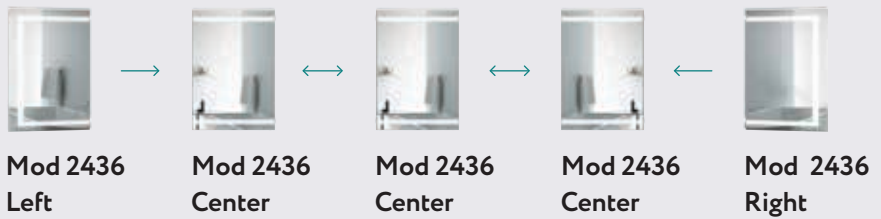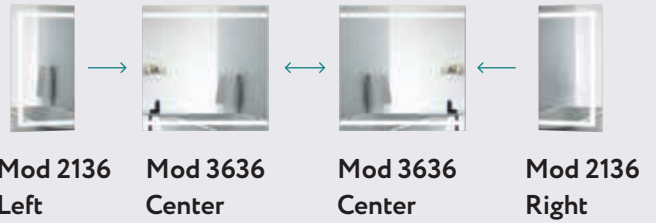


MODULAR LED MIRROR SYSTEM



STANDARD FEATURES

- Corner installation possible
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- Combine to make any size LED mirror
- 5000 Kelvins Light Temp
- Works with outside dimmer or regular switch

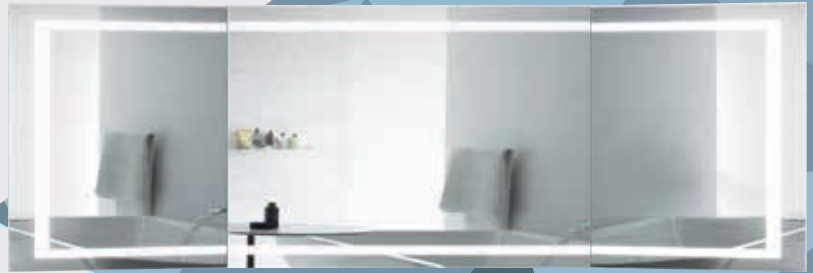

Options



**Mod 1836 Corner
18" x 36" Left
LED Mirror**

\$550



**Mod 2436 Center
24" x 36"
LED Mirror**

\$710



**Mod 1836 Corner
18" x 36" Right
LED Mirror**

\$550



**Mod 2136 Corner
21" x 36" Left
LED Mirror**

\$600



**Mod 3636 Center
36" x 36"
LED Mirror**

\$1150



**Mod 2136 Corner
21" x 36" Right
LED Mirror**

\$600



**Mod 2436 Corner
24" x 36" Left
LED Mirror**

\$710



**Mod 4836 Center
48" x 36"
LED Mirror**

\$1500



**Mod 2436 Corner
24" x 36" Right
LED Mirror**

\$710



**Mod 3636 Corner
36" x 36" Left
LED Mirror**

\$1200



**Mod 3636 Corner
36" x 36" Right
LED Mirror**

\$1,200





MODULAR LED MIRROR SYSTEM



STANDARD FEATURES

- Corner installation possible
- Energy Saving LED Lighting
- 50,000 Hours LED Life
- Top Grade silver backed glass
- Defogger Element included
- Combine to make any size LED mirror
- 5000 Kelvins Light Temp
- Works with outside dimmer or regular switch



	Product ID	List Price
	Mod-SM-Corner-18D Combo of Mod1836L and R	\$1,100
	Mod-SM-Corner-21D Combo of Mod2136L and R	\$1,200
	Mod-SM-Corner-24D Combo of Mod2436L and R	\$1,420
	Mod-SM-Corner-36D Combo Mod 3636L and R	\$2,400

MODULAR LED MIRROR SYSTEM



Product ID



9' Mod-SM-Long-9

\$3,550

Combo Mod 3636 Left Corner + Mod 3636 Center
+ Mod 3636 Right Corner



10' Mod-SM-Long-10

\$3,900

Combo Mod 3636 Left Corner + Mod 4836 Center
+ Mod 3636 Right Corner



11' Mod-SM-Long-11

\$4,100

Combo Mod 1836 Left Corner + Mod 4836 Center
+ Mod 4836 Center + Mod 1836 Right Corner



12' Mod-SM-Long-12

\$4,700

Combo Mod 3636 Left Corner + Mod 3636 Center
+ Mod 3636 Center + Mod 3636 Right Corner



Sol 22" Round Backlit mirror



Icon 60x30 LED Mirror



Icon 24x36 LED Mirror

Soho 24x36 Black Frame LED mirror



Svange 24x36 LED Medicine cabinets



Sol 20x30 Backlit mirror

Tudor 24x42 Octagon LED mirror





PHONE **347-794-9654**

FAX **800 672 1914**

1957 PIONEER RD BUILDING G
HUNTINGDON VALLEY PA 19006

Orders@krugg.us
www.KruggUSA.com

