

The logo for Krugger Reflections USA features the brand name 'Krugger' in a bold, black, serif font. To the right of the text is a teal-colored square frame with a thin border. Below the brand name, the words 'Reflections USA' are written in a smaller, black, sans-serif font.

Krugger
Reflections USA



2022-23

**Medicine Cabinet
PRICE BOOK**

TERMS AND CONDITIONS



PRICING: This retail price list supersedes all previous price lists. Prices and specifications are subject to change without prior notice.

PAYMENT TERMS: Net 30 days with prior approved credit application on file.

PAST DUE ACCOUNTS: All past due accounts are placed on credit hold. No orders will be processed until the account is brought current. Accounts continually past due will be changed to C.O.D. or the account may be closed.

KRUGGSafe PACKAGING: All items are designed for easy and safe drop ship carrier methods.

ORDER SUBMISSION: Orders can be placed in a few ways listed and prioritized below:

Krugg Dealer Portal www.Krugg.us/Dealer-Login

Emailed to Orders@Krugg.us

Or Faxed 800 672 1914

All orders will be confirmed by email. (Faxed by request)

RETURNS

BUYER'S REMORSE: No restocking fee will be charged for returns that are requested 120 days from date of delivery. Original shipping charge will not be refunded; rather, a prepaid n/c return shipping label will be issued. Return claims must be accompanied with a picture of the product in good condition. If the packaging was lost or destroyed, the product must be repackaged as per UPS guidelines

DAMAGE CLAIMS:

Full credit or replacement must be requested no more than 30 days from day of delivery. Returns with proof of damage (photos must include packaging as well as the damaged item) are eligible for full refund or replacement.

KRUGG LIMITED LIFETIME WARRANTY

Subject to the terms and conditions specified herein, Krugg Reflections USA LLC, ("KRUGG") hereby extends a limited lifetime warranty (this "Limited Warranty") to original Purchasers (as defined below) of the Krugg LED Lighted Mirror (the "Product") with respect to certain specified structural components of the Product. Specifically, KRUGG, by this Limited Warranty, warrants that, for the durations specified herein, Products purchased directly from KRUGG or KRUGG's authorized retailers will be free of defects in the material and workmanship of the Product's electrical components, glass and mirrors, which defects would cause the Product to substantially fail to function when subject to normal use.

For full warranty information please visit us at <https://www.krugg.us/warranty/>

FLAT RATE SHIPPING OPTIONS

Phone: 347-794-9654

Fax: 800 672 1914



SKU	Shipping type
Plaza 1230, Plaza 1530, Plaza 1830, Kinetic 1530	Small Cabinet
Plaza 2030, Plaza 2430, Kinetic 2030	Medium Cabinet
COMBINE ANY OF THE ABOVE CABINETS FOR AN EXTRA \$35.95 FEE	
Svange 2430, Svange 2436, Svange 2442, Kinetic 3030	Standard Cabinet
Svange 3636, Svange 3642, Svange 2430, Svange 4236, Svange 4242, Svange 4836, Svange 4842, Svange 6036, Svange 6042, Svange 6636, Svange 6642, Rolls 48	Large Cabinet
Svange 7236, Svange 7242, Svange 8436, Svange 8442, Svange 9636, Svange 9642, Svange 10236, Svange 10242, Svange 12036, Svange 12042	Oversize Cabinet

Shipping Type	Geographic Location	Standard Rate	Expediated 2nd Day
Small Cabinet	Continental USA (Continuous 48 states)	\$35.95	\$105.95
Medium Cabinet	Continental USA (Continuous 48 states)	\$45.95	\$115.95
Standard Cabinet	Continental USA (Continuous 48 states)	\$79.95	N/A
Large Cabinet	Continental USA (Continuous 48 states)	\$119.95	N/A
Oversize Cabinet	Continental USA (Continuous 48 states)	\$249.95	N/A

For International Shipments Including Alaska, Hawaii and American Territories Please Call or Email for a Rate Quote

DROP SHIPPING

\$15 per order Fee Not Applicable to Gold and Platinum dealers

To prevent issues during delivery, drop shipping orders must include the customer's full name, full address, and best contact phone number. If the customer cannot be reached by the carrier to schedule delivery or the delivery address is incorrect, the carrier will consider this shipment as undelivered and the shipment will come back to our facility. In this case, we will have to charge a 25% restocking fee up to a maximum of \$99, and the original shipping charge will not be credited back. If the order needs to be resent, we will charge the standard delivery fee on the new shipment.

SVANGE COLLECTION




SVANGE COLLECTION



KruggReflect⁺

KruggReflect⁺ Offer a perfectly clear and bright Reflection. It's beautiful turquoise color backing provides a natural looking glass eliminating black edging found on interior mirrors.

KruggClear⁺

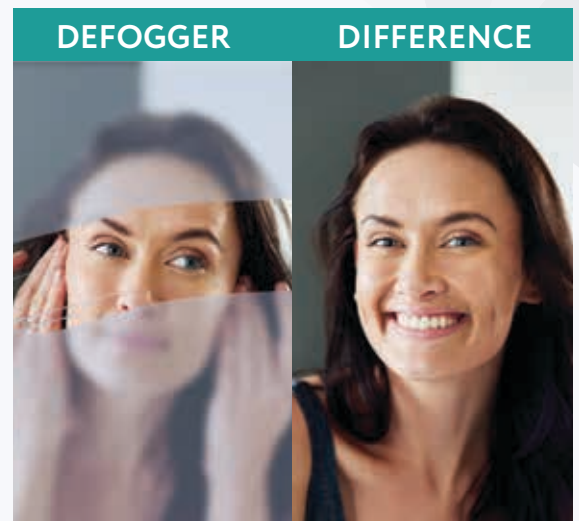

Good
Competitor



BEST
KruggReflect



Better
Competitor



LED SVANGE MEDICINE CABINETS




- Blum 170 degree German Hinges
- Recessed or Surface Mount

Standard Features Lighted Section Only

- E-Z On/Off Memory Sensor Dimmer
 - Built in Electric outlet with USB port
 - 50,000 Hours LED Life
 - CRI 90
 - Defogger Element included (Lighted Section only)
 - Automatic Interior Lighting
 - 3x Lighted Magnifying Mirror on inside
-
- 5000 Kelvins Light Temp



LED MEDICINE CABINET

	Product ID	List Price
	Svange 2430 L 24" x 30" LED Cabinet Lumens 3100	\$1,150
	Svange 2430 R 24" x 30" LED Cabinet Lumens 3100	\$1,150
	Svange 2436 L 24" x 36" LED Cabinet Lumens 3720	\$1,244
	Svange 2436 R 24" x 36" LED Cabinet Lumens 3720	\$1,244
	Svange 2442 L 24" x 42" LED Cabinet Lumens 4100	\$1,832
	Svange 2442 R 24" x 42" LED Cabinet Lumens 4100	\$1,832

LED SVANGE MEDICINE CABINETS





- Blum 170 degree German Hinges
- Recessed or Surface Mount

Standard Features Lighted Section Only

- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included (Lighted Section only)
- Automatic Interior Lighting
- 3x Lighted Magnifying Mirror on inside
- 5000 Kelvins Light Temp



COMBO 24" WIDE LIGHTED CABINET + 12" WIDE NON-LIGHTED CABINET

	Product ID	List Price
	Svange 3636 R	\$1,905
	36" x 36" LED Cabinet Lumens 3720	
	Svange 3642 R	\$2,809
	36" x 42" LED Cabinet Lumens 4100	
	Svange 3636 L	\$1,905
	36" x 36" LED Cabinet Lumens 3720	
	Svange 3642 L	\$2,809
	36" x 42" LED Cabinet Lumens 4100	

LED SVANGE MEDICINE CABINETS

- Blum 170 degree German Hinges
- Recessed or Surface Mount

Standard Features Lighted Section Only

- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included (Lighted Section only)
- Automatic Interior Lighting
- 3x Lighted Magnifying Mirror on inside
- 5000 Kelvins Light Temp



COMBO 24" WIDE LIGHTED CABINET + 18" WIDE NON-LIGHTED

	Product ID	List Price
--	------------	------------



Svange 4236 R
42"x36" LED Cabinet
Lumens 3720

\$2,031

Svange 4242 R
42" x 42" LED Cabinet
Lumens 4100

\$2,993



Svange 4236 L
42" x 36" LED Cabinet
Lumens 3720

\$2,031

Svange 4242 L
42" x 42" LED Cabinet
Lumens 4100

\$2,993



LED SVANGE MEDICINE CABINETS



STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- Defogger Element included
(Lighted Section only)
- 3x Lighted Magnifying Mirror on inside
- Blum 170 degree German Hinges
- Automatic Interior Lighting
- Recessed or Surface Mount
- CRI 90
- 5000 Kelvins Light Temp

COMBO OF QTY 2 LIGHTED 24"X36" CABINETS

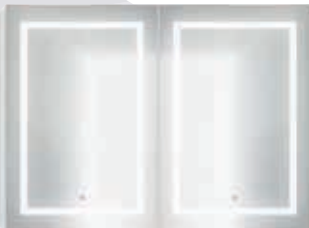	Product ID	List Price
	Svange 4836 D 48"x36" Lighted Cabinets Lumens 7440	\$2,483
	Svange 4842 D 48"x42" Lighted Cabinets Lumens 8200	\$3,722

LED SVANGE MEDICINE CABINETS

- Blum 170 degree German Hinges
- Recessed or Surface Mount

Standard Features Lighted Section Only

- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included (Lighted Section only)
- Automatic Interior Lighting
- 3x Lighted Magnifying Mirror on inside
- 5000 Kelvins Light Temp



COMBO 24" LIGHTED CABINET 2 QTY 12" NON-LIGHTED CABINETS

	Product ID	List Price
	Svange 4836 LLR	\$2,546
	48"x36" LED Cabinet Lumens 3720	
	Svange 4842 LLR	\$3,752
	48" x 42" LED Cabinet Lumens 4100	
	Svange 4836 LRR	\$2,546
	48"x 36" LED Cabinet Lumens 3720	
	Svange 4842 LRR	\$3,752
	48"x 42" LED Cabinet Lumens 4100	

LED SVANGE MEDICINE CABINETS

- Blum 170 degree German Hinges
- Recessed or Surface Mount

Standard Features Lighted Section Only

- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included (Lighted Section only)
- Automatic Interior Lighting
- 3x Lighted Magnifying Mirror on inside
- 5000 Kelvins Light Temp



COMBO 24" LIGHTED CABINET 2 QTY 18" NON-LIGHTED CABINETS

	Product ID	List Price
	Svange 6036 LRR 60"x36" LED Cabinet Lumens 3720	\$2,798
	Svange 6042 LRR 60" x 42" LED Cabinet Lumens 4100	\$4,676
	Svange 6036 LLR 60"x 36" LED Cabinet Lumens 3720	\$2,798
	Svange 6042 LLR 60"x 42" LED Cabinet Lumens 4100	\$4,676

LED SVANGE MEDICINE CABINETS



- Blum 170 degree German Hinges
- Recessed or Surface Mount

Standard Features Lighted Section Only

- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included (Lighted Section only)
- Automatic Interior Lighting
- 3x Lighted Magnifying Mirror on inside
- 5000 Kelvins Light Temp



COMBO OF TWO 24" LIGHTED CABINETS + 12" NON-LIGHTED CABINETS

	Product ID	List Price
--	------------	------------



Svange 6036 DLLR \$3,176
60"x36" LED Cabinet
Lumens 7440

Svange 6042 DLLR \$4,861
60" x 42" LED Cabinet
Lumens 8200



Svange 6036 DLRR \$3,176
60"x 36" LED Cabinet
Lumens 7440

Svange 6042 DLRR \$4,861
60"x 42" LED Cabinet
Lumens 8200

LED SVANGE MEDICINE CABINETS



- Blum 170 degree German Hinges
- Recessed or Surface Mount

Standard Features Lighted Section Only


- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included (Lighted Section only)
- Automatic Interior Lighting
- 3x Lighted Magnifying Mirror on inside
- 5000 Kelvins Light Temp



COMBO OF TWO 24" LIGHTED CABINETS + 18" NON-LIGHTED CABINETS

	Product ID	List Price
	Svange 6636 DLLR 66"x36" LED Cabinet Lumens 7440	\$3,302
	Svange 6642 DLLR 66" x 42" LED Cabinet Lumens 8200	\$4,861
	Svange 6636 DLRR 66"x 36" LED Cabinet Lumens 7440	\$3,302
	Svange 6642 DLRR 66" x 42" LED Cabinet Lumens 8200	\$4,861

LED SVANGE MEDICINE CABINETS

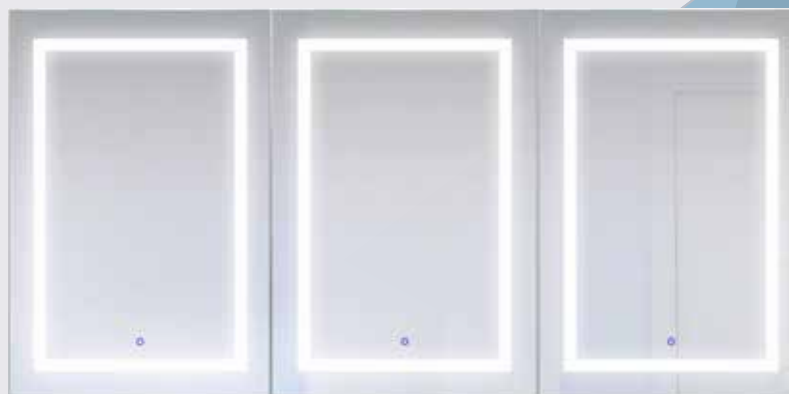

STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- Defogger Element included
(Lighted Section only)
- 3x Lighted Magnifying Mirror on inside
- Blum 170 degree German Hinges
- Automatic Interior Lighting
- Recessed or Surface Mount
- CRI 90
- 5000 Kelvins Light Temp

COMBO OF THREE 24" LIGHTED CABINETS

	Product ID	List Price
--	------------	------------



Svange 7236 TLLR \$3,733
 72"x36" LED Cabinet
 Lumens 11160

Svange 7242 TLLR \$5,601
 72" x 42" LED Cabinet
 lumens 12300



Svange 7236 TLRR \$3,733
 72"x 36" LED Cabinet
 Lumens 11160

Svange 7242 TLRR \$5,601
 72"x 42" LED Cabinet
 lumens 12300

LED SVANGE MEDICINE CABINETS



- Blum 170 degree German Hinges
- Recessed or Surface Mount

Standard Features Lighted Section Only

- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included (Lighted Section only)
- Automatic Interior Lighting
- 3x Lighted Magnifying Mirror on inside
- 5000 Kelvins Light Temp



COMBO OF TWO 24" LIGHTED CABINETS AND TWO 18" NON-LIGHTED CABINETS



Product ID	List Price
------------	------------

Svange 8436 DLLRR 84" x 36" LED Cabinet Lumens 7440	\$3,570
---	---------

Svange 8442 DLLRR 84" x 42" LED Cabinet Lumens 8200	\$5,355
---	---------

LED SVANGE MEDICINE CABINETS

- Blum 170 degree German Hinges
- Recessed or Surface Mount

Standard Features Lighted Section Only

- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included (Lighted Section only)
- Automatic Interior Lighting
- 3x Lighted Magnifying Mirror on inside
- 5000 Kelvins Light Temp



COMBO OF TWO 24" LIGHTED CABINETS AND FOUR 12" NON-LIGHTED CABINETS

	Product ID	List Price
	Svange 9636 DLLLLRRR 96" x 36" LED Cabinet Lumens 7440	\$4,767
	Svange 9642 DLLLLRRR 96" x 42" LED Cabinet Lumens 8200	\$7,150

LED SVANGE MEDICINE CABINETS



- Blum 170 degree German Hinges
- Recessed or Surface Mount

Standard Features Lighted Section Only

- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included (Lighted Section only)
- Automatic Interior Lighting
- 3x Lighted Magnifying Mirror on inside
- 5000 Kelvins Light Temp



COMBO OF TWO 24" LIGHTED CABINETS AND THREE 18" NON-LIGHTED CABINETS

	Product ID	List Price
--	------------	------------



Svange 10236 DLLRRR \$4,515
 102"x 36" LED Cabinet
 Lumens 7440

Svange 10242 DLLRRR \$6,772
 102"x 42" LED Cabinet
 Lumens 8200

LED SVANGE MEDICINE CABINETS



STANDARD FEATURES

- E-Z On/Off Memory Sensor Dimmer
- Built in Electric outlet with USB port
- 50,000 Hours LED Life
- Defogger Element included
(Lighted Section only)
- 3x Lighted Magnifying Mirror on inside
- Blum 170 degree German Hinges
- Automatic Interior Lighting
- Recessed or Surface Mount
- CRI 90
- 5000 Kelvins Light Temp

COMBO OF TWO 24" LIGHTED CABINETS AND FOUR 18" NON-LIGHTED CABINETS

	Product ID	List Price
	Svange 12036 DLLLLRRR 120" x 36" LED Cabinet Lumens 7440	\$5,231
	Svange 12042 DLLLLRRR 120" x 42" LED Cabinet Lumens 8200	\$7,846

LED SVANGE MEDICINE CABINETS



KINETIC COLLECTION




KINETIC COLLECTION



KruggReflect⁺

KruggReflect⁺ Offer a perfectly clear and bright Reflection. It's beautiful turquoise color backing provides a natural looking glass eliminating black edging found on interior mirrors.

KruggClear⁺

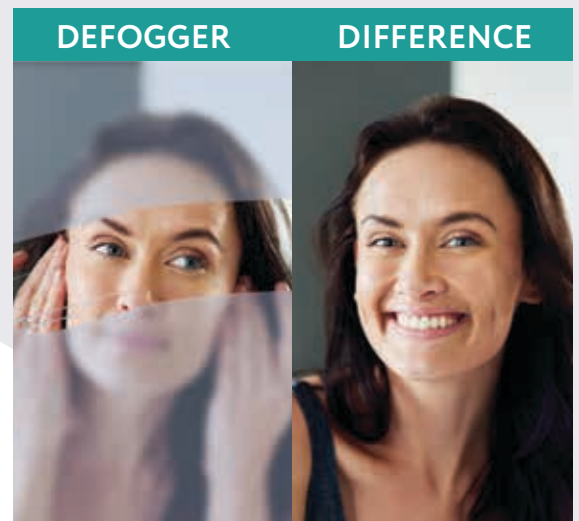

Good
Competitor



BEST
KruggReflect



Better
Competitor



LED KINETIC MEDICINE CABINETS



STANDARD FEATURES

- Blum 170 degree German Hinges
- Recessed or Surface Mount
- E-Z On/Off Memory Sensor Dimmer
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included
- Automatic Interior Lighting
- 5000 Kelvins Light Temp
- Modular units can be combined to create larger cabinets



Product ID	List Price
------------	------------



Kinetic 1530L
15" x 30" LED Cabinet
Lumens 1800

\$982



Kinetic 1530R
15" x 30" LED Cabinet
Lumens 1800

\$982

LED KINETIC MEDICINE CABINETS



STANDARD FEATURES

- Blum 170 degree German Hinges
- Recessed or Surface Mount
- E-Z On/Off Memory Sensor Dimmer
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included
- Automatic Interior Lighting
- 5000 Kelvins Light Temp
- Modular units can be combined to create larger cabinets



	Product ID	List Price
--	------------	------------



Kinetic 2030L
20" x 30" LED Cabinet
Lumens 1800

\$1,076



Kinetic 2030R
20" x 30" LED Cabinet
Lumens 1800

\$1,076

LED KINETIC MEDICINE CABINETS



STANDARD FEATURES

- Blum 170 degree German Hinges
- Recessed or Surface Mount
- E-Z On/Off Memory Sensor Dimmer
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included
- Automatic Interior Lighting
- 5000 Kelvins Light Temp
- Modular units can be combined to create larger cabinets



COMBO OF THREE 15" LIGHTED CABINETS

Product ID	List Price
------------	------------



Kinetic 4530LRR
45" x 30" LED Cabinet
Lumens 5400

\$2,945



Kinetic 4530LLR
45" x 30" LED Cabinet
Lumens 5400

\$2,945

LED KINETIC MEDICINE CABINETS



STANDARD FEATURES

- Blum 170 degree German Hinges
- Recessed or Surface Mount
- E-Z On/Off Memory Sensor Dimmer
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included
- Automatic Interior Lighting
- 5000 Kelvins Light Temp
- Modular units can be combined to create larger cabinets



COMBO OF TWO 20" LIGHTED CABINETS

Product ID	List Price
------------	------------



Kinetic 4030
40" x 30" LED Cabinet
Lumens 3600

\$2,150

LED KINETIC MEDICINE CABINETS



STANDARD FEATURES

- Blum 170 degree German Hinges
- Recessed or Surface Mount
- E-Z On/Off Memory Sensor Dimmer
- 50,000 Hours LED Life
- CRI 90
- Defogger Element included
- Automatic Interior Lighting
- 5000 Kelvins Light Temp
- Modular units can be combined to create larger cabinets



Product ID	List Price
------------	------------



Kinetic 3030
30" x 30" LED Cabinet
Lumens 1800

\$1,284

LED KINETIC MEDICINE CABINETS



PLAZA COLLECTION

Mirrored back panel

Mirrored on back of door



170 degree blum hinges
(soft close hinge)

Recessed or
Surfaced Mounted

PLAZA CABINETS



STANDARD FEATURES

- Blum Soft Close 170 degree Hinges
- Surface Mount or Recess Mount option
- True Clear Glass Shelves Included
- Fully Mirrored, Including Door, Back of Door, and Back panel
- Modular can combine with any other Plaza cabinet (Ganging Kit Included)
- Quality Aluminum Construction
- Reversible Left or Right hinge location

	Product ID	List Price
--	------------	------------



Plaza Cabinet 1230
12" x 30"

\$410



Plaza Cabinet 1530
15" x 30"

\$400



Plaza Cabinet 1830
18" x 30"

\$420

Mirror Side Kit

\$73

PLAZA CABINETS

STANDARD FEATURES

- Blum Soft Close 170 degree Hinges
- Surface Mount or Recess Mount option
- True Clear Glass Shelves Included
- Fully Mirrored, Including Door, Back of Door, and Back panel
- Modular can combine with any other Plaza cabinet (Ganging Kit Included)
- Quality Aluminum Construction
- Reversible Left or Right hinge location



	Product ID	List Price
	Plaza Cabinet 2030 20" x 30"	\$460
	Plaza Cabinet 2430 24" x 30"	\$560
	Mirror Side Kit	\$73

PLAZA CABINETS

STANDARD FEATURES

- Blum Soft Close 170 degree Hinges
- Surface Mount or Recess Mount option
- True Clear Glass Shelves Included
- Fully Mirrored, Including Door, Back of Door, and Back panel
- Modular can combine with any other Plaza cabinet (Ganging Kit Included)
- Quality Aluminum Construction
- Reversible Left or Right hinge location
- 5000 Kelvins Light Temp



		Product ID	List Price
		Plaza Cabinet 4830 48" x 30"	\$1,380
		Plaza Cabinet 6030 60" x 30"	\$1,510
		Plaza Cabinet 7230 72" x 30"	\$1,680
		Mirror Side Kit	\$73



PHONE **347-794-9654**

FAX **800 672 1914**

1957 PIONEER RD BUILDING G
HUNTINGDON VALLEY PA 19006

Orders@krugg.us
www.KruggUSA.com

