

# The Bright Choice

Enlightened Projection with  
Lamp-Free LED Projectors



**The ViewSonic® LS Series of lamp-free LED projectors are the bright and versatile projection choice for education environments.**

These projectors deliver incredible cost savings, amazing colors and incredible light source life for long-term, virtually maintenance-free usage.



**LS610HDH Full HD LED Projector**

- 4,000 ANSI lumens
- Long-lasting 30,000-hour LED light source\*
- 1080p Full HD Resolution with HDR/HLG Support
- Convenient auto power on/off
- 360-degree orientation

**LS610WH WXGA LED Projector**

- 4,000 ANSI lumens
- Long-lasting 30,000-hour LED light source\*
- Convenient auto power on/off
- 360-degree orientation



**LS600W WXGA LED Projector**

- 3,500 ANSI lumens
- Long-lasting 30,000-hour LED light source\*
- Convenient auto power on/off
- 360-degree orientation





### LS500WH WXGA LED Projector

- 2,000 ANSI lumens
- Long-lasting 30,000 hour LED light source\*
- Convenient auto power on/off
- 360-degree orientation



### LS510WH-2 WXGA LED Projector

- 3,000 ANSI lumens
- Long-lasting 30,000-hour LED light source\*
- Convenient auto power on/off
- 360-degree orientation



### LS550WH WXGA Short Throw LED Projector


- 2,000 ANSI lumens
- Long-lasting 30,000 hour LED light source\*
- 0.49 short throw ratio for large images in small spaces
- 360-degree orientation



### LS560WH WXGA LED Projector

- 3,000 ANSI lumens
- Long-lasting 30,000-hour LED light source\*
- 0.49 short throw ratio for large images in small spaces
- 360-degree orientation



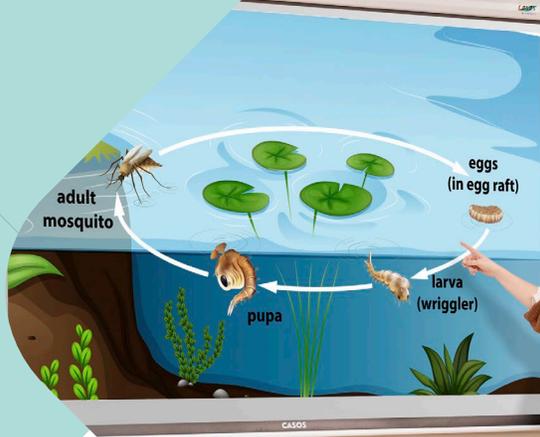

MODEL NAME	LS500WH	LS550WH	LS510WH-2	LS560WH	LS600W	LS610WH	LS610HDH
Light Source	LED	LED	LED	LED	LED	LED	LED
Resolution	WXGA 1280 x 800	WXGA 1280 x 800	WXGA 1280 x 800	WXGA 1280 x 800	WXGA 1280 x 800	WXGA 1280 x 800	FHD 1920 x 1080
Brightness	2,000	2,000	3,000	3,000	3,500	4,000	4,000
Contrast	ANSI Im 3,000,000:1	ANSI Im 3,000,000:1	ANSI Im 3,000,000:1	ANSI Im 3,000,000:1	ANSI Im 3,000,000:1	ANSI Im 3,000,000:1	ANSI Im 3,000,000:1
Aspect Ratio	16:10 (Selectable)	16:10 (Selectable)	16:10 (Selectable)	16:10 (Selectable)	16:10 (Selectable)	16:10 (Selectable)	16:9 (Selectable)
Throw Ratio	1.55 - 1.70	0.49	1.55 - 1.70	0.49	1.37 - 1.64	1.37 - 1.64	1.3-1.56
Lens	1.1x Optical Zoom	Fixed Zoom	1.1x Optical Zoom	Fixed Zoom	1.2x Optical Zoom	1.2x Optical Zoom	1.2x Optical Zoom
H/V Lens Shift	Yes	Yes	Yes	Yes	Yes	Yes	Yes
360-degree Projection	Yes	Yes	Yes	Yes	Yes	Yes	Yes
4 Corner Adjustment	Yes	Yes	Yes	Yes	Yes	Yes	Yes
Connectivity	USB Type-A, 3.5mm Audio In/Out, Control (RS-232), HDMI	USB Type-A, Ethernet LAN (RJ45), 3.5mm Audio In/Out, Control (RS-232), HDMI	USB Type-A, Ethernet LAN (RJ45), 3.5mm Audio In/Out, Control (RS-232), HDMI (x1)	USB Type-A, Ethernet LAN (RJ45), 3.5mm Audio In/Out, Control (RS-232), HDMI (x1)	USB Type-A, Ethernet LAN (RJ45), 3.5mm Audio In/Out, Control (RS-232), HDMI (x2), VGA In/Out, Video In, RCA Audio In/Out (L/R)	USB Type-A, Ethernet LAN (RJ45), 3.5mm Audio In/Out, Control (RS-232), HDMI (x2)	USB Type-A, Ethernet LAN (RJ45), 3.5mm Audio In/Out, Control (RS-232), HDMI (x2)

**For more information contact your ViewSonic representative today.**

viewsonic.com | (888) 881-8781  
salesinfo@viewsonic.com

**Connect With Us**

twitter.com/viewsonic  
facebook.com/viewsoniccorp  
instagram.com/viewsonicedu



\*Light source lifespan may vary based on actual usage and other factors. Program, pricing, specifications and availability are subject to change without notice. Selections, offers, and programs may vary by country. Corporate names and trademarks stated herein are the property of their respective companies. Copyright © 2023, ViewSonic Corporation. All rights reserved [23PRJ-EDU1291]