

ELKAY[®]



Drinking Water Portfolio Model Number Matrix



TABLE OF CONTENTS

- Matrix Guidelines** **2**
- ezH2O® Bottle Filler Models** **2**
 - Enhanced ezH2O Bottle Filler — Water Cooler Combos 2
 - ezH2O Bottle Filler — Water Cooler Combos 3
 - ezH2O, Other Models 3
 - ezH2O Liv Residential and Commercial 4
 - ezH2O In-wall Bottle Filler Models 4
 - Architectural Fountains with Integral ezH2O 5
 - Architectural Fountains with ezH2O Retrofit Bottle Filler 5
 - ezH2O with Architectural Water Cooler 6
 - ezH2O Outdoor Tubular Bottle Filling Stations 6
- Wall Mount Water Cooler Models** **7**
 - EZ and EMABF Family Water Coolers 7
 - Vandal-resistant VRC Water Coolers 8
- SwirlFlo® and Soft Sides® Models** **9**
 - SwirlFlo Water Coolers 9
 - Soft Sides Water Coolers 10
 - SwirlFlo and Soft Sides Fountains 11
- Outdoor Fountains** **12**
 - Outdoor Tubular Fountains 12
 - Outdoor Stone Fountains 12
- Legacy Wall and Floor Mount Models** **13**



All Elkay drinking water solutions are ADA-compliant when properly installed. See product specification sheet for details.

MATRIX GUIDELINES


- **Filtered water coolers** and bottle fillers begin with an “L.”
- **Models ending in “K”** indicate a kit or pick-to-order (PTO) item, which ships in multiple cartons (except for EZWSRK and LZWSRK models).
- **Standard “TL” bi-level design** is left-high/right-low. “TLR” indicates a bi-level reverse configuration with left-low/right-high. EZS and LZS units feature a versatile design that accommodates both.
- **“G” or “GRN” indicates a green**, high-efficiency refrigeration system.
- **Units with “F” indicate glass filler prepped and** require purchase of the glass filler accessory (LK1110 and LK1114) to be field installed. Models with a back or recessed design, such as EHFSA and EFRC, use the LK109A glass filler, which is factory installed.
- **“BL”** means blank.
- **“VR”** indicates vandal-resistant model.



ezH2O® BOTTLE FILLER MODELS

Enhanced ezH2O Bottle Filler — Water Cooler Combos


LZS TL 8 WS L P

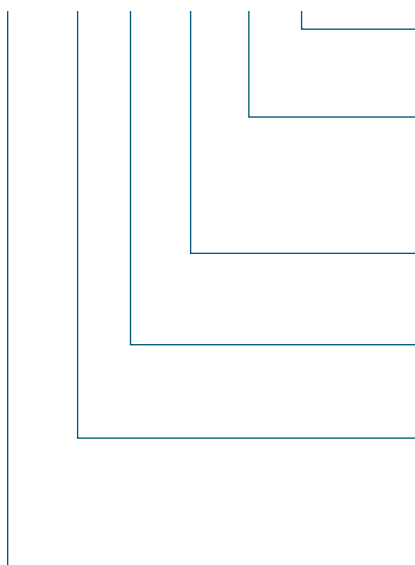

PACKAGING		
P	=	One-box Packaging
COOLER CABINET FINISH		
L	=	Light Gray Granite
S	=	Stainless Steel
BOTTLE FILLER		
WS	=	Water Station
CHILLING CAPACITY		
8	=	8.0 GPH Refrigeration System
CONFIGURATION		
BL	=	Single Unit
TL	=	Versatile Bi-level Unit (left-high/right-low)
FAMILY		
LZS	=	Filtered

ezH2O Bottle Filler — Water Cooler Combos

LZS TL 8 WS VR L 2 K

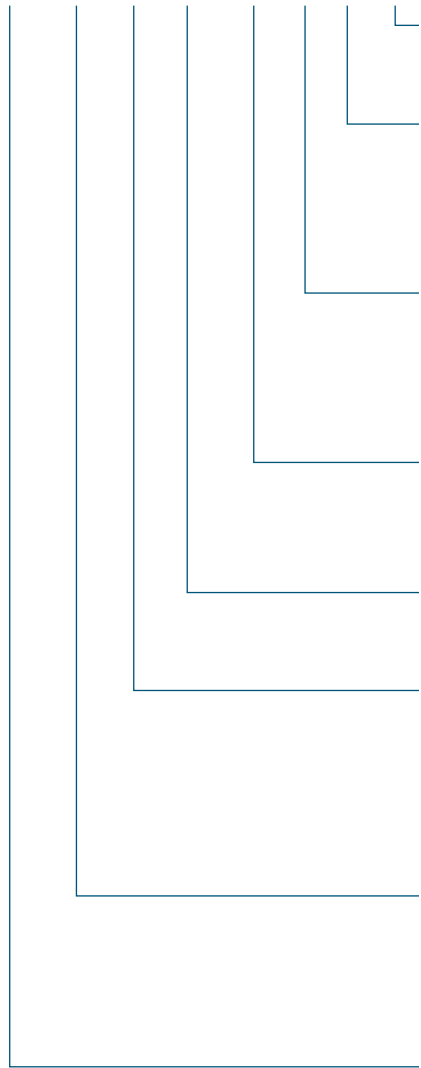


PACKAGING	
K	= Kit (pick-to-order item); ships in multiple cartons
ELECTRICAL SYSTEM	
BL	= 115V/60Hz
2	= 220V/50Hz
3	= 220V/60Hz
COOLER CABINET FINISH	
L	= Light Gray Granite
S	= Stainless Steel
BL	= Stainless Steel (VRC/LVRC models only)
BUBBLER STYLE	
VR	= Optional VR Bubbler (except VRC models)
BL	= Standard Bubbler (VR on VRC/LVRC models; Flexi-Guard® on others)
BOTTLE FILLER	
WS	= Water Station
CHILLING CAPACITY	
8	= 8.0 GPH Refrigeration System
G8	= GRN 8.0 GPH Refrigeration System (EZS/LZS models)
D	= Non-refrigerated Single
DD	= Non-refrigerated Bi-Level
CONFIGURATION	
BL	= Single Unit
TL	= Bi-level Unit (left-high/right-low); EZS/LZS have versatile design
TLR	= Bi-level Reverse Unit (left-low/right-high)
FAMILY	
EZOO	= Non-filtered, (2) Sensor-operated Bubblers / LZOO = Filtered, (2) Sensor-operated Bubblers
EZS	= Non-filtered / LZS = Filtered
EMABF	= Non-filtered / LMABF = Filtered
VRC	= Non-filtered VR / LVRCGRN = Filtered VR
VRCGRN	= Non-filtered GRN / LVRCGRN = Filtered GRN

Other ezH2O Bottle Filler Models:

- **EZWSRK** = Non-filtered Retrofit / **LZWSRK** = Filtered Retrofit
- **EZWSSM** = Non-filtered Surface Mount / **LZWSSM** = Filtered Surface Mount
- **EMASM** = Non-filtered Mechanical Surface Mount
- **EMASMB** = Non-filtered Mechanical Surface Mount Battery-powered with Visual Monitor / **LMASMB** = Filtered
- **EZ8WSSSMC** = Non-filtered Refrigerated Surface Mount / **LZ8WSSSMC** = Filtered Refrigerated Surface Mount
- **DSSBF8S** = Filtered Refrigerated Floor Standing Bottle Filling Station

ezH2O Liv Residential and Commercial


LBWD 2 06 WH K

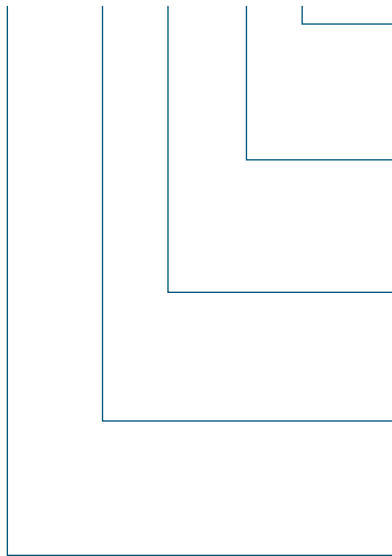

PACKAGING	
C	= Complete (filter box included); ships in single carton (water dispenser)
K	= Kit (no filter box); ships in multiple cartons (water dispenser and chiller)
FRONT GLASS FINISH	
WH	= Aspen White
BK	= Midnight
CHILLING CAPACITY	
06	= Includes 1.5 GPH Remote Chiller
00	= Chiller Not Included
ELECTRICAL SYSTEM	
BL	= 115V/60Hz
2	= 220-240V/50-60Hz
FAMILY	
LBWD	= Filtered, Built-in Water Dispenser, Residential
LBWDC	= Filtered, In-wall Water Dispenser, Commercial

ezH2O In-Wall Bottle Filler Models

 
EZWS M 8 K



PACKAGING	
K	= Kit (pick-to-order item); ships in multiple cartons
CHILLING CAPACITY	
8	= 8.0 GPH Refrigeration System
D	= Non-refrigerated
MOUNTING	
M	= Includes Mounting Frame
BL	= Mounting Frame Not Included (order and purchase separately)
BOTTLE FILLER	
EZWS	= Non-Filtered
EZWSGRN	= Non-Filtered with GRN Chiller
LZWS	= Filtered
LZWSGRN	= Filtered with GRN Chiller

Architectural Fountains with Integral ezH2O


EZWS ERPB M 2 8 K

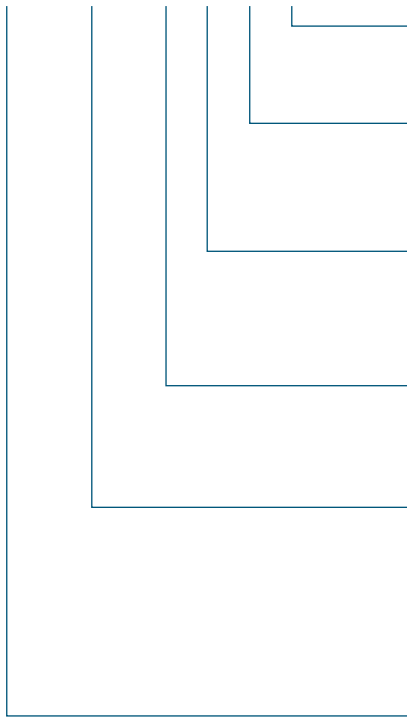

PACKAGING		
K	=	Kit (pick-to-order item); ships in multiple cartons
CHILLING CAPACITY		
8	=	8.0 GPH Refrigeration System
BL	=	Non-refrigerated
CONFIGURATION		
114	=	Single Unit
2, 117, 217	=	Bi-level Unit
MOUNTING		
M	=	Mounting Frame Included (also included with 217 model configuration)
FOUNTAIN FAMILY		
EDFPB	=	Swirlflo
ERPB	=	Swirlflo
LRPB	=	Swirlflo
EDFP	=	Soft Sides
BOTTLE FILLER		
EZWS	=	Non-filtered
LZWS	=	Filtered

Architectural Fountains with ezH2O Retrofit Bottle Filler

 
EZWS ERPB 8 RF



CONFIGURATION		
RF	=	Retrofit (chiller, fountain and lower panel not included)
CHILLING CAPACITY		
8	=	8.0 GPH Refrigeration System
FOUNTAIN FAMILY		
ERPB	=	Swirlflo
ERFP	=	Soft Sides
BOTTLE FILLER		
EZWS	=	Non-filtered
LZWS	=	Filtered

ezH2O with Architectural Water Cooler


EZWS SFGRN 2 8 K

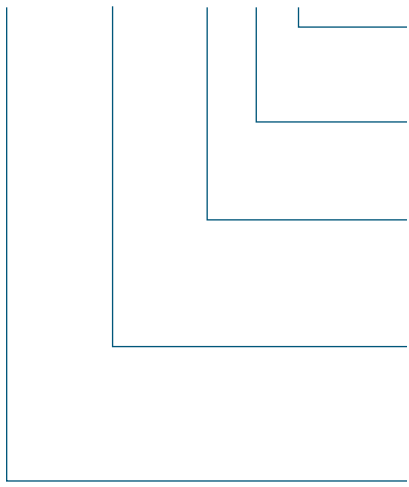

PACKAGING			
K	=	Kit (pick-to-order item); ships in multiple cartons	
CHILLING CAPACITY			
8	=	8.0 GPH Refrigeration System	
CONFIGURATION			
BL	=	Single Unit	
2	=	Bi-level Unit	
FOUNTAIN FAMILY			
SFGRN	=	SwirlFlo with GRN Chiller	
SS	=	Soft Sides	
BOTTLE FILLER			
EZWS	=	Non-filtered	
LZWS	=	Filtered	

ezH2O Outdoor Tubular Bottle Filling Stations

 LK4420BF 1U FRK BLU




FINISH					
BGE	=	Beige	ORN	=	Orange
BLK	=	Black	PUR	=	Purple
BLU	=	Blue	RED	=	Red
BRN	=	Brown	TER	=	Terracotta
EVG	=	Evergreen	WHT	=	White
GRY	=	Gray	YLW	=	Yellow
FREEZE-RESISTANT OPTION					
BL	=	Standard (ships in single carton)			
FRK	=	Freeze-resistant ("K" indicates the complete model); ships in multiple cartons			
CONFIGURATION					
1L	=	Single Bottle Filler, Lower Height Location			
1M	=	Single Bottle Filler, Middle Height Location			
1U	=	Single Bottle Filler, Upper Height Location			
DB	=	Includes Pet Fountain			
MODEL					
LK4400BF	=	Single Pedestal			
LK4405BF	=	Single Wall Mount ADA			
LK4410BF	=	Single Pedestal			
LK4420BF	=	Dual ADA Pedestal			
LK4430BF	=	Triple ADA Pedestal			
LK4481BF	=	Hands-free Foot Pedal Accessory (order and purchase separately); compatible with select models; available in every finish			

WALL MOUNT WATER COOLER MODELS

EZ and EMABF Family Water Coolers

LZS TL VR 8 L F 2JO C

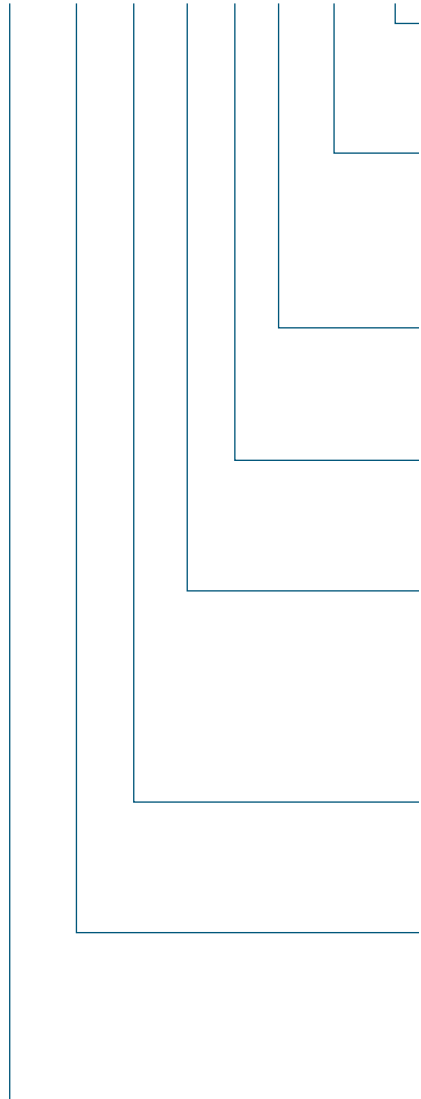

PACKAGING		
C	=	Complete Bi-level Unit
BL	=	Singles will be blank; Bi-level Unit; One-side replacement only
ELECTRICAL SYSTEM		
BL	=	115V/60Hz
2JO	=	220V/50Hz
3JO	=	220V/60Hz
GLASS FILLER OPTION		
F	=	Prepped for Glass Filler (order and purchase separately)
BL	=	Not Prepped for Glass Filler
COOLER CABINET FINISH		
L	=	Light Gray Granite
S	=	Stainless Steel
CHILLING CAPACITY		
8	=	8.0 GPH Refrigeration System
G8	=	GRN 8.0 GPH Refrigeration System (EZS/LZS models only)
D	=	Non-refrigerated, Single
DD	=	Non-refrigerated, Bi-level
BUBBLER STYLE		
VR	=	Optional VR Bubbler (except VRC models)
BL	=	Standard Bubbler (VR on VRC/LVRC models; Flexi-Guard on others)
CONFIGURATION		
BL	=	Single Unit
TL	=	Bi-level Unit (left-high/right-low); EZS/LZS have versatile design
TLR	=	Bi-level Reverse Unit (left-low/right-high)
FAMILY		
EZS	=	Non-filtered / LZS = Filtered
EZO(S)	=	Non-filtered, (1) Sensor-operated Bubbler
EZOO(S)	=	Non-filtered, (2) Sensor-operated Bubblers
EMABF	=	Non-filtered / LMABF = Filtered
LZO(S)	=	Filtered, (1) Sensor-operated Bubbler
LZOO(S)	=	Filtered, (2) Sensor-operated Bubblers

Vandal-resistant VRC Water Coolers

LVRC TL SC FR 8 S F 2JO C

PACKAGING

C	=	Complete Bi-level Unit
BL	=	Singles will be blank; Bi-level Unit; One-side replacement only

ELECTRICAL SYSTEM

BL	=	115V/60Hz
2JO	=	220V/50Hz
3JO	=	220V/60Hz

GLASS FILLER OPTION

F	=	Prepped for Glass Filler (order and purchase separately)
BL	=	Not Prepped for Glass Filler

COOLER CABINET FINISH

S	=	Stainless Steel (not noted on (L)VRCGRN models)
----------	---	---

CHILLING CAPACITY

8	=	8.0 GPH Refrigeration System
D	=	Non-refrigerated Single
DD	=	Non-refrigerated Bi-level

FROST RESISTANCE

FR	=	Optional Frost Resistance (includes heater strip)
BL	=	Frost Resistance Not Included

LOUVER SCREENS

SC	=	Includes Louver Screens
BL	=	Louver Screens Not Included

CONFIGURATION

BL	=	Single Unit
TL	=	Bi-level Unit (left-high/right-low)
TLR	=	Bi-level Reverse Unit (left-low/right-high)


FAMILY

LVRC	=	Filtered VR
LVRCGRN	=	Filtered GRN
LVRCHD	=	Filtered
VRC	=	Non-filtered VR
VRCGRN	=	Non-filtered GRN
VRCHD	=	Non-filtered VR 14 Gauge

SWIRLFLO® AND SOFT SIDES® MODELS

SwirlFlo Water Coolers


ERP B M V 28 2 RA K

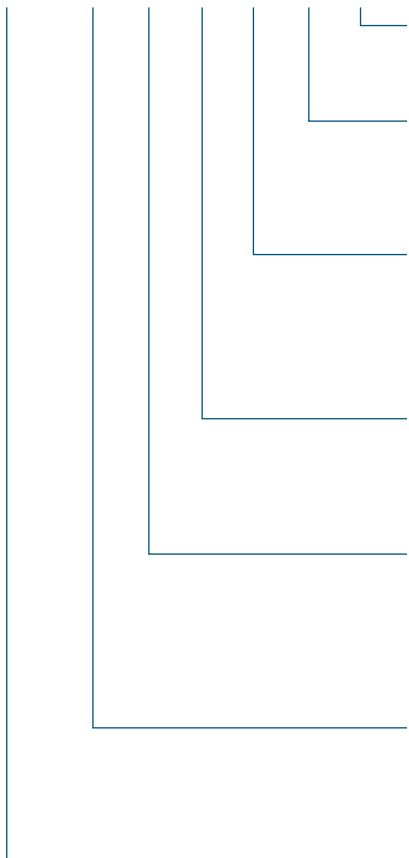

PACKAGING	
K	= Kit (pick-to-order item); ships in multiple cartons
CONFIGURATION	
RA	= Bi-level Reverse Unit (left-low/right-high)
BL	= Standard Bi-Level Unit (left-high/right-low)
ELECTRICAL SYSTEM	
BL	= 115V/60Hz
2	= 220V/50Hz
3	= 220V/60Hz
CHILLING CAPACITY	
8	= Single 8.0 GPH
28	= Bi-level 8.0 GPH
BUBBLER STYLE	
V	= Optional VR Bubbler (except VRC models)
BL	= Standard Bubbler (VR on VRC/LVRC models; StreamSaver™ Flexi-Guard on GRN models; standard Flexi-Guard on others)
MOUNTING	
M	= Includes Mounting Frame
BL	= Mounting Frame Not Included (order and purchase separately)
FAMILY	
ERP B	= Non-filtered
ERP BGRN	= Non-filtered GRN
ENOB	= Non-filtered Sensor-activated
LRP B	= Filtered
LRP BGRN	= Filtered GRN

Soft Sides Water Coolers

ERFP M VR 8 2 F RA K

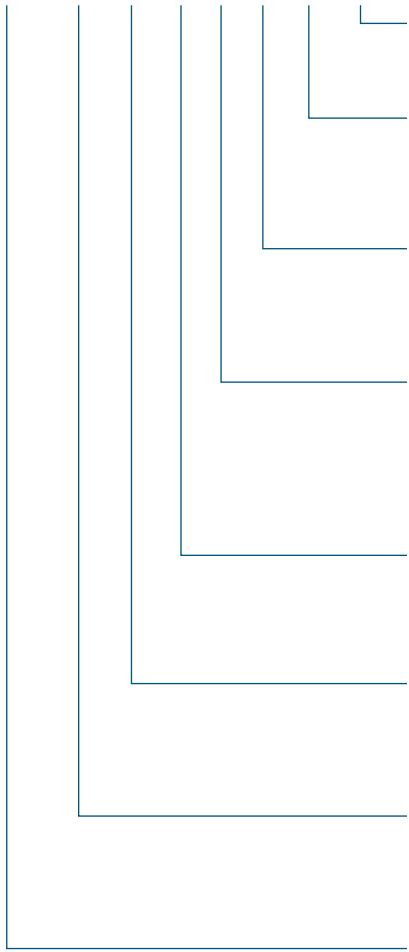

PACKAGING

K	=	Kit (pick-to-order item); ships in multiple cartons
----------	---	---

CONFIGURATION

RA	=	Bi-level Reverse Unit (left-low/right-high)
BL	=	Standard Bi-level Unit (left-high/right-low)

GLASS FILLER OPTION

F	=	Prepped for Glass Filler (order and purchase separately)
BL	=	Not Prepped for Glass Filler

ELECTRICAL SYSTEM

BL	=	115V/60Hz
2	=	220V/50Hz
3	=	220V/60Hz

CHILLING CAPACITY

8	=	Single 8.0 GPH
28	=	Bi-level 8.0 GPH

BUBBLER STYLE

VR	=	Optional VR Bubbler
BL	=	Standard Flexi-Guard Bubbler

MOUNTING


M	=	Includes Mounting Frame
BL	=	Mounting Frame Not Included (order and purchase separately)

FAMILY

ECRSP	=	Non-filtered Slimline®
ERFP	=	Non-filtered
ERO	=	Non-filtered Sensor-activated
LCRSP	=	Filtered Slimline
LNFE	=	Filtered Single
LNTE	=	Filtered Bi-level

SwirlFlo and Soft Sides Fountains

 EDFPB M V 117 FP RA C



PACKAGING

C	=	Complete Fountain
K	=	Kit (pick-to-order item); ships in multiple cartons; Freeze-resistant

CONFIGURATION

RA	=	Bi-level Reverse Unit (left-low/right-high)
BL	=	Standard Bi-level Unit (left-high/right-low)

FREEZE PROTECTION OR GLASS FILLER OPTION

FP	=	Freeze Protection
F	=	Prepped for Glass Filler (order and purchase separately)
BL	=	No Option Included

OPTIONS

114	=	Single SwirlFlo (EDFPB)
117	=	Bi-level SwirlFlo (EDFPB)
210	=	Short (non-ADA) Single Soft Sides (EDFP)
214	=	Single Soft Sides (EDFP)
217	=	Bi-level Soft Sides (EDFP)
314	=	Single Slimline® Soft Sides (ECDFPW)
14	=	Single Slimline Soft Sides 14 Gauge (EHWM)
17	=	Bi-level Slimline Soft Sides 14 Gauge (EHWM)
214	=	Single Soft Sides 14 Gauge (EHW)
217	=	Bi-level Soft Sides 14 Gauge (EHW)

BUBBLER STYLE

V	=	Optional VR Bubbler (except VRC models)
BL	=	Standard Flexi-Guard Bubbler

MOUNTING

M	=	Includes Surface Mounting Plate
BL	=	No Mounting Included (must purchase in-wall carrier separately, except for models EDFP210C, EDFP214, EDFPB114C and ECDFPW)

FAMILY


EDFPB	=	Non-filtered SwirlFlo
EDFPBW	=	Single with Backpanel
EDFP	=	Non-filtered Soft Sides
ECDFPW	=	Non-filtered Slimline Soft Sides
EHW	=	Non-filtered Soft Sides 14 Gauge

NOTE: The Premium Composite models are indicated with an R, such as EDFP214RC and EDFPVR217RFPK.

OUTDOOR FOUNTAINS

Outdoor Tubular Fountains

 4405 FRK RED




FINISH					
BGE	=	Beige	ORN	=	Orange
BLK	=	Black	PUR	=	Purple
BLU	=	Blue	RED	=	Red
BRN	=	Brown	TER	=	Terracotta
EVG	=	Evergreen	WHT	=	White
GRY	=	Gray	YLW	=	Yellow

OPTIONS	
BL	= Standard; ships in single carton
DB	= Pet Fountain
FRK	= Freeze-resistant ("K" indicates complete model)
SFRK	= Sanitary Freeze-resistant ("K" indicates complete model)

MODEL	
LF4430	= Triple ADA Pedestal
LK4400	= Single Pedestal
LK4405	= Single Wall Mount ADA
LK4410	= Single Pedestal
LK4420	= Dual ADA Pedestal
LK4460YHHB	= Yard Hydrant with Hose Bib
LK4461YHLHB	= Yard Hydrant with Locking Hose Bib
LK4470NLHB	= Non-locking Hose Bib Accessory (replaces 97887C)
LK4471LHB	= Locking Hose Bib Accessory (replaces 97889C)

Outdoor Stone Fountains

 LK4590 SFR (4590 FR FOUNTAIN)



OPTIONS	
BL	= Standard; ships in single carton
FR	= Freeze-resistant; ships in multiple cartons
SFR	= Sanitary Freeze-resistant; ships in multiple cartons

MODEL	
LK4590	= Single ADA Pedestal Arm
LK4591	= Single Pedestal (not ADA)
LK4592	= Single Wall Mount (not ADA)
LK4593	= Single Wall Mount ADA
LK4595	= Dual ADA Pedestal

LEGACY WALL AND FLOOR MOUNT MODELS

EWTLA 8 L F 2 K
EWCA 8 T F 3YJO

PACKAGING	
K	= Kit (pick-to-order item); ships in multiple cartons; EWTLA/LWTLA models
BL	= Singles will be blank; Bi-level Unit; One-side replacement only; ships in single carton

ELECTRICAL SYSTEM	
BL	= 115V/60Hz
2(Y/Z) (JO)	= 220V/50Hz
3(Y/Z) (JO)	= 220V/60Hz

OPTIONS	
F	= Prepped for Glass Filler (order and purchase separately) (except EHfSA and ESWA models)
F	= Glass Filler Included (LK109A, EHfSA and ESWA models)
P	= Foot Pedal Activation
K	= Backpanel Included
BL	= Not Prepped for Glass Filler

COOLER CABINET FINISH	
L	= Light Gray Granite
S	= Stainless Steel
T	= Sandalwood

CHILLING CAPACITY			
3	= 3.0 GPH Refrigeration System	14	= 14.0 GPH Refrigeration System
4	= 4.0 GPH Refrigeration System	16	= 16.0 GPH Refrigeration System
5	= 5.0 GPH Refrigeration System	20	= 20.0 GPH Refrigeration System
8	= 8.0 GPH Refrigeration System	D	= Non-refrigerated
10	= 10.0 GPH Refrigeration System		

FAMILY	
EWA	= Non-filtered Deluxe Wall Mount Single / LWAE = Filtered version
EWTLA	= Non-filtered Deluxe Wall Mount Bi-Level / LWTLA = Filtered version
EWCA	= Non-filtered Compact Wall Mount / LWCE = Filtered version
HEW	= Non-filtered Slant Front Compact Wall Mount
ESWA	= Non-filtered Simulated Semi-recessed
EHfSA	= Non-filtered ADA Wall Mount / OHfA = VR
FD700	= Non-filtered Space-ette® Floor Mount / LFDE = Filtered version
EFA	= Non-filtered Deluxe Floor Mount / LFAE = Filtered version
EFHA	= Non-filtered Deluxe Floor Mount Hot and Cold
EFO	= Non-filtered Deluxe Floor Mount Sensor-activated
EFW	= Non-filtered Deluxe Floor Mount Water-cooled
EFWC	= Non-filtered Deluxe Floor Mount Corrosion-resistant
EFY	= Non-filtered Deluxe Floor Mount Hazardous Location



About Elkay

For more than 101 years, Elkay® Manufacturing has been making innovative products and providing exceptional customer care. Family owned since 1920, Elkay began by making residential butler and pantry sinks. Today, the company has grown to include faucets, foodservice fixtures, water delivery products and architectural millwork in addition to world-class sinks. We are proud to be America's No. 1 selling kitchen sink company, as well as a leading manufacturer of award-winning water delivery products, including the ezH2O® bottle filling station.

Like your family, Elkay has values and traditions that endure. We take pride in offering reliable products that inspire change and leave the world a better place for generations to come. Headquartered in Downers Grove, Illinois, Elkay is American owned and operated providing thousands of jobs that support our families and communities.

ELKAY

1333 Butterfield Road, Suite 200 | Downers Grove, IL 60515
630.574.8484 | elkay.com | ©2021 Elkay Manufacturing Company

(11/21) F-6200-ELK