



TRADITIONAL SPECIFICATIONS

HOSPITALITY DIVISION  
**eurotech**  
LUXURY SHOWER DOORS

# FEATURES

- Anodized aluminum top track, wall jambs, and bottom sill
- (4) hanger roller brackets enclosed inside top track
- Up to 3/8" out of plumb adjustability
- 2 configurations
- (1) 24" round style towel bar with bumper knob on backside & (1) back to back bumper knob
- Standard 3/8" (10mm) clear tempered glass with optional ultra-clear (low iron) tempered glass
- EuroSafe glass film included on both panels (refer to "safety/warranty" for additional information)
- Option for Enduroshield coating to reduce cleaning time by up to 90%



## FINISHES



Chrome




Matte Black




Brushed Nickel

## TRADITIONAL



# HANDLE & TOWEL BAR OPTIONS

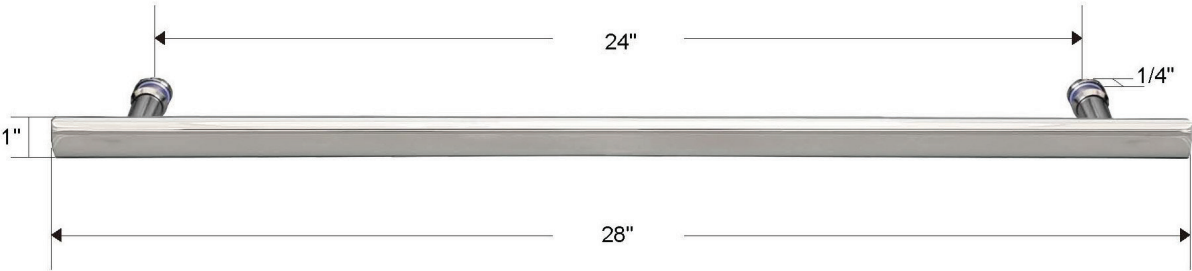


24 inch Ladder Style Towel Bar

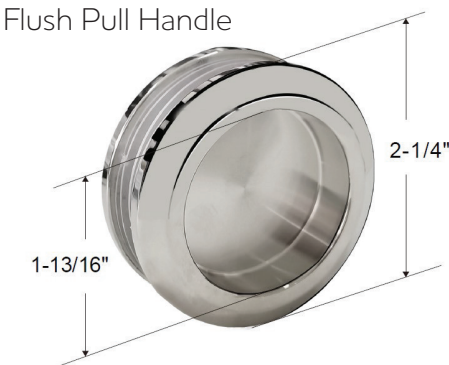


8 inch  
Ladder Style  
Handle

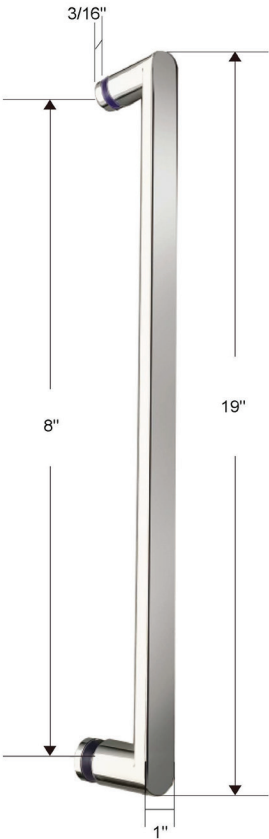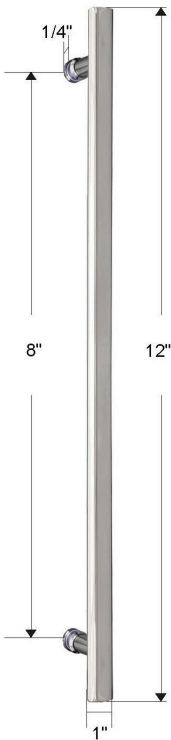

18 inch Flat Style Handle

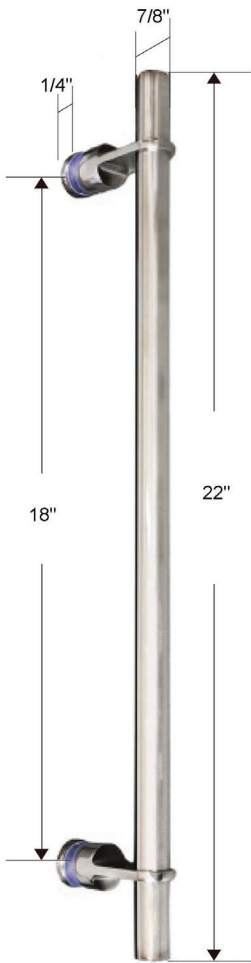


18 inch Ladder Style Handle

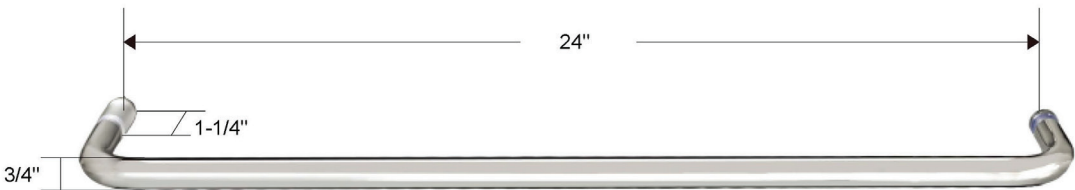



24 inch Rounded Towel Bar

# SPECIFICATIONS

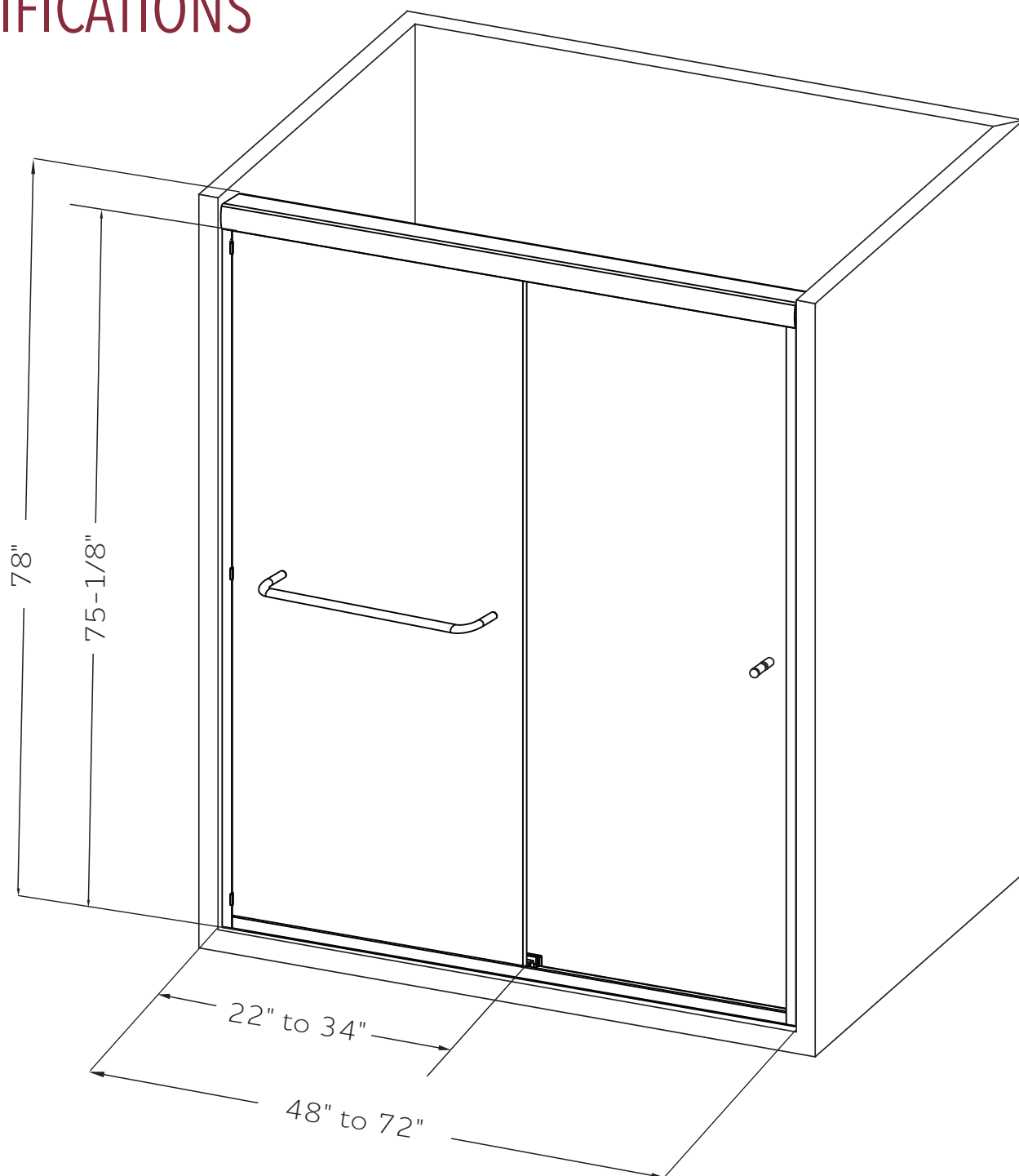


## CONFIGURATIONS

exterior or interior door capability

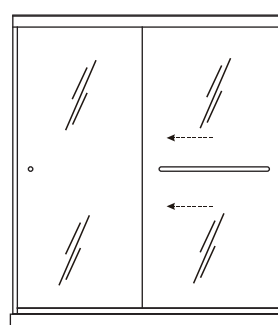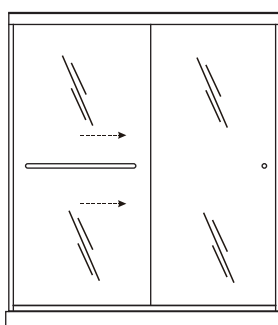




# SPECIFICATIONS

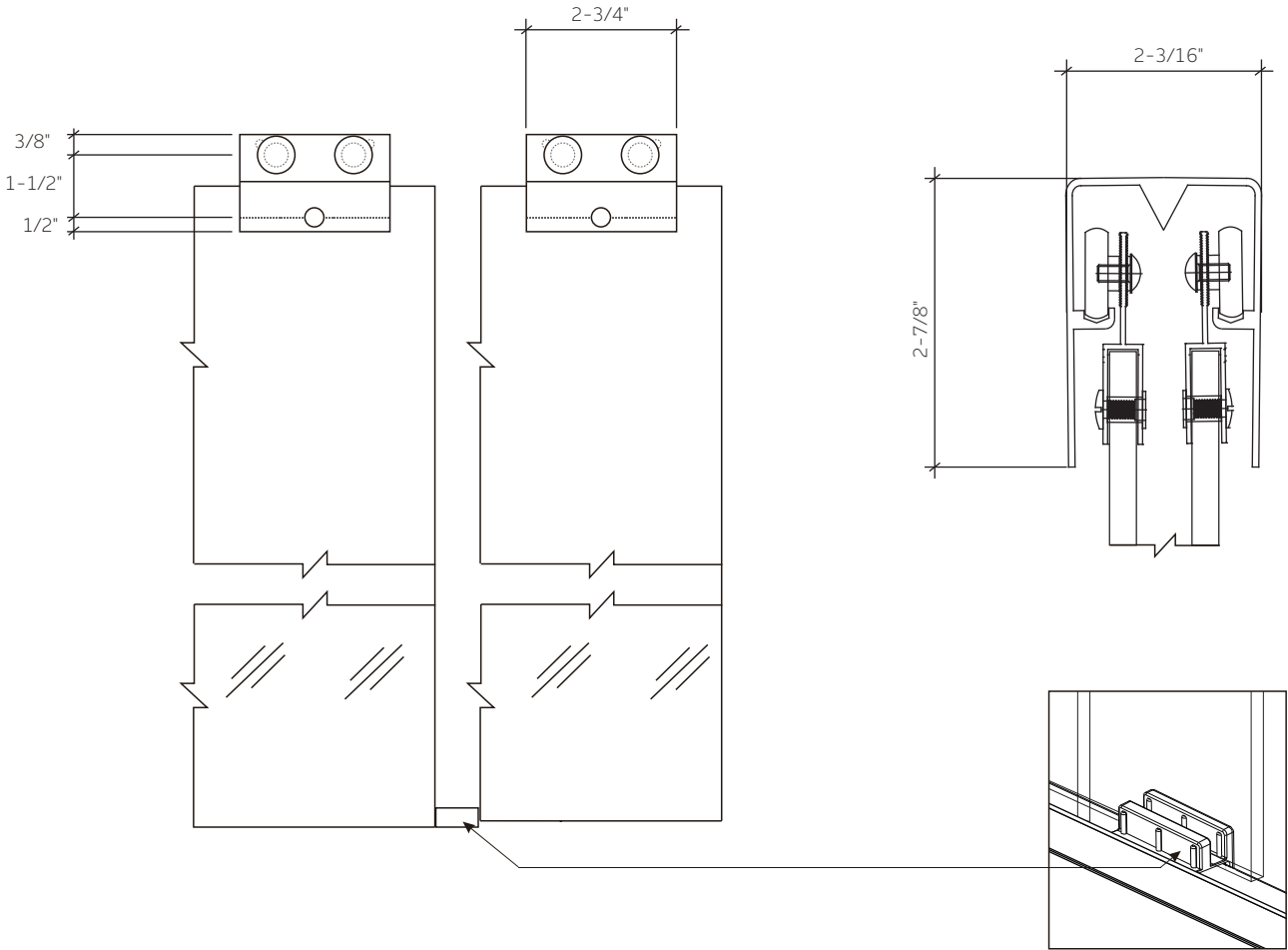

FOOTPRINT FOR BOTTOM SILL

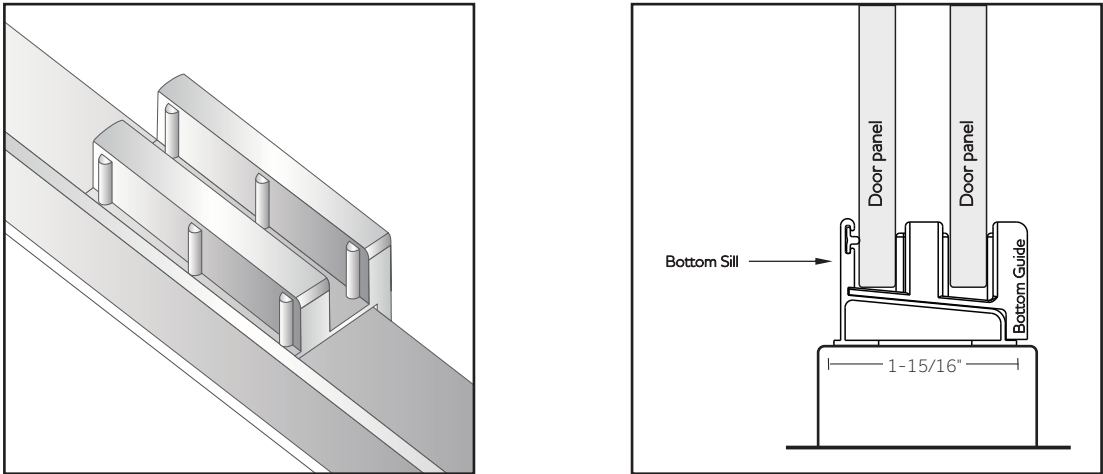

# PARTS LIST

- |                    |                 |
|--------------------|-----------------|
| 1) wall jamb       | 6) door panel   |
| 2) bumper assembly | 7) bottom guide |
| 3) track           | 8) sill         |
| 4) roller bracket  | 9) knob         |
| 5) towel bar       |                 |

