



WINDSOR SPECIFICATIONS

HOSPITALITY DIVISION
eurotech
LUXURY SHOWER DOORS

FEATURES

- 304 stainless steel hardware
- (4) 70mm dual sided top rollers
- (4) 40mm dual sided bottom rollers
- Up to 3/8" out of plumb adjustability
- 2 configurations
- Dual water diverter sets (aluminum and polycarbonate)
- (2) 19" flat style handles with knob on backside
- Standard clear tempered glass with optional ultra-clear (low iron) tempered glass
- 5/16" (8mm) or 3/8" (10mm) glass options
- EuroSafe glass film included on both panels (refer to "safety/warranty" for additional information)
- Option for Enduroshield coating to reduce cleaning time by up to 90%



FINISHES



Polished Stainless



Matte Black




Brushed Stainless





Satin Brass

HANDLE & TOWEL BAR OPTIONS

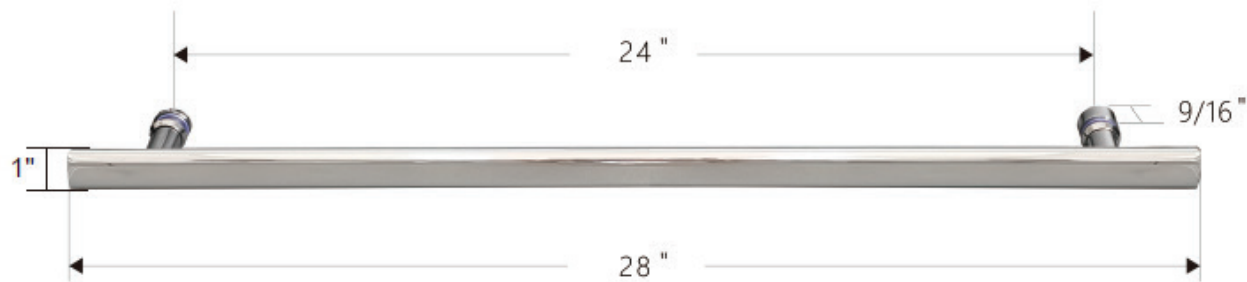


24 inch Ladder Style Towel Bar


Flush Pull Handle

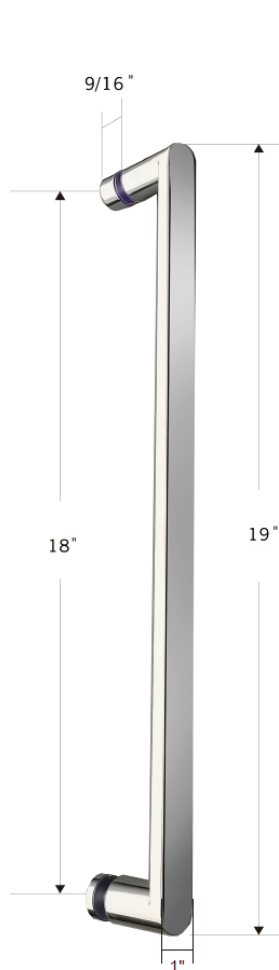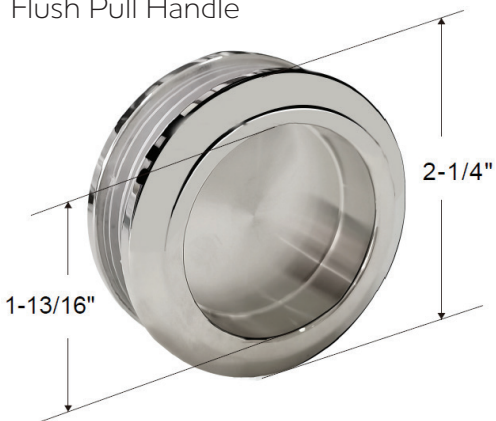

18 inch Flat Style Handle

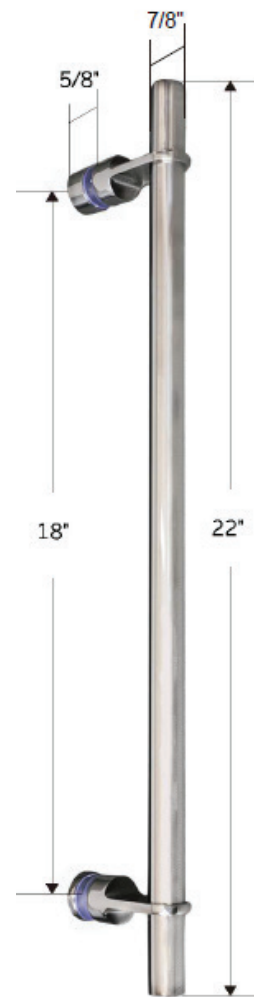

18 inch Ladder Style Handle

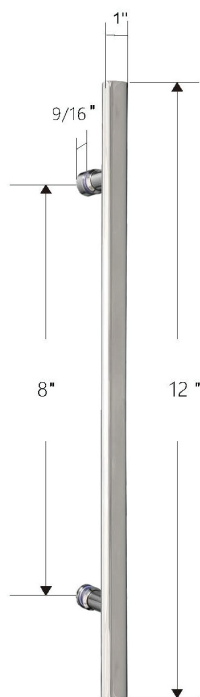


8 inch
Ladder Style
Handle





24 inch Rounded Towel Bar

SPECIFICATIONS

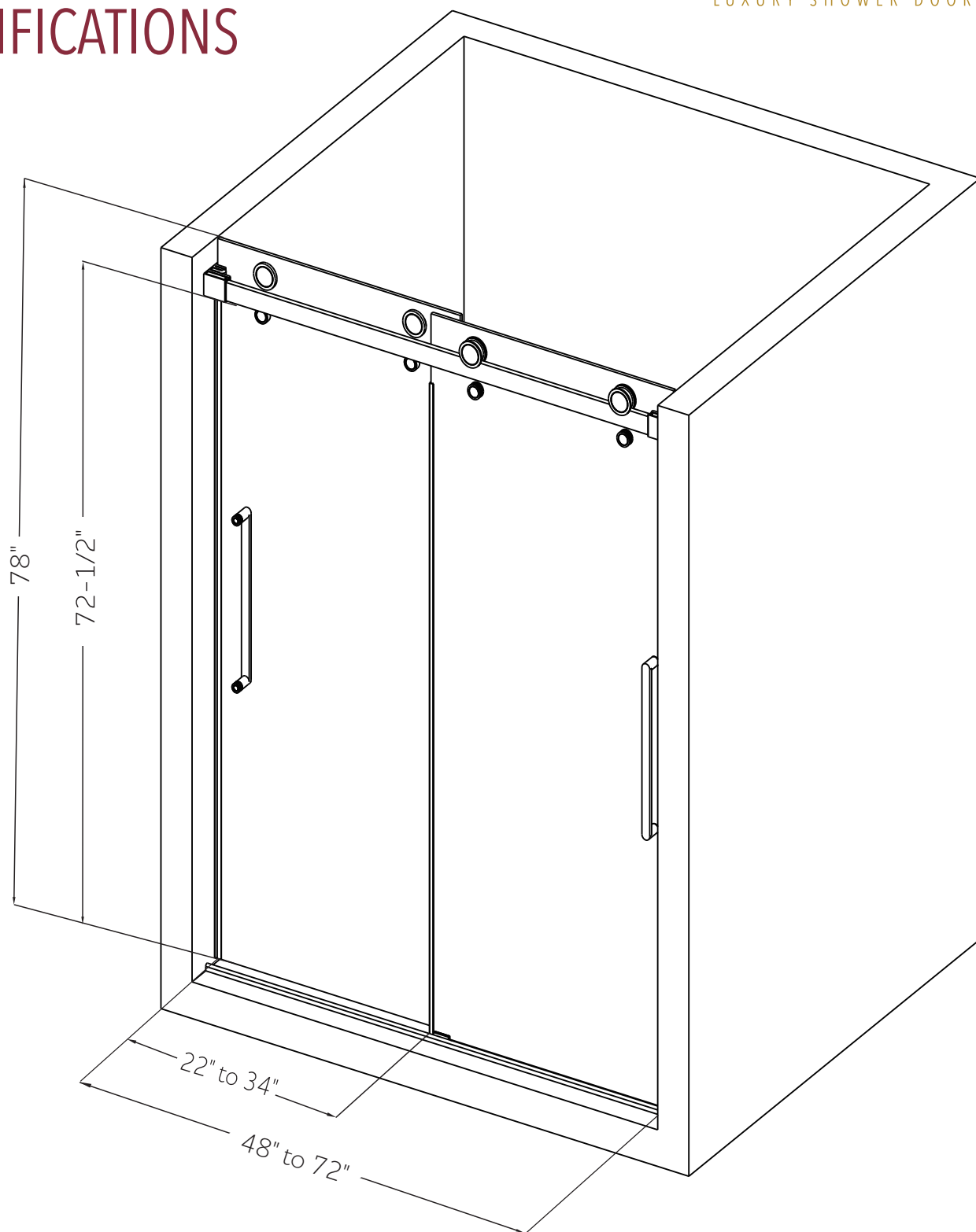


CONFIGURATIONS



exterior or interior door capability

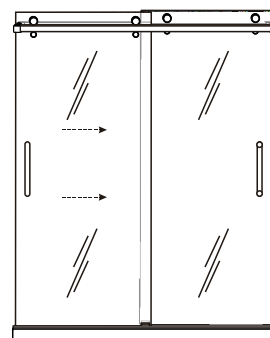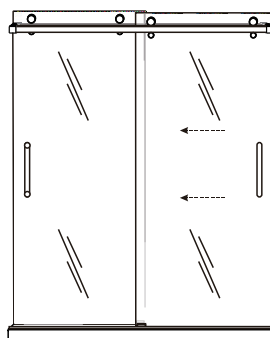



SPECIFICATIONS

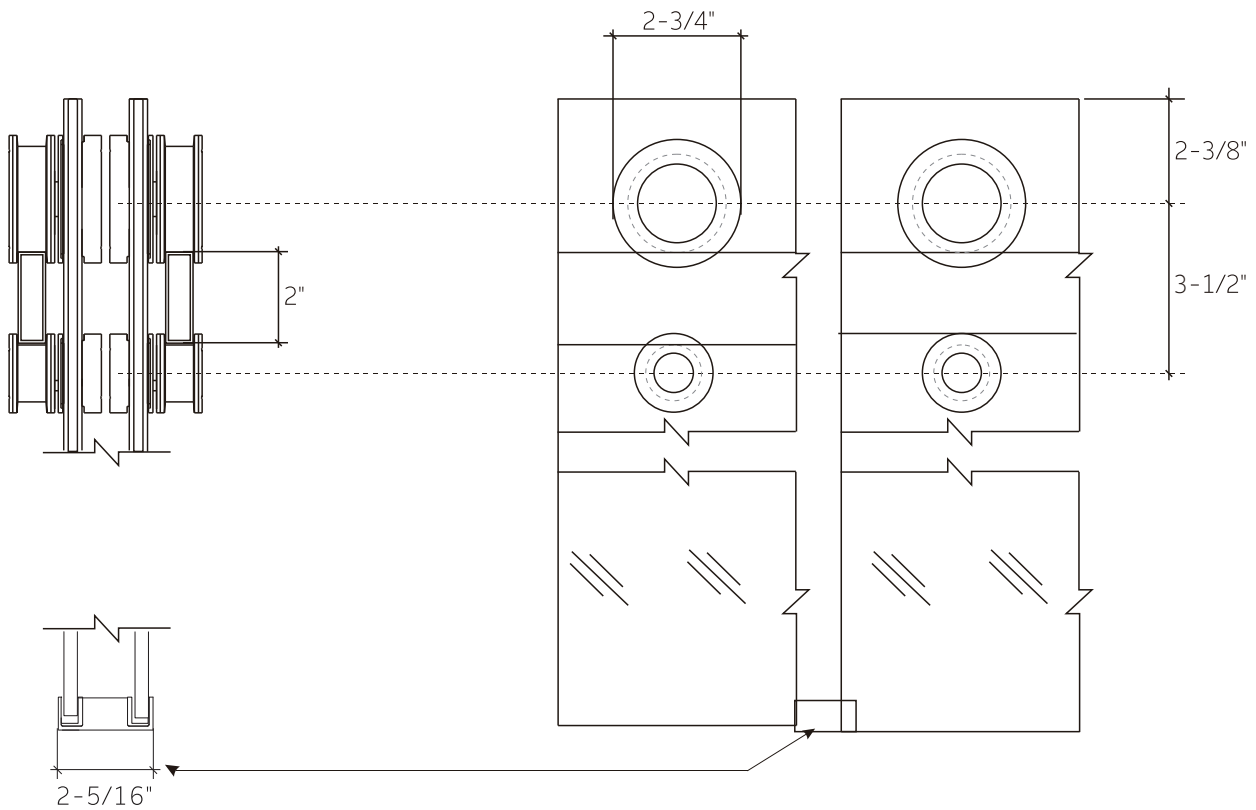

**FOOTPRINT USING
 ALUMINUM WATER GUARD**

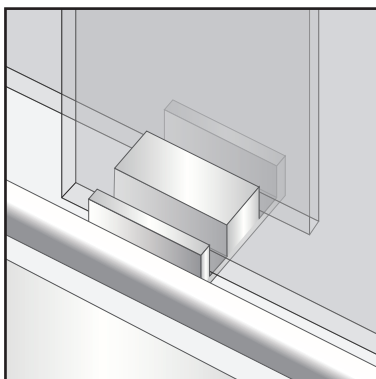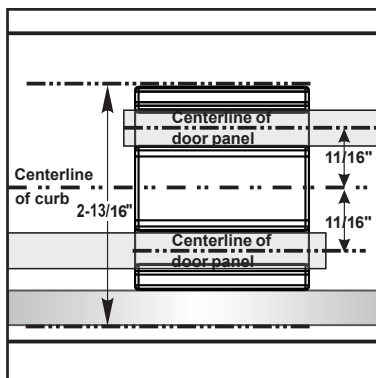

**FOOTPRINT USING
 POLYCARBONATE L-SEAL**

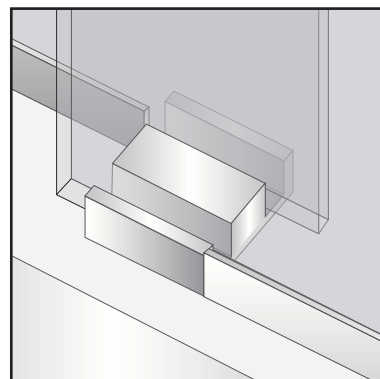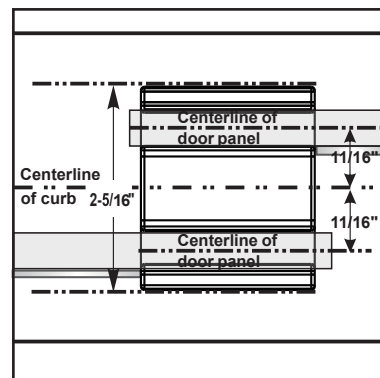

HOSPITALITY DIVISION
eurotech
LUXURY SHOWER DOORS

- 1) wall bracket
- 2) safety bumper
- 3) track
- 4) top roller
- 5) bottom roller
- 6) V-seal
- 7) handle
- 8) door panel
- 9) F-seal
- 10) aluminum water guard
- 11) bottom guide
- 12) L-seal

