



MONACO W/ JAMBS SPECIFICATIONS

HOSPITALITY DIVISION
eurotech
LUXURY SHOWER DOORS

FEATURES

- Anodized aluminum top track and wall jambs
- (8) 45mm dual sided rollers
- Up to 3/8" out of plumb adjustability
- 2 configurations
- Dual water diverter sets (aluminum and polycarbonate)
- (2) 19" flat style handles with knob on backside
- Standard clear tempered glass with optional ultra-clear (low iron) tempered glass
- 5/16" (8mm) or 3/8" (10mm) glass options
- EuroSafe glass film included on both panels (refer to "safety/warranty" for additional information)
- Option for Enduroshield coating to reduce cleaning time by up to 90%



FINISHES



Chrome




Matte Black




Brushed Nickel


HANDLE & TOWEL BAR OPTIONS

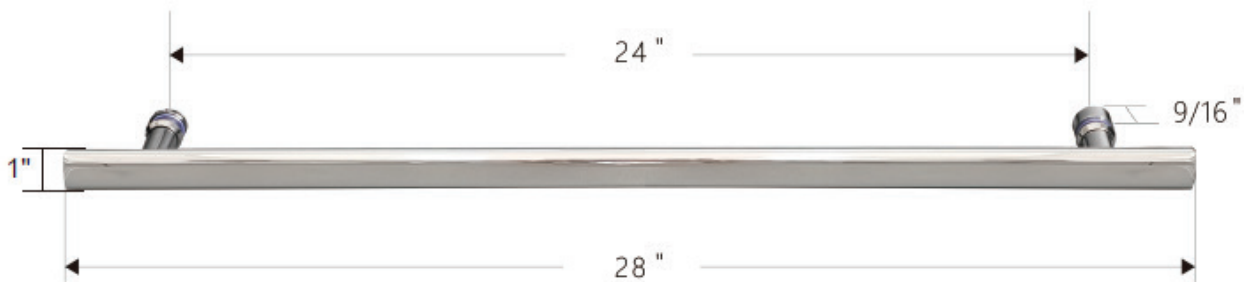


24 inch Ladder Style Towel Bar

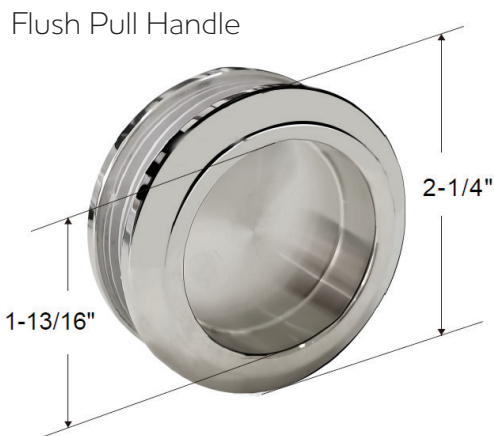


Flush Pull Handle

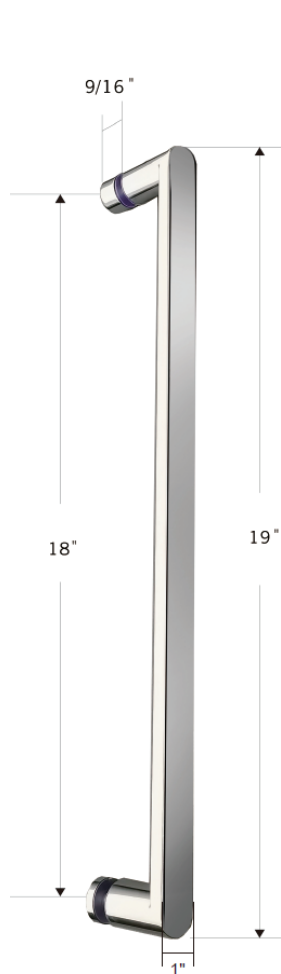


18 inch Flat Style Handle

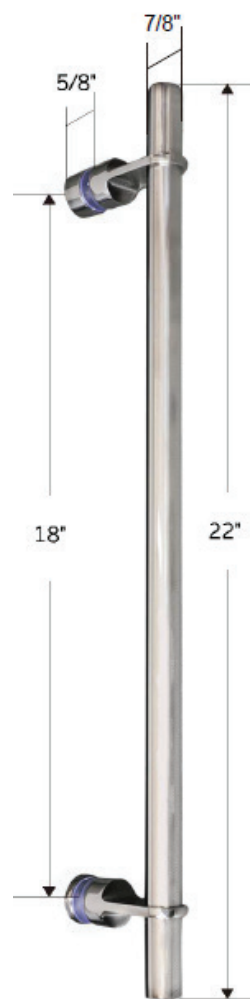

18 inch Ladder Style Handle

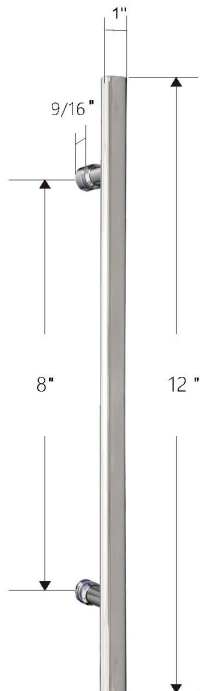


8 inch
Ladder Style
Handle

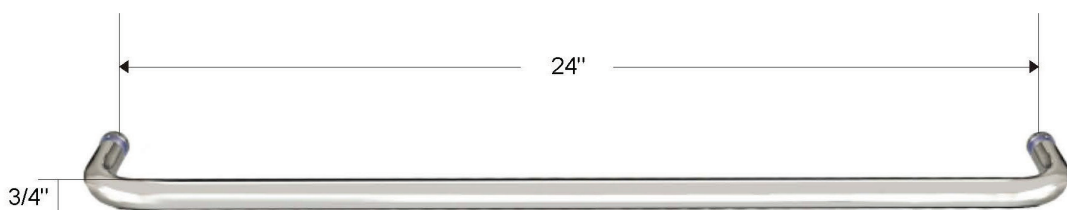



24 inch Rounded Towel Bar

SPECIFICATIONS

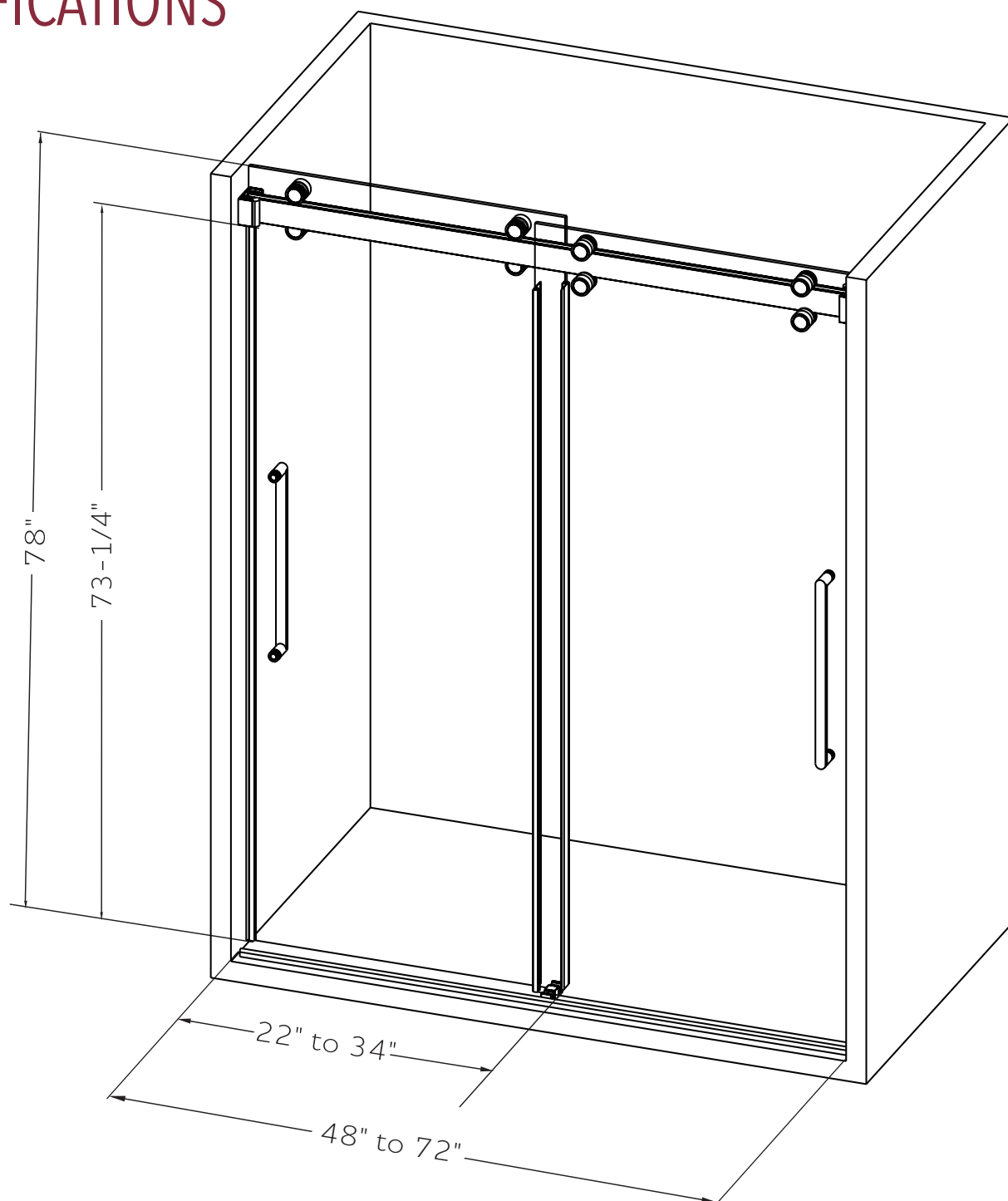


CONFIGURATIONS



exterior or interior door capability

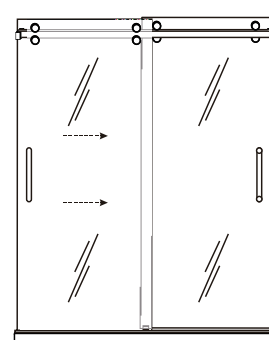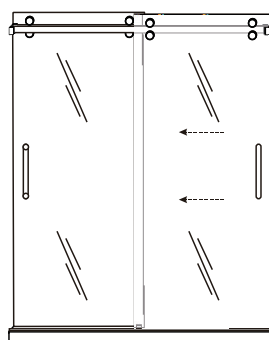



SPECIFICATIONS

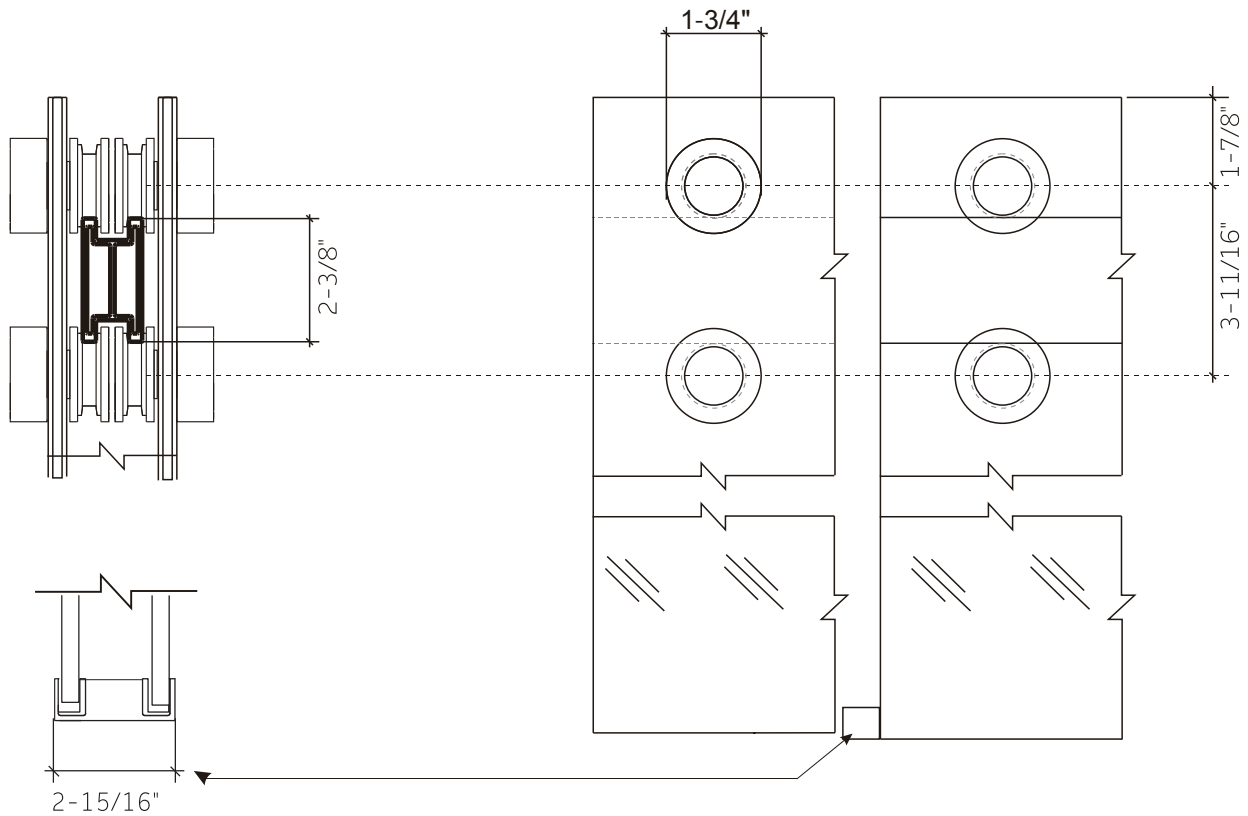

**FOOTPRINT USING
 ALUMINUM WATER GUARD**

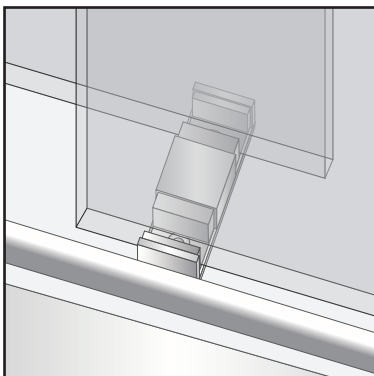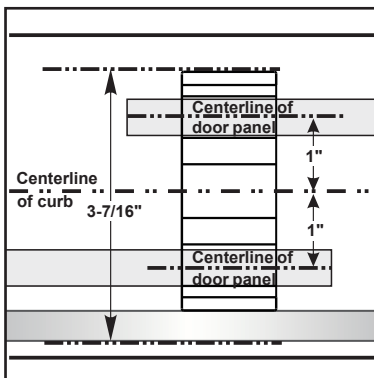

**FOOTPRINT USING
 POLYCARBONATE L-SEAL**

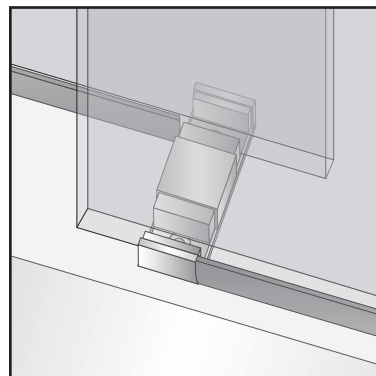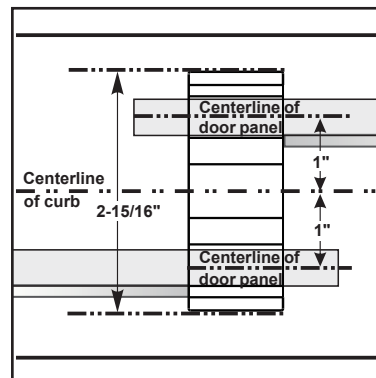

PARTS LIST

- | | |
|------------------|-------------------------|
| 1) wall bracket | 6) handle |
| 2) safety bumper | 7) door panel |
| 3) track | 8) F-seal |
| 4) roller | 9) aluminum water guard |
| 5) wall jamb | 10) bottom guide |
| 5A) jamb guide | 11) L-seal |

