



VITRA-100 SPECIFICATIONS

FEATURES

- 304 Stainless Steel Hardware
- (2) 45mm single sided rollers
- (2) 28mm dual sided anti-jump pins
- Up to 3/8" out of plumb adjustability
- 4 configurations
- Dual water diverter sets (aluminum and polycarbonate)
- 8" square handle with knob on backside
- Standard clear tempered glass with optional ultra-clear (low iron) tempered glass
- 3/8" (10mm) glass option
- EuroSafe glass film included on both panels (refer to "safety/warranty" for additional information)
- Option for Enduroshield treatment to reduce cleaning time by up to 90%



FINISHES



Polished Stainless



Matte Black




Brushed Stainless




Satin Brass


HANDLE & TOWEL BAR OPTIONS

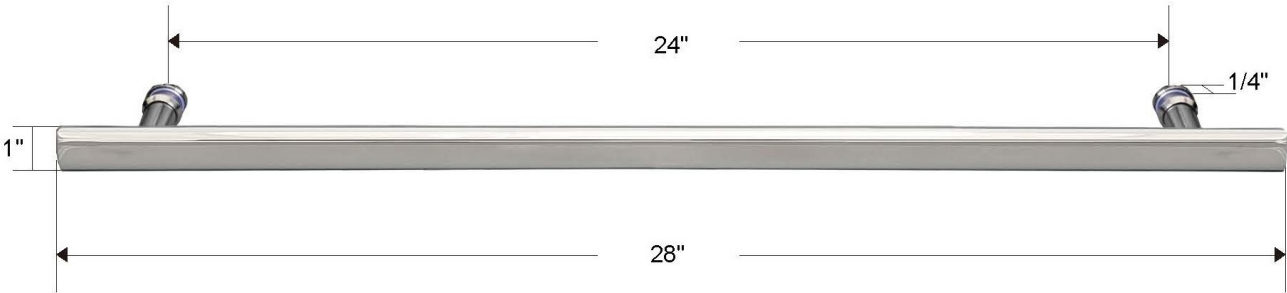


24 inch Ladder Style Towel Bar

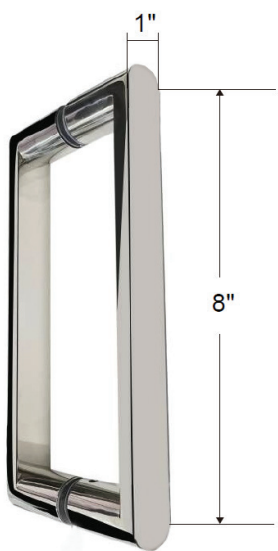


8 inch Back to Back Flat Handle

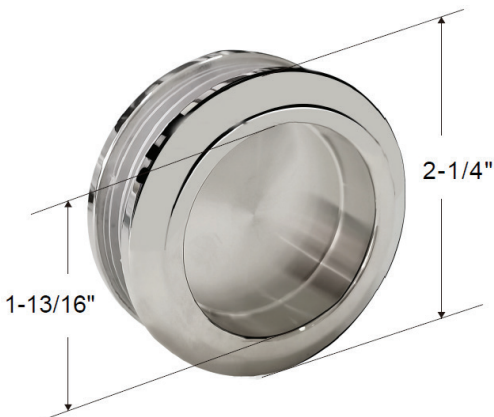


Flush Pull Handle

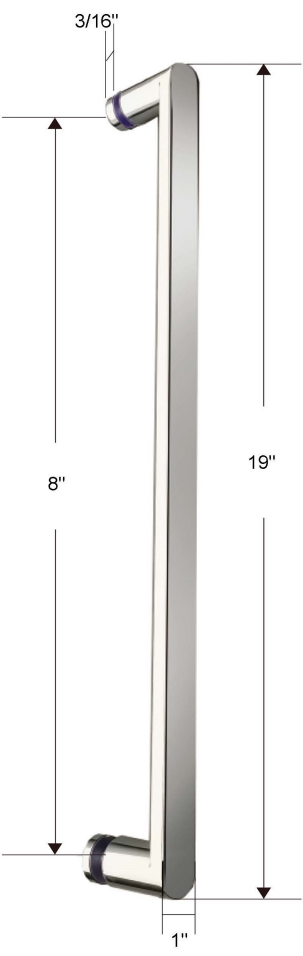

18 inch Flat Style Handle

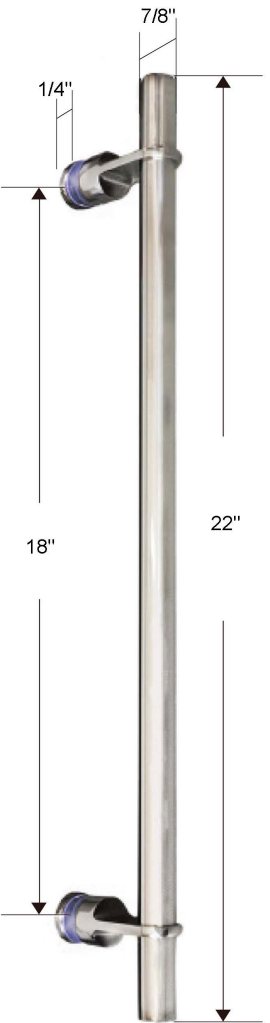


18 inch Ladder Style Handle

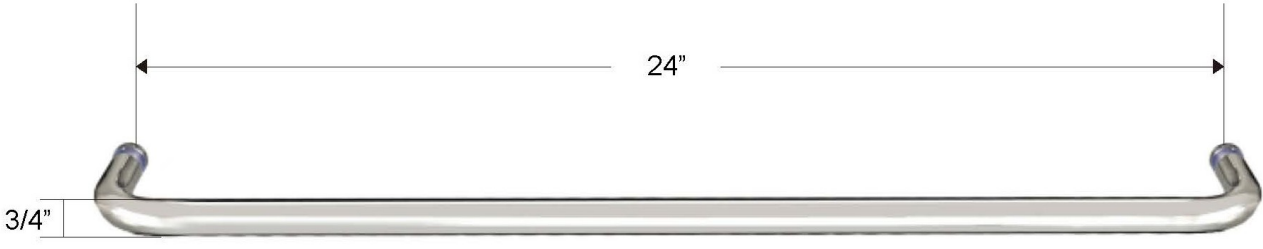



24 inch Rounded Towel Bar

SPECIFICATIONS

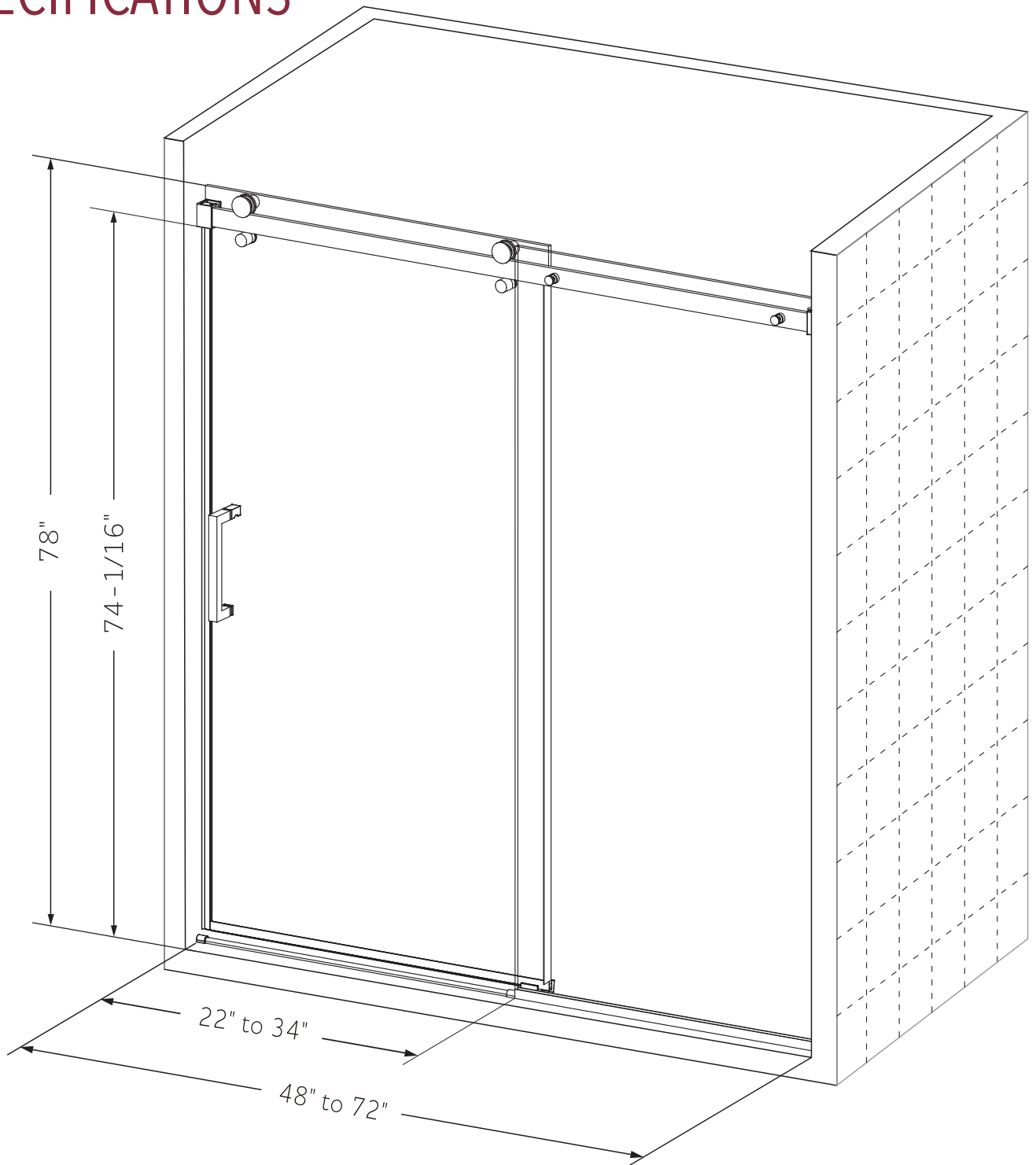


CONFIGURATIONS



exterior or interior door capability

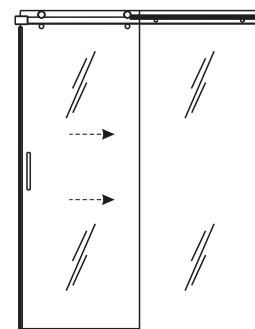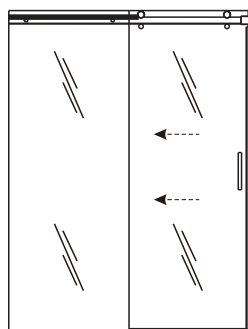



SPECIFICATIONS

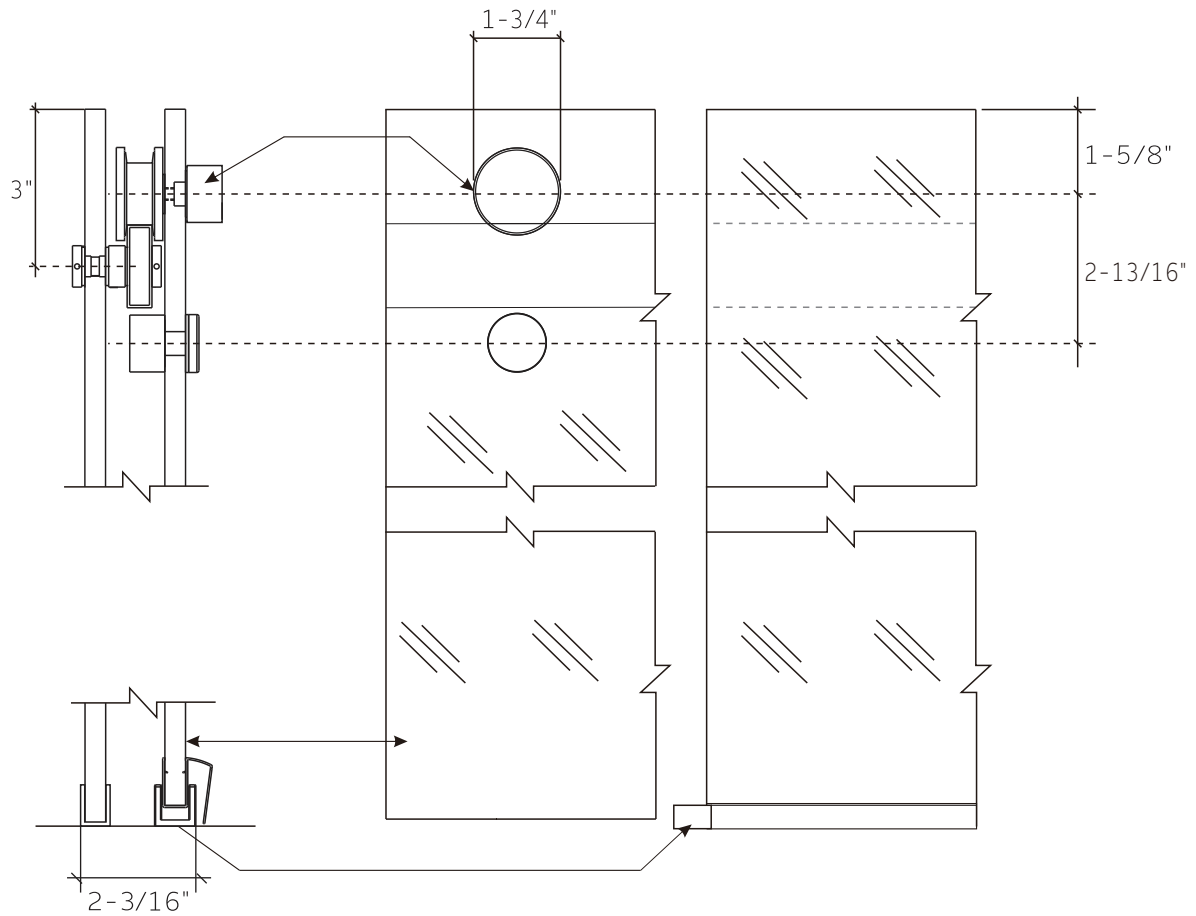

**FOOTPRINT FOR DOOR ON INSIDE
 USING ALUMINUM WATER GUARD**

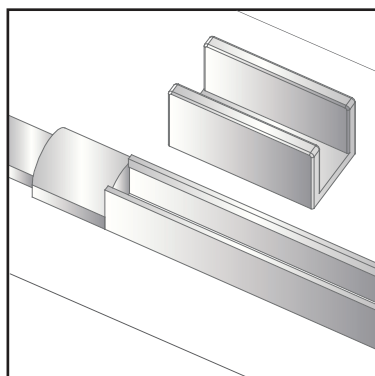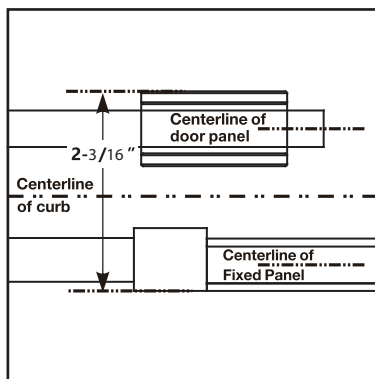

**FOOTPRINT FOR DOOR ON OUTSIDE
 USING ALUMINUM WATER GUARD**

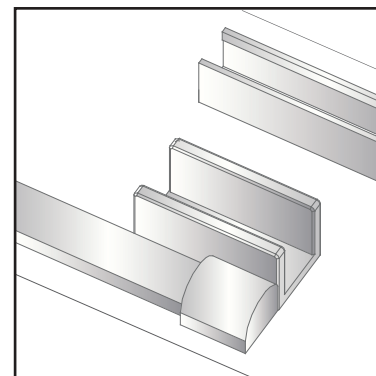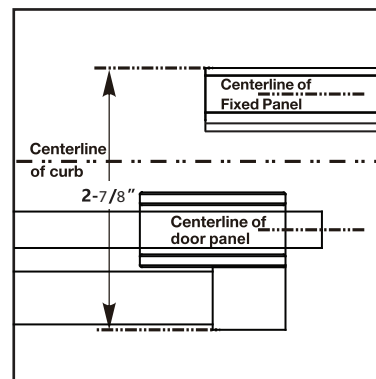

PARTS LIST

- | | |
|-----------------------|--------------------------|
| 1) wall bracket | 10) fixed panel |
| 2) roller | 11) bottom slip-on seal |
| 3) fixed panel holder | 12) aluminum water guard |
| 4) track | 13) end block |
| 5) safety bumper | 14) bottom guide |
| 6) handle | 15) aluminum u-channel |
| 7) V-seal | 16) anti-lift pins |
| 8) door panel | |
| 9) F-seal | |

