



REGENCY SPECIFICATIONS

HOSPITALITY DIVISION
eurotech
LUXURY SHOWER DOORS

FEATURES

- 304 stainless steel hinges and handle
- Wall channel allows for up to 1" width adjustment
- 2 configurations
- Dual water diverter sets (acrylic and polycarbonate)
- 12" ladder style, back to back handle
- Standard 3/8" (10mm) clear tempered glass with optional ultra-clear (low iron) tempered glass
- EuroSafe glass film included on both panels (refer to "safety/warranty" for additional information)
- Option for Enduroshield coating to reduce cleaning time by up to 90%



FINISHES



Chrome




Matte Black




Brushed Nickel

HANDLE & TOWEL BAR OPTIONS

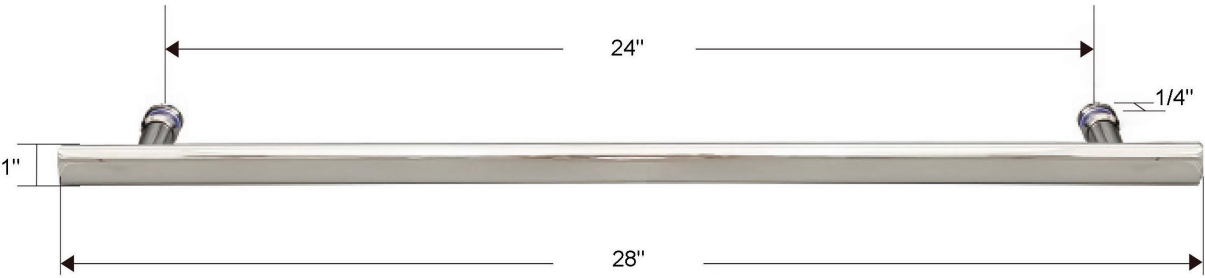


24 inch Ladder Style Towel Bar

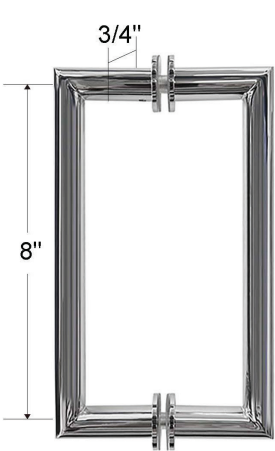


8 inch Miter Style Handle




8 inch Round Handle

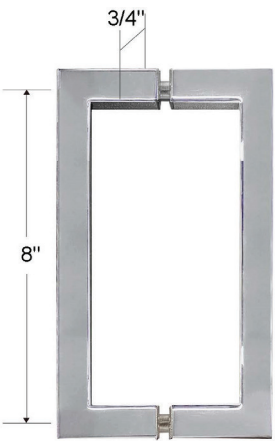


8 inch Square Handle

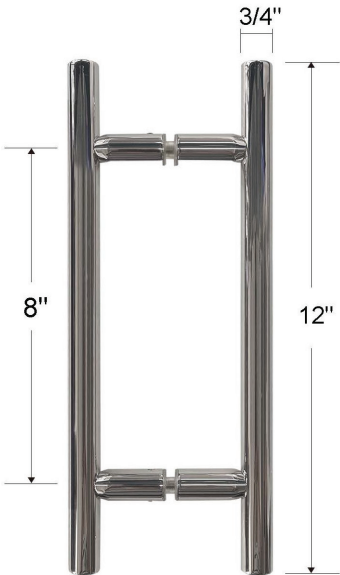

8 inch Ladder Style Handle

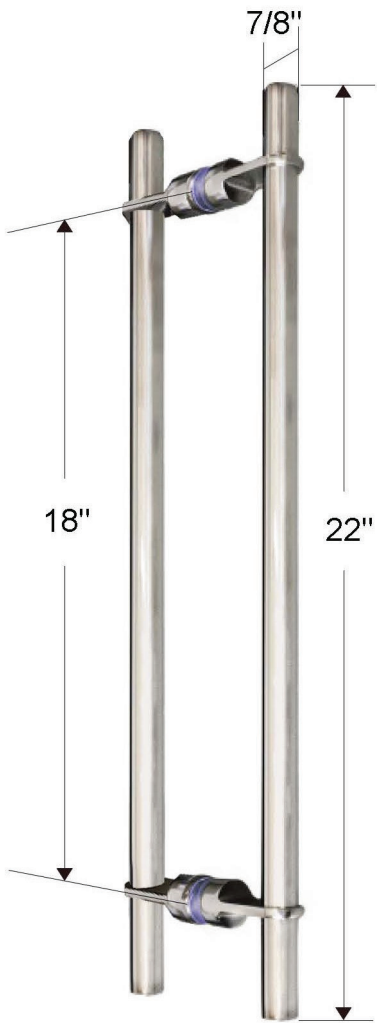


18 inch Ladder Style Handle

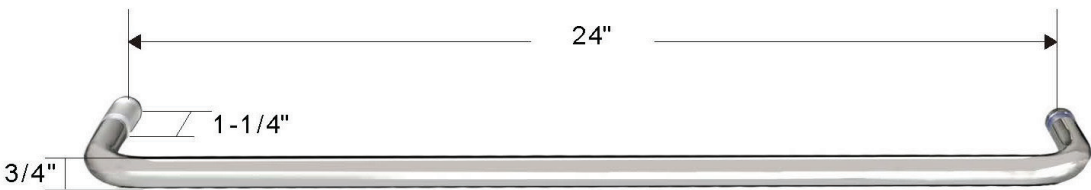



24 inch Rounded Towel Bar

SPECIFICATIONS

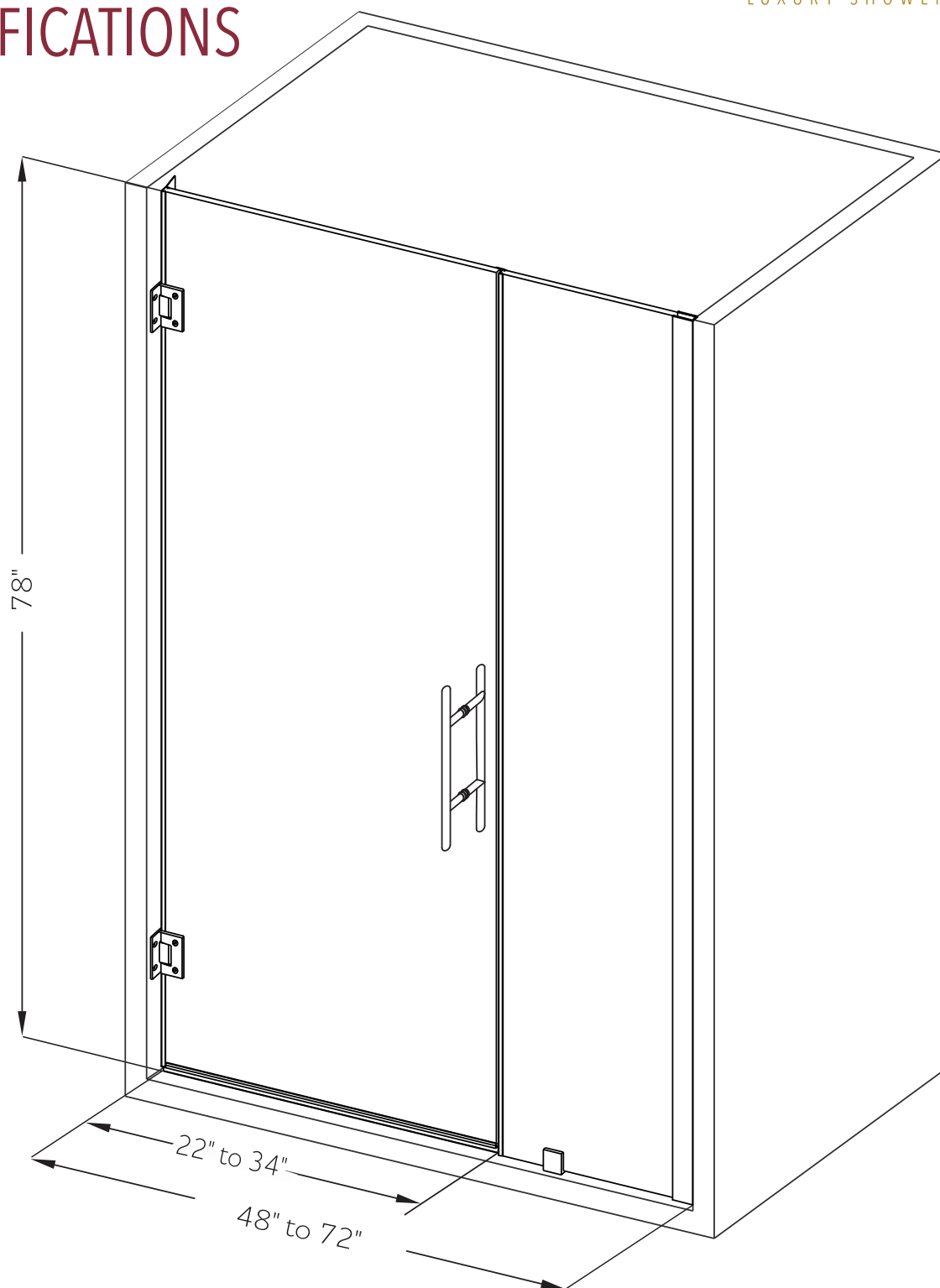


CONFIGURATIONS


exterior or interior door capability

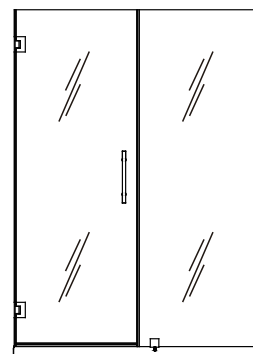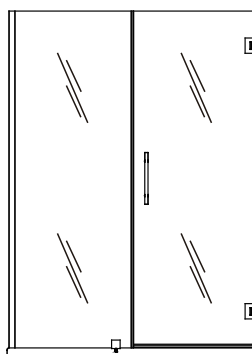


SPECIFICATIONS

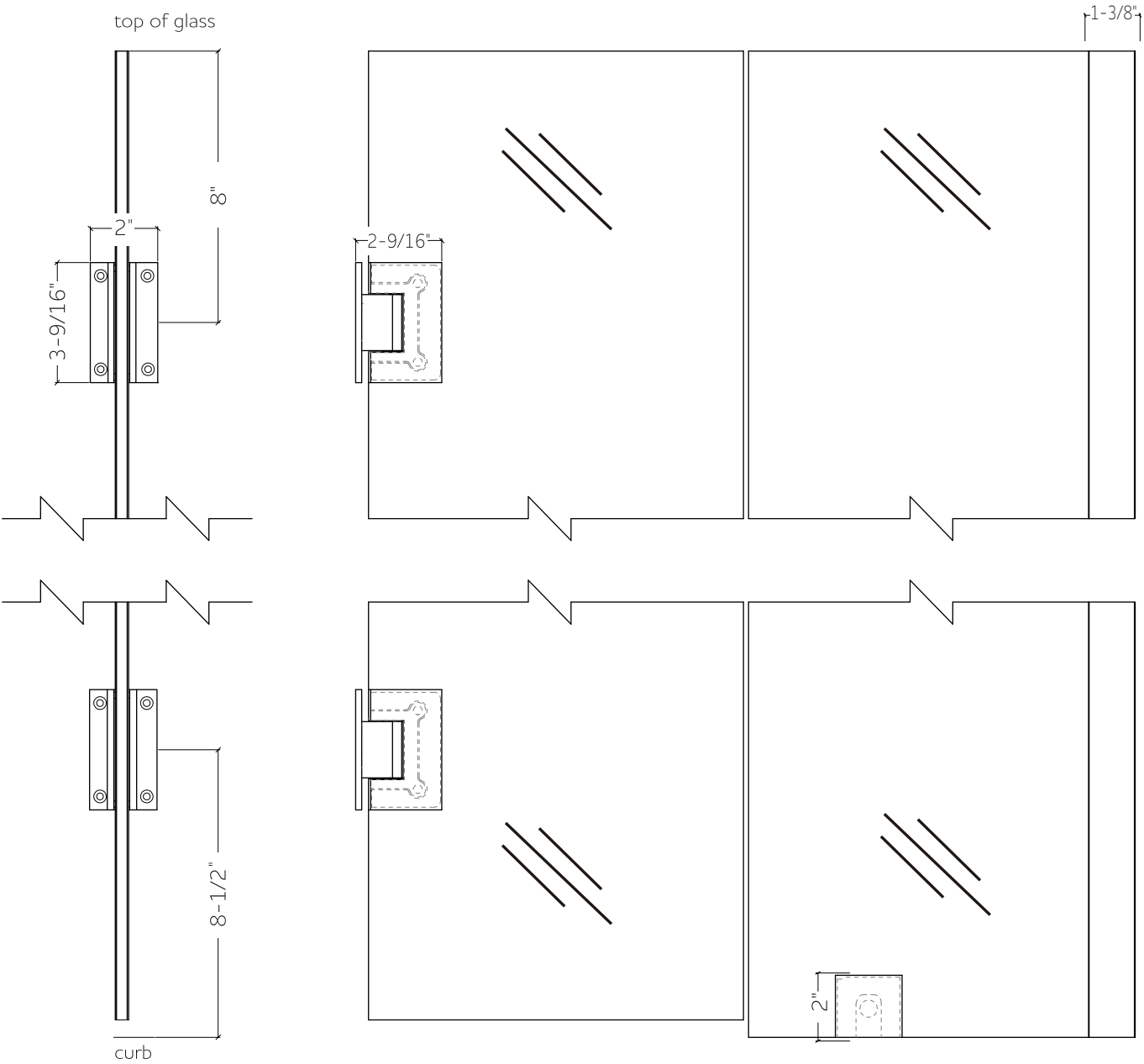

OVERHEAD VIEW

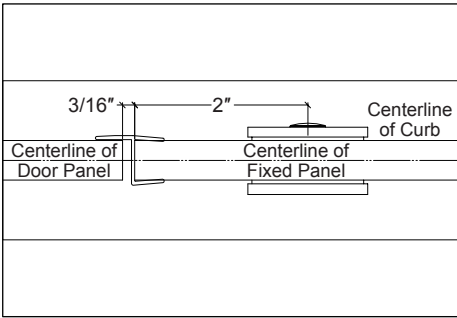

SIDE VIEW

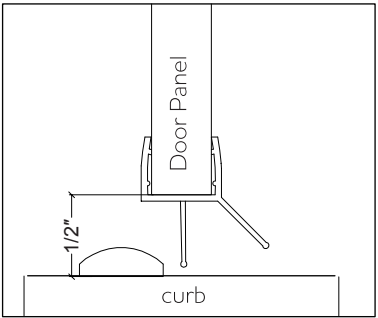

PARTS LIST

- | | |
|-----------------|-----------------------|
| 1) wall channel | 6) bottom clamp |
| 2) door panel | 7) handle |
| 3) fixed panel | 8) wall hinge |
| 4) H-seal | 9) bottom sweep seal |
| 5) jamb seal | 10) acrylic threshold |

