



MONACO SPECIFICATIONS

HOSPITALITY DIVISION  
**eurotech**  
LUXURY SHOWER DOORS

# FEATURES

- Anodized aluminum top track
- (8) 45mm dual sided rollers
- Up to 3/8" out of plumb adjustability
- 2 configurations
- Dual water diverter sets (aluminum and polycarbonate)
- (2) 19" flat style handles with knob on backside
- Standard clear tempered glass with optional ultra-clear (low iron) tempered glass
- 5/16" (8mm) or 3/8" (10mm) glass options
- EuroSafe glass film included on both panels (refer to "safety/warranty" for additional information)
- Option for Enduroshield coating to reduce cleaning time by up to 90%



## FINISHES



Chrome




Matte Black





Brushed Nickel


# HANDLE & TOWEL BAR OPTIONS

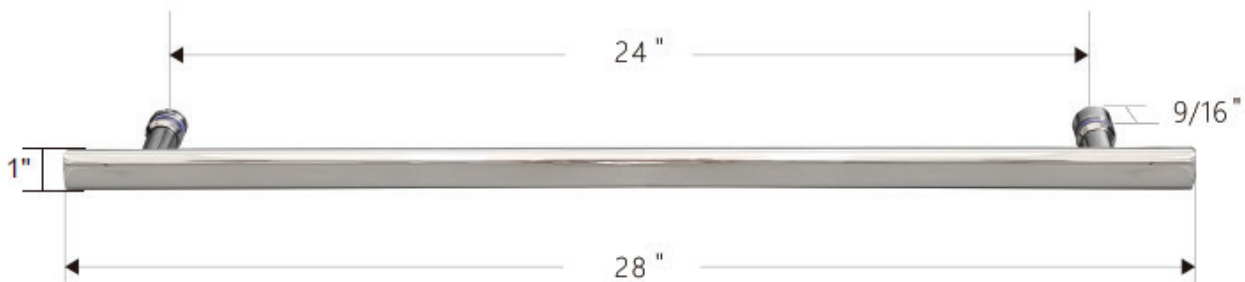


24 inch Ladder Style Towel Bar

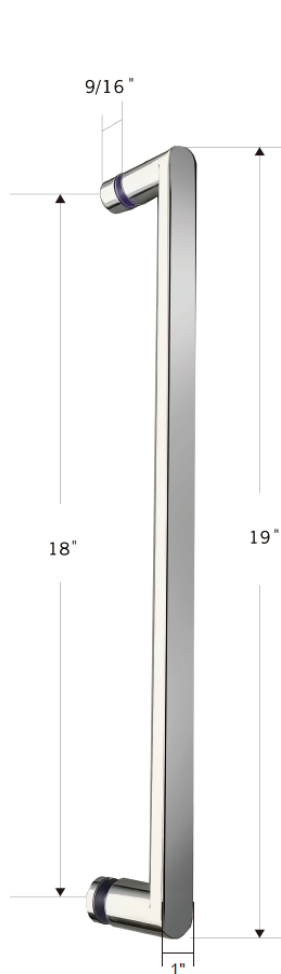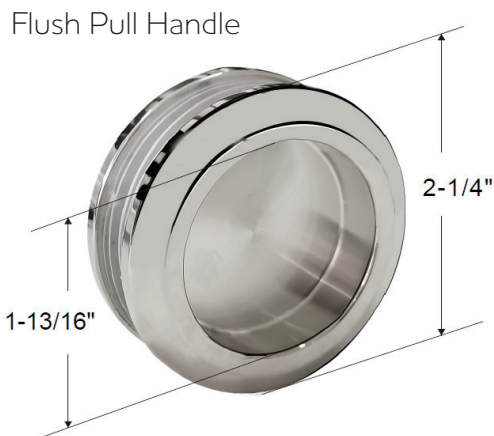

18 inch Flat Style Handle

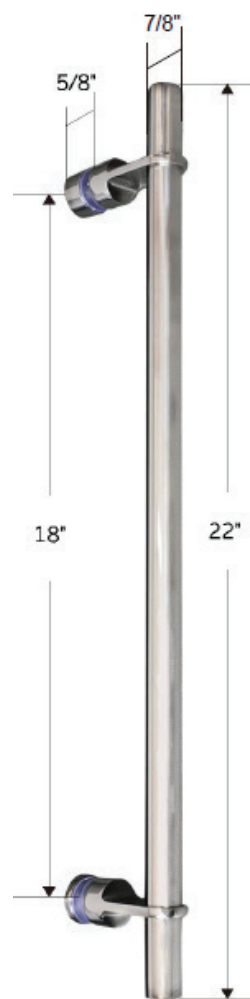

18 inch Ladder Style Handle

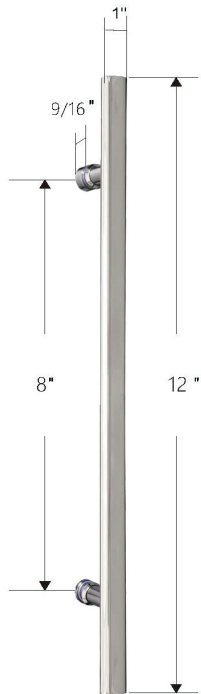


8 inch  
 Ladder Style  
 Handle





24 inch Rounded Towel Bar

# SPECIFICATIONS

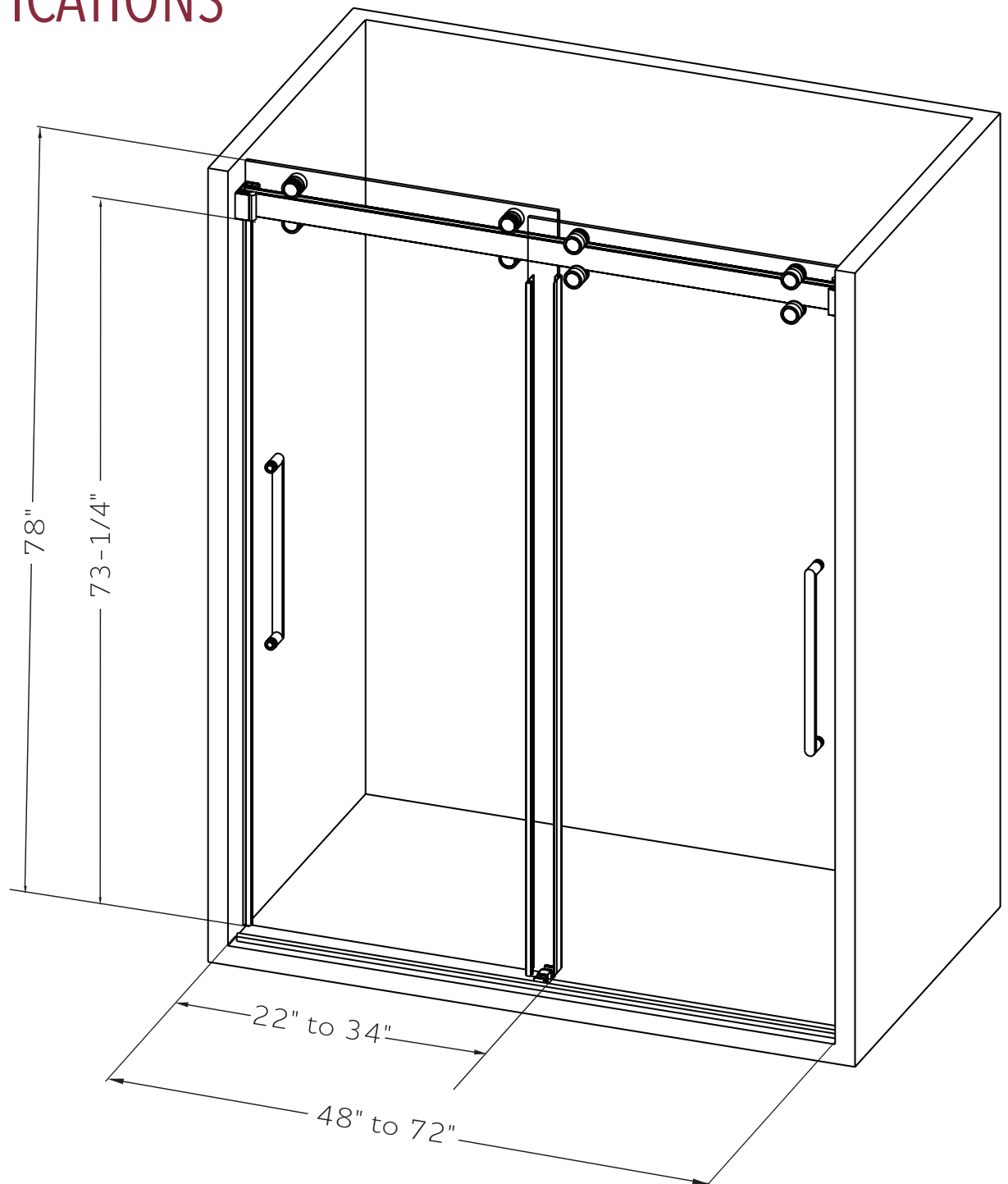


## CONFIGURATIONS



exterior or interior door capability

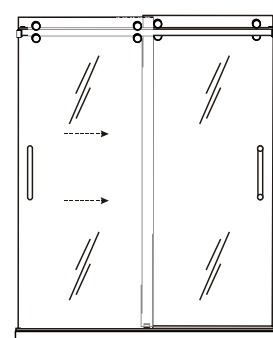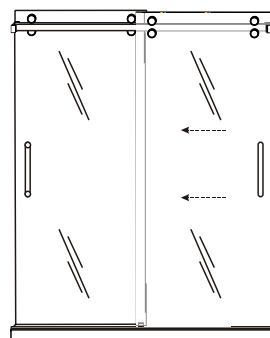



# SPECIFICATIONS

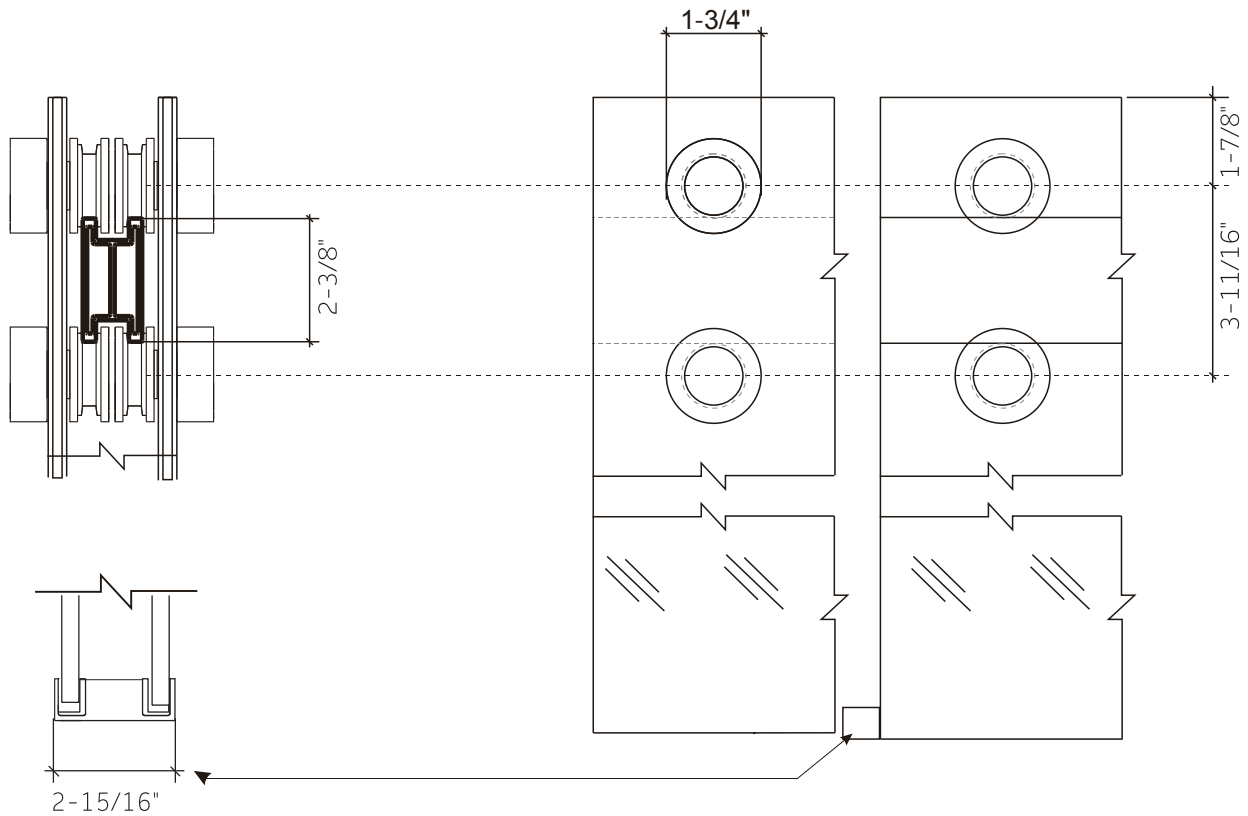

**FOOTPRINT USING  
 ALUMINUM WATER GUARD**

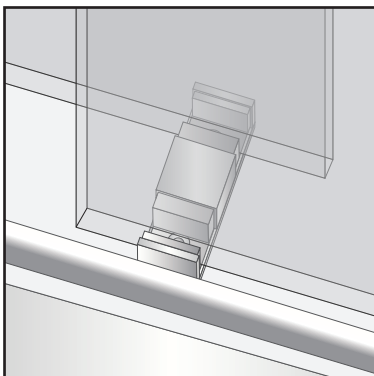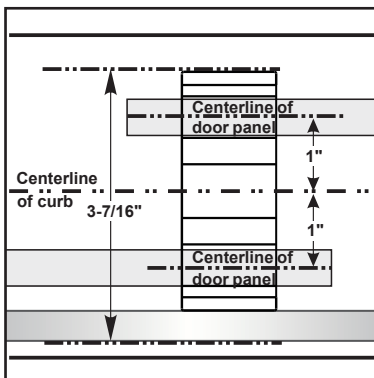

**FOOTPRINT USING  
 POLYCARBONATE L-SEAL**

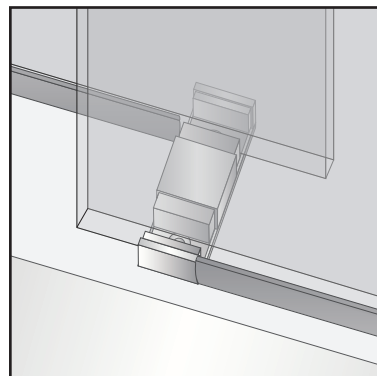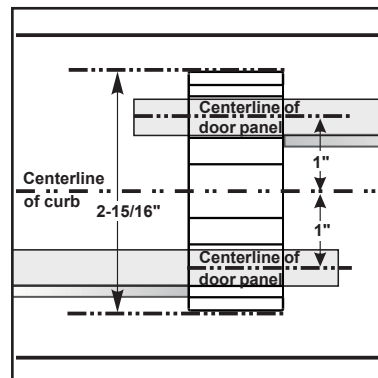

# PARTS LIST

- |                  |                         |
|------------------|-------------------------|
| 1) wall bracket  | 7) door panel           |
| 2) safety bumper | 8) F-seal               |
| 3) track         | 9) aluminum water guard |
| 4) roller        | 10) bottom guide        |
| 5) V-seal        | 11) L-seal              |
| 6) handle        |                         |

