



VITRA-200X SPECIFICATIONS

HOSPITALITY DIVISION
eurotech
LUXURY SHOWER DOORS

FEATURES

- 304 stainless steel
- (4) 2-3/8" dual sided rollers
- (4) 1-1/8" dual sided anti-jump pins
- Up to 3/8" out of plumb adjustability
- 2 configurations
- Dual water diverter sets (aluminum and polycarbonate)
- (1) 24" ladder style towel bar with knob on backside & (1) back-to-back knob
- Door grippers incorporated into wall brackets
- EuroSafe Glass Film (safety film) included on both panels
- Standard clear tempered glass with optional ultra-clear (low iron) tempered glass or rain tempered glass
- 5/16" (8mm) or 3/8" (10mm) glass options
- Option for Enduroshield treatment to reduce cleaning time up to 90%



FINISHES



Polished Stainless



Matte Black




Brushed Stainless





Satin Brass


HANDLE & TOWEL BAR OPTIONS

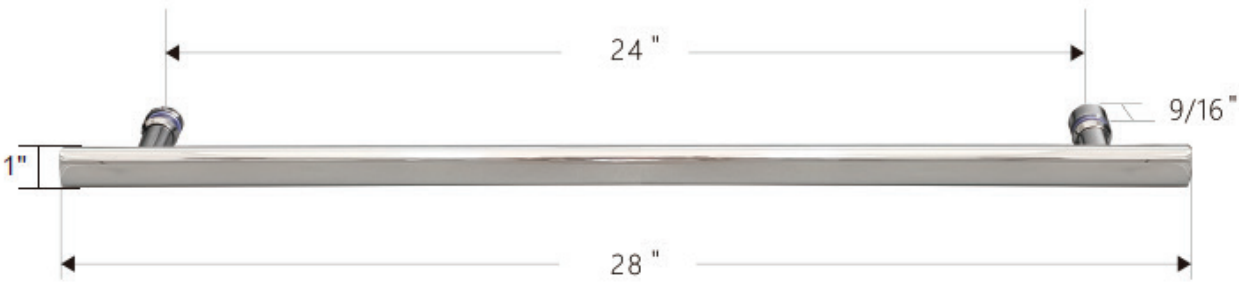


24 inch Ladder Style Towel Bar

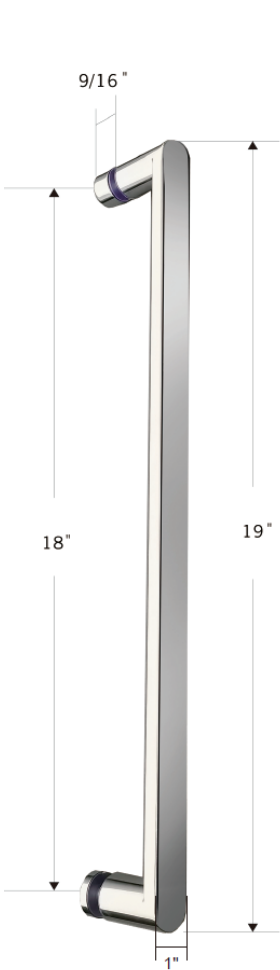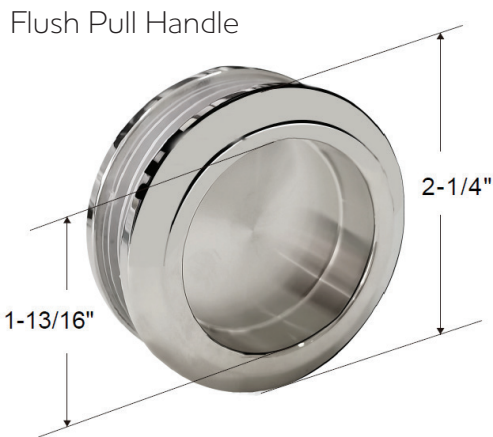


18 inch Flat Style Handle

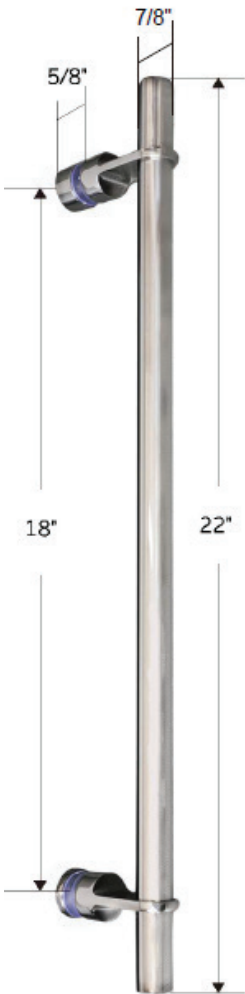


18 inch Ladder Style Handle

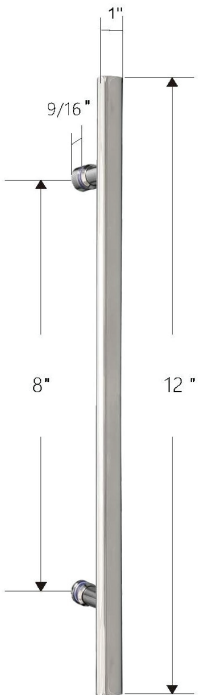

8 inch
Ladder Style
Handle


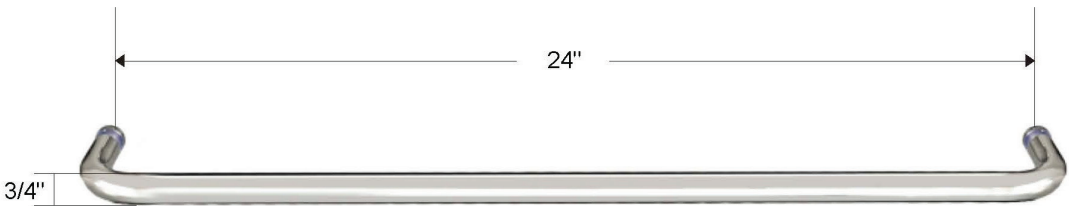



24 inch Rounded Towel Bar

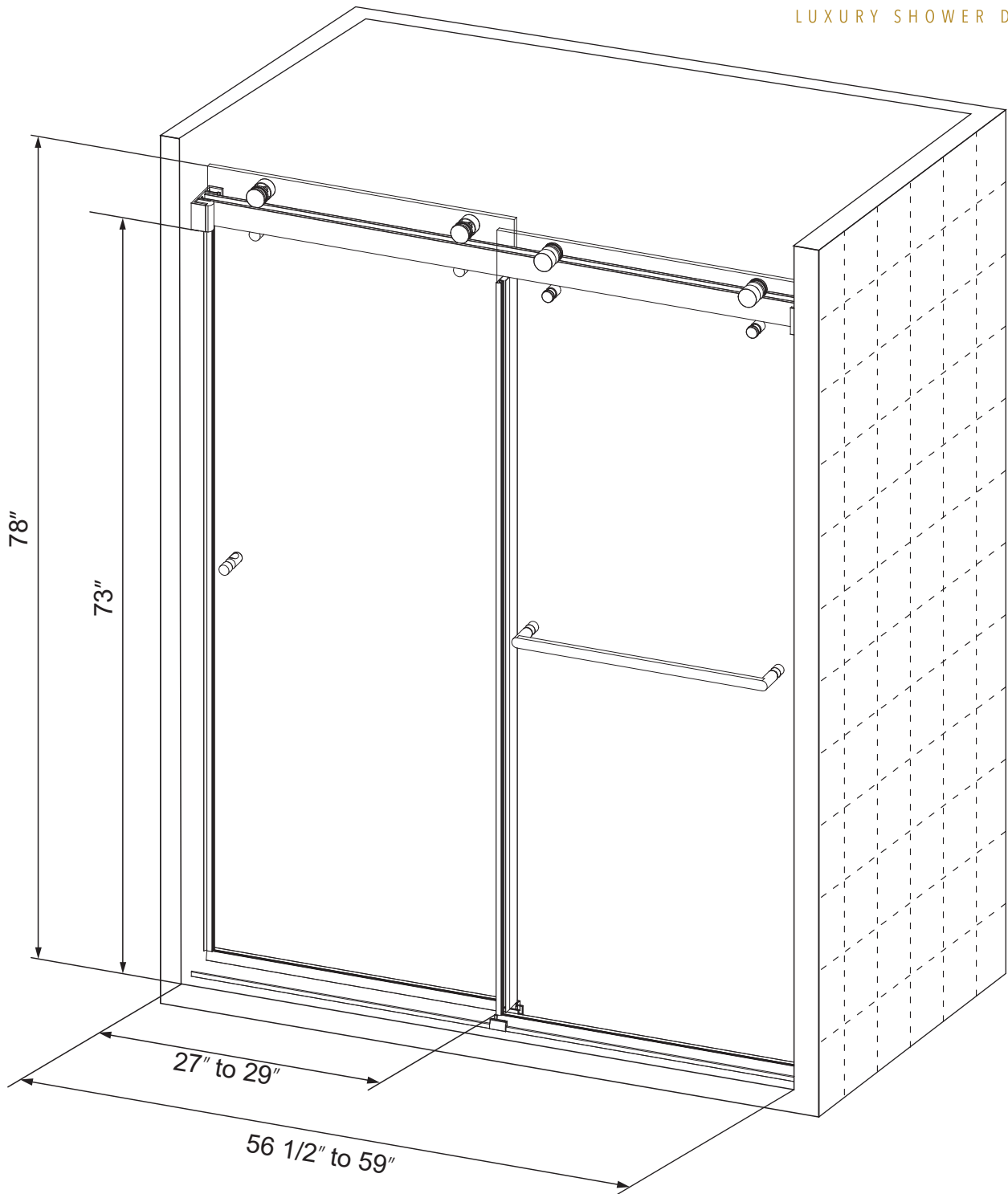



CONFIGURATIONS

exterior or interior door capability

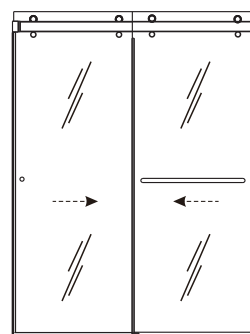
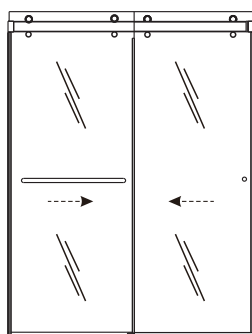


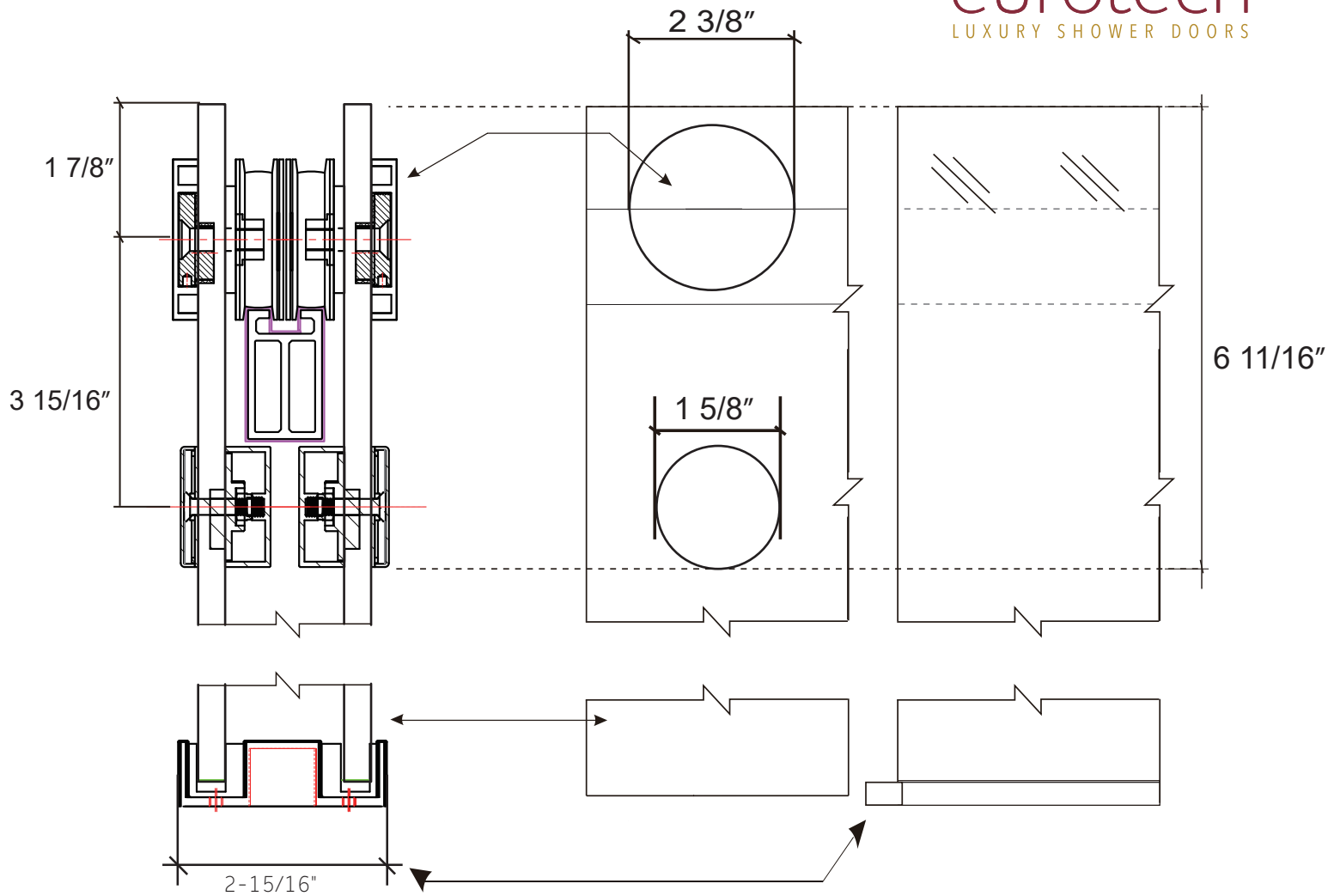

**FOOTPRINT USING
 ALUMINUM WATER GUARD**

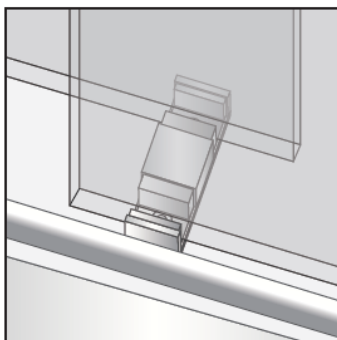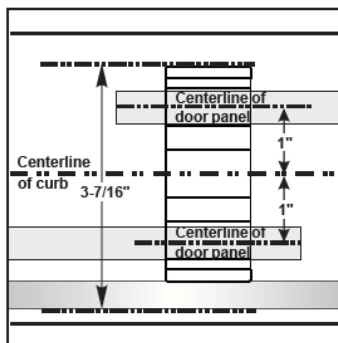

**FOOTPRINT USING
 POLYCARBONATE L-SEAL**

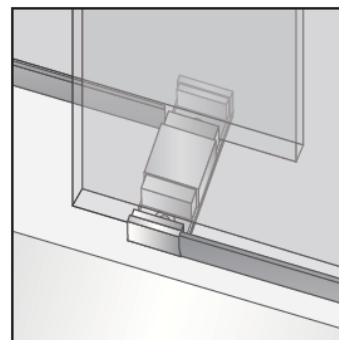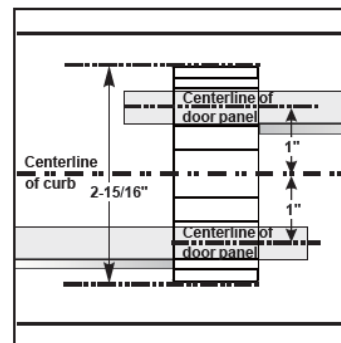

PARTS LIST

- 1) wall bracket
- 2) safety bumper
- 3) track
- 4) roller
- 5) anti-lift pin
- 6) V-seal
- 7) towel bar
- 8) door panel
- 9) aluminum water guard
- 10) L-seal
- 11) bottom guide
- 12) knob
- 13) F-seal

