



CLASSIC SPECIFICATIONS

HOSPITALITY DIVISION
eurotech
LUXURY SHOWER DOORS

FEATURES

- Anodized aluminum top track, wall jambs, and bottom sill
- (4) hanger roller brackets enclosed inside top track
- Up to 3/8" out of plumb adjustability
- 2 configurations
- (2) 24" round style towel bar with bumper knobs
- Standard 1/4" (6mm) clear tempered glass
- EuroSafe glass film included on both panels (refer to "safety/warranty" for additional information)
- Option for Enduroshield coating to reduce cleaning time by up to 90%



FINISHES



Chrome




Matte Black




Brushed Nickel



HANDLE & TOWEL BAR OPTIONS

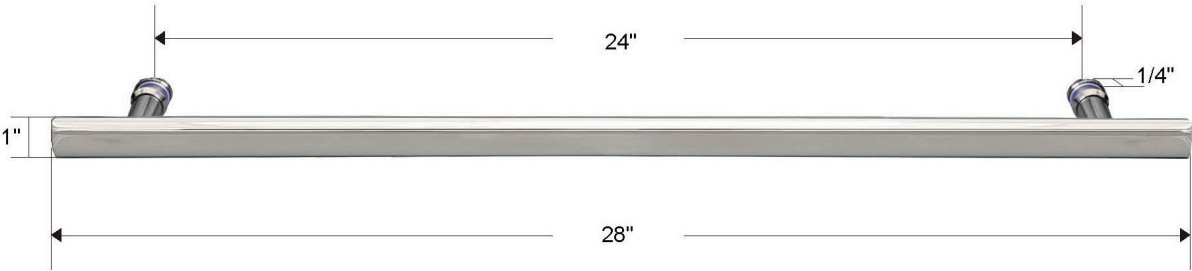


24 inch Ladder Style Towel Bar

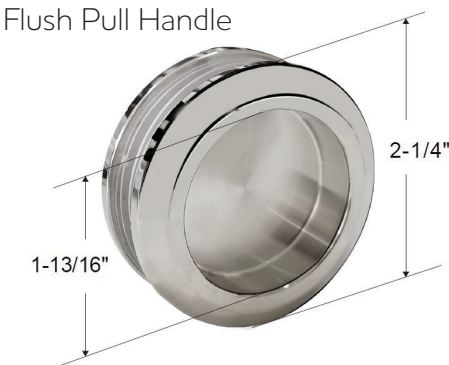


8 inch
Ladder Style
Handle

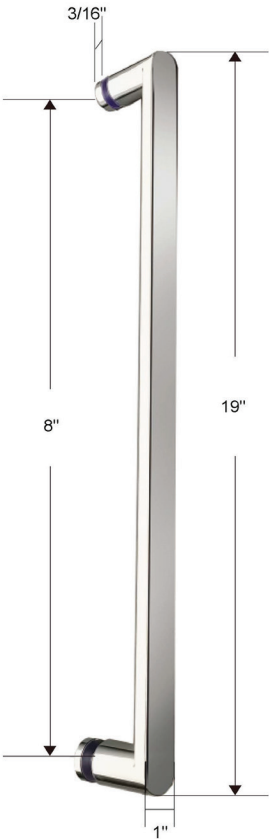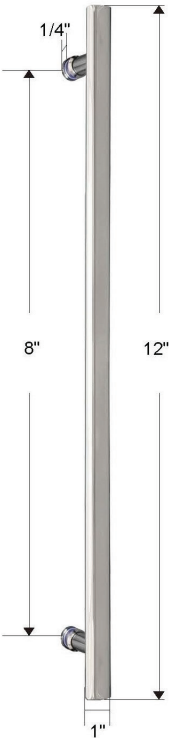

18 inch Flat Style Handle

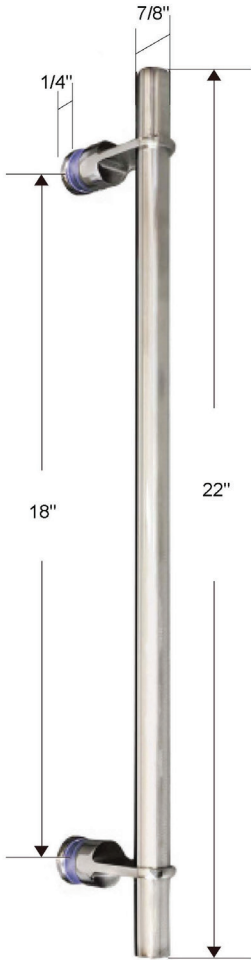


18 inch Ladder Style Handle

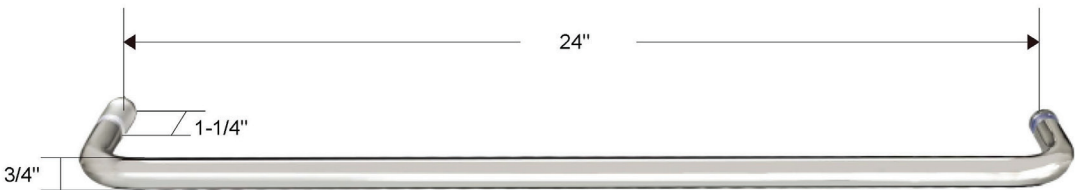



24 inch Rounded Towel Bar

SPECIFICATIONS

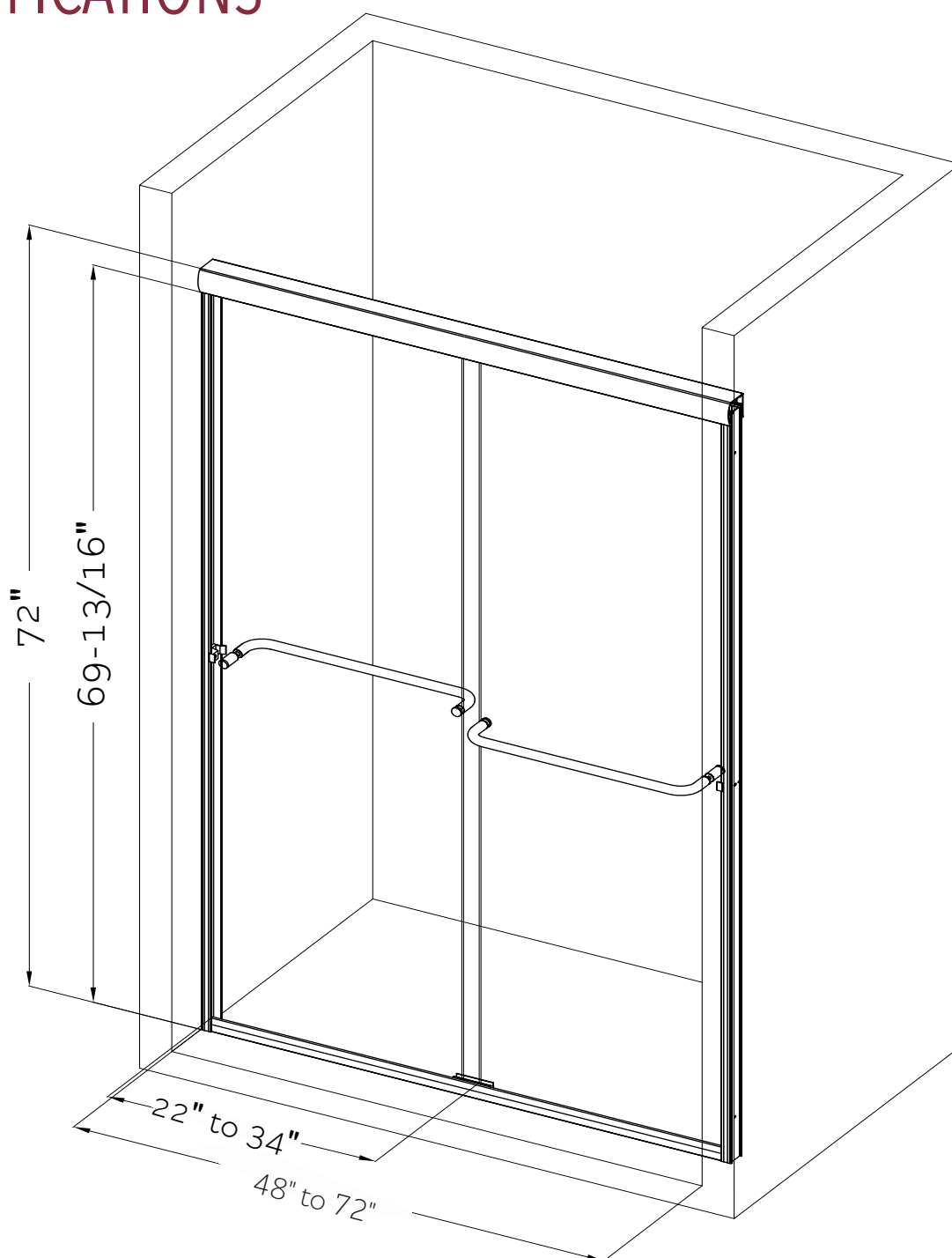


CONFIGURATIONS


exterior or interior door capability

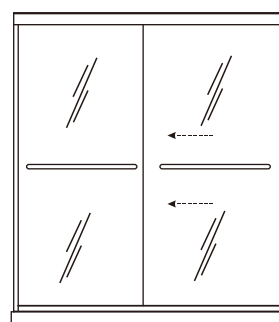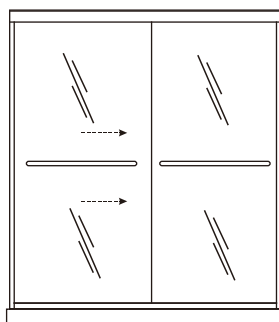

SPECIFICATIONS

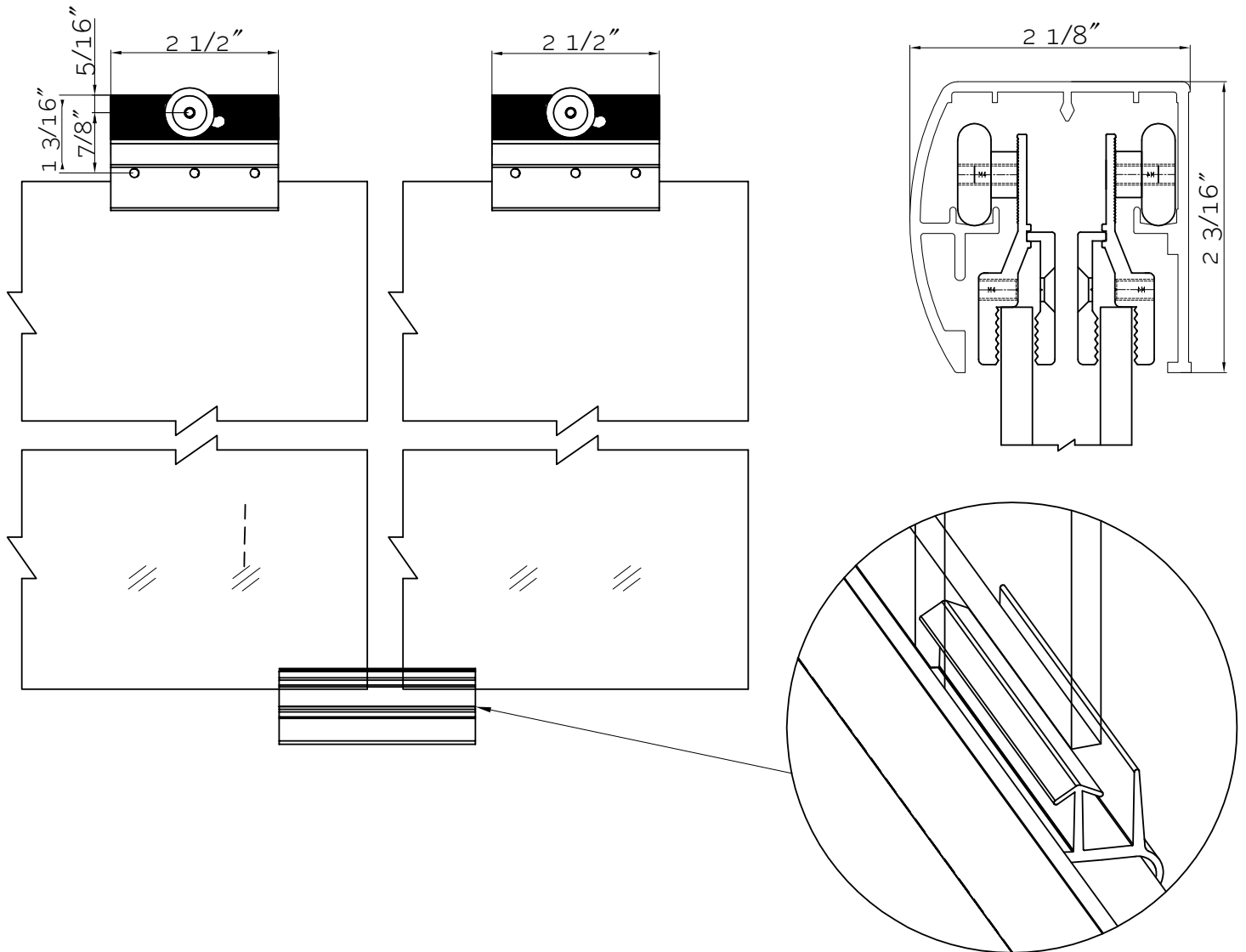

FOOTPRINT FOR BOTTOM SILL

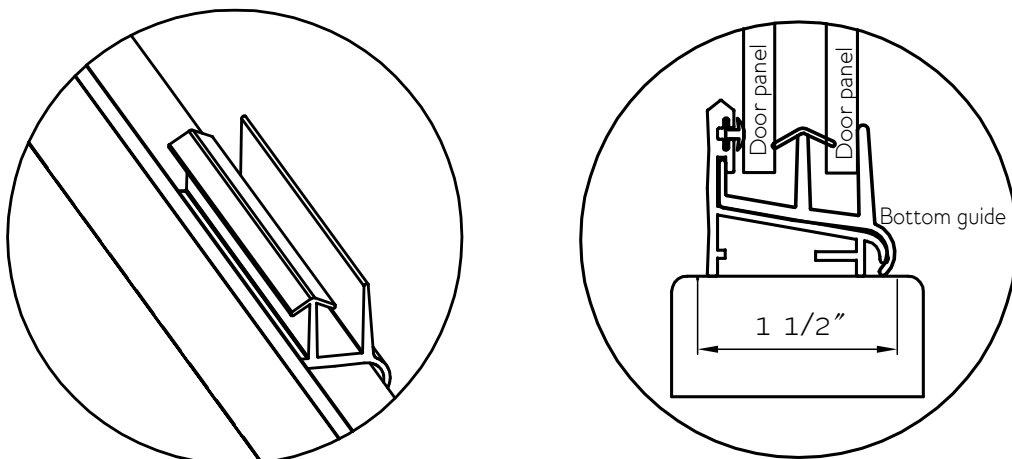

PARTS LIST

- | | |
|-------------------|--------------------|
| 1) wall jamb | 7) door panel |
| 2) bumper guide 1 | 8) bottom guide |
| 3) bumper guide 2 | 9) bottom sill |
| 4) track | 10) screw caps |
| 5) roller bracket | 11) blind fastener |
| 6) towel bar | |

