

# Blue Series: Dry wall




Discover the wide  
range and its technical  
information



# Mechanisms boxes

Save up to 40% of installation time!

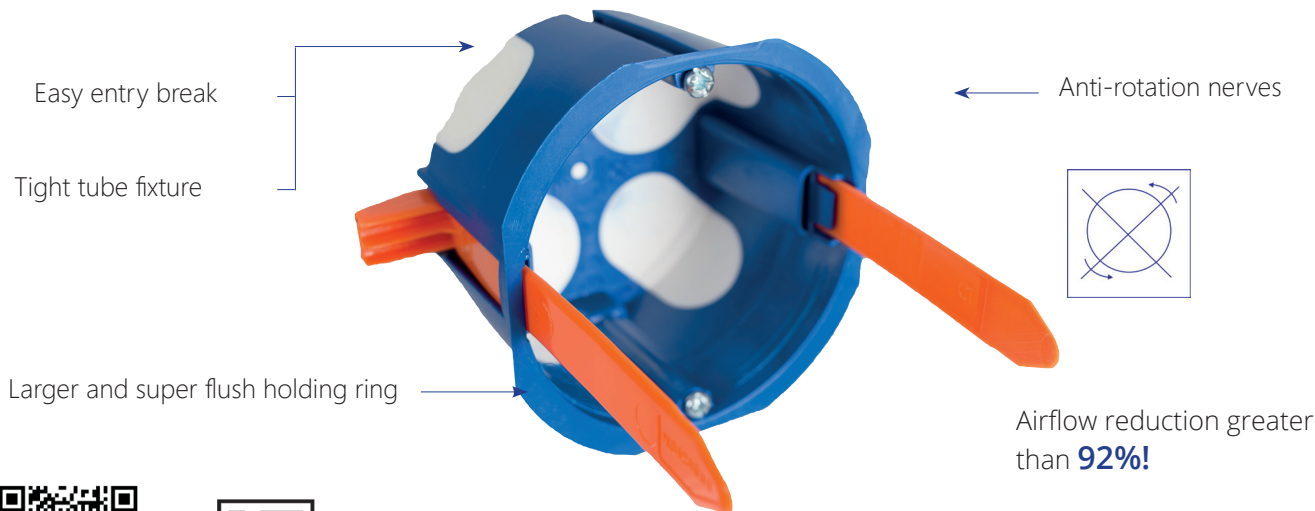

VIDEO



## References with Nylon ties




### Ref. 5625GW

Ø 68 x 46.  
4 x Ø20 & 2 x Ø25.



### Ref. 5625E

Preserves energy in the building.  
Flexible rubber: perfect tube fitting  
Ø 68 x 46. 4 x Ø20 & 2 x Ø25.

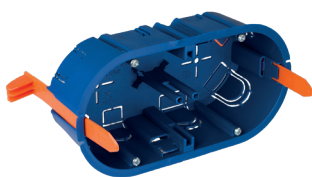


### Ref. 5725GW

139 x 68 x 46. 2 modules.  
4 x Ø20 & 4 x Ø25.



### Ref. 5725E

139 x 68 x 46. 2 modules.  
4 x Ø16-20 & 2 x Ø20-25.

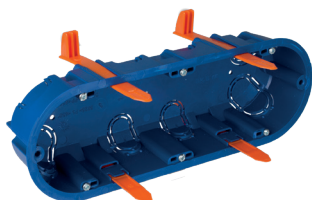


### Ref. 5825GW

219 x 68 x 46. 3 modules.  
6 x Ø20 & 4 x Ø25.



### Ref. 5825GW

219 x 68 x 46. 3 modules.  
6 x Ø20 & 4 x Ø25.

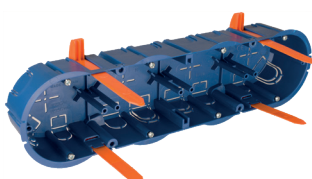

### Ref. 5925GW


281 x 68 x 46. 4 modules.  
12 x Ø20, 8 x Ø25 & 5 x Ø16.



### Ref. COR68TH

Hole saw for hollow partition. Ø 2,7 in. With spindle, countersink and ejector spring.

# Back junction boxes

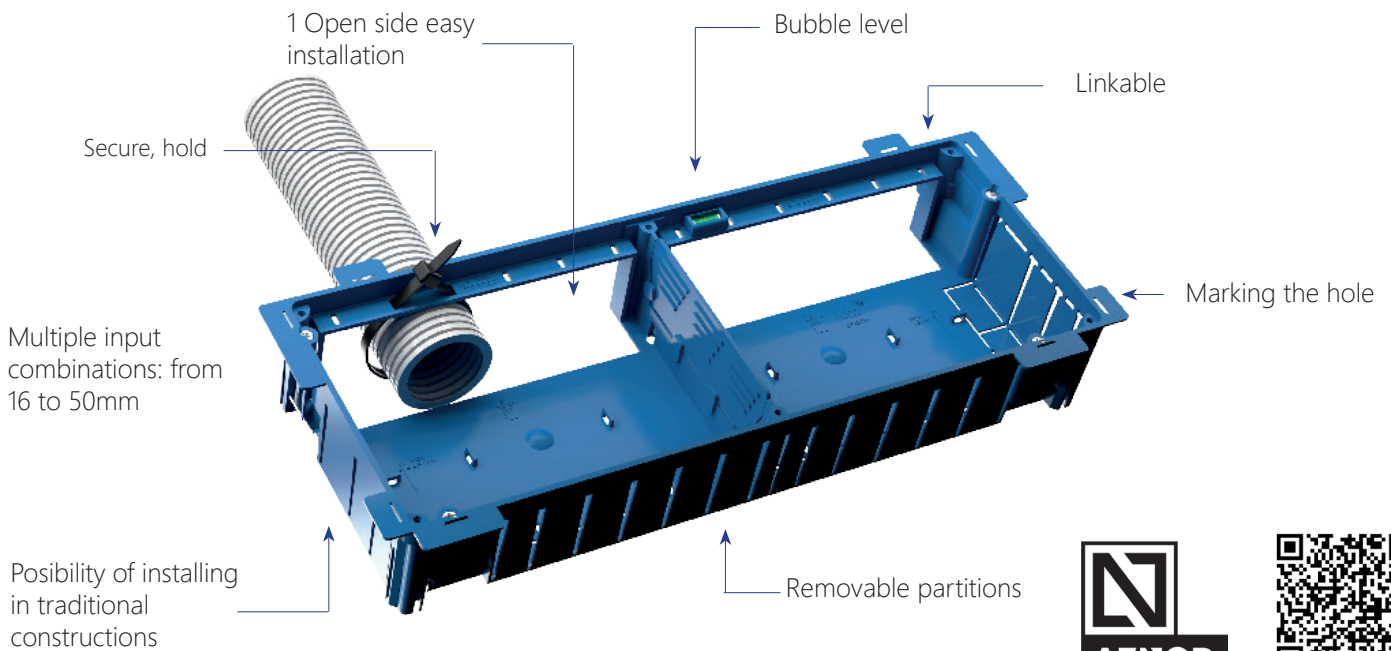

VIDEO

## References with Nylon ties or claw fix system



### Ref. 5362GW

107 x 107 x 45.  
12 x Ø25.  
Screw lid fixture.



### Ref. 5363GW

170 x 112 x 47.  
16 x Ø25.  
Screw lid fixture




### Ref. 5314GW

188 x 148 x 50.  
8 x Ø25, 2 x Ø32 & 6 x Ø40.  
Screw lid fixture



### Ref. 324GW

252 x 252 x 50.  
12 x Ø25 & 12 x Ø30.  
Screw lid fixture

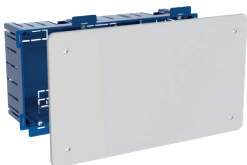

### Ref. 5530GW

300 x 150 x 75.  
Metal claw fixture  
Screw lid fixture

### Ref. 5530GDW

With DIN rail.




### Ref. 5540GW

390 x 150 x 60.  
From Ø16 to Ø50.  
Metal claw fixture  
Screw lid fixture



# Claw fix system

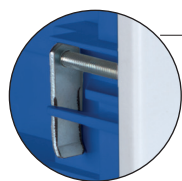

Detail of claw



55514GW / 515GW  
Ø100 x 46 / Ø150 x 46



5516GW  
Ø150 x 46



Detail of claw




5506GW  
300 x 500 x 60



5507GW  
300 x 500 x 60

## ARELOS

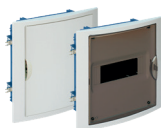

5108HGW & 5108PFHGW  
205 x 233 x 72



5012HGW & 5012PFHGW  
320 x 233 x 75



8690HGW & 8690PFHGW  
450 x 220 x 72




5250HGW & 5250PFHGW  
320 x 420 x 75




5270HGW & 5270PFHGW  
320 x 670 x 75

Detail of claw

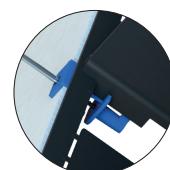

## METALBOX

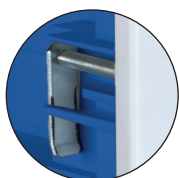

Detail of claw



MP14HGW  
333 x 300 x 88



MP28HGW  
333 x 435 x 88



MP42HGW  
333 x 616 x 88



MP56HGW  
333 x 751 x 88

## IT



MP42/2HGW  
730 x 610 x 88



MP42/2BHGW  
730 x 610 x 88

**Solera**

Portalámparas y Accesorios Solera S.A. - C/ Villa de Madrid, 53  
46988 Paterna (Valencia) España-Spain  
solera@psolera.com - export@psolera.com

www.psolera.com

