

LEDVANCE.COM



LEDVANCE

THE NEW PANEL RANGE

WHATEVER YOUR PROJECT –
CEILINGS LOVE OUR PANELS

POWERED THROUGH
OUR NEW PORTFOLIO

THE NEW PANEL PORTFOLIO

SOLUTIONS FOR EVERY CEILING AND APPLICATION


Our panel portfolio is designed to match different project needs. From everyday installations to demanding projects, each family offers clear advantages in performance, flexibility and installation.



PANEL COMFORT GEN 2


FOR PROJECTS THAT REQUIRE HIGHEST PERFORMANCE

AVAILABLE LATER IN 2026

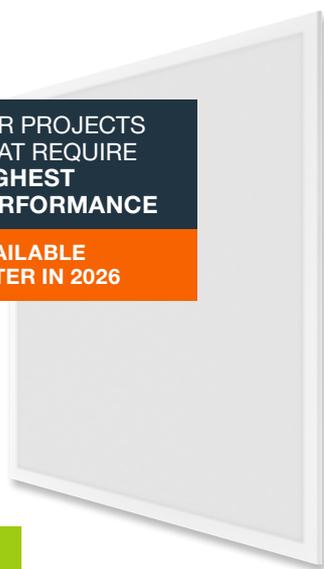

PANEL COMPACT GEN 2

MAIN PANEL RANGE FOR STANDARD APPLICATIONS

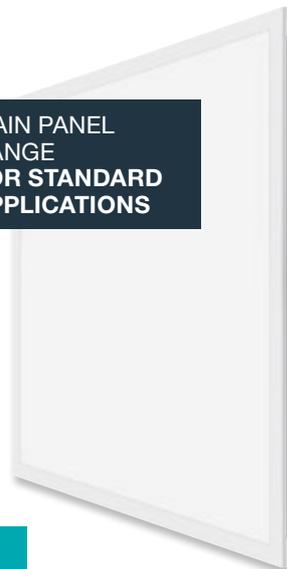

LUMEN/WATT PERFORMANCE

175 lm/W*

140 lm/W

LIFETIME

100 kh*

75 kh

LUMEN OUTPUT

5 100 lm*

4 200 lm

GUARANTEE

7 years*

5 years






MULTI SELECT LUMINAIRES

Easily switch colour temperatures and/or luminous flux on-site for maximum flexibility.

MULTI COLOUR FUNCTION


Choose from up to three different colour temperatures directly on the luminaire: warm, cool, or daylight white.



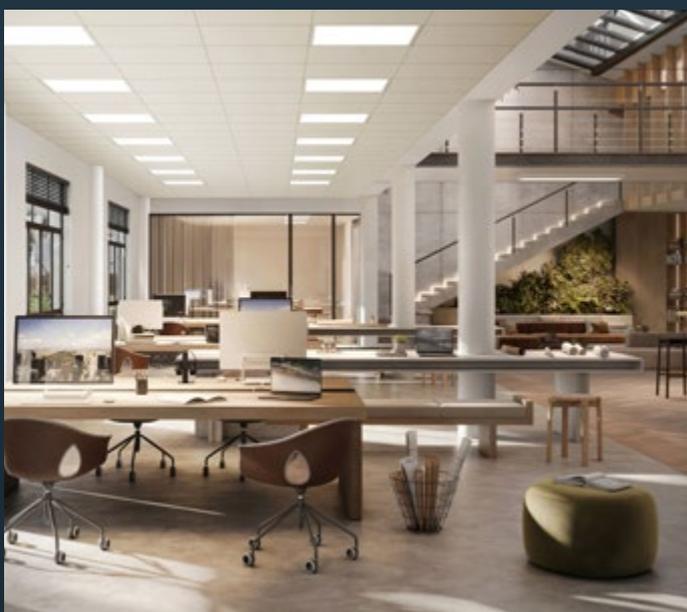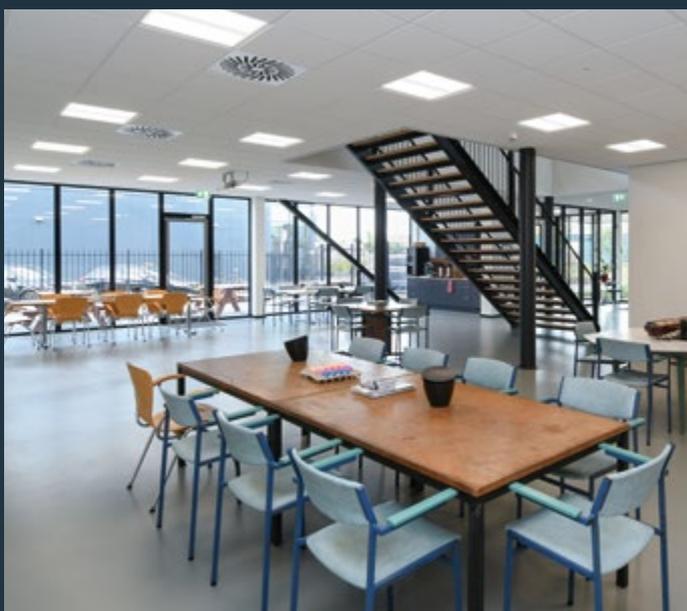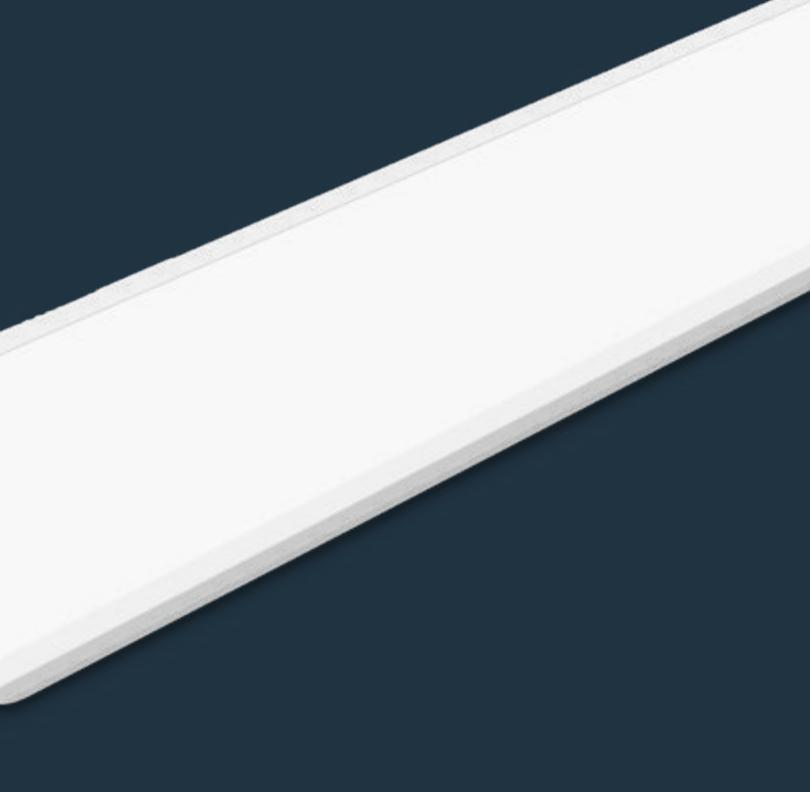

PANEL ECO GEN 3

PANEL RANGE
FOR
ESSENTIAL
LIGHTING

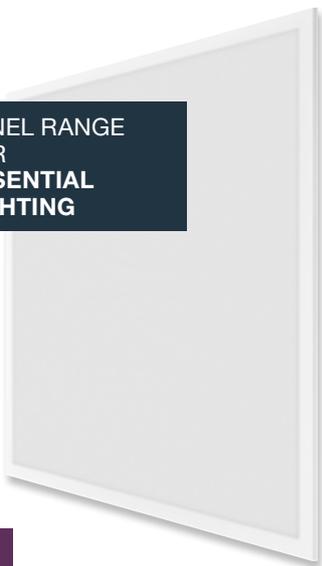

110 lm/W

50 kh

3600 lm

3 years

*Preliminary data, subject to change without notice

MULTI LUMEN FUNCTION

Adjust luminous flux (lm)
and brightness on-site
to suit ceiling height or
lighting requirements.



THE LEDVANCE PANEL PORTFOLIO AT A GLANCE

CLEARLY STRUCTURED.
APPLICATION-DRIVEN. EASY TO UPGRADE.

VALUE CLASS

PANEL COMPACT GEN 2

Standard office applications & public areas

- MULTI SELECT versions available
- Best value for great performance

PERFORMANCE CLASS

PANEL INDIVILED GEN 2

Performance-driven office projects

- EVERLOOP design
- High efficiency, CRI 90
- Advanced controls

COMING LATER IN 2026

PERFORMANCE CLASS

PANEL COMFORT GEN 2

Demanding project applications

- Excellent performance
- Modular versions
- TW and DIRECT EASY versions available

PERFORMANCE CLASS

PANEL PROTECT

Special offices & public areas

- IP54 protection
- Heavy-duty applications
- Sensor ready


VALUE CLASS

PANEL SURFACE

Refurbishment without ceiling changes

- Oversized dimensions
- Surface-mounted solution
- MULTI SELECT

QUICKLY IDENTIFY THE RIGHT PANEL FAMILY FOR EACH APPLICATION. SEE KEY ADVANTAGES AT A GLANCE TO SIMPLIFY SELECTION AND PLANNING.

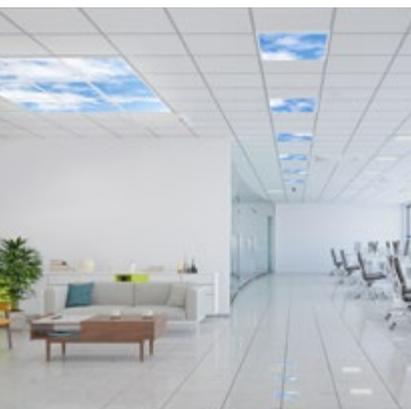

COMPLETING THE PORTFOLIO: PANEL ADD-ONS & SERVICES

ACCESSORIES

Complete solutions for every installation

- Suspension kits
- Surface mounting frames
- Installation & safety accessories

PANEL PRINT SKY

Decorative luminous panels for special projects

- Design your luminaire panel

LEDVANCE PROJECT SERVICES

Specification & customised solutions for your project

See pages 10–13

▶▶▶ AVAILABLE LATER IN 2026

PERFOR-
MANCE
CLASS

PANEL COMFORT GEN 2

PROJECT-READY PANEL FOR
MAXIMUM PERFORMANCE



EXCELLENT PERFORMANCE

High lumen output,
efficiency and lifetime



TUNABLE WHITE & LIGHTING CONTROL

- DALI-2
- Zigbee 3.0



PROJECT READY

Ideal for offices, hospitality,
and public areas – replaces
existing T8/T5 recessed
grid panels



MODULAR VERSIONS

Mix and match by
selecting panel, driver
and quick-connector
versions individually

PANEL COMPACT GEN 2

VALUE
CLASS

THE SMART CHOICE FOR
STANDARD APPLICATIONS



WIDE RANGE

Available in multiple versions and sizes



MULTI SELECT

Select lumen and CCT at some types for flexible installation




APPLICATION READY

Ideal for offices, corridors, and public areas – replaces standard T8/T5 panels

GRID CEILING SIZES

600 mm × 600 mm or
626 mm × 625 mm

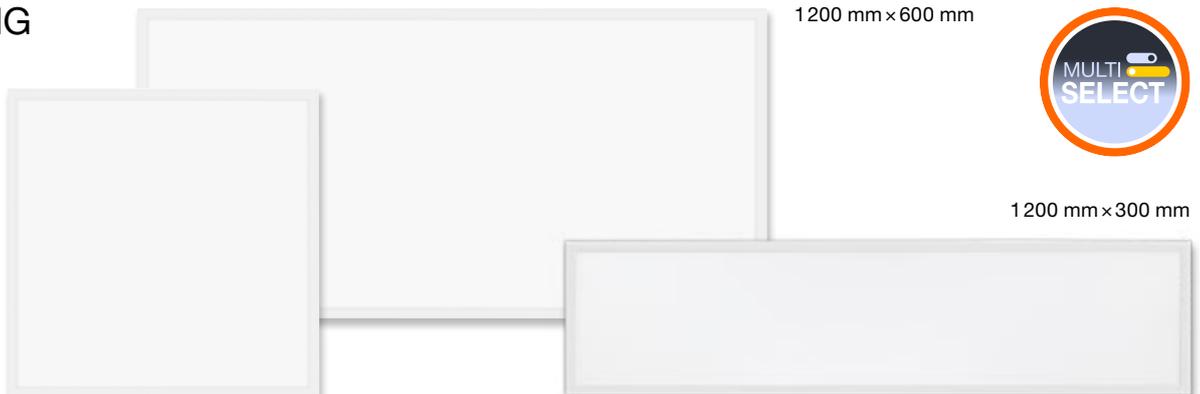

1200 mm × 600 mm



1200 mm × 300 mm



PANEL INDIVILED GEN 2

HIGH PERFORMANCE PANEL
WITH EVERLOOP TECHNOLOGY



EVERLOOP

Easy replacement & upgrade of light source and driver



HIGH PERFORMANCE

Up to 140 lm/W, CRI 90 – brilliant, efficient light



LIGHTING CONTROL

- DALI-2
- Zigbee 3.0
- DIRECT EASY



MULTI LUMEN


Several lumen options per size – adapt to project needs

PERFORMANCE CLASS

Ideal design mix of PANEL INDIVILED with LINEAR INDIVILED, which was used for desk lighting here.

GRID CEILING SIZES & COLOURS

600 mm × 600 mm or
626 mm × 625 mm
Black and white

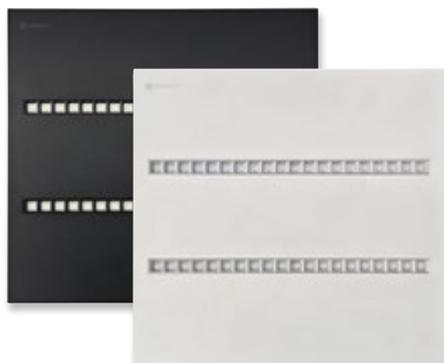

1200 mm × 300 mm
Black and white





+ **HEAVY DUTY**
IP54 protection for safety in wet or dusty areas, low-profile fitting for narrow spaces

+ **TOUGH APPLICATIONS**
For offices near production, labs, healthcare & workshops – replaces T8/T5 panels in demanding environments

+ **SENSOR READY**
Individual sensor integration possible on request

PERFORMANCE CLASS



PANEL PROTECT

ROBUST PANEL FOR DEMANDING ENVIRONMENTS



600 mm x 600 mm or
625 mm x 625 mm



PANEL SURFACE

SURFACE-MOUNTED PANEL
MADE FOR REFURBISHMENT

+ REFURBISHMENT READY
Oversized dimensions cover existing mounting marks

+ COMFORTABLE LIGHT
CRI 90 & SDCM < 3 for pleasant, glare-free lighting in offices and educational spaces

+ ENERGY SAVING
DALI-2/ZIGBEE DIRECT/sensor versions

+ EMERGENCY READY
Central/decentral emergency lighting integration

VALUE CLASS

PRODUCT SIZES



674 mm × 674 mm
(replacing 4 × 18W T8)



1274 mm × 374 mm
(replacing 2 × 36W T8)



1574 mm × 374 mm
(replacing 2 × 58W T8)

PANEL ACCESSORIES

COMPATIBILITY OF PANEL ACCESSORIES WITH PANEL FAMILIES¹

1. SURFACE MOUNT KIT H75/H50



- Pre-assembled and ready to install
- Simple fixing with magnets
- Cross brace for greater stability
- Material: aluminium

2. SURFACE MOUNT KIT VALUE



- Kit for tool-free mounting with corner clips
- Material: aluminium

3. SUSPENSION KIT



- Suspension length: 1 500 mm
- Material: steel

4. PANEL SECURITY KIT 4 x



- Includes wires and brackets
- Material: steel

5. RECESSED MOUNT CLIPS



- Ceiling thickness: 10 to 20 mm
- Material: steel

6. RECESSED MOUNT FRAME



- Pre-assembled and ready to install
- Seamless recessed mounting
- Ceiling thickness: 8 to 30 mm
- Material: aluminium

7. CONNECTOR BOX 5-POLE



- Tool-free electrical connection due to pushbutton connector
- Through-wiring made possible
- Suitable for cable cross section up to $5 \times 2.5 \text{ mm}^2$

8. PANEL 1200 CABLE EXTENSION TWIST LOCK



- Improves visual appearance of the Panel in suspended application
- Extension cable on DC side allowing to hide the driver behind the ceiling
- Tool-free installation via twist-lock connection

EMERGENCY CONVERSION BOX TEMPERATURE SENSOR



- Conversion of selected LEDVANCE panels to emergency luminaires
- Plug-and-play system allows easy installation
- Battery technology: LiFePO4

¹The accessories are compatible with the Panels in the respectively matching size. For details refer to the User Instructions.



COMPATIBILITIES AT A GLANCE

Accessories	GTIN (EAN)	PANEL TW/ BIOLUX	PANEL FLEX	PANEL INDIVILED	PANEL PROTECT	PANEL COMFORT	PANEL COMPACT
1	Panel 600 Surface Mount Kit H75	4058075472914	✓	✓	✓	✓	✓
	Panel 625 Surface Mount Kit H75	4058075472938	✓	✓	✓	✓	✓
	Panel 1200x300 Surface Mount Kit	4058075108820	✓				✓
	Panel 600 Surface Mount Kit H75 BK	4058075834330	✓	✓		✓	✓
	Panel 625 Surface Mount Kit H75 BK	4058075834354	✓	✓		✓	✓
	Panel 1200x300 Surface Mount Kit BK	4058075834378	✓				✓
	Panel 600 Surface Mount Kit H50	4058075826397	✓			✓	
	Panel 625 Surface Mount Kit H50	4058075826403	✓			✓	
2	Panel 600 Surface Mount Kit H70 Value	4058075402843	✓	✓	✓	✓	✓
	Panel 625 Surface Mount Kit H70 Value	4058075402867	✓	✓	✓	✓	✓
	Panel 1200x300 SF Mount Kit H70 Value	4099854018497	✓				✓
	Panel 1200x600 Surface Mount Kit Value	4058075389823	✓				✓
3	Panel Suspension Kit	4058075402928	✓	✓	✓ ²	✓	✓
4	Panel Security Kit 4x	4058075472990	✓ ⁵	pre-installed		pre-installed	pre-installed
5	Panel Recessed Mount Clips Value 4x	4058075409859	✓	✓	✓	✓	✓
6	Panel 600 Recessed Mount Frame	4058075402881	✓	✓		✓	✓
	Panel 625 Recessed Mount Frame	4058075402904	✓	✓		✓	✓
	Panel 1200x300 Recessed Mount Frame	4058075472976	✓				✓
7	Connector Box 5-Pole L/N	4058075473010		pre-installed	✓ ³	pre-installed	pre-installed
	Connector Box 5-Pole L/N/PE/D+/D-	4058075691292	pre-installed ⁶	pre-installed	✓ ⁴	pre-installed	pre-installed
8	Panel 1200 Cable Extension Twist Lock	4099854018510				✓	

¹ The accessories are compatible with the Panels in the respectively matching size. For details refer to the User Instructions. | ² Not in combination with Panel IndivILED Emergency
³ Only with standard versions, not for DALI or Emergency versions | ⁴ Only with DALI or Emergency versions | ⁵ DALI versions only | ⁶ Zigbee version only



PANEL PRINT SKY

A NEW WORLD OF LIGHT

+ DESIGNED LIGHT EXPERIENCE
Individually printed luminous panels creating a natural-looking sky or featuring your own logo, photo, or design

+ HIGH-QUALITY PRINT
Premium printing realised in France for vivid, durable visuals


+ LIGHT CONTROL
DALI versions available for convenient dimming

TRY NOW. DESIGN YOUR LIGHT.
Contact your local LEDVANCE sales representative.


PRODUCT SIZES



PANEL SKY INDIVIDUAL
600 mm x 600 mm or
625 mm x 625 mm

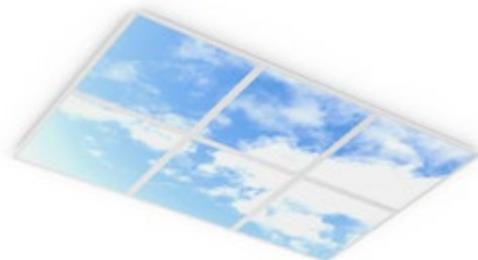

PANEL SKY SET6
6 x 600 mm x 600 mm or
6 x 625 mm x 625 mm

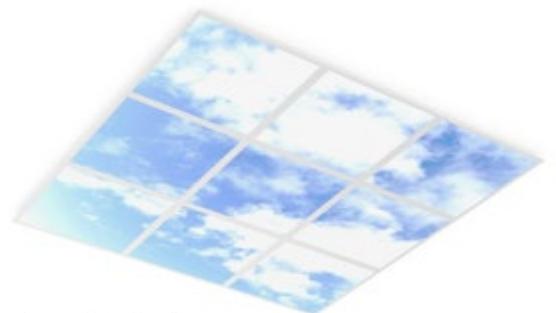

PANEL SKY SET9
9 x 600 mm x 600 mm or
9 x 625 mm x 625 mm

SPECIFICATION SERVICES FROM LEDVANCE



LEDVANCE
PROJECT SERVICES

ALL INFORMATION ON SUCCESSFUL PROJECTS CAN BE FOUND HERE:

ledvance.com/project-services

Besides LEDVANCE catalogue-standard products, we provide tailored solutions that match the complexity and specific needs of your project.

YOUR PROJECT IS OUR BUSINESS

Your competent contact person at LEDVANCE accompanies you through your whole project.

Being your single source for all lighting products and components makes working with us even more comfortable.

TESTING

We test products in our own accredited labs. This ensures that the highest quality standards are maintained even after the specification has been finalised.



IP water chamber testing



IP dust chamber testing



Electromagnetic compatibility (EMC) testing

SPECIFICATION


	EASY & FAST CHANGES	Add your specific setup and project requirements to our standard offerings.
	MID-LEVEL COMPLEXITY	Choose from our SPECIFY range and your customised modification.
	HIGH COMPLEXITY FROM SCRATCH	Completely customised products for your specific lighting needs.

ANY QUESTIONS? TALK TO US.

Are you interested in our services for your projects? Our project business experts are happy to advise you.

You can reach us at contact@ledvance.com or by phone on +49 89 780673-600

 
PANEL COMPACT 600 GEN 2



1

PANEL COMPACT 600

 Square recessed panel luminaires, 600 x 600 mm



2

PANEL COMPACT 600 MULTI SELECT

Square recessed panel luminaire with Multi Select function, 600 x 600 mm



3

PANEL COMPACT 600 DALI

Square recessed panel luminaire with DALI-2 IoT driver, 600 x 600 mm



4

PANEL COMPACT 600 DALI MULTI SELECT

Square recessed panel luminaire with Multi Select function and DALI-2 IoT driver, 600 x 600 mm

Product name ²		GTIN (EAN)	Replacement for	W	Im	lm/W	K	L80	△	⌒	L x W x H [mm] Ø x H [mm]	Light No.
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL COMPACT 600 <div style="display: flex; gap: 5px;"> </div> </div>												
NEW	PL COMP 600 V 26W 830	4099854734441	4x18/4x14 FL	26	3640	140	3000	75000	110		595 x 595 x 34	1
NEW	PL COMP 600 V 26W 840	4099854734489	4x18/4x14 FL	26	3640	140	4000	75000	110		595 x 595 x 34	1
NEW	PL COMP 600 V 26W 830 U19	4099854734465	4x18/4x14 FL	26	3640	140	3000	75000	90		595 x 595 x 34	1
NEW	PL COMP 600 V 26W 840 U19	4099854734502	4x18/4x14 FL	26	3640	140	4000	75000	90		595 x 595 x 34	1
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL COMPACT 600 MULTI SELECT <div style="display: flex; gap: 5px;"> </div> </div>												
NEW	PL COMP 600 V 30W ML 83040	4099854734526	4x18/4x14 FL	30 / 26 / 22	4200 / 3640 / 3080	140	3000 / 4000	75000	110		595 x 595 x 34	2
NEW	PL COMP 600 V 30W ML 84065	4099854734564	4x18/4x14 FL	30 / 26 / 22	4200 / 3640 / 3080	140	4000 / 6500	75000	110		595 x 595 x 34	2
NEW	PL COMP 600 V 30W ML 83040 U19	4099854734540	4x18/4x14 FL	30 / 26 / 22	4200 / 3640 / 3080	140	3000 / 4000	75000	90		595 x 595 x 34	2
NEW	PL COMP 600 V 30W ML 84065 U19	4099854734588	4x18/4x14 FL	30 / 26 / 22	4200 / 3640 / 3080	140	4000 / 6500	75000	90		595 x 595 x 34	2
NEW	PL COMP 600 V 30W ML 93040 U19	4099854734601	4x18/4x14 FL	30 / 26 / 22	4200 / 3640 / 3080	140	3000 / 4000	75000	90		595 x 595 x 34	2
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL COMPACT 600 DALI <div style="display: flex; gap: 5px;"> </div> </div>												
NEW	PL COMP 600 DA V 26W 830	4099854734762	4x18/4x14 FL	26	3640	140	3000	75000	110	DALI-2, IoT	595 x 595 x 34	3
NEW	PL COMP 600 DA V 26W 840	4099854734847	4x18/4x14 FL	26	3640	140	4000	75000	110	DALI-2, IoT	595 x 595 x 34	3
NEW	PL COMP 600 DA V 26W 830 U19	4099854734809	4x18/4x14 FL	26	3640	140	3000	75000	90	DALI-2, IoT	595 x 595 x 34	3
NEW	PL COMP 600 DA V 26W 840 U19	4099854734861	4x18/4x14 FL	26	3640	140	4000	75000	90	DALI-2, IoT	595 x 595 x 34	3
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL COMPACT 600 DALI MULTI SELECT <div style="display: flex; gap: 5px;"> </div> </div>												
NEW	PL COMP 600 DA V 30W 83040	4099854734885	4x18/4x14 FL	30	4200	140	3000 / 4000	75000	110	DALI-2, IoT	595 x 595 x 34	4
NEW	PL COMP 600 DA V 30W 84065	4099854734946	4x18/4x14 FL	30	4200	140	4000 / 6500	75000	110	DALI-2, IoT	595 x 595 x 34	4
NEW	PL COMP 600 DA V 30W 83040 U19	4099854734922	4x18/4x14 FL	30	4200	140	3000 / 4000	75000	90	DALI-2, IoT	595 x 595 x 34	4
NEW	PL COMP 600 DA V 30W 84065 U19	4099854734960	4x18/4x14 FL	30	4200	140	4000 / 6500	75000	90	DALI-2, IoT	595 x 595 x 34	4
NEW	PL COMP 600 DA V 30W 93040 U19	4099854734984	4x18/4x14 FL	30	4050	135	3000 / 4000	75000	90	DALI-2, IoT	595 x 595 x 34	4

■ SUPERIOR CLASS ■ PERFORMANCE CLASS ■ VALUE CLASS

¹ Refer to www.ledvance.com/guarantee for precise conditions | ² Available from March 2026

PANEL COMPACT 1200 GEN 2



PANEL COMPACT 1200
Rectangular recessed panel luminaires, 1200 x 300 mm

PANEL COMPACT 1200 MULTI SELECT
Rectangular recessed panel luminaire with Multi Select function, 1200 x 300 mm

PANEL COMPACT 1200 DALI
Rectangular recessed panel luminaire with DALI-2 IoT driver, 1200 x 300 mm



PANEL COMPACT 1200 DALI MULTI SELECT
Rectangular recessed panel luminaire with DALI-2 IoT driver, 1200 x 300 mm



PANEL COMPACT 1200 X 600
Rectangular recessed panel luminaires, 1200 x 600 mm



PANEL COMPACT 1200 X 600 DALI
Rectangular recessed panel luminaire with DALI-2 IoT driver, 1200 x 600 mm

Product name ²	GTIN (EAN)	Replacement for	W	lm	lm/W	K	L80	▲	⤵	L x W x H [mm] Ø x H [mm]	💡 No.
---------------------------	------------	-----------------	---	----	------	---	-----	---	---	------------------------------	----------

PANEL COMPACT 1200											
NEW	PL COMP 1200 V 26W 840	4099854735165	4x18/4x14 FL	26	3640	140	4000	75000	110	1195 x 295 x 34	1
NEW	PL COMP 1200 V 26W 840 U19	4099854735684	4x18/4x14 FL	26	3640	140	4000	75000	90	1195 x 295 x 34	1

PANEL COMPACT 1200 MULTI SELECT											
	PL COMP 1200 V 30W ML 83040	4099854735707	4x18/4x14 FL	30 / 26 / 22	4200 / 3640 / 3080	140	3000 / 4000	75000	110	1195 x 295 x 34	2
	PL COMP 1200 V 30W ML 83040 U19	4099854735721	4x18/4x14 FL	30 / 26 / 22	4200 / 3640 / 3080	140	3000 / 4000	75000	90	1195 x 295 x 34	2
	PL COMP 1200 V 30W ML 84065 U19	4099854735745	4x18/4x14 FL	30 / 26 / 22	4200 / 3640 / 3080	140	4000 / 6500	75000	90	1195 x 295 x 34	2
	PL COMP 1200 V 30W ML 93040 U19	4099854735769	4x18/4x14 FL	30 / 26 / 22	4200 / 3640 / 3080	140	3000 / 4000	75000	90	1195 x 295 x 34	2

PANEL COMPACT 1200 DALI												
	PL COMP 1200 DA V 26W 840	4099854735806	4x18/4x14 FL	26	3640	140	4000	75000	110	DALI-2, IoT	1195 x 295 x 34	3
	PL COMP 1200 DA V 26W 840 U19	4099854735844	4x18/4x14 FL	26	3640	140	4000	75000	90	DALI-2, IoT	1195 x 295 x 34	3

PANEL COMPACT 1200 DALI MULTI SELECT												
	PL COMP 1200 DA V 30W 83040	4099854735882	4x18/4x14 FL	30	4200	140	3000 / 4000	75000	110	DALI-2, IoT	1195 x 295 x 34	4
	PL COMP 1200 DA V 30W 83040 U19	4099854735929	4x18/4x14 FL	30	4200	140	3000 / 4000	75000	90	DALI-2, IoT	1195 x 295 x 34	4
	PL COMP 1200 DA V 30W 84065 U19	4099854735967	4x18/4x14 FL	30	4200	140	4000 / 6500	75000	90	DALI-2, IoT	1195 x 295 x 34	4
	PL COMP 1200 DA V 30W 93040 U19	4099854735981	4x18/4x14 FL	30	4050	135	3000 / 4000	75000	90	DALI-2, IoT	1195 x 295 x 34	4

PANEL COMPACT 1200 X 600											
NEW	PL COMP 1200X600 V 42W ML 83040	4099854736865	4x18/4x14 FL	42 / 32 / 28	5880 / 4480 / 3920	140	3000 / 4000	75000	110	1195 x 595 x 34	5
	PL COMP 1200X600 V 42W ML 83040 U19	4099854736988	4x18/4x14 FL	42 / 32 / 28	5880 / 4480 / 3920	140	3000 / 4000	75000	90	1195 x 595 x 34	5


PANEL COMPACT 1200 X 600 DALI												
	PL COMP 1200X600 DA V 42W 83040	4099854737046	4x18/4x14 FL	42	5880	140	3000 / 4000	75000	110	DALI-2, IoT	1195 x 595 x 34	6
NEW	PL COMP 1200X600 DA V 42W 83040 U19	4099854737183	4x18/4x14 FL	42	5880	140	3000 / 4000	75000	90	DALI-2, IoT	1195 x 595 x 34	6

■ SUPERIOR CLASS ■ PERFORMANCE CLASS ■ VALUE CLASS

¹ Refer to www.ledvance.com/guarantee for precise conditions | ² Available from March 2026

PANEL COMPACT DRIVERS

Sparepart drivers for PANEL COMPACT GEN 2

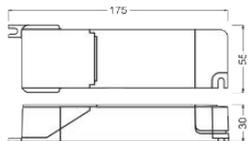

Product name ²	GTIN (EAN)	W		L x W x H [mm] Ø x H [mm]
DR DS-V 26/220-240/700 PL COMP	4099854748813	26	Not dimmable	175 x 55 x 30
DR DS-V 30/220-240/800 PL COMP	4099854748837	30 / 26 / 22	Not dimmable	175 x 55 x 30
DR DS-V 42/220-240/1150 PL COMP1260	4099854748851	42 / 32 / 28	Not dimmable	175 x 55 x 30

PANEL INDIVILED 600 / 625 GEN 2



1

PANEL INDIVILED 600 DALI UGR<19 GEN 2

Square recessed panel luminaires with Multi Select, DALI-2 IoT driver, EVERLOOP design and low glare, 600 x 600 mm



2

PANEL INDIVILED 600 ZIGBEE UGR<19 GEN 2

Square recessed panel luminaires with Zigbee 3.0, EVERLOOP design and low glare, 600 x 600 mm



3

PANEL INDIVILED 625 DALI UGR<19 GEN 2

Square recessed panel luminaires with Multi Select, DALI-2 IoT driver, EVERLOOP design and low glare, 625 x 625 mm



4

PANEL INDIVILED 625 ZIGBEE UGR<19 GEN 2

Square recessed panel luminaires with Multi Select, Zigbee 3.0, EVERLOOP design and low glare, 625 x 625 mm

Product name ²		GTIN (EAN)	Replacement for	W	lm	lm/W	K	L80	△	⌒	L x W x H [mm] ∅ x H [mm]	Light No.
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL INDIVILED 600 DALI UGR<19 GEN 2 <div style="display: flex; gap: 5px;"> </div> </div>												
	PL INV 600 DA P 38W ML 930 U19 WT	4099854736162	4x18 FL	38 / 34 / 29 / 24	4900 / 4350 / 3850 / 3150	129 / 128 / 133 / 131	3000	70000	90	DALI-2, IoT	595 x 595 x 22	1
	PL INV 600 DA P 38W ML 930 U19 BK	4099854736247	4x18 FL	38 / 34 / 29 / 24	4700 / 4250 / 3700 / 3100	124 / 125 / 128 / 129	3000	70000	90	DALI-2, IoT	595 x 595 x 22	1
	PL INV 600 DA P 38W ML 940 U19 WT	4099854736209	4x18 FL	38 / 34 / 29 / 24	5150 / 4650 / 4000 / 3350	136 / 137 / 138 / 140	4000	70000	90	DALI-2, IoT	595 x 595 x 22	1
	PL INV 600 DA P 38W ML 940 U19 BK	4099854736285	4x18 FL	38 / 34 / 29 / 24	4900 / 4300 / 3750 / 3150	129 / 126 / 131	4000	70000	90	DALI-2, IoT	595 x 595 x 22	1
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL INDIVILED 600 ZIGBEE UGR<19 GEN 2 <div style="display: flex; gap: 5px;"> </div> </div>												
NEW	PL INV 600 ZB P 38W 930 U19 WT	4099854789175	4x18 FL	38	4900	129	3000	70000	90	Zigbee Direct, IoT	595 x 595 x 22	2
NEW	PL INV 600 ZB P 38W 930 U19 BK	4099854789199	4x18 FL	38	4700	124	3000	70000	90	Zigbee Direct, IoT	595 x 595 x 22	2
NEW	PL INV 600 ZB P 38W 940 U19 WT	4099854789212	4x18 FL	38	5150	136	4000	70000	90	Zigbee Direct, IoT	595 x 595 x 22	2
NEW	PL INV 600 ZB P 38W 940 U19 BK	4099854789236	4x18 FL	38	4900	129	4000	70000	90	Zigbee Direct, IoT	595 x 595 x 22	2
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL INDIVILED 625 DALI UGR<19 GEN 2 <div style="display: flex; gap: 5px;"> </div> </div>												
	PL INV 625 DA P 38W ML 930 U19 WT	4099854736186	4x18 FL	38 / 34 / 29 / 24	4900 / 4300 / 3850 / 3150	129 / 128 / 133 / 131	3000	70000	90	DALI-2, IoT	620 x 620 x 22	3
NEW	PL INV 625 DA P 38W ML 930 U19 BK	4099854736261	4x18 FL	38 / 34 / 29 / 24	4700 / 4250 / 3700 / 3100	124 / 125 / 128 / 129	3000	70000	90	DALI-2, IoT	620 x 620 x 22	3
	PL INV 625 DA P 38W ML 940 U19 WT	4099854736223	4x18 FL	38 / 34 / 29 / 24	5150 / 4650 / 4000 / 3350	136 / 137 / 138 / 140	4000	70000	90	DALI-2, IoT	620 x 620 x 22	3
	PL INV 625 DA P 38W ML 940 U19 BK	4099854736308	4x18 FL	38 / 34 / 29 / 24	4900 / 4300 / 3750 / 3150	129 / 126 / 131	4000	70000	90	DALI-2, IoT	620 x 620 x 22	3
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL INDIVILED 625 ZIGBEE UGR<19 GEN 2 <div style="display: flex; gap: 5px;"> </div> </div>												
NEW	PL INV 625 ZB P 38W 930 U19 WT	4099854789250	4x18 FL	38	4900	129	3000	70000	90	Zigbee Direct, IoT	620 x 620 x 22	4
NEW	PL INV 625 ZB P 38W 930 U19 BK	4099854789274	4x18 FL	38	4700	124	3000	70000	90	Zigbee Direct, IoT	620 x 620 x 22	4
NEW	PL INV 625 ZB P 38W 940 U19 WT	4099854789298	4x18 FL	38	5150	136	4000	70000	90	Zigbee Direct, IoT	620 x 620 x 22	4
NEW	PL INV 625 ZB P 38W 940 U19 BK	4099854789311	4x18 FL	38	4900	129	4000	70000	90	Zigbee Direct, IoT	620 x 620 x 22	4

■ SUPERIOR CLASS ■ PERFORMANCE CLASS ■ VALUE CLASS

¹ Refer to www.ledvance.com/guarantee for precise conditions | ² Available from March 2026

PANEL INDIVILED LIGHT SOURCES DIRECT

Upgrade or replacement light source unit for symmetric light distribution



PRODUCT FEATURES

- Symmetric light distribution
- Lifetime (L80/B10): 70,000 h (at 25 °C)
- Beam angle: 90°


PRODUCT BENEFITS

- Easy upgradeability of light source and driver (EVERLOOP design)
- Easy installation, no tools required for connection
- Homogenous light distribution and reduced glare (UGR ≤ 19) thanks to IndiviLED® optics
- High performance with CRI90

AREAS OF APPLICATION

- Direct replacement for luminaires with fluorescent lamps
- Offices, education, public buildings

FURTHER PRODUCT DETAILS

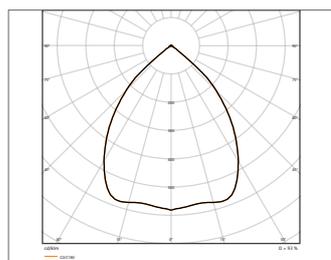

LISOEV 544X29 24 19W 930 S90U19 BK

UGR
<19

IP20

LEDVANCE
5
year
guarantee

Product name ²	GTIN (EAN)	W	lm	lm/W	K	L80	°	L × W × H [mm] Ø × H [mm]
NEW LISOEV 544X29 24 19W 930 S90U19 BK	4099854793752	19	2350	124	3000	70000	90	544 x 29 x 19
NEW LISOEV 544X29 25 19W 930 S90U19 GY	4099854793691	19	2450	129	3000	70000	90	544 x 29 x 19
NEW LISOEV 544X29 25 19W 940 S90U19 BK	4099854793783	19	2450	129	4000	70000	90	544 x 29 x 19
NEW LISOEV 544X29 26 19W 940 S90U19 GY	4099854793721	19	2600	137	4000	70000	90	544 x 29 x 19

SAFETY ADVICE

All electrical connections must be made by a qualified person.

LINEAR INDIVILED LIGHT SOURCES DIRECT

Upgrade or replacement light source unit for symmetric light distribution



PRODUCT FEATURES

- Symmetric light distribution
- Lifetime (L80/B10): 70,000 h (at 25 °C)
- Beam angle: 90°


PRODUCT BENEFITS

- Easy upgradeability of light source and driver (EVERLOOP design)
- Easy installation, no tools required for connection
- Homogenous light distribution and reduced glare (UGR \leq 19) thanks to IndiviLED® optics
- High performance with CRI90

AREAS OF APPLICATION

- Direct replacement for luminaires with fluorescent lamps
- Offices, education, public buildings

FURTHER PRODUCT DETAILS

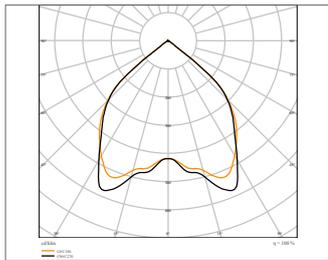

LISOEV 1074x29 46 40W 930 S90U19 BK

UGR
< 19

CRI
≥ 90

IP 20


LEDVANCE
5 year
guarantee

Product name	GTIN (EAN)	W	lm	lm/w	K	L80	°	L x W x H [mm] Ø x H [mm]
LISOEV 1074x29 46 40W 930 S90U19 BK	4099854652059	40	4650	116	3000	70000	90	1074 x 29 x 19
LISOEV 1074x29 48 40W 930 S90U19 GY	4099854284359	40	4800	120	3000	70000	90	1074 x 29 x 19
LISOEV 1074x29 49 40W 940 S90U19 BK	4099854652080	40	4900	123	4000	70000	90	1074 x 29 x 19
LISOEV 1074x29 50 40W 940 S90U19 GY	4099854284809	40	5050	126	4000	70000	90	1074 x 29 x 19

SAFETY ADVICE

All electrical connections must be made by a qualified person.

PANEL PROTECT 600

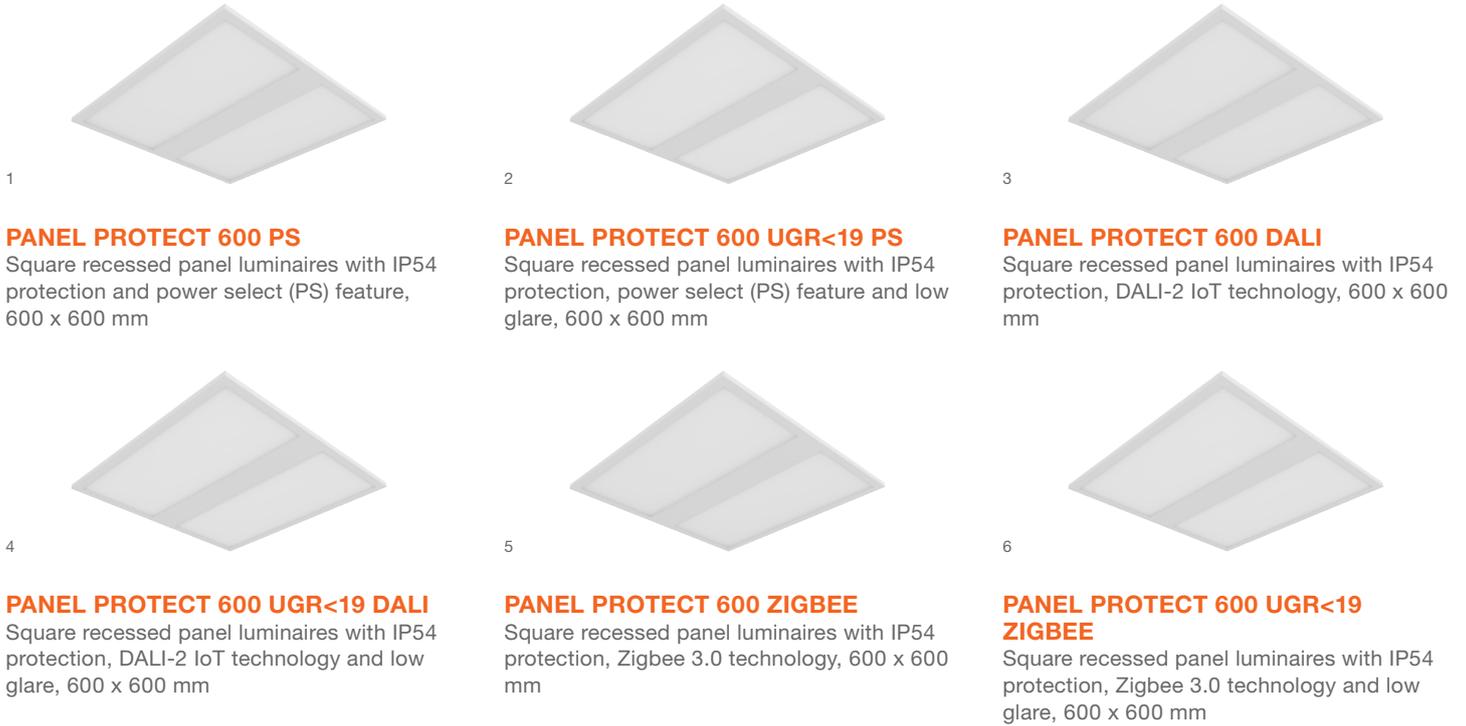

PANEL PROTECT 600 PS
Square recessed panel luminaires with IP54 protection and power select (PS) feature, 600 x 600 mm

PANEL PROTECT 600 UGR<19 PS
Square recessed panel luminaires with IP54 protection, power select (PS) feature and low glare, 600 x 600 mm

PANEL PROTECT 600 DALI
Square recessed panel luminaires with IP54 protection, DALI-2 IoT technology, 600 x 600 mm

PANEL PROTECT 600 UGR<19 DALI
Square recessed panel luminaires with IP54 protection, DALI-2 IoT technology and low glare, 600 x 600 mm

PANEL PROTECT 600 ZIGBEE
Square recessed panel luminaires with IP54 protection, Zigbee 3.0 technology, 600 x 600 mm

PANEL PROTECT 600 UGR<19 ZIGBEE
Square recessed panel luminaires with IP54 protection, Zigbee 3.0 technology and low glare, 600 x 600 mm

Product name	GTIN (EAN)	Replacement for	W ²	lm ²	lm/W ²	K	L80	°	°	L x W x H [mm] Ø x H [mm]	Light No.
<div style="display: flex; justify-content: space-between; align-items: center;"> EFFICIENT CLASS UNIVERSAL RES TUV DIM DALI-2 IoT IP54 5 year guarantee </div>											
PANEL PROTECT 600 PS											
PL PROT 600 P 36W 830 PS	4099854082863	4x18 FL	36 / 31 / 26 / 22	5040 / 4340 / 3640 / 3080	140	3000	70000	120		595 x 595 x 34	1
PL PROT 600 P 36W 840 PS	4099854082887	4x18 FL	36 / 31 / 26 / 22	5040 / 4340 / 3640 / 3080	140	4000	70000	120		595 x 595 x 34	1
PANEL PROTECT 600 UGR<19 PS											
PL PROT 600 P 36W 840 U19 PS	4099854083303	4x18 FL	36 / 31 / 26 / 22	5040 / 4340 / 3640 / 3080	140	4000	70000	90		595 x 595 x 34	2
PANEL PROTECT 600 DALI											
PL PROT 600 P 36W 830 DALIVR	4099854082900	4x18 FL	36	5040	140	3000	70000	120	DALI-2, IoT	595 x 595 x 34	3
PL PROT 600 P 36W 840 DALIVR	4099854083105	4x18 FL	36	5040	140	4000	70000	120	DALI-2, IoT	595 x 595 x 34	3
PANEL PROTECT 600 UGR<19 DALI											
PL PROT 600 P 36W 840 U19 DALIVR	4099854083327	4x18 FL	36	5040	140	4000	70000	90	DALI-2, IoT	595 x 595 x 34	4
PANEL PROTECT 600 ZIGBEE											
PL PROT 600 ZB P 36W 830	4099854514531	4x18 FL	36	5040	140	3000	70000	120	Zigbee Direct, IoT	595 x 595 x 34	5
PL PROT 600 ZB P 36W 840	4099854514555	4x18 FL	36	5040	140	4000	70000	120	Zigbee Direct, IoT	595 x 595 x 34	5
PANEL PROTECT 600 UGR<19 ZIGBEE											
PL PROT 600 ZB P 36W 840 U19	4099854514593	4x18 FL	36	5040	140	4000	70000	90	Zigbee Direct, IoT	595 x 595 x 34	6

■ SUPERIOR CLASS ■ PERFORMANCE CLASS ■ VALUE CLASS

¹ Refer to www.ledvance.com/guarantee for precise conditions | ² The Panel Protect family is fulfilling the technical minimum requirements according to the German BEG subsidy program for energy efficient luminaires

PANEL PROTECT 625



PANEL PROTECT 625 PS
Square recessed panel luminaires with IP54 protection and power select (PS) feature, 625 x 625 mm



PANEL PROTECT 625 UGR<19 PS
Square recessed panel luminaires with IP54 protection, power select (PS) feature and low glare, 625 x 625 mm



PANEL PROTECT 625 DALI
Square recessed panel luminaires with IP54 protection, DALI-2 IoT technology, 625 x 625 mm



PANEL PROTECT 625 UGR<19 DALI
Square recessed panel luminaires with IP54 protection, DALI-2 IoT technology and low glare, 625 x 625 mm



PANEL PROTECT 625 ZIGBEE
Square recessed panel luminaires with IP54 protection, Zigbee 3.0 technology, 625 x 625 mm




PANEL PROTECT 625 UGR<19 ZIGBEE
Square recessed panel luminaires with IP54 protection, Zigbee 3.0 technology and low glare, 625 x 625 mm

Product name	GTIN (EAN)	Replacement for	W ²	lm ²	lm/W ²	K	L80	°	°	L x W x H [mm] Ø x H [mm]	Light No.
<div style="display: flex; justify-content: space-between; align-items: center;"> EFFICIENT CLASS UNIVERSAL RES TUV DIM DALI-2 IoT IP54 5 year guarantee </div>											
PANEL PROTECT 625 PS											
PL PROT 625 P 36W 830 PS	4099854083365	4x18 FL	36 / 31 / 26 / 22	5040 / 4340 / 3640 / 3080	140	3000	70000	120		620 x 620 x 34	1
PL PROT 625 P 36W 840 PS	4099854083389	4x18 FL	36 / 31 / 26 / 22	5040 / 4340 / 3640 / 3080	140	4000	70000	120		620 x 620 x 34	1
PANEL PROTECT 625 UGR<19 PS											
PL PROT 625 P 36W 840 U19 PS	4099854083488	4x18 FL	36 / 31 / 26 / 22	5040 / 4340 / 3640 / 3080	140	4000	70000	90		620 x 620 x 34	2
PANEL PROTECT 625 DALI											
PL PROT 625 P 36W 830 DALIVR	4099854083402	4x18 FL	36	5040	140	3000	70000	120	DALI-2, IoT	620 x 620 x 34	3
PL PROT 625 P 36W 840 DALIVR	4099854083440	4x18 FL	36	5040	140	4000	70000	120	DALI-2, IoT	620 x 620 x 34	3
PANEL PROTECT 625 UGR<19 DALI											
PL PROT 625 P 36W 840 U19 DALIVR	4099854083501	4x18 FL	36	5040	140	4000	70000	90	DALI-2, IoT	620 x 620 x 34	4
PANEL PROTECT 625 ZIGBEE											
PL PROT 625 ZB P 36W 830	4099854514630	4x18 FL	36	5040	140	3000	70000	120	Zigbee Direct, IoT	620 x 620 x 34	5
PL PROT 625 ZB P 36W 840	4099854514654	4x18 FL	36	5040	140	4000	70000	120	Zigbee Direct, IoT	620 x 620 x 34	5
PANEL PROTECT 625 UGR<19 ZIGBEE											
PL PROT 625 ZB P 36W 840 U19	4099854514692	4x18 FL	36	5040	140	4000	70000	90	Zigbee Direct, IoT	620 x 620 x 34	6

■ SUPERIOR CLASS ■ PERFORMANCE CLASS ■ VALUE CLASS

¹ Refer to www.ledvance.com/guarantee for precise conditions | ² The Panel Protect family is fulfilling the technical minimum requirements according to the German BEG subsidy program for energy efficient luminaires

PANEL SURFACE 674

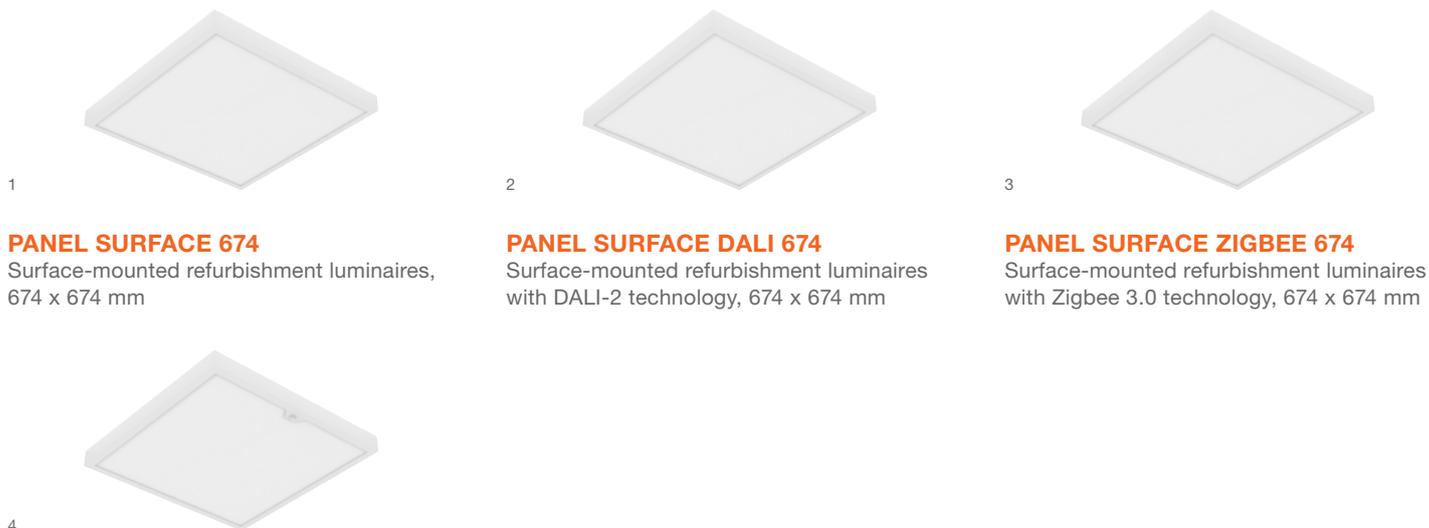

PANEL SURFACE 674
Surface-mounted refurbishment luminaire, 674 x 674 mm

PANEL SURFACE DALI 674
Surface-mounted refurbishment luminaire with DALI-2 technology, 674 x 674 mm

PANEL SURFACE ZIGBEE 674
Surface-mounted refurbishment luminaire with Zigbee 3.0 technology, 674 x 674 mm

PANEL SURFACE SENSOR 674
Surface-mounted refurbishment luminaire with integrated PIR sensor, 674 x 674 mm

Product name ²		GTIN (EAN)	W	lm ³	lm/W	K	L80	°	⤵	L x W x H [mm] Ø x H [mm]	Light No.
PANEL SURFACE 674											
NEW	PL SF 674 V 32W ML 93040	4099854729935	32 / 27 / 21	4160 / 3645 / 2940	140 / 135 / 130	3000 / 4000	75000	120	VALUE CLASS	674 x 674 x 69	1
NEW	PL SF 674 V 32W ML 93040 U19	4099854729959	32 / 27 / 21	4160 / 3645 / 2940	140 / 135 / 130	3000 / 4000	75000	90	VALUE CLASS	674 x 674 x 69	1
PANEL SURFACE DALI 674											
NEW	PL SF 674 DA V 32W 93040	4099854731563	32	4160	130	3000 / 4000	75000	120	DALI-2, IoT	674 x 674 x 69	2
NEW	PL SF 674 DA V 32W 93040 U19	4099854731587	32	4160	130	3000 / 4000	75000	90	DALI-2, IoT	674 x 674 x 69	2
PANEL SURFACE ZIGBEE 674											
NEW	PL SF 674 ZB V 32W 93040	4099854730566	32	4160	130	3000 / 4000	75000	120	Zigbee Direct, IoT	674 x 674 x 69	3
NEW	PL SF 674 ZB V 32W 93040 U19	4099854730665	32	4160	130	3000 / 4000	75000	90	Zigbee Direct, IoT	674 x 674 x 69	3
PANEL SURFACE SENSOR 674											
NEW	PL SF 674 SNP V 32W ML 93040	4099854731808	32 / 27 / 21	4160 / 3645 / 2940	140 / 135 / 130	3000 / 4000	75000	120	VALUE CLASS	674 x 674 x 78	4
NEW	PL SF 674 SNP V 32W ML 93040 U19	4099854731884	32 / 27 / 21	4160 / 3645 / 2940	140 / 135 / 130	3000 / 4000	75000	90	VALUE CLASS	674 x 674 x 78	4

SENSOR PROPERTIES

Product name	GTIN (EAN)	Type of sensor	Sensor technology	Detection threshold of daylight sensor	Detection range of motion sensor	Sensor detection angle	Sensor controlled switching time
PL SF 674 SNP V 32W ML 93040	4099854731808	Motion	Passive infrared (PIR)	10...150	1...3	360	5 s...20
PL SF 674 SNP V 32W ML 93040 U19	4099854731884	Motion	Passive infrared (PIR)	10...150	1...3	360	5 s...20

■ SUPERIOR CLASS ■ PERFORMANCE CLASS ■ VALUE CLASS

¹ Refer to www.ledvance.com/guarantee for precise conditions | ² Available from March 2026 | ³ 4000 lm / 3510 lm / 2835 lm @3000K | ⁴ 4000 lm @3000K

PANEL SURFACE 1274



1



2



3

PANEL SURFACE 1274

Surface-mounted refurbishment luminaires, 1274 x 374 mm

PANEL SURFACE DALI 1274

Surface-mounted refurbishment luminaires with DALI-2 technology, 1274 x 374 mm

PANEL SURFACE ZIGBEE 1274

Surface-mounted refurbishment luminaires with Zigbee 3.0 technology, 1274 x 374 mm



4

PANEL SURFACE SENSOR 1274

Surface-mounted refurbishment luminaires with integrated PIR sensor, 1274 x 374 mm

Product name ²		GTIN (EAN)	W	lm ³	lm/w	K	L80	⚡	🔄	L x W x H [mm] Ø x H [mm]	💡 No.
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL SURFACE 1274 <div style="display: flex; gap: 5px;"> VALUE CLASS MINI LED LEDVANCE 🔧 📐 FLICKER FREE <5% CRI >90 5 year guarantee </div> </div>											
NEW	PL SF 1274 V 38W ML 93040	4099854729973	38 / 31 / 27	5000 / 4030 / 3645	135 / 130	3000 / 4000	75000	120		1274 x 373 x 69	1
NEW	PL SF 1274 V 38W ML 93040 U19	4099854729997	38 / 31 / 27	5000 / 4030 / 3645	135 / 130	3000 / 4000	75000	90		1274 x 373 x 69	1
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL SURFACE DALI 1274 <div style="display: flex; gap: 5px;"> VALUE CLASS MINI LED LEDVANCE 🔧 📐 FLICKER FREE <5% CRI >90 5 year guarantee </div> </div>											
NEW	PL SF 1274 DA V 38W 93040	4099854731648	38	5000	130	3000 / 4000	75000	120	DALI-2, IoT	1274 x 373 x 69	2
	PL SF 1274 DA V 38W 93040 U19	4099854731662	38	5000	130	3000 / 4000	75000	90	DALI-2, IoT	1274 x 373 x 69	2
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL SURFACE ZIGBEE 1274 <div style="display: flex; gap: 5px;"> VALUE CLASS MINI LED LEDVANCE 🔧 📐 FLICKER FREE <5% CRI >90 5 year guarantee </div> </div>											
NEW	PL SF 1274 ZB V 38W 93040	4099854731600	38	5000	130	3000 / 4000	75000	120	Zigbee Direct, IoT	1274 x 373 x 69	3
NEW	PL SF 1274 ZB V 38W 93040 U19	4099854731624	38	5000	130	3000 / 4000	75000	90	Zigbee Direct, IoT	1274 x 373 x 69	3
<div style="display: flex; justify-content: space-between; align-items: center;"> PANEL SURFACE SENSOR 1274 <div style="display: flex; gap: 5px;"> VALUE CLASS MINI LED LEDVANCE 🔧 📐 FLICKER FREE <5% CRI >90 5 year guarantee </div> </div>											
NEW	PL SF 1274 SNP V 38W ML 93040	4099854731907	38 / 31 / 27	5000 / 4030 / 3645	135 / 130	3000 / 4000	75000	120		1274 x 373 x 78	4
NEW	PL SF 1274 SNP V 38W ML 93040 U19	4099854731921	38 / 31 / 27	5000 / 4030 / 3645	135 / 130	3000 / 4000	75000	90		1274 x 373 x 78	4

SENSOR PROPERTIES

Product name	GTIN (EAN)	Type of sensor	Sensor technology	Detection threshold of daylight sensor	Detection range of motion sensor	Sensor detection angle	Sensor controlled switching time
PL SF 1274 SNP V 38W ML 93040	4099854731907	Motion	Passive infrared (PIR)	10...150	1...3	360	5 s...20
PL SF 1274 SNP V 38W ML 93040 U19	4099854731921	Motion	Passive infrared (PIR)	10...150	1...3	360	5 s...20

■ SUPERIOR CLASS ■ PERFORMANCE CLASS ■ VALUE CLASS

¹ Refer to www.ledvance.com/guarantee for precise conditions | ² Available from March 2026 | ³ 4750 lm / 4030 lm / 3510 lm @3000K | ⁴ 4750 lm @3000K

PANEL SURFACE 1574



PANEL SURFACE 1574
Surface-mounted refurbishment luminaire,
1574 x 374 mm

PANEL SURFACE DALI 1574
Surface-mounted refurbishment luminaire
with DALI-2 technology, 1574 x 374 mm

PANEL SURFACE ZIGBEE 1574
Surface-mounted refurbishment luminaire
with Zigbee 3.0 technology, 1574 x 374 mm



PANEL SURFACE SENSOR 1574
Surface-mounted refurbishment luminaire
with integrated PIR sensor, 1574 x 374 mm

Product name ²		GTIN (EAN)	W	lm ³	lm/w	K	L80	°	⤵	L x W x H [mm] Ø x H [mm]	💡 No.
PANEL SURFACE 1574											
NEW	PL SF 1574 V 48W ML 93040	4099854 730016	48 / 39 / 31	6240 / 5265 / 4030	140 / 135 / 130	3000 / 4000	75000	120		1574 x 373 x 69	1
NEW	PL SF 1574 V 48W ML 93040 U19	4099854 730542	48 / 39 / 31	6240 / 5265 / 4030	140 / 135 / 130	3000 / 4000	75000	90		1574 x 373 x 69	1
PANEL SURFACE DALI 1574											
	PL SF 1574 DA V 48W 93040	4099854 731723	48	6240	130	3000 / 4000	75000	120	DALI-2, IoT	1574 x 373 x 69	2
	PL SF 1574 DA V 48W 93040 U19	4099854 731747	48	6240	130	3000 / 4000	75000	90	DALI-2, IoT	1574 x 373 x 69	2
PANEL SURFACE ZIGBEE 1574											
NEW	PL SF 1574 ZB V 48W 93040	4099854 731686	48	6240	130	3000 / 4000	75000	120	Zigbee Direct, IoT	1574 x 373 x 69	3
NEW	PL SF 1574 ZB V 48W 93040 U19	4099854 731709	48	6240	130	3000 / 4000	75000	90	Zigbee Direct, IoT	1574 x 373 x 69	3
PANEL SURFACE SENSOR 1574											
NEW	PL SF 1574 SNP V 48W ML 93040	4099854 731969	48 / 39 / 31	6240 / 5265 / 4030	140 / 135 / 130	3000 / 4000	75000	120		1574 x 373 x 78	4
NEW	PL SF 1574 SNP V 48W ML 93040 U19	4099854 731983	48 / 39 / 31	6240 / 5265 / 4030	140 / 135 / 130	3000 / 4000	75000	90		1574 x 373 x 78	4

SENSOR PROPERTIES

Product name	GTIN (EAN)	Type of sensor	Sensor technology	Detection threshold of daylight sensor	Detection range of motion sensor	Sensor detection angle	Sensor controlled switching time
PL SF 1574 SNP V 48W ML 93040	4099854 731969	Motion	Passive infrared (PIR)	10...150	1...3	360	5 s...20
PL SF 1574 SNP V 48W ML 93040 U19	4099854 731983	Motion	Passive infrared (PIR)	10...150	1...3	360	5 s...20

■ SUPERIOR CLASS ■ PERFORMANCE CLASS ■ VALUE CLASS

¹ Refer to www.ledvance.com/guarantee for precise conditions | ² Available from March 2026 | ³ 6000 lm / 5070 lm / 4185 lm @3000K | ⁴ 6000 lm @3000K

PANEL SURFACE SUSPENSION KIT

Suspension kit with integrated cable and terminal block



	Product name ²	GTIN (EAN)	L x W x H [mm] Ø x H [mm]
NEW	PL SF SUSPENSION KIT L/E/N	4099854732003	151 x 50
NEW	PL SF SUSPENSION KIT L/E/N/DA+/DA-	4099854732027	151 x 50

PANEL PRINT SKY 600



1

PANEL PRINT SKY 600
Panel luminaires featuring a printed realistic sky image, for 600 x 600 ceiling systems



2

PANEL PRINT SKY 600 DALI
Panel luminaires featuring a printed realistic sky image, for 600 x 600 mm ceiling systems and DALI-2 technology



3

PANEL PRINT SKY 600
Panel luminaires featuring a printed realistic sky image, for 600 x 600 ceiling systems



4

PANEL PRINT SKY 600 DALI
Panel luminaires featuring a printed realistic sky image, for 600 x 600 mm ceiling systems and DALI-2 technology



5

PANEL PRINT SKY 600
Panel luminaires featuring a printed realistic sky image, for 600 x 600 ceiling systems



6

PANEL PRINT SKY 600 DALI
Panel luminaires featuring a printed realistic sky image, for 600 x 600 mm ceiling systems and DALI-2 technology

Product name	GTIN (EAN)	W	lm ²	lm/W ²	L80	△ _c	⌚	L x W x H [mm] Ø x H [mm]	Light No.
PANEL PRINT SKY 600									
PL PRINT SKY1 600 V 33W	4099854535413	33	3630	110	50000	120		595 x 595 x 32	1
PANEL PRINT SKY 600 DALI									
PL PRINT SKY1 DA 600 V 33W	4099854534744	33	3630	110	50000	120	DALI-2, IoT	595 x 595 x 32	2
PANEL PRINT SKY 600									
PL PRINT SKY 600 V 33W SET6	4099854538377	198	21870	110	50000	120		595 x 595 x 32	3
PANEL PRINT SKY 600 DALI									
PL PRINT SKY DA 600 V 33W SET6	4099854538360	198	21870	110	50000	120	DALI-2, IoT	595 x 595 x 32	4
PANEL PRINT SKY 600									
PL PRINT SKY 600 V 33W SET9	4099854538414	297	32670	110	50000	120		595 x 595 x 32	5
PANEL PRINT SKY 600 DALI									
PL PRINT SKY DA 600 V 33W SET9	4099854538407	297	32670	110	50000	120	DALI-2, IoT	595 x 595 x 32	6

SAFETY ADVICE
The individual pattern can have influence on the perceived CRI, color temperature and lumen value.

■ SUPERIOR CLASS ■ PERFORMANCE CLASS ■ VALUE CLASS

¹ Refer to www.ledvance.com/guarantee for precise conditions | ² Decorative Panel: Lumen/Efficacy as well as SDCM and CRI will vary from the original Panel values based on the printed image

PANEL PRINT SKY 625



1

PANEL PRINT SKY 625

Panel luminaires featuring a printed realistic sky image, for 625 x 625 ceiling systems



2

PANEL PRINT SKY 625 DALI

Panel luminaires featuring a printed realistic sky image, for 625 x 625 mm ceiling systems and DALI-2 technology



3

PANEL PRINT SKY 625

Panel luminaires featuring a printed realistic sky image, for 625 x 625 ceiling systems



4

PANEL PRINT SKY 625 DALI

Panel luminaires featuring a printed realistic sky image, for 625 x 625 mm ceiling systems and DALI-2 technology



5

PANEL PRINT SKY 625

Panel luminaires featuring a printed realistic sky image, for 625 x 625 ceiling systems



6

PANEL PRINT SKY 625 DALI

Panel luminaires featuring a printed realistic sky image, for 625 x 625 mm ceiling systems and DALI-2 technology

Product name	GTIN (EAN)	W	lm ²	lm/W ²	L80	△ ^c	⌚	L x W x H [mm] Ø x H [mm]	💡 No.
PANEL PRINT SKY 625									
PL PRINT SKY1 625 V 33W	4099854536212	33	3630	110	50000	120		620 x 620 x 32	1
PANEL PRINT SKY 625 DALI									
PL PRINT SKY1 DA 625 V 33W	4099854536038	33	3630	110	50000	120	DALI-2, IoT	620 x 620 x 32	2
PANEL PRINT SKY 625									
PL PRINT SKY 625 V 33W SET6	4099854538353	198	21870	110	50000	120		620 x 620 x 32	3
PANEL PRINT SKY 625 DALI									
PL PRINT SKY DA 625 V 33W SET6	4099854538346	198	21870	110	50000	120	DALI-2, IoT	620 x 620 x 32	4
PANEL PRINT SKY 625									
PL PRINT SKY 625 V 33W SET9	4099854538391	297	32670	110	50000	120		620 x 620 x 32	5
PANEL PRINT SKY 625 DALI									
PL PRINT SKY DA 625 V 33W SET9	4099854538384	297	32670	110	50000	120	DALI-2, IoT	620 x 620 x 32	6


SAFETY ADVICE

The individual pattern can have influence on the perceived CRI, color temperature and lumen value.

■ SUPERIOR CLASS ■ PERFORMANCE CLASS ■ VALUE CLASS

¹ Refer to www.ledvance.com/guarantee for precise conditions | ² Decorative Panel: Lumen/Efficacy as well as SDCM and CRI will vary from the original Panel values based on the printed image

PANEL ACCESSORIES

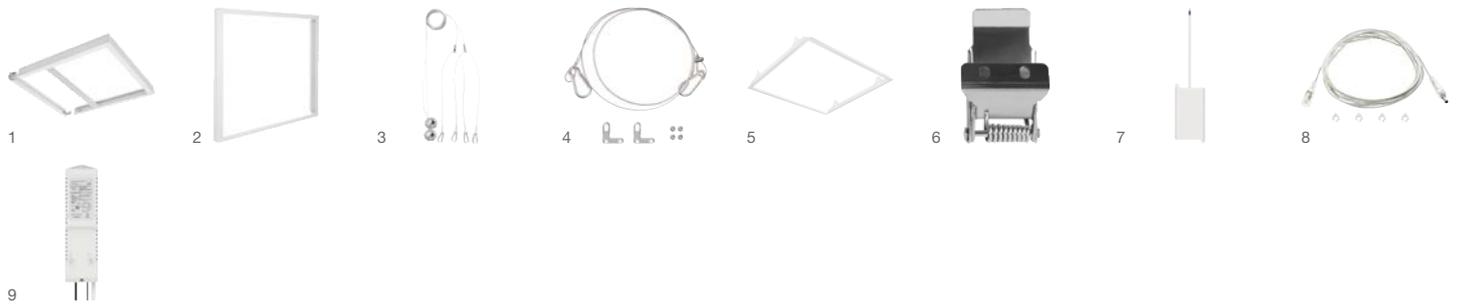

Product name	GTIN (EAN)	MATERIAL	COLOR	L x W x H [mm] Ø x H [mm]	Ø x H [mm]	No.
SURFACE MOUNT KIT						
Reinforced surface mount frames for panel luminaires						
PANEL 600 SURFACE MOUNT KIT H75	4058075472914	Aluminum	White	601 x 601 x 75	75	1
PANEL 625 SURFACE MOUNT KIT H75	4058075472938	Aluminum	White	626 x 626 x 75	75	1
PANEL 1200 Surface Mount Kit	4058075108820	Aluminum	White	1201 x 301 x 56	56	1
PANEL 600 SURFACE MOUNT KIT H75 BK	4058075834330	Aluminum	Black	600 x 600 x 76	76	1
PANEL 625 SURFACE MOUNT KIT H75 BK	4058075834354	Aluminum	Black	625 x 625 x 76	76	1
PANEL 1200 SURFACE MOUNT KIT BK	4058075834378	Aluminum	Black	1200 x 300 x 56	56	1
PANEL 600 SURFACE MOUNT KIT H50	4058075826397	Aluminum	White	600 x 600 x 50	50	1
PANEL 625 SURFACE MOUNT KIT H50	4058075826403	Aluminum	White	625 x 625 x 50	50	1
SURFACE MOUNT KIT VALUE						
Surface mount frames for panel luminaires						
PANEL 600 SURFACE MOUNT KIT H70 VAL	4058075402843	Aluminum	White	613 x 613 x 70	70	2
PANEL 625 SURFACE MOUNT KIT H70 VAL	4058075402867	Aluminum	White	638 x 638 x 70	70	2
PANEL 1200 X 300 SF MOUNT KIT H70 VAL	4099854018497	Aluminum	White	1215 x 315 x 72	72	2
PANEL 1200 X 600 SURFACE MOUNT KIT VAL	4058075389823	Aluminum	White	1213 x 613 x 72	72	2
SUSPENSION KIT						
Suspension kit for panel luminaires						
PANEL Suspension Kit	4058075402928	Steel	Steel	1500 x 30	30	3
SECURITY KIT						
Security kits for panel luminaires						
PANEL SECURITY KIT 4x	4058075472990	Steel	Steel	1000 x 17 x 4	4	4
RECESSED MOUNT FRAME						
Recessed mount frames for panel luminaires						
PANEL 600 RECESSED MOUNT FRAME	4058075402881	Aluminum	White	625 x 625 x 76	76	5
PANEL 625 RECESSED MOUNT FRAME	4058075402904	Aluminum	White	650 x 650 x 76	76	5
PANEL 1200x300 RECESSED MOUNT FRAME	4058075472976	Aluminum	White	1231 x 331 x 76	76	5
RECESSED MOUNT CLIPS						
Recessed mount clips for panel luminaires						
PANEL RECESSED MOUNT CLIPS VAL 4x	4058075409859	Steel	Steel	25 x 45 x 33	33	6
CONNECTOR BOX						
Connector boxes for recessed luminaires						
CONNECTOR BOX 5POLE L/N 4x	4058075473010	Polycarbonate (PC)	White	115 x 56 x 19	19	7
PANEL 1200 TWIST LOCK EXTENSION						
Twist lock cable extension for Panel Comfort 1200						
PANEL 1200 CABLE EXT TWIST LOCK	4099854018510	Polyvinylchlorid (PVC)	Transparent	2400 x 13	13	8

Product name	GTIN (EAN)	L x W x H [mm] Ø x H [mm]	No.
EMERGENCY CONVERSION BOX TEMPERATURE SENSOR			
Emergency conversion box to convert recessed luminaires to self-contained emergency luminaires with battery temperature monitoring			
EM CONVERSION BOX TEMPERATURE SENSOR	4099854455933	292 x 81 x 41	9


■ SUPERIOR CLASS ■ PERFORMANCE CLASS ■ VALUE CLASS

¹ Refer to www.ledvance.com/guarantee for precise conditions

ABOUT LEDVANCE

With business activities in over 140 countries, LEDVANCE is one of the world's leading general lighting companies. Emerging from OSRAM's general lighting division, LEDVANCE's portfolio includes LED lamps and luminaires, intelligent lighting products, traditional lamps and renewable energy solutions.

#POWERTHROUGHLIGHT

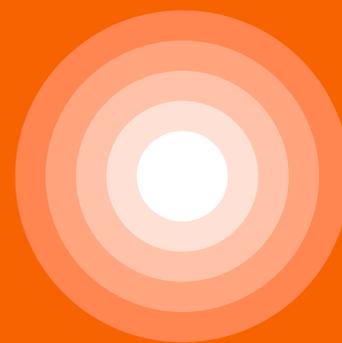

LEDVANCE

LEDVANCE GmbH
Parkring 1–5
85748 Garching
Germany

[LEDVANCE.COM](https://www.ledvance.com)