



CaviLock Overview




CaviLock®

Our CaviLock hardware solutions seamlessly blend functionality and style.

Expertly designed in New Zealand, our premium pocket and sliding door hardware range offers versatile options perfect for residential, commercial, and hospitality settings.

CL400® Magnetic

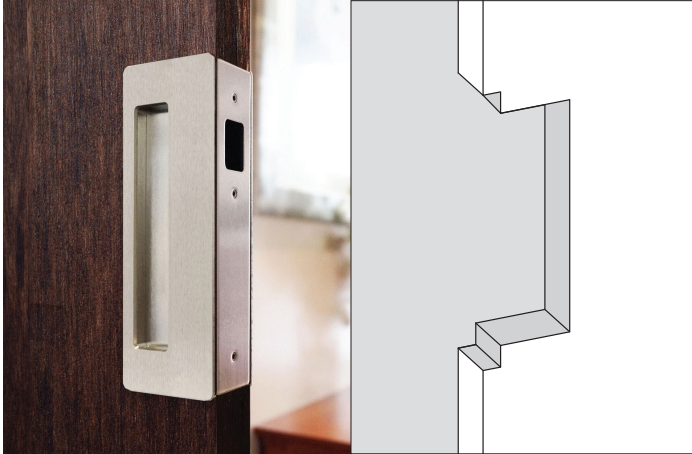

Design Features & Options

- Configurations include Passage, Privacy, Key Locking, Bi-Parting
- Design ensures that the doors slides flush back into the pocket
- Suitable for doors 1-3/8" and 1-3/4" thick
- "C" notch cut out – NO mortise prep required

CL200 Range



Design Features & Options


- Configurations include Passage, Privacy, and Bi-Parting
- Elegant and functional design
- Large finger pull has more depth for greater purchase when pulling a door out of a cavity.

Available finishes for CL400 and CL200 Range Handles




Bright Chrome Satin Chrome Oil Rubbed Bronze Satin Nickel Matte Black


The CL400® Magnetic pocket door handle features a patented magnetic catch and plunger system. This innovation provides a positive 'hold close' for passage handles and a beautifully smooth action on locking hardware.

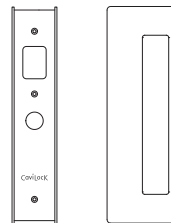


Passage (Magnetic Latching)

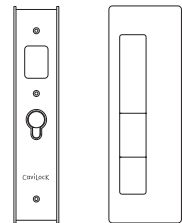

Privacy

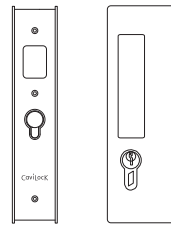


Key Locking

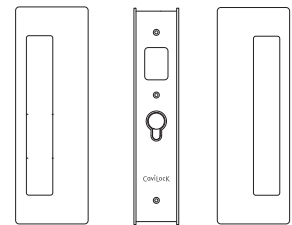


Bi-Parting


The CaviLock CL200 is a durable range of sliding door hardware suitable for residential, commercial, and hospitality applications. This handle is not handed.

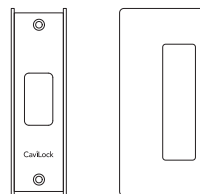

Passage

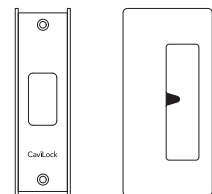

Privacy

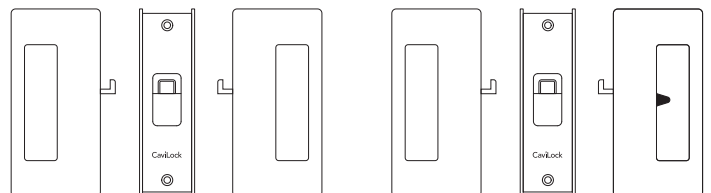

Bi-Parting

ADA Compliant Hardware



Introducing our ADA-compliant range of sliding door handles, designed for commercial projects. These handles meet accessibility standards set by the Americans with Disabilities Act, ensuring ease of use for everyone, including those with disabilities.

CL400® ADA Magnetic

The CL400® ADA Magnetic Handle matches the look and functionality of the existing CL400 Magnetic range of pocket door hardware, with added ADA functionality.



Design Features & Options


- Configurations include Passage, Privacy, and Bi-Parting
- Compliant with ADA Standards for Accessible Design
- Easy to use - no tight pinching or twisting of the wrist.
- Matches other hardware in the CL400 range.
- Striker sits flush with closing jamb.

CS BarnDoorStrike

The CS BarnDoorStrike makes the CL400 Magnetic range of sliding door hardware compatible for barn door applications.



Available finishes for CL400 ADA Handles

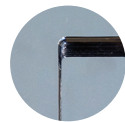

Bright Chrome




Satin Chrome



Oil Rubbed Bronze



Satin Nickel

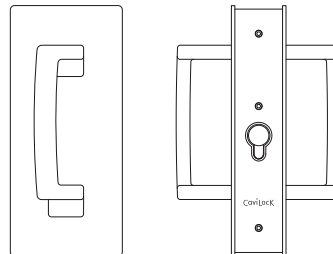


CL100 ADA Handles

The CL100 ADA Series is a range of accessibility-focused locksets designed for ease of use, durability, and compliance with ADA guidelines.




Design Features & Options


- Configurations include Indicator Lock, LaviLock, and Lever
- Designed to comply with ADA guidelines, ensuring effortless operation without pinching, grasping, or twisting.
- Built with brass and stainless steel components
- Features self-latching mechanisms, emergency release options, and positive pull-action levers for enhanced safety

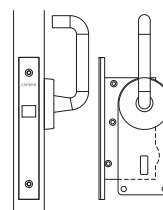

CL100 ADA
Indicator Lock

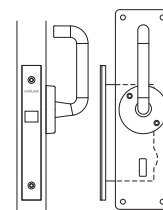

CL100 ADA
LaviLock

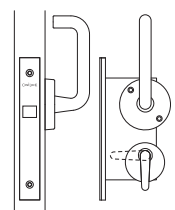

CL100 ADA
Lever


Choosing Your Pocket Door Hardware Handing

Each project is unique. Here are a few examples to help determine the type of carriage pack needed for your project.

- 1. Stand with your back against the door's closing jamb
- 2. Look directly into the door's pocket
- 3. Determine which side you'd like your snib (Privacy Function) or key on.

Example:

The homeowner would like to add a lock to this bathroom. Upon positioning themselves and looking into the pocket, the homeowner's RIGHT hand is inside the bathroom. Therefore, the door's handing would be: **Right Hand (RH) Snib/Left Hand (LH) Emergency**

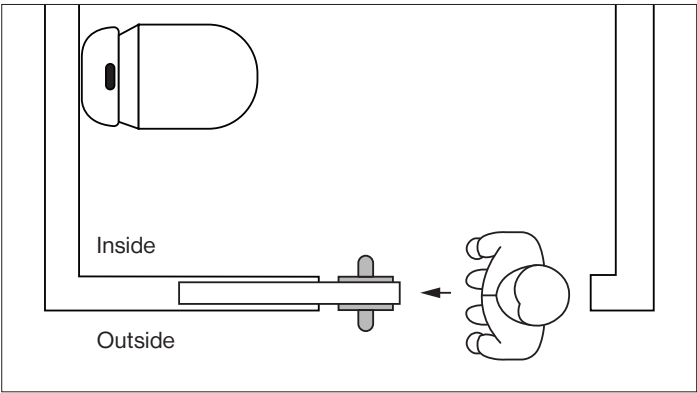

© All copyright and other property in this document is reserved by Cavity Sliders USA Inc. Details and specifications are subject to change without notice. Whilst all care is taken to ensure the accuracy of all information, no responsibility will be accepted for any errors or omissions. 04/2025

CavitySliders.com

sales@cavitysliders.com (888) 466-0030

Visit our website

