
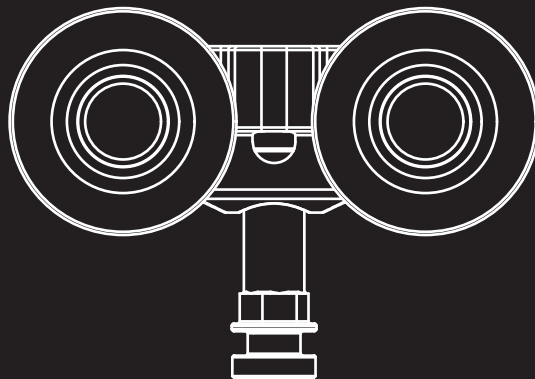


 **Cavity Sliders™**

# CS Track Kits™

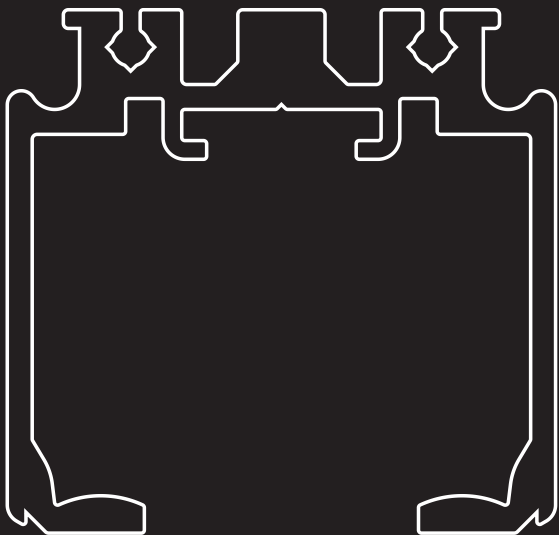

# CS Track Kits™

**CS Track Kits™ provide a streamlined, all-in-one solution for effortless sliding door performance.** Each kit includes a durable aluminum track and precision ball-bearing carriages for smooth, reliable operation. With just one kit, you have everything you need—designed to suit a variety of door types and spaces.



## CS TopMountTrack - Single


Versatile, top-fixed box track

### Features

CS TopMountTrack is a smooth running low profile track system. Its versatility makes it popular for a range of opening types including pocket, barn, partition and multi-sliding applications.

### Applications

- Site Built Pocket Doors
- Room Dividers & Partitions

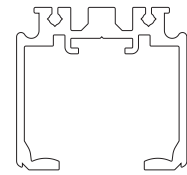

	Carriage	Product Code
6' Track Kit	200 lb (M6) with 1 Stop	KCT6-M611
	Twin SofStop with 1 Stop	KCT6-S711
8' Track Kit	200 lb (M6) with 1 Stop	KCT8-M611
	Twin SofStop with 1 Stop	KCT8-S711

## CS FH-CeilingMountTrack


Ceiling recessed track for pocket and barn doors

### Features

The CS FH-CeilingMountTrack features an innovative design with full-length fins that allow the ceiling lining to sit flush with the underside of the track, creating a seamless finish. The track is ideal for ceiling-recessed applications for pocket and barn doors.

### Applications

- Site Built Pocket Doors
- Room Dividers & Partitions
- Barn Doors

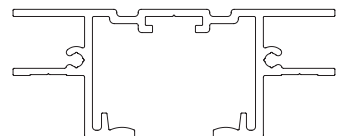

	Carriage	Product Code
6' Track Kit	200 lb (M6) with 2 Stops	KFH6-M621
	Twin SofStop with 2 Stops	KFH6-S721
8' Track Kit	200 lb (M6) with 2 Stops	KFH8-M621
	Twin SofStop with 2 Stops	KFH8-S721

# CS TopMountTrack - Bypass


Bypass track for closets and wardrobes

## Features


The CS TopMountTrack-Bypass is a smooth running, low profile track system suitable for incorporating into bypass wardrobe assemblies.

## Applications

- Bypass Wardrobes

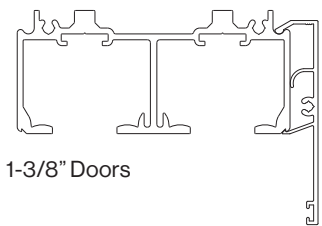

1-3/8" Doors

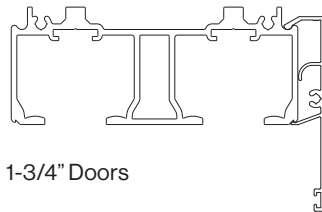

1-3/4" Doors

Door Thickness			Carriage	Product Code
6' Track Kit	1-3/8"	Natural	200 lb (M6) with 2 Stops	KTM2N6-M621-138
			Twin SofStop with 2 Stops	KTM2N6-S721-138
		Bronze	200 lb (M6) with 2 Stops	KTM2B6-M621-138
			Twin SofStop with 2 Stops	KTM2B6-S721-138
	1-3/4"	Natural	200 lb (M6) with 2 Stops	KTM2N6-M621-134
			Twin SofStop with 2 Stops	KTM2N6-S721-134
		Bronze	200 lb (M6) with 2 Stops	KTM2B6-M621-134
			Twin SofStop with 2 Stops	KTM2B6-S721-134
8' Track Kit	1-3/8"	Natural	200 lb (M6) with 2 Stops	KTM2N8-M621-138
			Twin SofStop with 2 Stops	KTM2N8-S721-138
		Bronze	200 lb (M6) with 2 Stops	KTM2B8-M621-138
			Twin SofStop with 2 Stops	KTM2B8-S721-138
	1-3/4"	Natural	200 lb (M6) with 2 Stops	KTM2N8-M621-134
			Twin SofStop with 2 Stops	KTM2N8-S721-134
		Bronze	200 lb (M6) with 2 Stops	KTM2B8-M621-134
			Twin SofStop with 2 Stops	KTM2B8-S721-134

# Fascia Finish Options

Included with CS SideMountTrack and CS TopMountTrack - Bypass

Natural Anodized



Bronze Anodized



# CS SideMountTrack


Contemporary barn door track

## Features

**CS SideMountTrack is an ideal surface sliding solution where vertical fixing space is limited.** This system is side fixed through the track profile.

## Applications

- Barn Doors

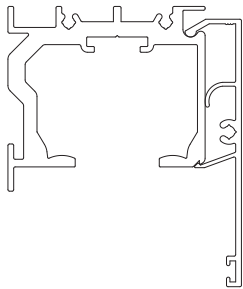

		Carriage	Product Code
6' Track Kit	Natural	200 lb (M6) with 2 Stops	KSMN6-M621
		Twin SofStop with 2 Stops	KSMN6-S721
	Bronze	200 lb (M6) with 2 Stops	KSMB6-M621
		Twin SofStop with 2 Stops	KSMB6-S721
8' Track Kit	Natural	200 lb (M6) with 2 Stops	KSMN8-M621
		Twin SofStop with 2 Stops	KSMN8-S721
	Bronze	200 lb (M6) with 2 Stops	KSMB8-M621
		Twin SofStop with 2 Stops	KSMB8-S721

Cavity Sliders USA  
2662 E Del Amo Blvd.  
Carson, CA 90221

Phone: 888 466 0030  
Email: sales@cavitysliders.com

CavitySliders.com

© All copyright and other property in this document is reserved by Cavity Sliders USA Inc. Details and specifications are subject to change without notice. Whilst all care is taken to ensure the accuracy of all information, no responsibility will be accepted for any errors or omissions. 04/2025 ZG00372

Visit our Website

