
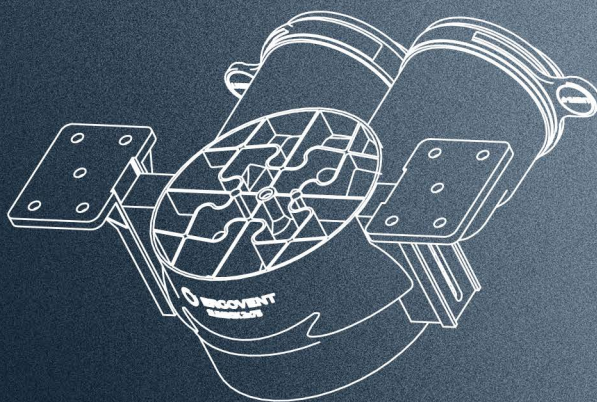
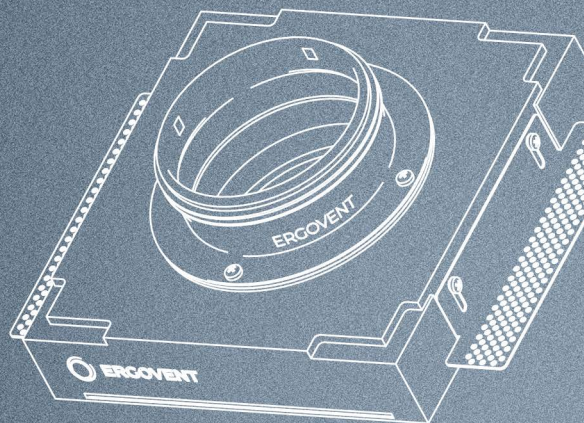
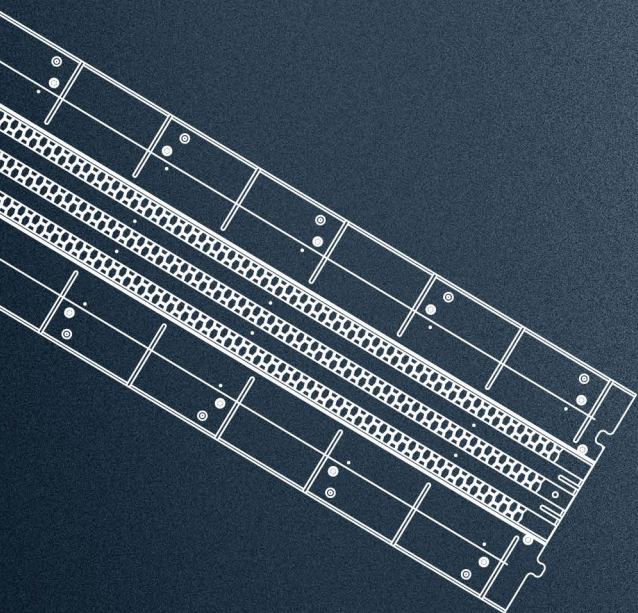



CATALOGUE

HVAC products


GYPSUM DIFFUSERS

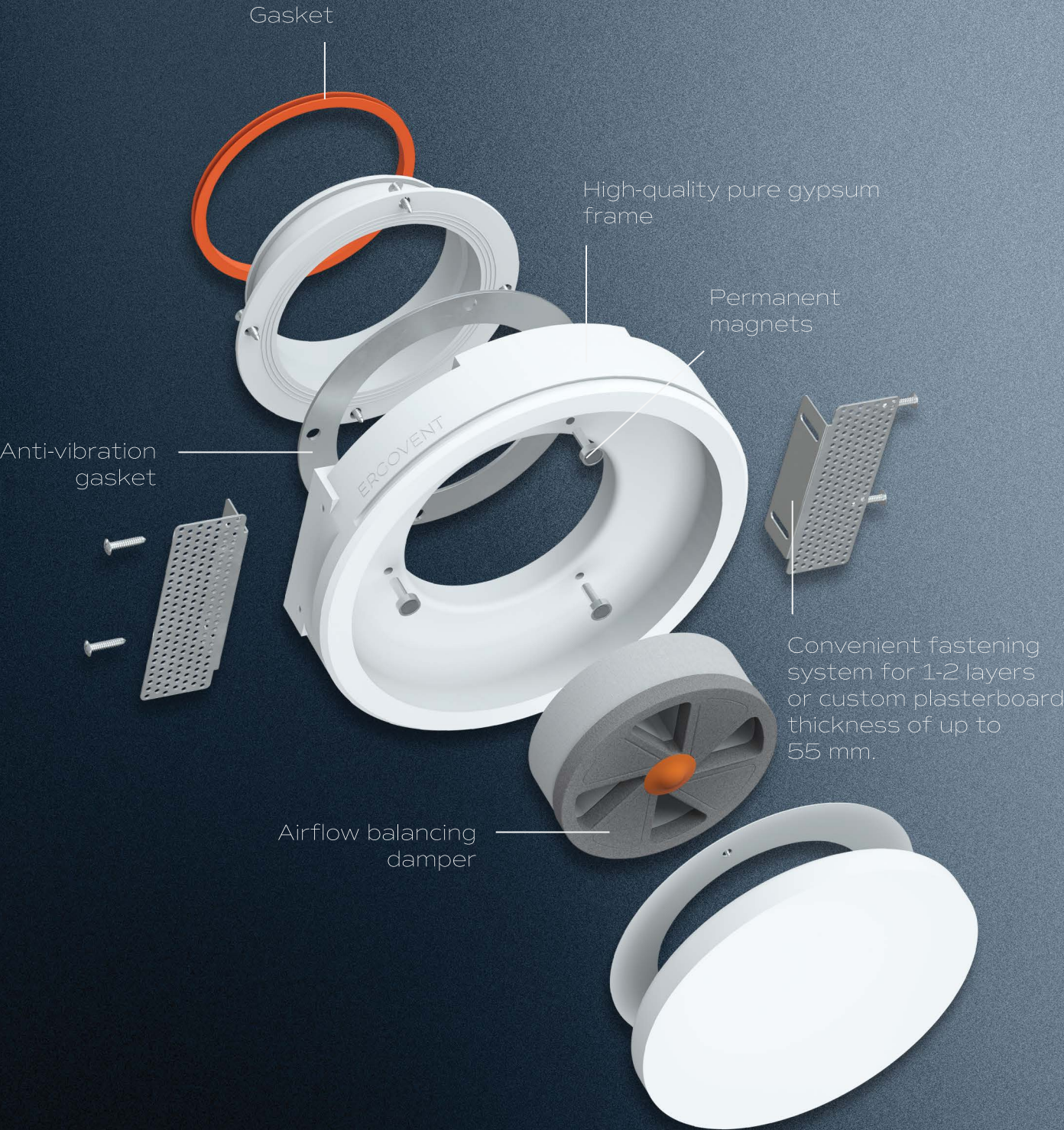


reddot winner 2023

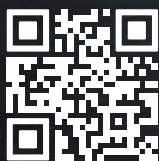

Scan QR code for
installation manual

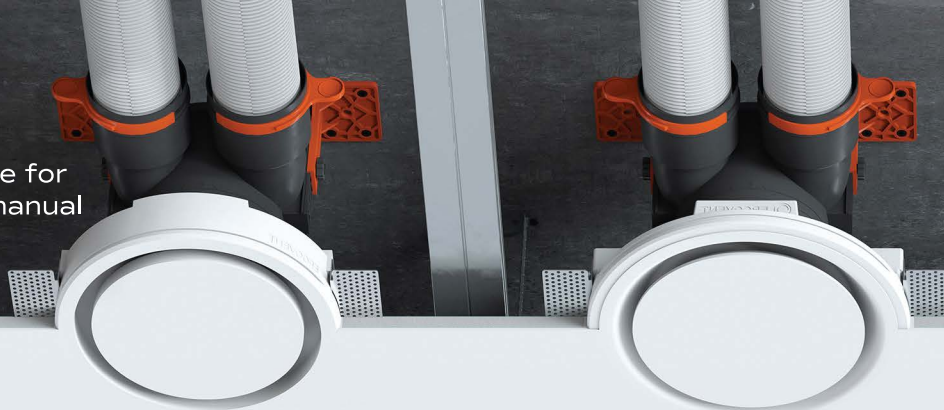


GYPSUM DIFFUSERS

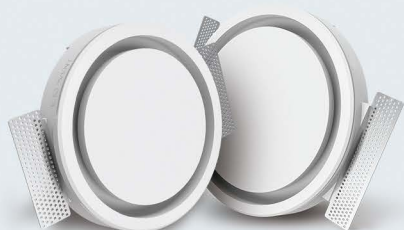

RONDO



RONDO-COANDA

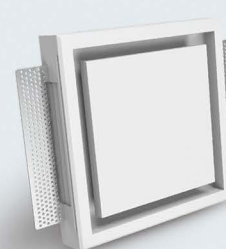


KVADRO

Hidden ventilation diffusers RONDO-COANDA with Coanda Effect

High-quality gypsum body:
Solid, bubble-free casting with
integrated mounting elements;
smooth, paint-ready surface.

Due to the Coanda effect,
the airflow is distributed
along the ceiling (optimized
for supply airflows).

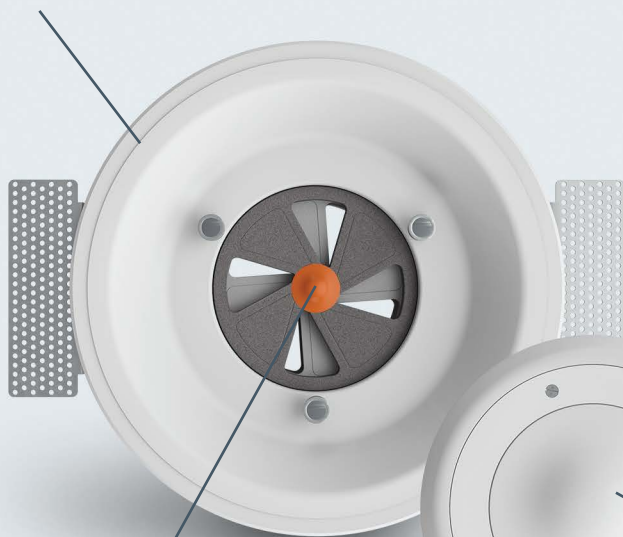

Balancing damper
included.



The gypsum cover "armor"
is a patented solution that
protects against any type
of damage.

Duct connections:

Ø 100 / 125 mm



ISO 9001
ISO 14001
ISO 45001


Technical data

RONDO

Photo	Fastening method	System	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
	For plasterboard	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT RONDO (100 mm / 4" connection / with damper)	4779051540112	RN100	Gross 3.1 kg Net 2.5 kg	315 x 315 x 140
	For plasterboard	Air conditioning / ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT RONDO (125 mm connection / with damper)	4779051540105	RN125	Gross 3.3 kg Net 2.5 kg	315 x 315 x 140
	For plasterboard	Air conditioning / ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT RONDO (150 mm / 6" connection / with damper)	4779051540327	RN150	Gross 4.9 kg Net 4.3 kg	365 x 365 x 165
	For plasterboard	Air conditioning / ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT RONDO (160 mm connection / with damper)	4779051540129	RN160	Gross 4.9 kg Net 4.3 kg	365 x 365 x 165
	For plasterboard	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT RONDO-COANDA (100 mm / 4" connection / with damper)	4779051541058	RN100.CO	Gross 3.4 kg Net 2.8 kg	315 x 315 x 140
	For plasterboard	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT RONDO-COANDA (125 mm connection / with damper)	4779051540877	RN125.CO	Gross 3.4 kg Net 2.8 kg	315 x 315 x 140

Technical data

KVADRO

 Photo	Fastening method	System	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
	For plasterboard	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT KVADRO (100 mm / 4" connection / with damper)	4779051540136	KV100	Gross 3.9 kg Net 3.3 kg	315 x 315 x 140
	For plasterboard	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT KVADRO (125 mm connection / with damper)	4779051540143	KV125	Gross 3.9 kg Net 3.3 kg	315 x 315 x 140

INSTALLATION MANUALS: RONDO



RONDO-COANDA



KVADRO




SPARE PARTS

Photo	Compatible with	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
	RONDO 100/125 mm	Hidden ventilation diffuser cap for RONDO 100/125 mm	4779051540280	RN125C	Gross 1 kg Net 1 kg	D176 x 30
	RONDO 150/160mm	Hidden ventilation diffuser cap for RONDO 150/160 mm	4779051540297	RN160C	Gross 1.5 kg Net 1.5 kg	D231 x 30
	RONDO-COANDA 100/125 mm	Hidden ventilation diffuser cap for RONDO-COANDA 100/125 mm	4779051541317	LP.P008	Gross 0.6 kg Net 0.6 kg	D194 x 32
	KVADRO 100/125 mm	Hidden ventilation diffuser cap for KVADRO 100/125 mm	4779051540303	KV125C	Gross 1.1 kg Net 1.1 kg	230 x 230 x 110
	RONDO 100/125 mm KVADRO 100/125 mm	Magnets 15mm diameter M5x16	4779051540310	MG100/125	Gross 0.1 kg Net 0.1 kg	D15x21
	RONDO 150/160mm	Magnets 17mm diameter M5x16	4779051540983	MG150/160	Gross 0.1 kg Net 0.1 kg	D17x21
	RONDO 100/125 mm	Hidden ventilation diffuser brackets ERGOVENT R-100/125	4779051541133	BR R-100/125	Gross 0.5 kg Net 0.5 kg	–
	RONDO 150/160 mm KVADRO 100/125 mm	Hidden ventilation diffuser brackets ERGOVENT R-160/KV	4779051541126	BR R-160/KV	Gross 0.6 kg Net 0.6 kg	–
	RONDO 100/125/150/160 mm KVADRO 100/125 mm	Safety line ERGOVENT RN/KV	4779051541140	SR RN/KV	Gross 0.03 kg Net 0.03 kg	–
	RONDO 100 mm KVADRO 100 mm	Damper ERGOVENT 100 mm	4779051541157	DM100	Gross 0.03 kg Net 0.03 kg	D89x50
	RONDO 125 mm KVADRO 125 mm	Damper ERGOVENT 125 mm	4779051541164	DM125	Gross 0.03 kg Net 0.03 kg	D114x50
	RONDO 150 mm	Damper ERGOVENT 150 mm	4779051541218	DM150	Gross 0.03 kg Net 0.03 kg	D139x50
	RONDO 160 mm	Damper ERGOVENT 160 mm	4779051541225	DM160	Gross 0.03 kg Net 0.03 kg	D149x50

SLOT DIFFUSERS






DESIGN
AWARD
2025

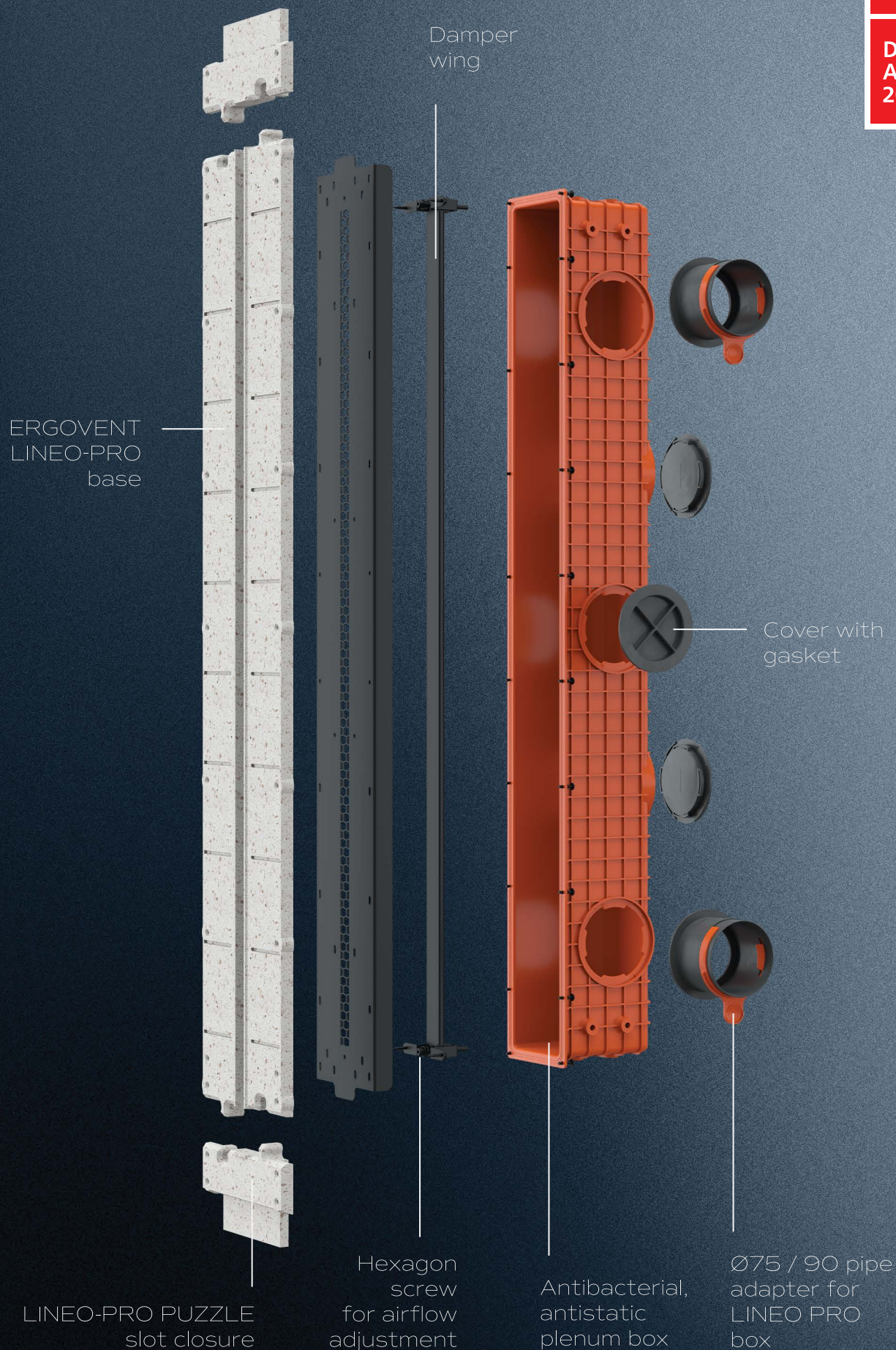



Technical data

LINEO-PRO 75

   Photo	Fastening method	System	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
1 SLOT							
	Universal	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT LINEO-PRO SINGLE (75mm connection / 1 slot x 1000mm x 20mm / with damper)	4779051540341	LP75.120.101	Gross 7.08 kg Net 5 kg	1235 x 175 x 195
	For CD profiles	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT LINEO-PRO PROFILE (75mm connection / 1 slot x 1000mm x 20mm / with damper)	4779051540365	LP75.120.201	Gross 8.54 kg Net 5.94 kg	1235 x 240 x 185
	For CD profiles	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT LINEO-PRO PUZZLE (75mm connection / 1 slot x 1050mm x 20mm / with damper)	4779051540389	LP75.120.301	Gross 8.24 kg Net 5.8 kg	1235 x 240 x 185
2 SLOT							
	For CD profiles	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT LINEO-PRO PUZZLE (75mm connection / 2 slot x 1050mm x 20mm / with damper)	4779051540884	LP75.220.301	Gross 7.84 kg Net 5.58 kg	1235 x 240 x 185

Technical data

LINEO-PRO 90

  Photo	Fastening method	System	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
1 SLOT							
	Universal	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT LINEO-PRO SINGLE (90mm connection / 1 slot x 1000mm x 20mm / with damper)	4779051540600	LP90.120.101	Gross 7.08 kg Net 5 kg	1235 x 175 x 195
	For CD profiles	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT LINEO-PRO PROFILE (90mm connection / 1 slot x 1000mm x 20mm / with damper)	4779051540617	LP90.120.201	Gross 8.54 kg Net 5.94 kg	1235 x 240 x 185
	For CD profiles	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT LINEO-PRO PUZZLE (90mm connection / 1 slot x 1050mm x 20mm / with damper)	4779051540624	LP90.120.301	Gross 8.24 kg Net 5.8 kg	1235 x 240 x 185
2 SLOT							
	For CD profiles	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT LINEO-PRO PUZZLE (90mm connection / 2 slot x 1050mm x 20mm / with damper)	4779051541041	LP90.220.301	Gross 7.84 kg Net 5.58 kg	1235 x 240 x 185

INSTALLATION MANUALS: LINEO-PRO



MIX & MATCH!

ERGOVENT LINEO-PRO
PUZZLE 75

ERGOVENT LINEO-PRO
CONDI 125

GYPSUM DIFFUSERS

Hidden linear diffusers for air conditioning systems

Thermally insulated connection box (made of EPP material). Minimal risk of condensate (all metal components are insulated)

Convenient duct connections
(3x top and 3x side)



Lighter product: technologically advanced solution

PUZZLE LOCK connect multiple diffusers (A/C and/or ventilation) into 1 continuous line effortlessly

DUCT CONNECTIONS:

LINEO-PRO CONDI 125 - 3x from the back and 3x from the side, 125 mm

LINEO-PRO CONDI 150/160 - 2x from the back and 3x from the side, 150/160 mm



Scan QR code for installation manual



Technical data

LINEO-PRO CONDI

Photo	Fastening method	System	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
1 SLOT							
	For CD profiles	Air conditioning (air supply)	Hidden ventilation diffuser ERGOVENT LINEO-PRO CONDI (125mm connection / 1 slot x 1050mm x 20mm / insulated)	4779051540594	LP125.120301	Gross 6.68 kg Net 4.56 kg	1218 x 198 x 191
2 SLOT							
	For CD profiles	Air conditioning (air supply)	Hidden ventilation diffuser ERGOVENT LINEO-PRO CONDI (125mm connection / 2 slot x 1050mm x 20mm / insulated)	4779051541072	LP125.220301	Gross 6.25 kg Net 4.20 kg	1218 x 198 x 191
3 SLOT							
	For CD profiles	Air conditioning (air supply)	Hidden ventilation diffuser ERGOVENT LINEO-PRO CONDI (150mm connection / 3 slot x 1000mm x 20mm / insulated)	4779051540952	LP150.320301	Gross 10.12 kg Net 7.22 kg	1113 x 340 x 298
	For CD profiles	Air conditioning (air supply)	Hidden ventilation diffuser ERGOVENT LINEO-PRO CONDI (160mm connection / 3 slot x 1000mm x 20mm / insulated)	4779051540891	LP160.320301	Gross 10.12 kg Net 7.22 kg	1113 x 340 x 298

INSTALLATION MANUALS: LINEO-PRO CONDI



SLOT DIFFUSERS



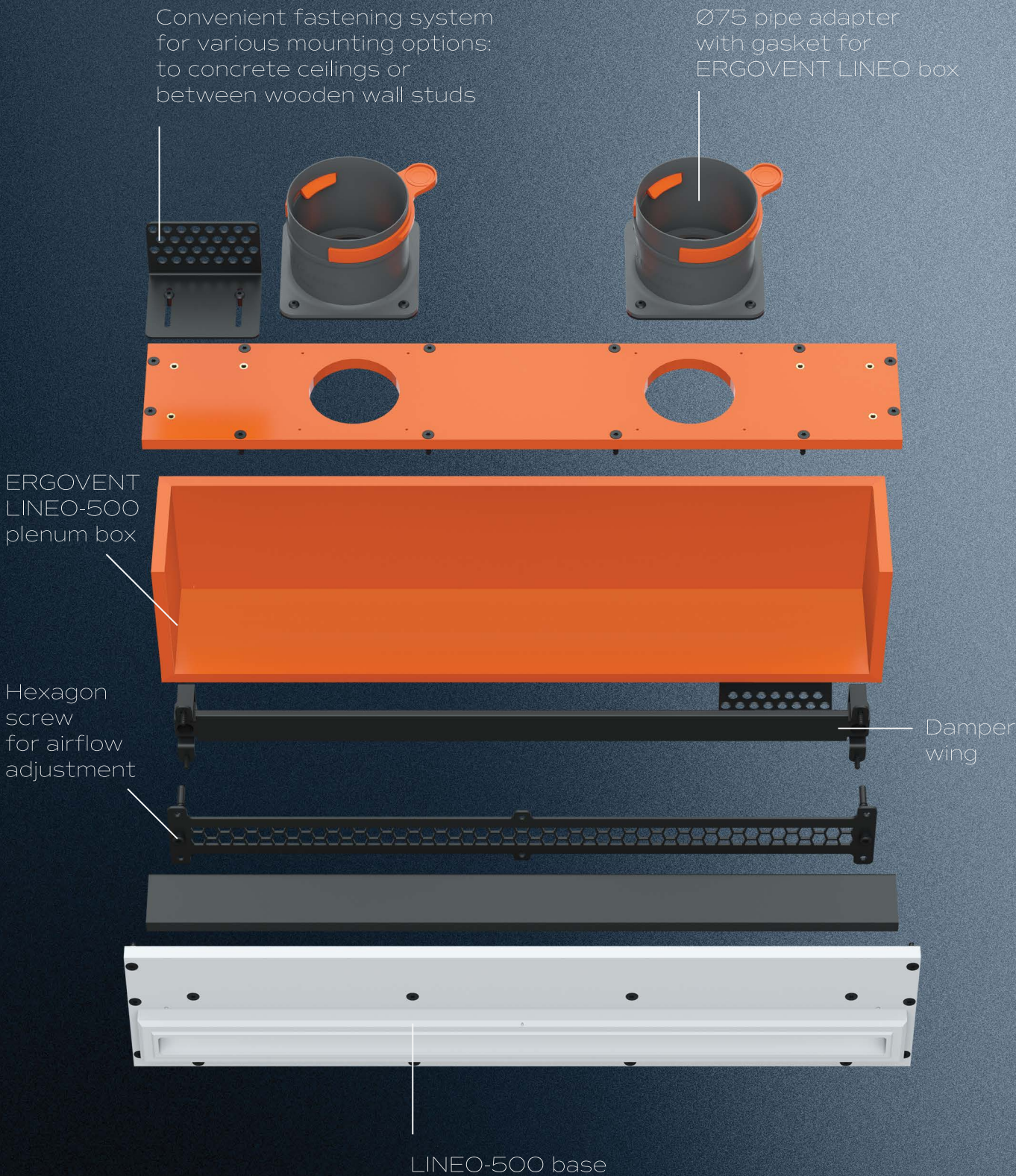


Photo	Fastening method	System	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
	Universal	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT LINEO-500 (75mm * 2pcs / 1 slot x 500mm x 20mm / with damper)	4779051540402	LN75.120.101	Gross 3.34 kg Net 2.88 kg	600 x 230 x 140
	For CD profiles	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT LINEO-600 VERTICAL (75mm * 2pcs / 1 slot x 600mm x 20mm / with damper)	4779051540426	LN75.120.202	Gross 3.76 kg Net 3.16 kg	740 x 240 x 210
	For CD profiles	Ventilation (air supply / exhaust)	Hidden ventilation diffuser ERGOVENT LINEO-600 (75mm * 2pcs / 1 slot x 600mm x 20mm / with damper)	4779051540433	LN75.120.201	Gross 3.76 kg Net 3.16 kg	740 x 240 x 210

INSTALLATION MANUALS: LINEO

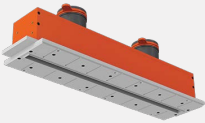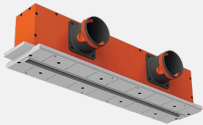

ACCESSORIES & SPARE PARTS

Photo	Compatible with	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
	LINEO-PRO diffusers that have 75 or 90mm connections	End cap for ERGOVENT LINEO-PRO with gasket	4779051541010	LNDCl	Gross 0.07 kg Net 0.03 kg	50 x 50 x 10
	LINEO-PRO 1x slot diffusers	Diffuser slot ending piece for ERGOVENT LINEO-PRO (1 slot)	4779051540723	LP.P001	Gross 0.09 kg Net 0.09 kg	194 x 70 x 25
	LINEO-PRO 2x diffusers	Diffuser slot ending piece for ERGOVENT LINEO-PRO (2 slot)	4779051541027	LP.P002	Gross 0.12 kg Net 0.12 kg	194 x 70 x 25
	LINEO-PRO CONDI 3x slot diffusers	Diffuser slot ending piece for ERGOVENT LINEO-PRO (3 slot)	4779051541034	LP.P003	Gross 0.21 kg Net 0.21 kg	290 x 65 x 25
	LINEO PRO 2x or 3x slot diffusers	Slot diffuser intermediate connector for ERGOVENT 2/3 slots	4779051541119	LP.P005	Gross 0.005 kg Net 0.005 kg	30 x 10 x 4
	LINEO-PRO diffusers that have 75 or 90mm connections	Diffuser spigot for ERGOVENT LINEO-PRO 75 mm connection (with gasket / with duct fastener)	4779051540686	LND75	Gross 0.1 kg Net 0.06 kg	115 x 115 x 90
	LINEO-PRO diffusers that have 75 or 90mm connections	Diffuser spigot for ERGOVENT LINEO-PRO 90 mm connection (with gasket / with duct fastener)	4779051540693	LND90	Gross 0.2 kg Net 0.16 kg	115 x 115 x 90
	LINEO series diffusers with 75mm duct connection	Duct spigot ERGOVENT 75 mm	4779051541102	CND75	Gross 0.05 kg Net 0.05 kg	115 x 115 x 90
	LINEO-PRO CONDI series diffusers with 125 mm duct connection	Diffuser spigot for ERGOVENT 125 mm (with gasket)	4779051541393	LP.P009	Gross 0.19 kg Net 0.19 kg	214 x 125 x 152
	all products with 100mm duct connection	Duct spigot ERGOVENT 100 mm (with gasket)	4779051541171	CND100	Gross 0.07 kg Net 0.07 kg	D162x40
	all products with 125mm duct connection	Duct spigot ERGOVENT 125 mm (with gasket)	4779051541188	CND125	Gross 0.08 kg Net 0.08 kg	D162x40
	all products with 150mm duct connection	Duct spigot ERGOVENT 150 mm (with gasket)	4779051541195	CND150	Gross 0.1 kg Net 0.1 kg	D197x40
	all products with 160mm duct connection	Duct spigot ERGOVENT 160 mm (with gasket)	4779051541201	CND160	Gross 0.1 kg Net 0.1 kg	D197x40
 x4 pcs screws	LP150.320301 product	Duct spigot ERGOVENT 150 mm (with gasket / with 4x screws for EPP)	4779051541232	LP.P006	Gross 0.1 kg Net 0.1 kg	D197x40

ACCESSORIES & SPARE PARTS

Photo	Compatible with	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
 x4 pcs screws	LP160.320301 product	Duct spigot ERGOVENT 160 mm (with gasket / with 4x screws for EPP)	4779051541249	LP.P007	Gross 0.1 kg Net 0.1 kg	D197x40
	LINEO-PRO single type diffuser with damper	Damper position indicator for SINGLE type diffuser	4779051540990	DMS1	Gross 0.2 kg Net 0.2 kg	80 x 30 x 1
	LINEO-PRO diffusers with damper except single type	Damper position indicator for PROFILE and PUZZLE type diffuser	4779051541003	DMS2	Gross 0.2 kg Net 0.2 kg	80 x 30 x 1

Technical data | AERO-PRO

Photo	Fastening method	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
	Universal	Antistatic ERGOVENT AERO-PRO plenum box SLIM BOX (2x75mm / 125mm)	4779051540761	AE75.125.101	Gross 0.4 kg Net 0.4 kg	175 x 90 x 200

Photo	Compatible with	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
	all products that have 75 mm connections	Closing cap ERGOVENT D-75mm	4779051540754	D75-C	Gross 0.07 kg Net 0.07 kg	80 x 90 x 50

Technical data

LINEO-PRO MOULAGES

Photo	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
1 SLOT					
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (1 slot x 20mm x 200mm)	4779051540792	LPM.120.303	Gross 1.28 kg Net 0.88 kg	320 x 270 x 115
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (1 slot x 20mm / 90° angle)	4779051540808	LPM.120.304	Gross 1.34 kg Net 0.92 kg	320 x 270 x 115
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (1 slot x 20mm / 90° angle, rounded)	4779051540815	LPM.120.305	Gross 1.34 kg Net 0.92 kg	320 x 270 x 115
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (1 slot x 20mm x 500mm)	4779051540785	LPM.120.302	Gross 3 kg Net 2.32 kg	680 x 230 x 110
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (1 slot x 20mm x 1050mm)	4779051540778	LPM.120.301	Gross 6.2 kg Net 5.22 kg	1225 x 240x 110
2 SLOT					
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (2 slot x 20mm x 200mm)	4779051540846	LPM.220.303	Gross 1.28 kg Net 0.88 kg	320 x 270 x 115
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (2 slot x 20mm / 90° angle)	4779051540853	LPM.220.304	Gross 1.34 kg Net 0.92 kg	320 x 270 x 115
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (2 slot x 20mm / 90° angle, rounded)	4779051540860	LPM.220.305	Gross 1.34 kg Net 0.92 kg	320 x 270 x 115
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (2 slot x 20mm x 500mm)	4779051540839	LPM.220.302	Gross 3 kg Net 2.32 kg	680 x 230 x 110
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (2 slot x 20mm x 1050mm)	4779051540822	LPM.220.301	Gross 6.2 kg Net 5.22 kg	1225 x 240 x 110

Photo	Product name	EAN code	Product code	Weight	Package LxWxH [mm]
3 SLOT					
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (3 slot x 20mm x 200mm)	4779051541355	LPM.320.302	Gross 2.67 kg Net 1.97 kg	416 x 336 x 106
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (3-slot x 20 mm / 90° angle)	4779051541379	LPM.320.304	Gross 2.33 kg Net 1.93 kg	376 x 376 x 106
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (3 slot x 20mm / 90° angle, rounded)	4779051541386	LPM.320.305	Gross 2.42 kg Net 2.02 kg	376 x 376 x 106
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (3 slot x 20mm x 500mm)	4779051541362	LPM.320.303	Gross 4.83 kg Net 4.13 kg	716 x 336 x 106
	Moulage for ERGOVENT LINEO-PRO PUZZLE diffuser (3 slot x 20mm x 1000mm)	4779051541324	LPM.320.301	Gross 9 kg Net 7.94 kg	1176 x 340 x 106

Success story in > 40 markets

ERGOVENT - a rapidly growing manufacturer of integrated ventilation solutions, based in Lithuania, Northern Europe and exporting to more than 40 countries worldwide.

We take great pride in some of the best ventilation diffusers in the industry, earning appreciation from interior designers, ventilation specialists, and end-customers.

Our premium quality products ensure functional and aesthetic solutions for ventilation that organically blend into modern, stylish and trendy interiors.

We aim to become a leading brand in creating new design trends in the HVAC market.



Scan the QR code to find out
more about ERGOVENT.



www.ergovent.com