

kreon nuit




kreon nuit is an elementary designed beam that can be used as a massive line to bring graphical elements into architecture.


kreon profile systems provide the perfect containment for luminaires. A profile system can add character and architectural unity to a space. All kreon profiles are precision engineered and finished to the highest standards and utilise quality components and electronics.

The advanced LED system requires a slim gap of just 10mm to unfold a variety of beam angles. Its basic form draws minimal attention and can easily be used in combination with other kreon tools of light, creating an artistic yet responsible use of light sources in a recessed, surface mounted or suspended installation, making it a highly versatile and performing linear lighting system.

The standard preconfigured lengths bring glare free accent lighting where as made to measure configurations, including corner cuts, offer the specifier maximal application freedom. The ideal kreon tools of light for residential, high end office and edgy hospitality projects.

kreon nuit can be recessed, surface or pendant mounted and can be arranged so that light modules are positioned just where the light is needed. Profiles can be ordered as standard lengths or bespoke to suit project requirements.




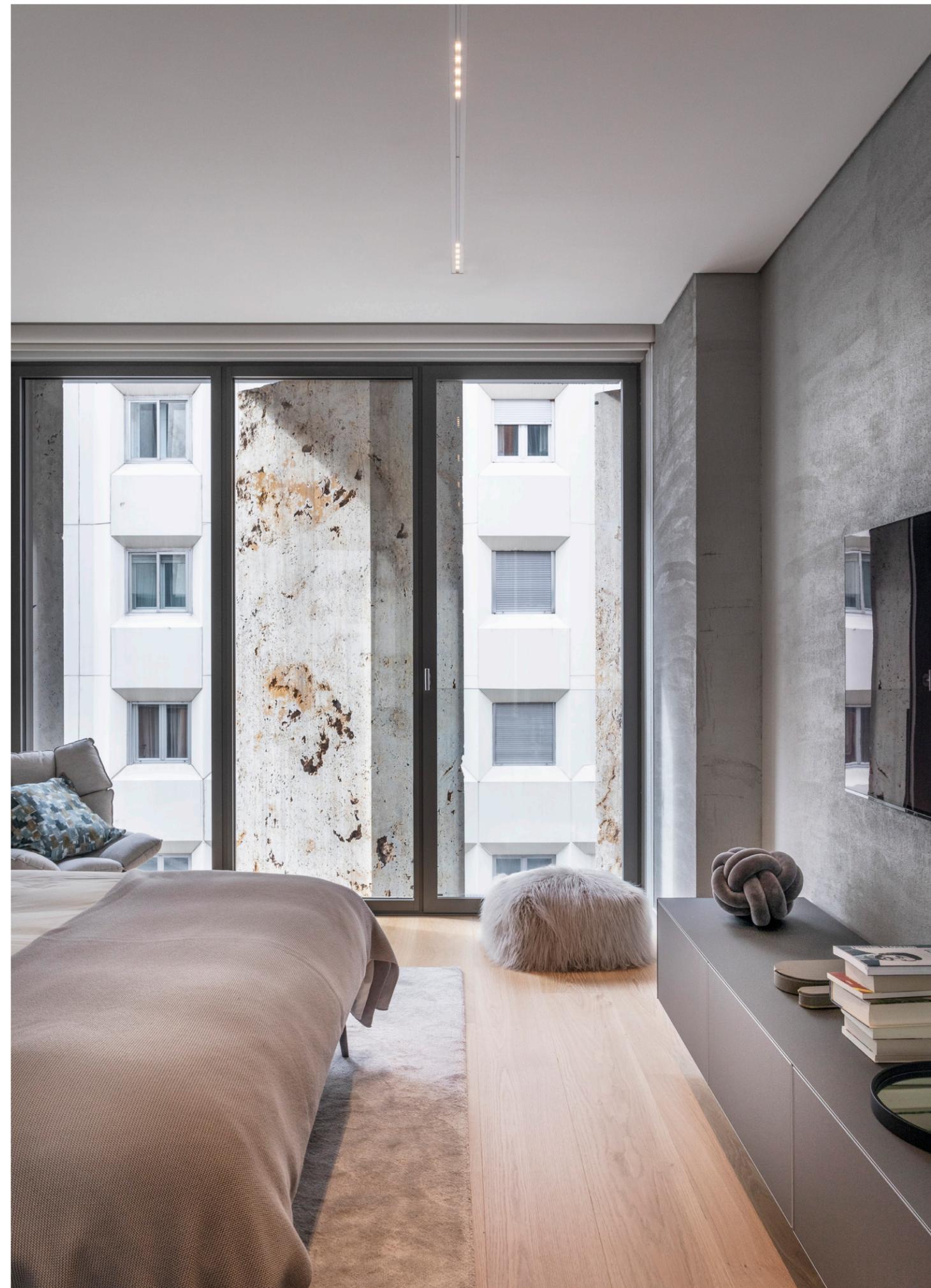


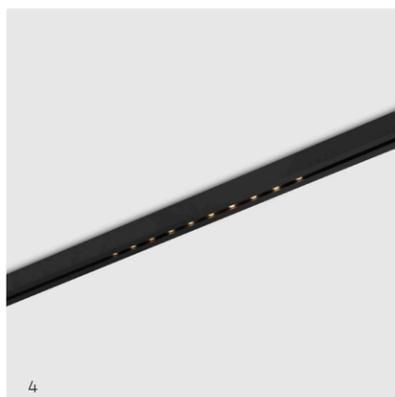

- 1. nuit 1x5 profile,
recessed mounted, black
- 2. nuit 2x5 profile,
recessed mounted, white/black
- 3. nuit 1x5 profile
surface mounted, white/black
- 4. nuit 2x5 profile,
surface mounted, black



kreon nuit profile

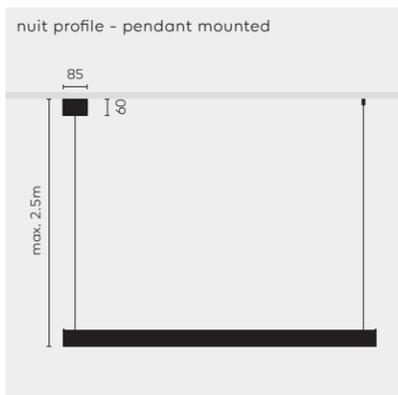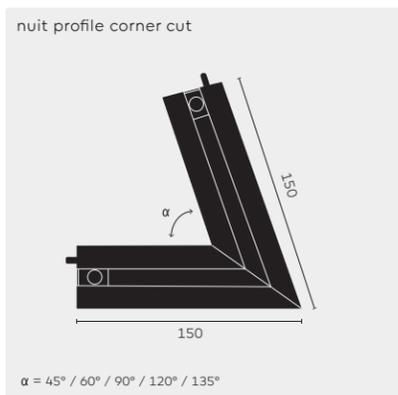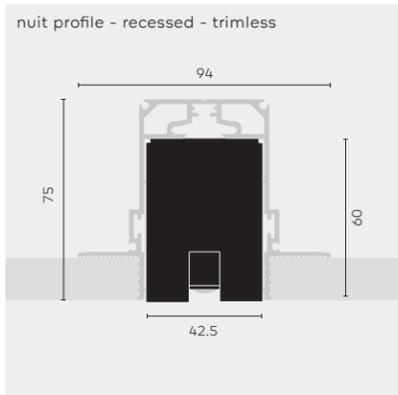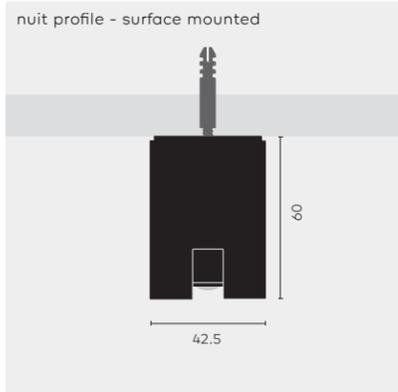

nuit profile
 Gear: incl. or excl., dim options: phase, 1-10V, DALI
 Min. length: 500mm, max length: 6000mm ❶

■ **Optional accessories**

Recessed mounting

Pendant mounting ❷

Electrical wiring

IP44 coating

Colour
 KR-code
 Required accessories
 Optional accessories

○	KR703211	■	■
●	KR703212	■	■
◐	KR703215	■	■

[KR703155](#) Trimless plasterkit profile

[KR703555](#) Suspension kit

[KR703550](#) Additional suspension ❸

[KR774190](#) Extra electrical wiring (for an extra circuit)

[KR774290](#) IP44 coating

Corner cut ❹

[KR703411](#) nuit corner cut, white/white

[KR703412](#) nuit corner cut, black/black

[KR703415](#) nuit corner cut, white/black

[KR703455](#) Trimless plasterkit corner cut

45
Corner 45°
60
Corner 60°
90
Corner 90°
120
Corner 120°
135
Corner 135°

●	●	●	●	●
●	●	●	●	●
●	●	●	●	●
●	●	●	●	●

REMARKS


❶ Max. shipping length of a single run profile. Shipping length depends on transport possibilities. Fixation point every 2.3m. An additional circuit is possible on request

❷ kreon nuit pendant mounted only available with integrated gear.

❸ An additional suspension kit is required when the pendant kreon nuit is longer than 2,3m. Add an extra suspension per additional 2,3 meter in length.

❹ Corner cut has outside dimensions of 150 x 150mm. No luminaires can be placed in the corner cut.

The profile is supplied pre-assembled.
 IP20 standard; Can be supplied with additional coating for use in damp locations; driver must be placed on remote.



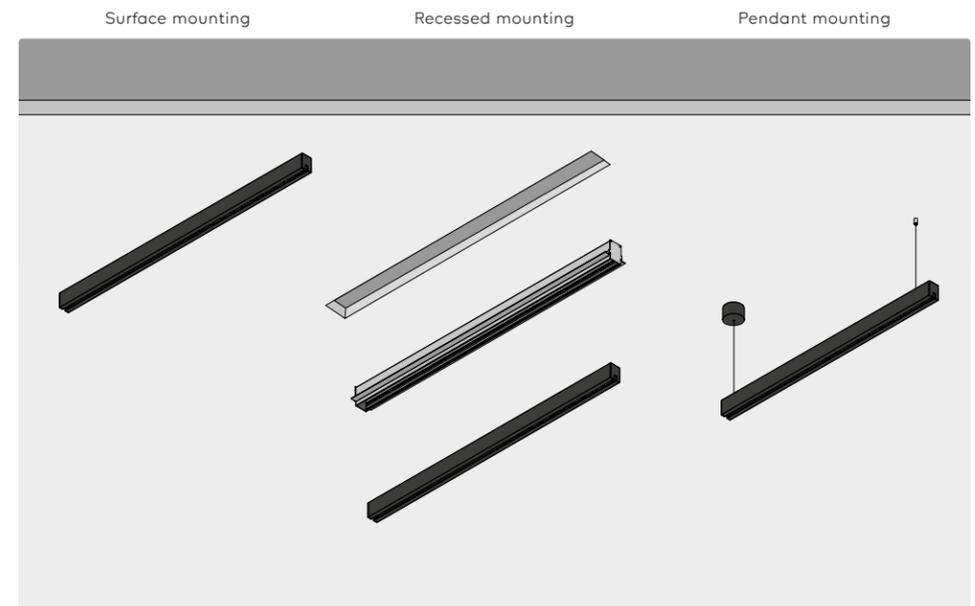






- 1. nuit 1x5, gear excl., black
- 2. nuit 2x5, gear excl., white/black
- 3. nuit 1x5, gear incl., white/black
- 4. nuit 2x5, gear incl., black



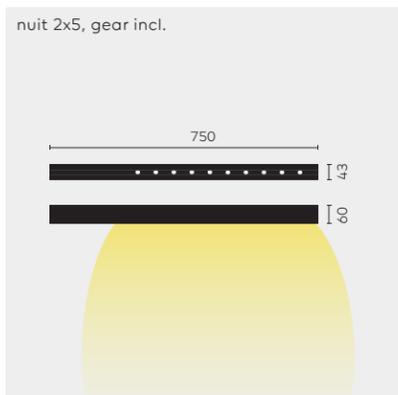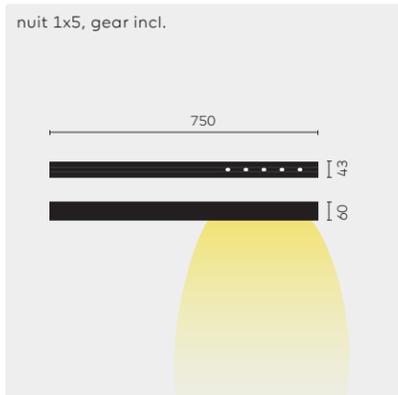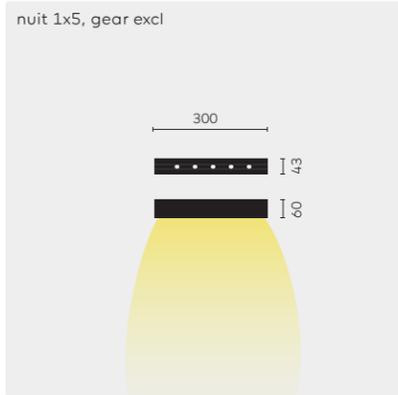

Colour	KR-code	Light sources	9027 2700K, CRI90+				9030 3000K, CRI90+				9040 4000K, CRI90+				SP Spot (12°)	FL Flood (29°)	WFL Wide flood (40°)	OV Oval (13°+ 36°)	PD Phase dimming/ ON-OFF	VD 1-10V dimming	DD DALI/touch dimming	Optional accessories
			●	●	●	●	●	●	●	●	●	●	●	●								
○	KR953501	①	●	●	●	●	●	●	●	●	●	●	●	●								■
●	KR953502	①	●	●	●	●	●	●	●	●	●	●	●	●								■
◐	KR953505	①	●	●	●	●	●	●	●	●	●	●	●	●								■
○	KR953511	②	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	■	■	■	■
●	KR953512	②	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	■	■	■	■
◐	KR953515	②	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	■	■	■	■
○	KR953521	③	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	■	■	■	■
●	KR953522	③	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	■	■	■	■
◐	KR953525	③	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	■	■	■	■

■ Optional accessories

Recessed mounting for nuit 1x5 gear excl.

KR753301 Trim, white

KR753302 Trim, black

KR753300 Trimless

Recessed mounting for nuit gear incl.

KR753311 Trim, white

KR753312 Trim, black

KR753310 Trimless

Driver


KR772024 LED driver, 500mA, ON/OFF, 20W


KR772220 LED driver, 500mA, 1-10V, 20W

KR772126 LED driver, 500mA, DALI, 18W

		CRI	CCT	Voltage	Wattage	Drive current	Fixture lumen
①	LED	CRI90+	2700K/3000K/4000K		7W	500mA	585lm
②	LED	CRI90+	2700K/3000K/4000K	230V	7W		585lm
③	LED	CRI90+	2700K/3000K/4000K	230V	2x7W		2x 585lm

 REMARKS
IP20


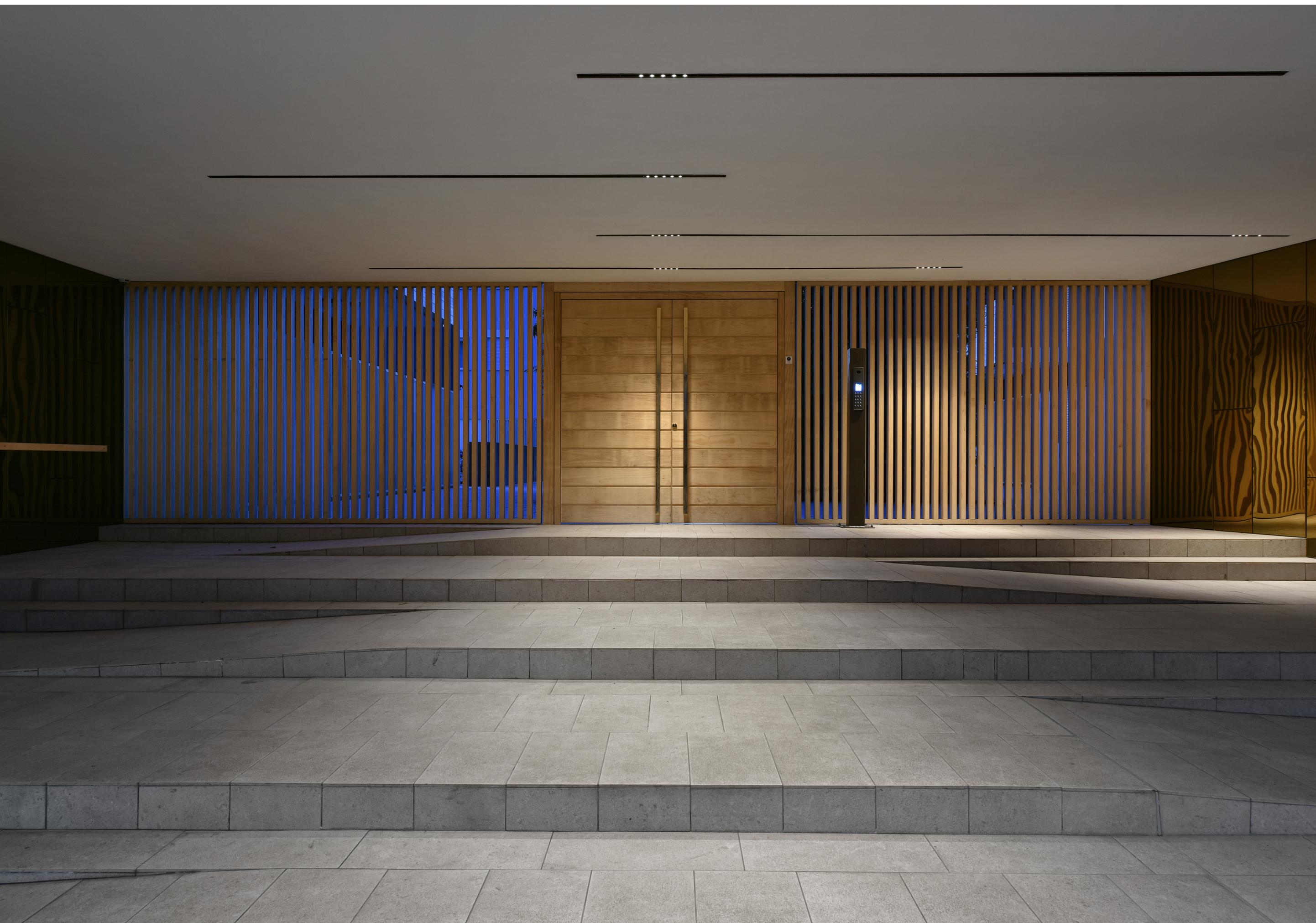




- 1. oran pendant stone in-nuit, long cylinder, black
- 2. oran pendant craft in-nuit, small bulb, white
- 3. oran pendant kap stone in-nuit, large cube, white
- 4. holon 40 pendant in-nuit, black LFO



kreon holon 40 in-nuit

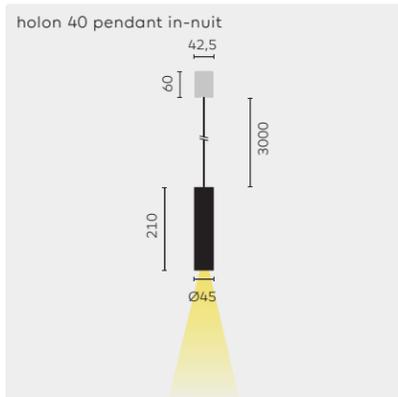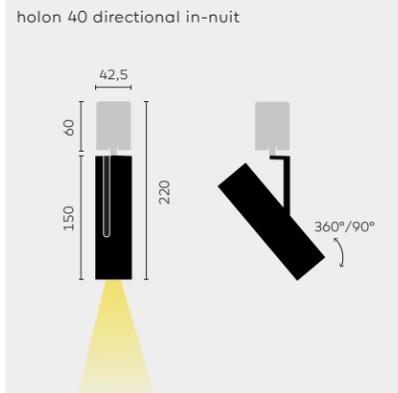

	Colour	KR-code	Light sources	9027 2700K, CRI90+	9030 3000K, CRI90+	SP Spot (20°)	FL Flood (30°)	WFL Wide flood (40°)	DL Darklight (40°)	WDL Wide darklight (76°)	P1 Louvre painted white ①	P2 Louvre painted black	A5 Louvre red copper	Required accessories
 holon 40 directional in-nuit	○	KR962711	①	●	●	●	●	●	●	●				■
	●	KR962712	①	●	●	●	●	●	●	●				■
 holon 40 pendant in-nuit	○	KR962811	①	●	●	●	●	●	●	●	●	●	●	■
	●	KR962812	①	●	●	●	●	●	●	●	●	●	●	■

■ Required accessories

Driver for holon/oran

[KR703030](#) LED driver, switchable ON/OFF (1 driver = max. 3 luminaires)

[KR703031](#) LED driver, phase dimmable (1 driver = max. 1 luminaire)

[KR703032](#) LED driver, 1-10V dimmable (1 driver = max. 3 luminaires)

[KR703033](#) LED driver, DALI dimmable (1 driver = max. 3 luminaires)


		CRI	CCT	Wattage	Drive current	Fixture lumen
①	LED	CRI90+	2700K/3000K	8,4W	700mA	558lm
	darklight	CRI90+	2700K/3000K	8,4W	700mA	420lm

REMARKS

① Only available for SP/FL/WFL

IP40

kreon oran pendant craft in-nuit

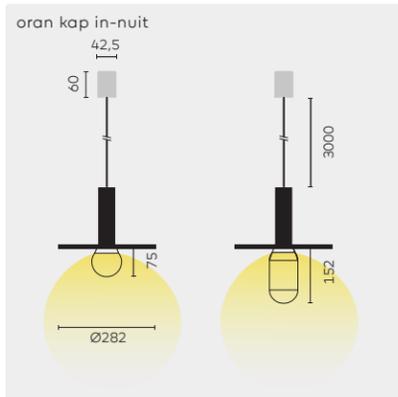


	Colour	KR-code	Light sources	9027 2700K, CRI90+	9030 3000K, CRI90+	P1 White shade bottom	P2 Black shade bottom	A3 Grey shade bottom	A4 Bronze shade bottom	Required accessories	
oran pendant craft sphere bulb in-nuit ①	○	KR991421	①	●	●					■	
	●	KR991422	①	●	●					■	
oran pendant craft long ampoule in-nuit ①	○	KR991821	①	●	●					■	
	●	KR991822	①	●	●					■	
oran pendant kap craft sphere bulb in-nuit ①	○	KR991441	①	●	●	●				■	
	●	KR991442	①	●	●		●	●	●	■	
oran pendant kap craft long ampoule in-nuit ①	○	KR991841	①	●	●	●				■	
	●	KR991842	①	●	●		●	●	●	■	
■ Required accessories											
Driver for oran				KR703030	LED driver, switchable ON/OFF (1 driver = max. 3 luminaires)						
				KR703031	LED driver, phase dimmable (1 driver = max. 1 luminaire)						
				KR703032	LED driver, 1-10V dimmable (1 driver = max. 3 luminaires)						
				KR703033	LED driver, DALI dimmable (1 driver = max. 3 luminaires)						

	CRI	CCT	Wattage	Drive current	Fixture lumen
① LED glass	CRI90+	2700K/3000K	6,7W	700mA	290lm

REMARKS

IP40

kreon oran pendant stone in-nuit

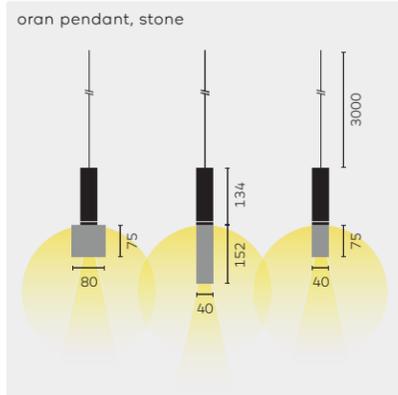

	Colour	KR-code	Light sources	9027 2700K, CRI90+	9030 3000K, CRI90+	P1 White shade bottom	P2 Black shade bottom	A3 Grey shade bottom	A4 Bronze shade bottom	Required accessories
	○	KR991711	①	●	●					■
	●	KR991712	①	●	●					■
	○	KR991611	①	●	●					■
	●	KR991612	①	●	●					■
	○	KR991811	①	●	●					■
	●	KR991812	①	●	●					■
	○	KR991911	①	●	●					■
	●	KR991912	①	●	●					■
	○	KR991731	①	●	●	●				■
	●	KR991732	①	●	●		●	●	●	■
	○	KR991631	①	●	●	●				■
	●	KR991632	①	●	●		●	●	●	■
	○	KR991831	①	●	●	●				■
	●	KR991832	①	●	●		●	●	●	■
	○	KR991931	①	●	●	●				■
	●	KR991932	①	●	●		●	●	●	■

■ Required accessories

Driver for oran

KR703030	LED driver, switchable ON/OFF (1 driver = max. 3 luminaires)
KR703031	LED driver, phase dimmable (1 driver = max. 1 luminaire)
KR703032	LED driver, 1-10V dimmable (1 driver = max. 3 luminaires)
KR703033	LED driver, DALI dimmable (1 driver = max. 3 luminaires)

REMARKS

- ① Protect the alabaster block against direct sunlight and temperatures above 50°C.
- ② Lumen output may vary due to the use of natural products.

Gear excluded.
◆ IP40



kreon luminaires can be arranged and customised to match your vision perfectly.

As well as the standard range, kreon also offers you the option of adapting the systems listed to the dimensions of your project and personalising them in terms of light source, colour and dimensions.

Please contact customer service for further information: mailbox@kreon.com or +32 89 81 97 80.



For this Paris office project kreon nuit LED profiles were equipped with custom corner cuts at various angles to meet the sharp edged graphics of the floor. kreon nuit makes the overall design come alive in a 3 dimensional architectural experience.



The aim of this Raf Segers project was to provide minimal lighting with maximum effect perfectly in tune with the sleek lines of the house.

The suspended nuit profiles blend perfectly and provide additional emphasis to those lines. To maintain the unity, the nuit profiles were installed at angles to each other to arrive at a compact structure that still provided the desired light level on the landing and stairs.

kreon offices

kreon HQ

Industrieweg Noord 1152
3660 Oudsbergen
Belgium
T +32 89 81 97 80
belgium@kreon.com
www.kreon.com

kreon Austria

Eva-Maria-Mazzucco-Platz 2
1220 Vienna
Austria
T +43 1 715 44 25
austria@kreon.com

kreon China / The Belgian House

Changle Road Lane 672, No. 33,
Building No. 5,
Jingan, Shanghai
China
T +86 183 1711 3541
china@kreon.com

kreon France

5, rue d'Aboukir
75002 Paris
France
T +33 1 44 50 53 54
france@kreon.com

kreon Germany

Brühler Straße 11-13
50968 Cologne
Germany
Tel +49 221 937 22 0
germany@kreon.com

kreon Italy

Via V. Forcella 5
20144 Milano
Italy
T +39 02 89 42 08 46
italy@kreon.com

kreon Middle East & India

Dubai Airport Free Zone Area (DAFZA)
West Wing 6
Office 6 WA 634
P.O. Box 293889
Dubai
United Arab Emirates
T +971 56 705 2522
middle.east@kreon.com

kreon Inc.

North America & Canada

20 Murray Hill Parkway
Suite #180
East Rutherford NJ 07073
United States of America
+1 (201) 298-44 48
usa@kreon.com

kreon Poland

T +48 504 788 355
poland@kreon.com

kreon Scandinavia

T +31 (0)652 39 16 80
auke.bakker@kreon.com

kreon South East Asia

Singapore
T +65 62 22 33 93
singapore@kreon.com

kreon Spain & Portugal

Ángel Guimera 7-9 local C
Barcelona 08017
Spain
T +34 600 462 551
spain@kreon.com

kreon Switzerland

Neufeldweg 6
5103 Möriken
Switzerland
T +41 61 316 74 01
switzerland@kreon.com

kreon The Netherlands

Danzigerbocht 39
1013 AM Amsterdam
The Netherlands
T +31 (0)6 52 391 680
the.netherlands@kreon.com

kreon Turkey

Sehit Murat Demirli Cad. Resadiye Yolu 76
Alemdag-Ümraniye 34794
Istanbul
Turkey
T +90 216 430 86 00
turkey@kreon.com

kreon UK

67 Maltings Place
169 Tower Bridge Road
London
SE1 3LJ
United Kingdom
T +44 (0)20 7740 2112
uk@kreon.com