

kreon prologe 40



kreon prologe 40

Light captured in a black box.

kreon prologe 40 complements the kreon tools of light collection based upon our principles for working with light: quality, architectural integration and design.

The name "prologe" has been adapted from "Prologus in Anthiphonarium" a manuscript by the mediaeval music theorist Guido d'Arezzo. He created the basics of the system of music notation that we all still know today. A concept that embraces both useful theoretical principles and the practical skill needed to perform music. kreon prologe 40 offers a wide flexibility for composing systematic yet highly individual light scenographies.

kreon prologe 40 wants to create functional light through the discreet presence of simple architectural volumes. The original element of this range is light, captured in a small surface mounted box. Different optics give this basic volumes the identity that fits its surroundings.

Kristof Pycke
Art director



kreon prologe 40

kreon prologe 40 is a miniaturized surface mounted downlight that thoroughly reflects kreon's principles in lighting: quality, design and architectural integration.

kreon prologe 40 is characterised by its compact form and hosts a single or double deepset invisible LED source. The kreon prologe 40 luminaires can be fitted with professional darklight optics with high lumen packages. Finished in black for a dramatic contrast or pure white to disappear in the surrounding architecture.






kreon prologe 40 single

Project Private residence
Location Milan, Italy

Architect M+T architects
Photographer Serge Brison

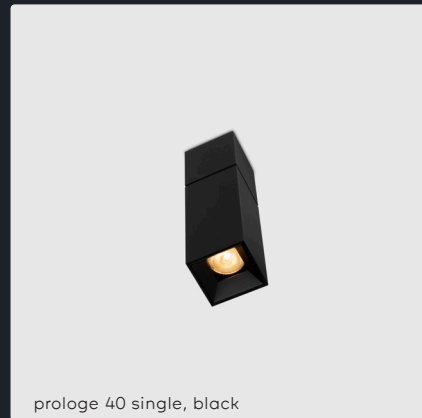


prologe 40 single, black



prologe 40 single, deep recessed, black




prologe 40 single, darklight, black

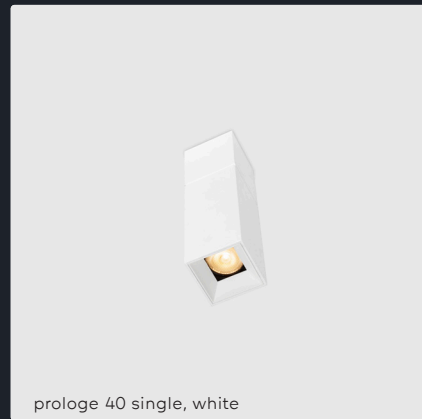

prologe 40 single, white



prologe 40 single, deep recessed, white


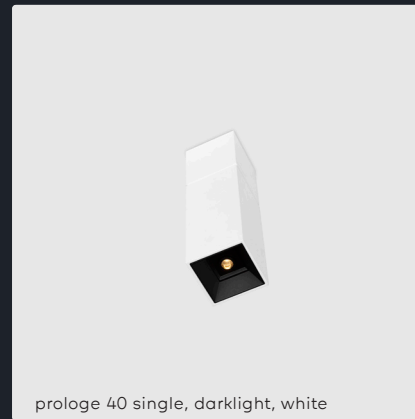


prologe 40 single, darklight, white

Ceiling needs to be higher than
3m for use in bathrooms



kreon prologe 40 single

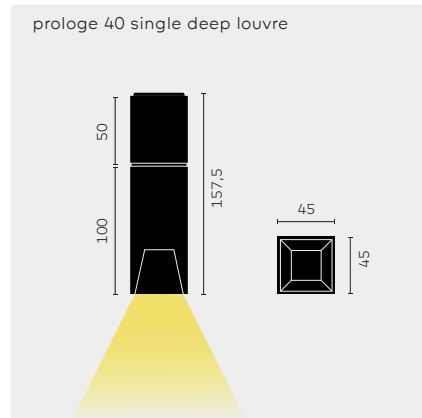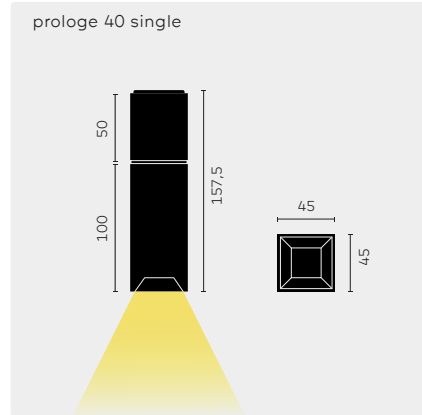

prologe 40 single

Driver: excl.

prologe 40 single, deep louvre

Driver: excl.

Optional accessories

Driver ②

Installation cover

Colour	KR-code	Light sources	9027 2700K, CRI90	9030 3000K, CRI90	SP Spot (20°)	FL Flood (30°)	WFL Wide flood (38°)	DL Dark light (40°) ①	WDL Wide dark light (76°) ①	Optional accessories
--------	---------	---------------	----------------------	----------------------	------------------	-------------------	-------------------------	--------------------------	--------------------------------	----------------------

○	KR967141	①	●	●	●	●	●	●	●	■
---	----------	---	---	---	---	---	---	---	---	---

●	KR967142	①	●	●	●	●	●	●	●	■
---	----------	---	---	---	---	---	---	---	---	---

○	KR967241	②	●	●	●	●	●			■
---	----------	---	---	---	---	---	---	--	--	---

●	KR967242	②	●	●	●	●	●			■
---	----------	---	---	---	---	---	---	--	--	---

KR772034 LED driver, 700mA, ON/OFF, 20W

KR762902 LED driver, 700mA, 1-10V, 25W

KR772430 LED driver, 700mA, phase dim, 14W

KR772236 LED driver, 700mA, DALI, 18W

KR766101 Installation cover prologe 40 single, white

KR766102 Installation cover prologe 40 single, black

		CRI	CCT	Voltage	Wattage	Drive current	Fixture lumen
① LED	FL	CRI90+	2700K/3000K		8,4W	700mA	547lm
	DL	CRI90+	2700K/3000K		8,4W	700mA	380lm
② LED	FL	CRI90+	2700K/3000K		8,4W	700mA	490lm


REMARKS

① Louvre for DL/WDL is always black














② Driver must be placed on remote

IP40

Installation cover prologe 40 single

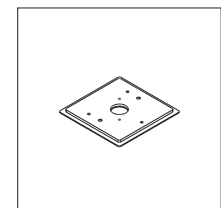


kreon prologe 40 single

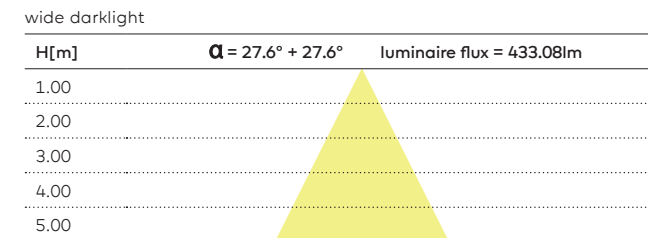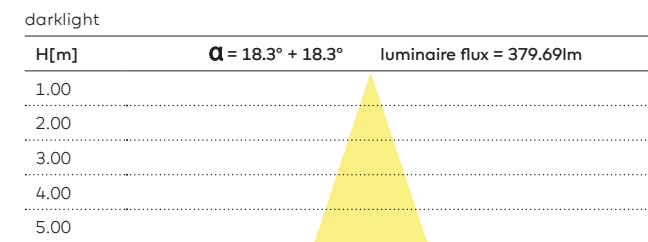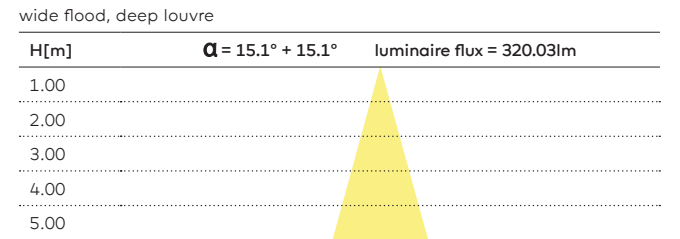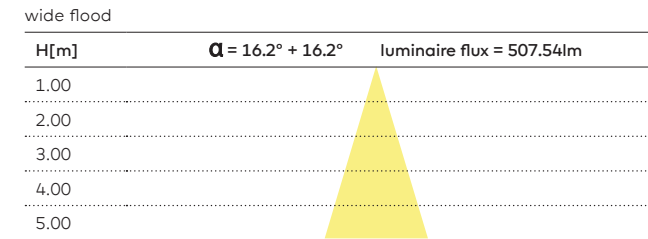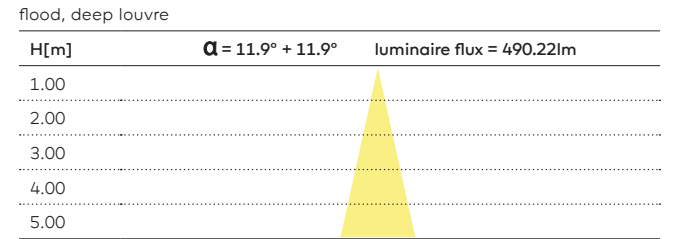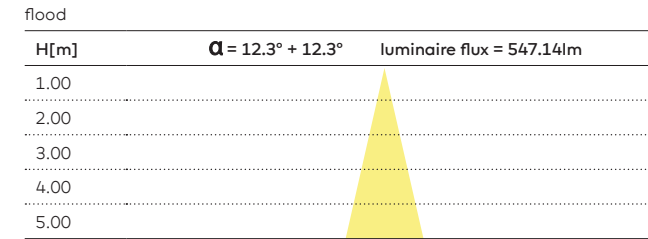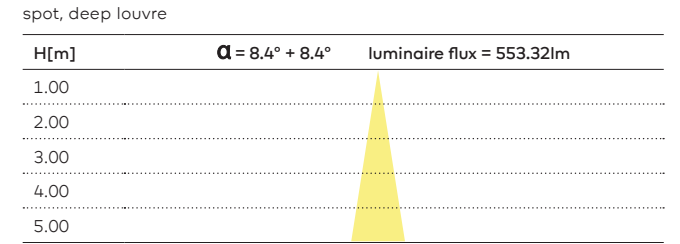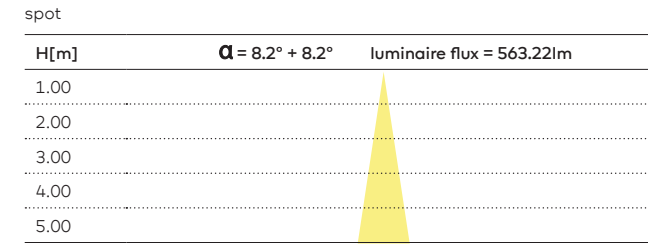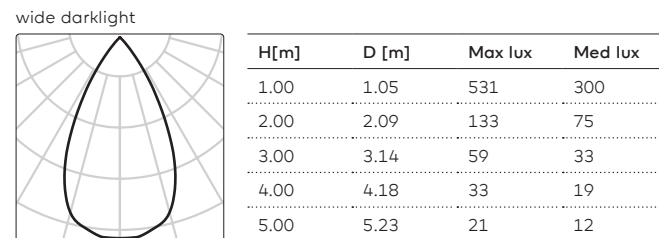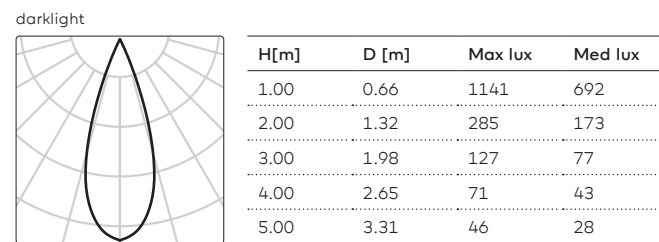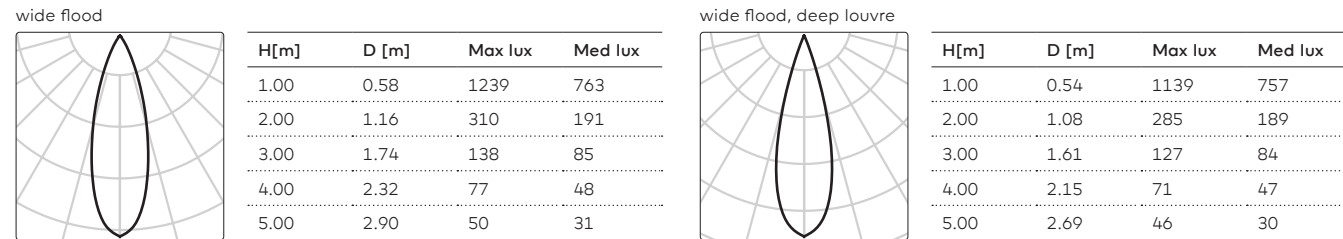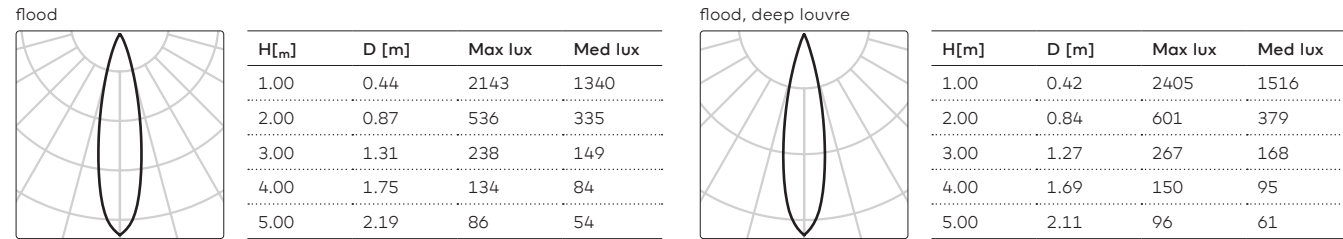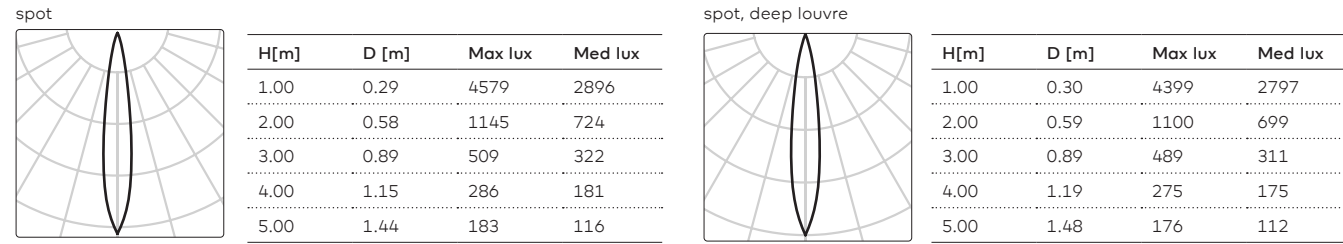

kreon prologe 40 double

Project Private residence
Location Paris, France

Architect Laurent Berkemoun
Photographer Serge Brison

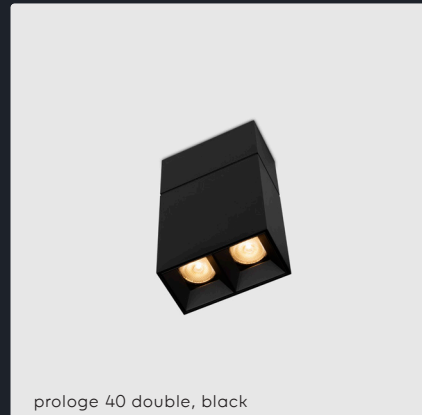


prologe 40 double, black



prologe 40 double, deep recessed, black




prologe 40 double, darklight, black

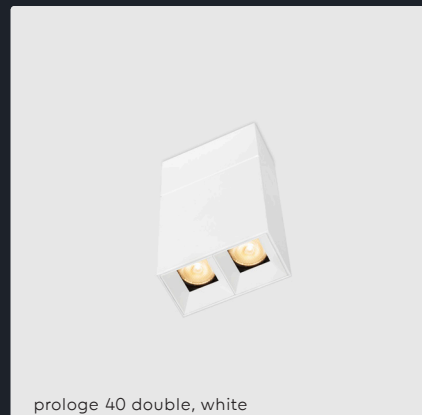

prologe 40 double, white





prologe 40 double, deep recessed, white

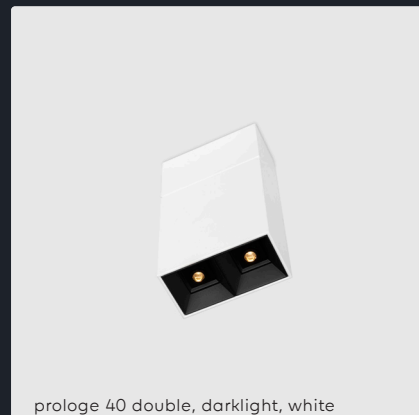

prologe 40 double, darklight, white



kreon prologe 40 double

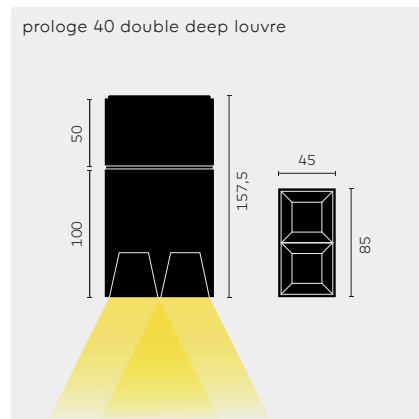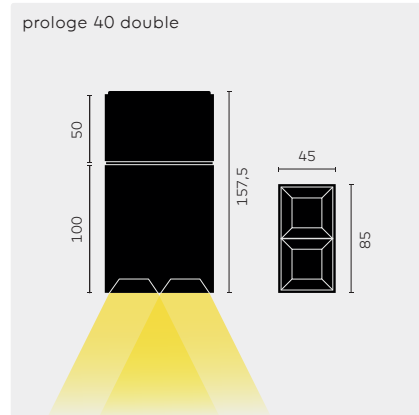

prologe 40 double

prologe 40 double, deep louvre Driver: excl.

Optional accessories

Driver ②

Installation cover

Colour	KR-code	Light sources	9027 2700K, CRI90	9030 3000K, CRI90	SP Spot (20°)	FL Flood (30°)	WFL Wide flood (38°)	DL Dark light (40°) ①	WDL Wide dark light (76°) ①	EX Driver excluded	SW Switchable ON/OFF	PD Phase dimming	Optional accessories
--------	---------	---------------	----------------------	----------------------	------------------	-------------------	-------------------------	--------------------------	--------------------------------	-----------------------	-------------------------	---------------------	----------------------

○	KR967341	①	●	●	●	●	●	●	●	●	●	●	■
●	KR967342	①	●	●	●	●	●	●	●	●	●	●	■
○	KR967441	②	●	●	●	●	●			●			■
●	KR967442	②	●	●	●	●	●			●			■

[KR772024](#) LED driver, 500mA, ON/OFF, 20W

[KR772220](#) LED driver, 500mA, 1-10V, 20W

[KR772542](#) LED driver, 500mA, phase dim, 18W

[KR752843](#) LED driver, 500mA, phase dim, 24W

[KR772126](#) LED driver, 500mA, DALI, 18W

[KR772123](#) LED driver, 500mA, DALI, 27W

[KR767241](#) Installation cover prologe 40 double, white

[KR767242](#) Installation cover prologe 40 double, black

			CRI	CCT	Voltage	Wattage	Drive current	Fixture lumen
①	LED	EX	FL	CRI90+	2700K/3000K	12W	500mA	912lm
			DL	CRI90+	2700K/3000K	12W	500mA	622lm
	SW/PD	FL	CRI90+	2700K/3000K	230V	12W	912lm	
			DL	CRI90+	2700K/3000K	230V	12W	621lm
②	LED	EX	FL	CRI90+	2700K/3000K	12W	500mA	747lm


REMARKS

① Louvre for DL/WDL is always black

② Driver must be placed on remote














IP40

Installation cover prologe 40 double

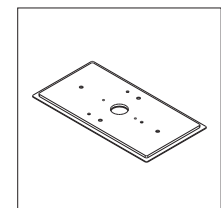



kreon prologe 40 double

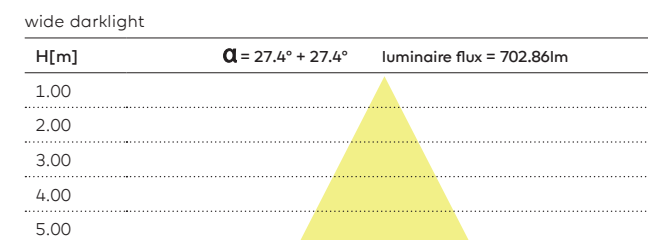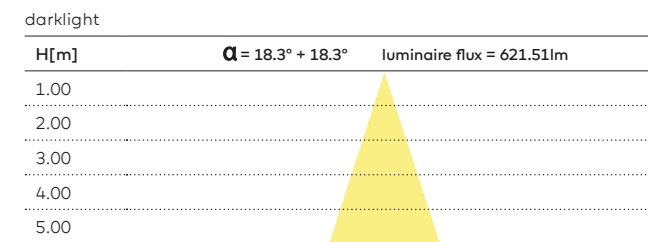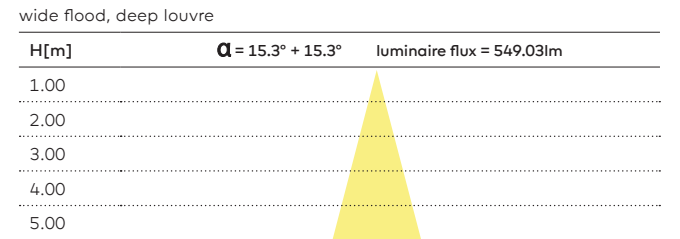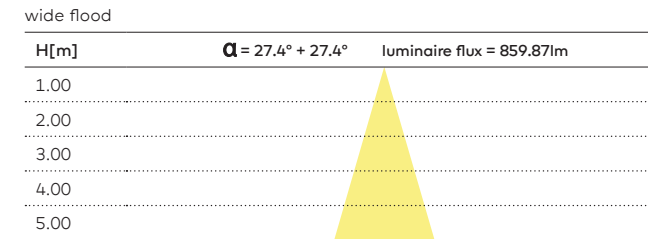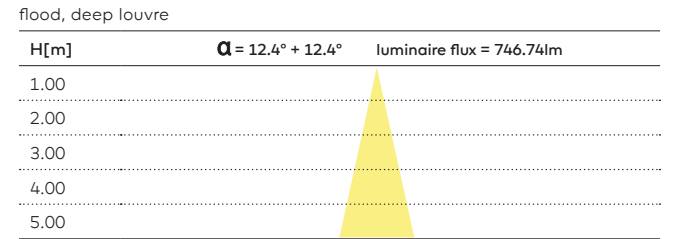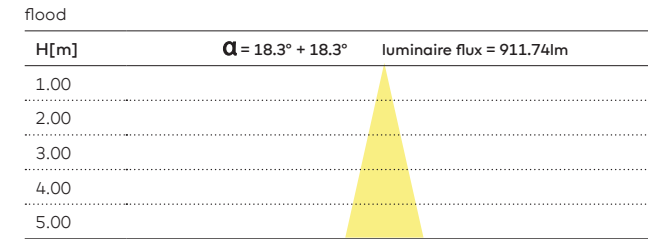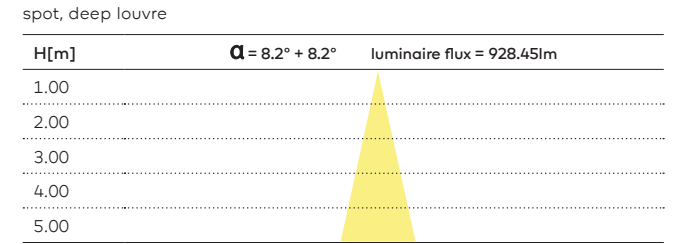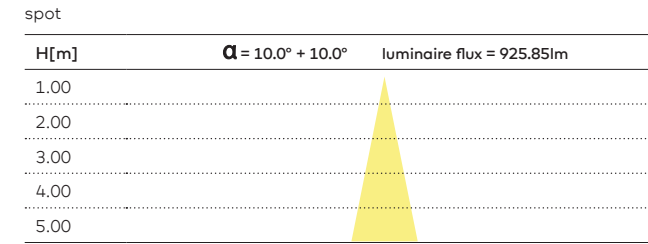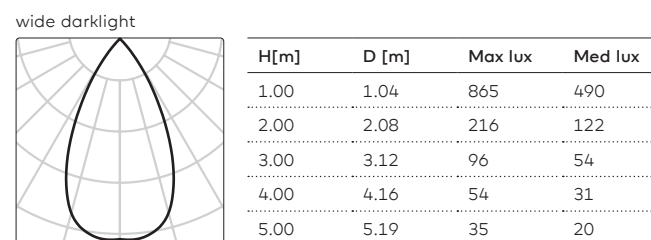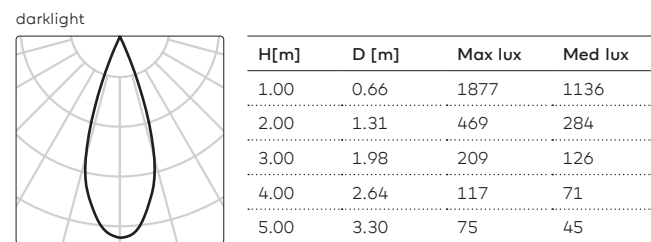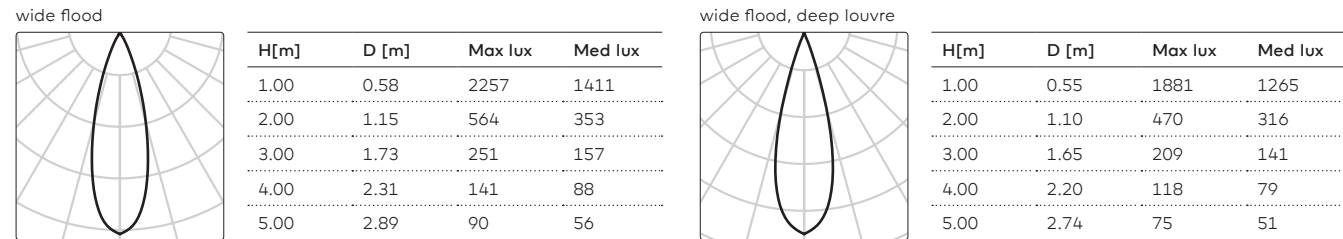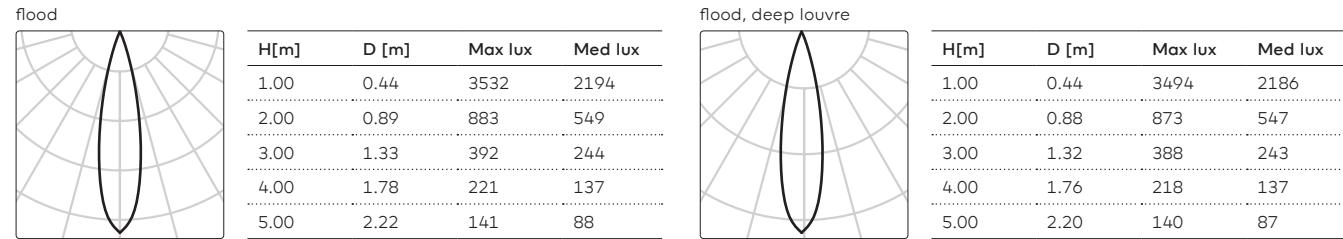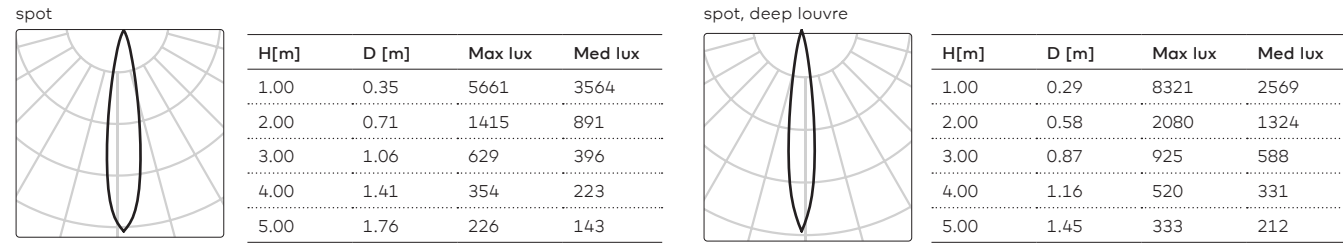

kreon offices

kreon HQ

Industrieweg Noord 1152
3660 Oudsbergen
Belgium
T +32 89 81 97 80
belgium@kreon.com
www.kreon.com

kreon Austria

Kärntner Ring 4
1010 Vienna
Austria
T +43 1 715 44 25
austria@kreon.com

kreon China / The Belgian House

Changle Road Lane 672, No. 33,
Building No. 5,
Jingan, Shanghai
China
china@kreon.com
T +86 183 1711 3541

kreon France

5, rue d'Aboukir
75002 Paris
France
T +33 1 44 50 53 54
france@kreon.com

kreon Germany

Brühler Straße 11-13
50968 Cologne
Germany
Tel +49 221 937 22 0
germany@kreon.com

kreon Italy

Via V. Forcella 5
20144 Milano
Italy
T +39 02 89 42 08 46
italy@kreon.com

kreon Middle East & India

Dubai Airport Free Zone Area (DAFZA)
West Wing 6
Office 6 WA 634
P.O. Box 293889
Dubai
United Arab Emirates
T +971 56 705 2522
middle.east@kreon.com

kreon Inc.

North America & Canada
20 Murray Hill Parkway
Suite #180
East Rutherford NJ 07073
United States of America
+1 (201) 298-44 48
usa@kreon.com

kreon Poland

T +48 504 788 355
poland@kreon.com

kreon Scandinavia

T +45 (0)7137 0239
hassan.elhindi@kreon.com

kreon South East Asia

63a Club Street
Singapore 069 437
Singapore
T +65 62 22 33 93
singapore@kreon.com

kreon Spain & Portugal

Ángel Guimera 7-9 local C
Barcelona 08017
Spain
T +34 600 462 551
spain@kreon.com

kreon Switzerland

Neufeldweg 6
5103 Möriken
Switzerland
T +41 61 316 74 01
switzerland@kreon.com

kreon The Netherlands

Danzigerbocht 39
1013 AM Amsterdam
The Netherlands
T +31 (0)6 52 391 680
the.netherlands@kreon.com

kreon Turkey

Sehit Murat Demirli Cad. Resadiye Yolu 76
Alemdag-Ümraniye 34794
Istanbul
Turkey
T +90 216 430 86 00
turkey@kreon.com

kreon UK

67 Maltings Place
169 Tower Bridge Road
London
SE1 3LJ
United Kingdom
T +44 (0)20 7740 2112
uk@kreon.com