

kreon esprit




# kreon esprit

In 2014, kreon esprit was released into the world. A range of three different luminaires with minimalistic, tubular lampheads mounted on a slim rod. One, free-standing with a square foot; the second, a vertical ceiling-mounted fixture and the latest, a horizontal pending luminaire with up to four luminaire heads.

On the eve of kreon esprit's 10th anniversary, two new additions to the product range see the light of day: a redesigned free-standing version and a brand-new desk light. Each of these newly developed luminaires feature the same signature slim-lined rotatable lampheads of the original design. Available in standard black and white finishes, plus newly released eye-catching metallic versions in gold, bronze, gun black or nickel-plated.

kreon esprit floor

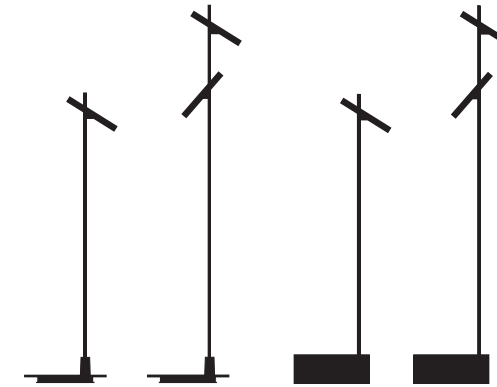

kreon esprit desk






kreon esprit ceiling



kreon esprit pendant





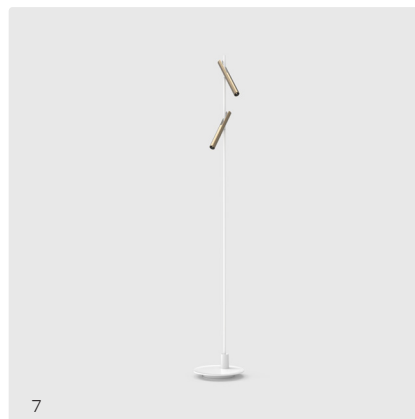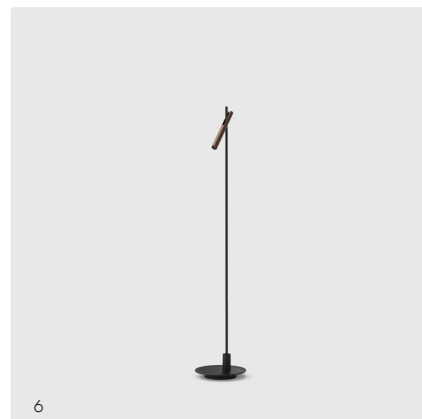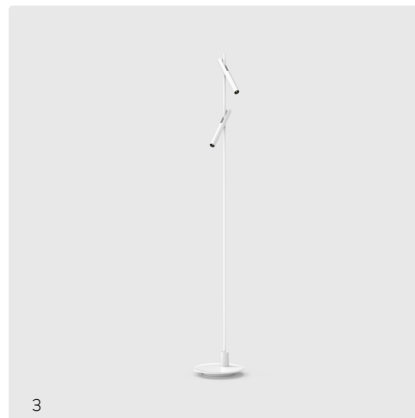

- 1. esprit double floor, carrara bianco, white-white
- 2. esprit single floor, natural steel blue, black-black
- 3. esprit double floor round base, white-white
- 4. esprit double floor round base, black-black
- 5. esprit double floor round base, white-nickel
- 6. esprit single floor round base, black-bronze
- 7. esprit double floor round base, white-gold



# kreon esprit floor

The design update of kreon esprit floor comes with a round base, which doubles as a cable depot and a push-dim button on top of the vertical rod. In this way, ease of use and design are perfectly combined.

The two lampheads can be positioned individually to aim the light beam wherever you require: highlighting a work of art in your interior with the top light, while providing light at table level with the lower one.


## Lamphead

Available in white, black, brushed bronze, brushed nickel, brushed gold and gun black.




## Push-dim

Press the button for less than 1 second for on/off and dimming by holding the button down. To change the intensity, release the button and press again.

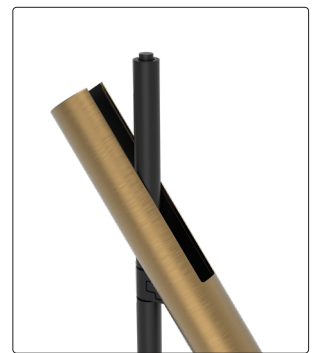





## Base

Available in Carrara marble, natural steel blue or the new elegant round base in white or black.

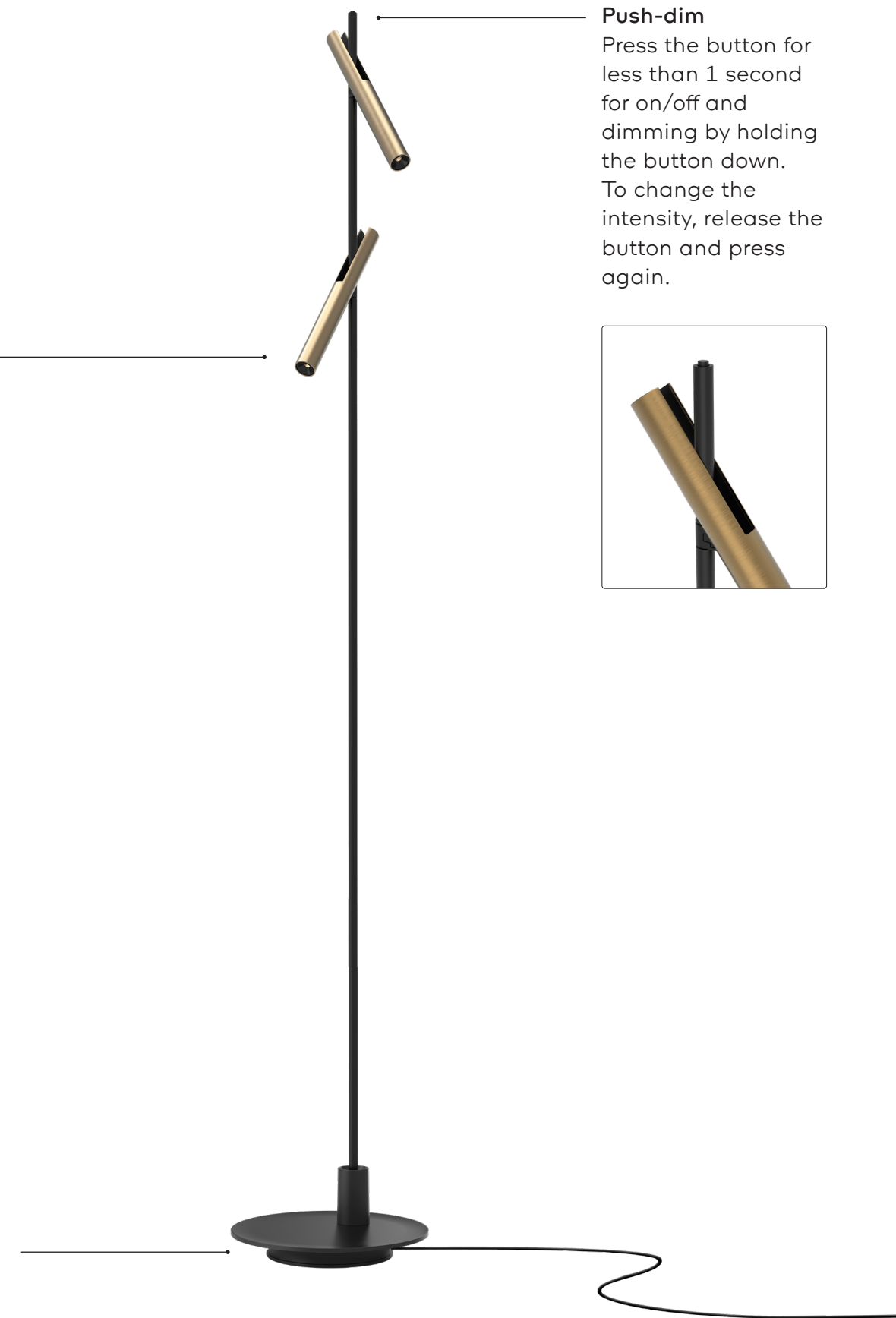



# kreon esprit floor

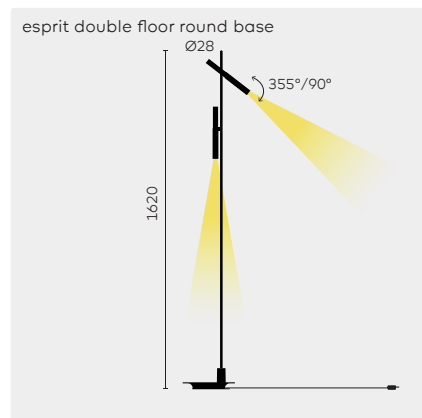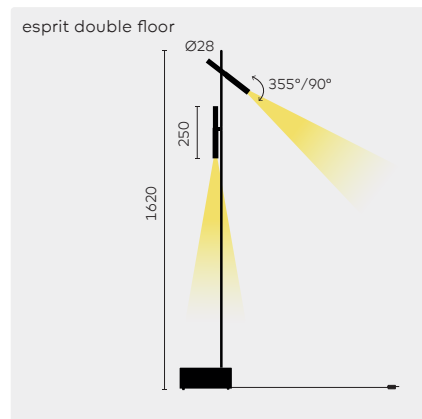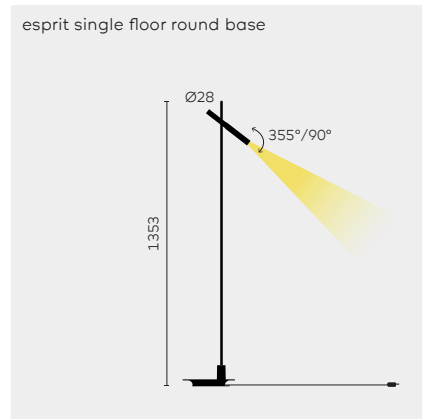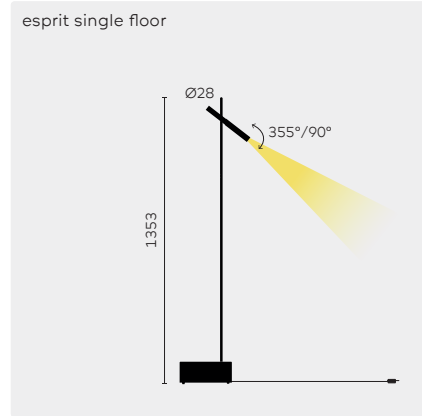

	Colour	KR-code	Light sources	9027 2700K, CRI90+	9030 3000K, CRI90+	SP Spot (20°)	DL Darklight (33°)	WDL Wide darklight (56°)	P1 White painted lamphead ①	P2 Black painted lamphead ①	A4 Brushed bronze lamphead ①	A7 Brushed nickel lamphead ①	AB Brushed gold lamphead ①	A9 Gun black lamphead ①
<b>esprit single floor carrara bianco</b> Gear: incl. in base	○	KR963211	①	●	●	●	●	●	●	●	●	●	●	●
	●	KR963212	①	●	●	●	●	●	●	●	●	●	●	●
<b>esprit single floor natural steel blue</b> Gear: incl. in base	○	KR963311	①	●	●	●	●	●	●	●	●	●	●	●
	●	KR963312	①	●	●	●	●	●	●	●	●	●	●	●
<b>esprit single floor round base</b> Gear: incl. in base	○	KR963411	①	●	●	●	●	●	●	●	●	●	●	●
	●	KR963412	①	●	●	●	●	●	●	●	●	●	●	●
<b>esprit double floor carrara bianco</b> Gear: incl. in base	○	KR963221	②	●	●	●	●	●	●	●	●	●	●	●
	●	KR963222	②	●	●	●	●	●	●	●	●	●	●	●
<b>esprit double floor natural steel blue</b> Gear: incl. in base	○	KR963321	②	●	●	●	●	●	●	●	●	●	●	●
	●	KR963322	②	●	●	●	●	●	●	●	●	●	●	●
<b>esprit double floor round base</b> Gear: incl. in base	○	KR963421	②	●	●	●	●	●	●	●	●	●	●	●
	●	KR963422	②	●	●	●	●	●	●	●	●	●	●	●

		CRI	CCT	Voltage	Wattage	Fixture lumen
①	SP	CRI90+	2700K/3000K	230V	2W	162lm
	DL/WDL	CRI90+	2700K/3000K	230V	8,4W	370lm
②	SP	CRI90+	2700K/3000K	230V	2x2W	2x162lm
	DL/WDL	CRI90+	2700K/3000K	230V	2x8,4W	2x370lm

## REMARKS

① Other types of finishes on request.


② Supplied with 2,5m black braided sleeved powercable.

IP40







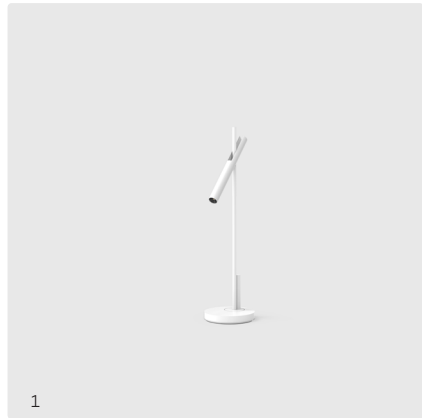

1



2



3




4




5



6

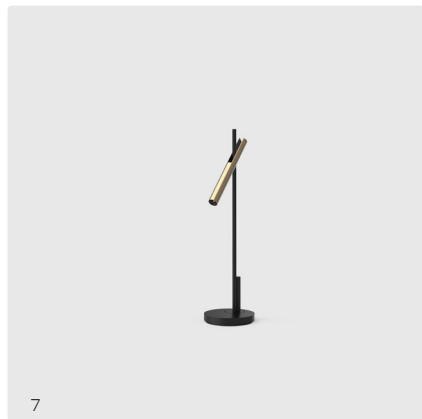

7

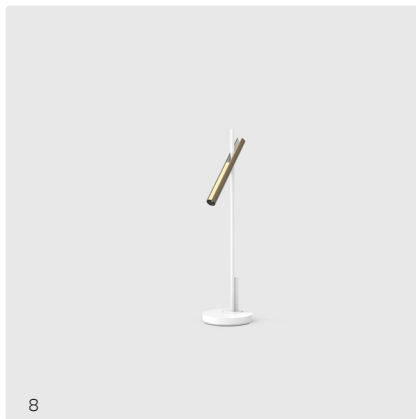

8

- 1. esprit desk, white-white
- 2. esprit desk, black-black
- 3. esprit desk, black-bronze
- 4. esprit desk, white-bronze
- 5. esprit desk, white-nickel
- 6. esprit desk, black-nickel
- 7. esprit desk, black-gold
- 8. esprit desk, white-gold




# kreon esprit desk

kreon esprit desk is the product range's little brother. Although small in size, kreon esprit desk harnesses the same performant luminaire head of its larger counterparts. The lamphead can be positioned to fulfill your needs. At full brightness as a desk light during a hard day's work, or dimmed using the built-in touchdim button for some bedtime reading.



**Touchdim**  
Touch the button for less than 1 second for on/off and dimming by holding your finger on the button. To change the intensity, release the button and press again.

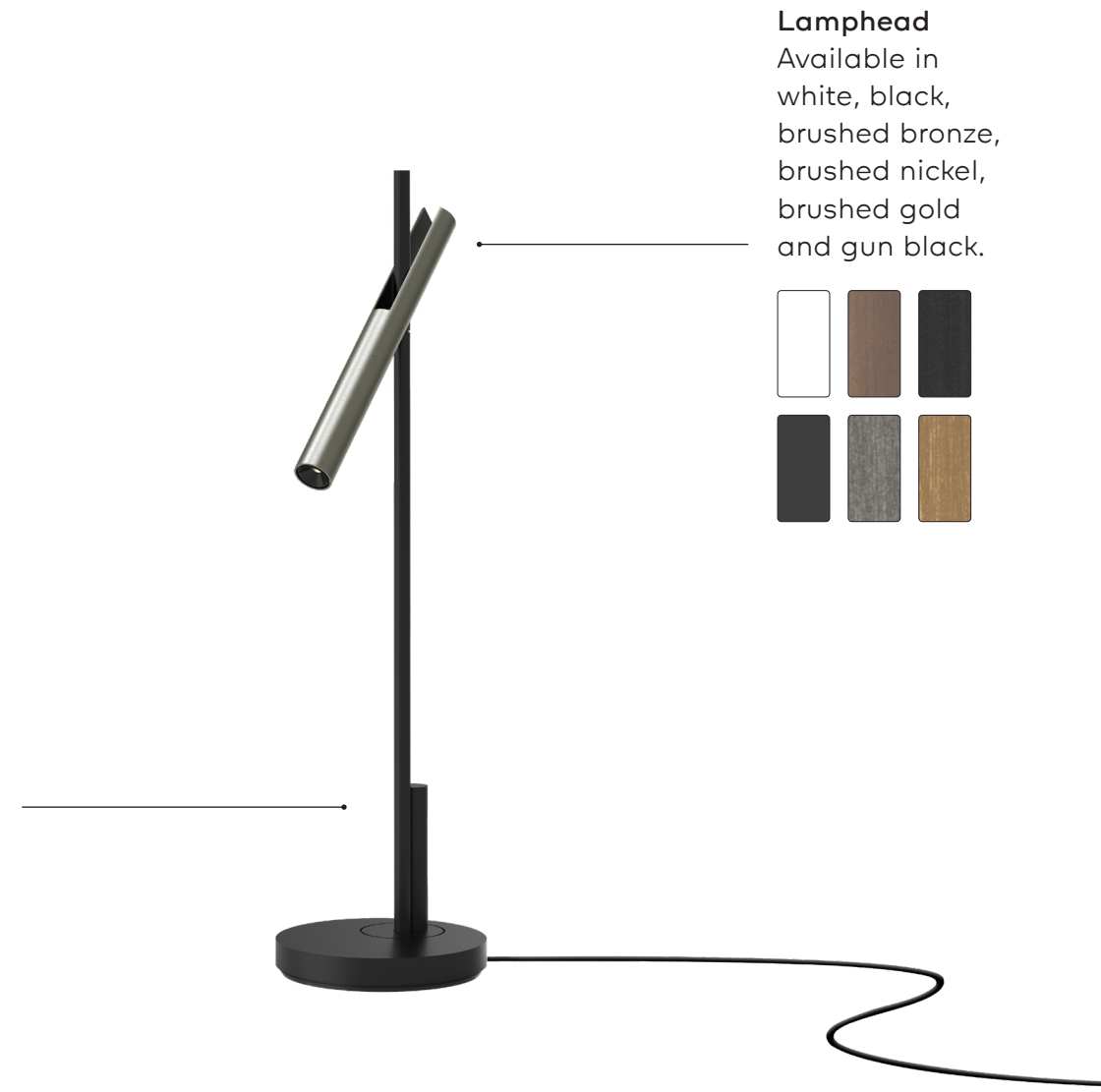


**Lamphead**  
Available in white, black, brushed bronze, brushed nickel, brushed gold and gun black.





# kreon esprit desk

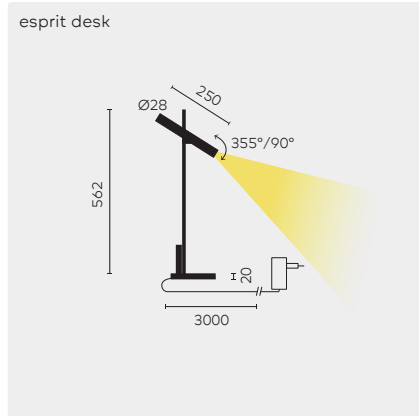

**esprit desk**  
Gear: incl.

Colour	KR-code	Light sources	9027 2700K, CRI90+	9030 3000K, CRI90+	WDL Wide daylight (56°)	P1 White painted lamphead	P2 Black painted lamphead	A4 Brushed bronze lamphead	A7 Brushed nickel lamphead	A8 Brushed gold lamphead	A9 Gun black lamphead
○	<u>KR963911</u>	①	●	●	●	●	●	●	●	●	●
●	<u>KR963912</u>	①	●	●	●	●	●	●	●	●	●

	CRI	CCT	Voltage	Wattage	Fixture lumen
①	WDL CRI90+	2700K	230V	8,4W	368lm



**REMARKS**

IP40







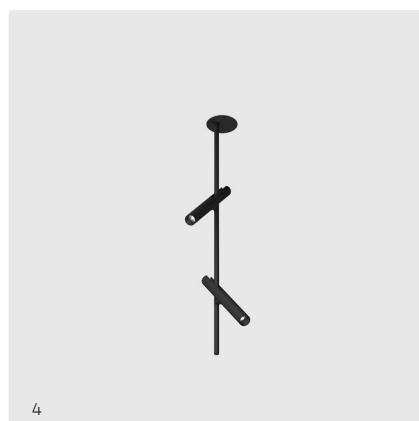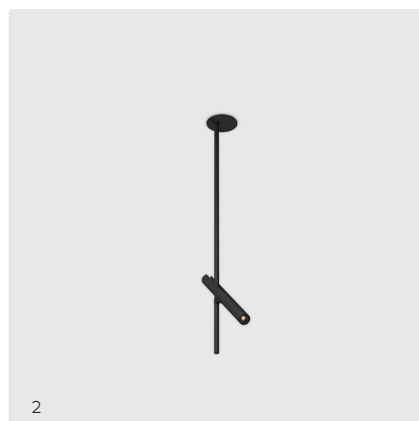


- 1. esprit single ceiling, white
- 2. esprit single ceiling, black
- 3. esprit double ceiling, white
- 4. esprit double ceiling, black




# kreon esprit ceiling

kreon esprit ceiling is a luminaire designed for ceiling mounting. It features one or two lampheads that are attached to a vertical rod. Each lamphead of the luminaire is capable of individually rotating up to 355°, allowing for flexible positioning at any angle between 0° and 90°. kreon esprit ceiling can be recessed mounted using the kreon aplis 80 trimless plasterkit.

**Mounting options**  
Multiple mounting options available:  
- gearbox with internal phasedim or DALI driver  
- connection box  
- plasterkit for recessed mounting


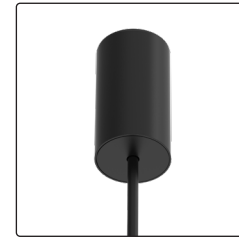


**Lamphead**  
Available in white, black, brushed bronze, brushed nickel, brushed gold and gun black.

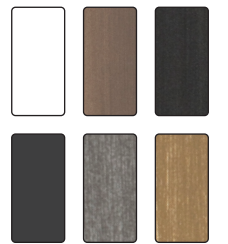



# kreon esprit ceiling



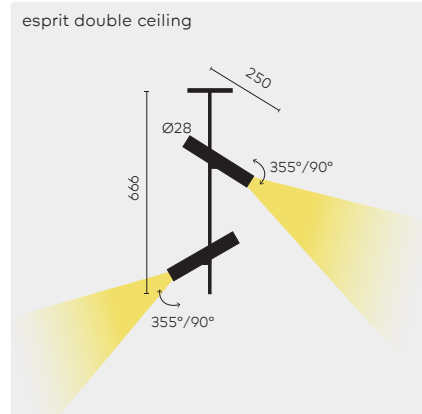
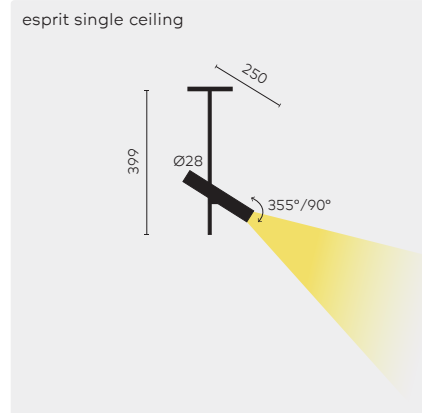


	Colour	KR-code	Light sources	9027 2700K, CRI90+	9030 3000K, CRI90+	SP Spot (20°)	DL Darklight (33°)	WDL Wide darklight (56°)	P1 White painted lamphead	P2 Black painted lamphead	A4 Brushed bronze lamphead	A7 Brushed nickel lamphead	AB Brushed gold lamphead	A9 Gun black lamphead	Required accessories	Optional accessories
<b>esprit single ceiling</b> Gear: excl.,	○	<u>KR963011</u>	①	●	●	●	●	●	●	●	●	●	●	●	■	■
	●	<u>KR963012</u>	①	●	●	●	●	●	●	●	●	●	●	●	■	■
<b>esprit double ceiling</b> Gear: excl.,	○	<u>KR963021</u>	②	●	●	●	●	●	●	●	●	●	●	●	■	■
	●	<u>KR963022</u>	②	●	●	●	●	●	●	●	●	●	●	●	■	■
<b>■ Required accessories</b>																
Installation boxes <span style="float: right;">See page 27-28</span>																
<b>■ Optional accessories</b>																
Drivers <span style="float: right;">See page 27-28</span>																

		CRI	CCT	Wattage	Drive Current	Fixture lumen
①	SP	CRI90+	2700K/3000K	2W	700mA	162lm
		CRI90+	2700K/3000K	3,2W	1050mA	218lm
	DL WDL	CRI90+	2700K/3000K	8W	700mA	368lm
		CRI90+	2700K/3000K	12W	1050mA	400lm
②	SP	CRI90+	2700K/3000K	2x2W	700mA	2x162lm
		CRI90+	2700K/3000K	2x3,2W	1050mA	2x218lm
	DL WDL	CRI90+	2700K/3000K	2x8W	700mA	2x368lm
		CRI90+	2700K/3000K	2x12W	1050mA	2x400lm



# kreon esprit ceiling mounting options

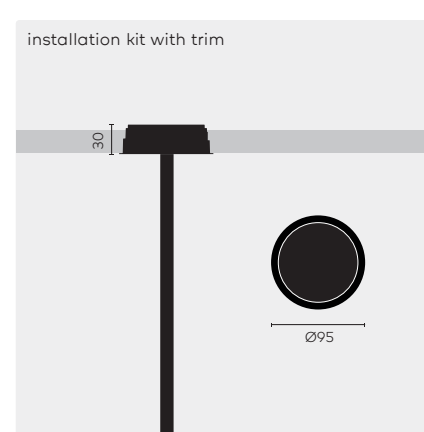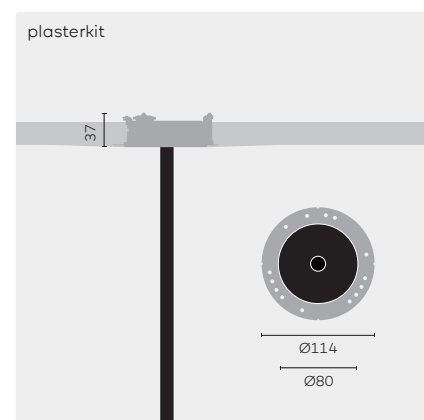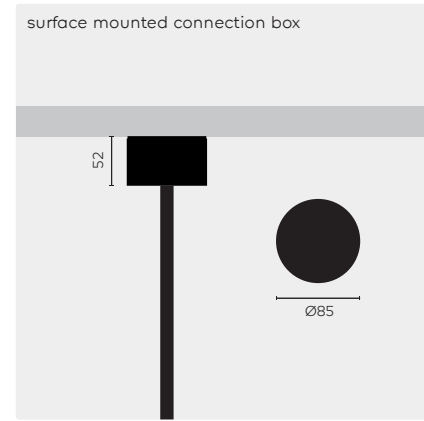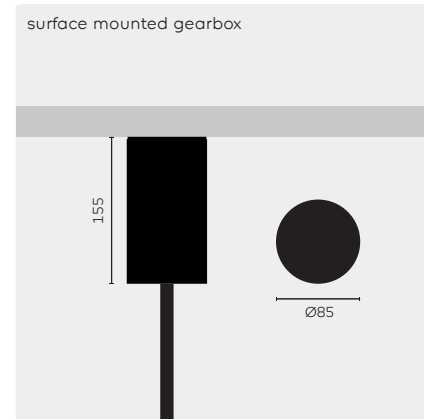

	Colour	KR-code	PD Phase dimming	DD DALI dimming 1	LV low voltage connection	Optional accessories
<b>surface mounted gearbox, 220-240Vdc, 50/60Hz</b> for single SP/DL/WDL and double SP Gear: incl., Ø85 H155	○	<a href="#">KR763591</a>	●	●		
	●	<a href="#">KR763592</a>	●	●		
<b>surface mounted gearbox, 220-240Vdc, 50/60Hz</b> for double DL/WDL Gear: incl., Ø85 H155	○	<a href="#">KR763791</a>	●	●		
	●	<a href="#">KR763792</a>	●	●		
<b>surface mounted connection box</b> Gear: excl., Ø85 H52	○	<a href="#">KR763691</a>			●	■
	●	<a href="#">KR763692</a>			●	■
<b>trimless plasterkit for recessed mounting, no shadowgap</b> Gear: excl.		<a href="#">KR717104</a>				■
<b>trimless plasterkit for recessed mounting, shadowgap</b> for recessed mounting Gear: excl.		<a href="#">KR717108</a>				■
<b>installation kit for recessed mounting, with trim</b> for recessed mounting Gear: excl., Ø90 D110	○	<a href="#">KR717021</a>				■
	●	<a href="#">KR717022</a>				■

■ **Optional accessories**

Driver	Code	Description
	<a href="#">KR762700</a>	LED driver, 700mA, ON/OFF, 11W 2
	<a href="#">KR752943</a>	LED driver, 700mA, phase dim, 32W 2
	<a href="#">KR772232</a>	LED driver, 700mA, 1-10V, 20W 2
	<a href="#">KR772142</a>	LED driver, 1050mA, 1-10V, 39W 2
	<a href="#">KR752733</a>	LED driver, 700mA, DALI, 20W 2
	<a href="#">KR772743</a>	LED driver, 1050mA, DALI, 38W 2
	<a href="#">KR772249</a>	LED driver, 1050mA, Casambi, 37W 2


**REMARKS**  
 1 Internal driver is touchdim compatible  
 2 Driver fits through the installation hole.

IP40







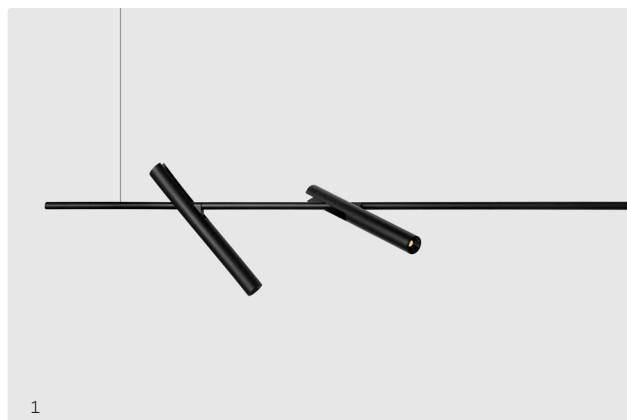

1

1. esprit pendant, black





# kreon esprit pendant

kreon esprit pendant are 3 or 4 individual lampheads mounted on a slender horizontal bar with steel tension cable suspension for maximum flexibility. It can be installed as an individual element or in a cluster of two or more.


Each lamphead of the luminaire is capable of individually rotating up to 355°, allowing for flexible positioning at any angle between 0° and 90°.

**Mounting options**  
Multiple mounting options available:

- gearbox with internal phasedim or DALI driver
- connection box
- plasterkit for recessed mounting



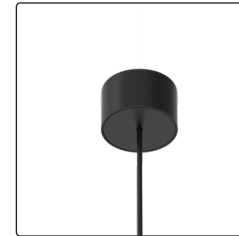
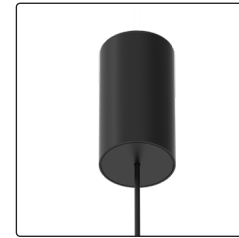


**Lamphead**  
Available in white, black, brushed bronze, brushed nickel, brushed gold and gun black.

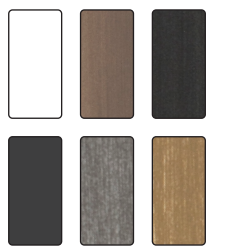



# kreon esprit pendant

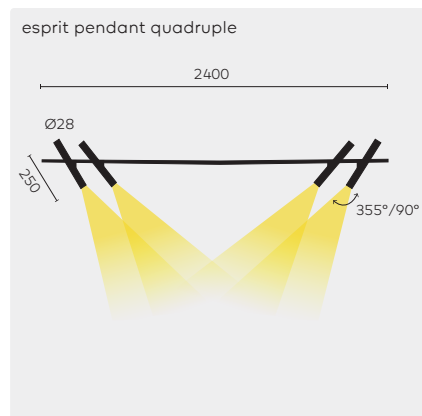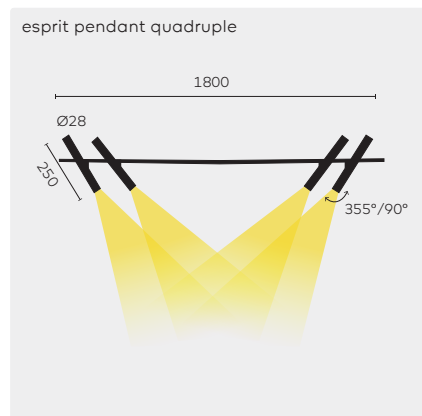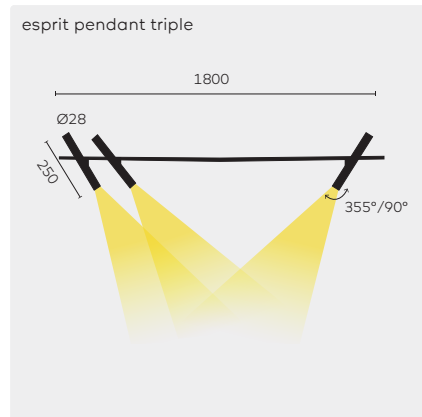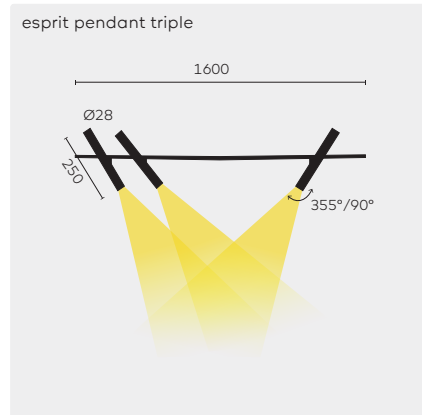

## esprit pendant triple ①

⚙ Gear: excl., L1600

## esprit pendant triple ①

⚙ Gear: excl., L1800

## esprit pendant quadruple ①

⚙ Gear: excl., L1800

## esprit pendant quadruple ①

⚙ Gear: excl., L2400

### ■ Required accessories

Installation boxes

See page 37-38

### ■ Optional accessories

Drivers

See page 37-38

Colour	KR-code	Light sources	9027 2700K, CRI90+	9030 3000K, CRI90+	SP Spot (20°)	DL Darklight (33°)	WDL Wide darklight (56°)	P2 Black painted lamphead	A4 Brushed bronze lamphead	A7 Brushed nickel lamphead	AB Brushed gold lamphead	A9 Gun black lamphead	Required accessories	Optional accessories
--------	---------	---------------	-----------------------	-----------------------	------------------	-----------------------	-----------------------------	------------------------------	-------------------------------	-------------------------------	-----------------------------	--------------------------	----------------------	----------------------

●	KR963732	①	●	●	●	●	●	●	●	●	●	●	■	■
●	KR963832	①	●	●	●	●	●	●	●	●	●	●	■	■
●	KR963842	②	●	●	●	●	●	●	●	●	●	●	■	■
●	KR963942	②	●	●	●	●	●	●	●	●	●	●	■	■

		CRI	CCT	Wattage	Drive Current	Fixture lumen
①	SP	CRI90+	2700K/3000K	3x2W	700mA	3x162lm
		CRI90+	2700K/3000K	3x3,2W	1050mA	3x218lm
	DL WDL	CRI90+	2700K/3000K	3x8W	700mA	3x368lm
		CRI90+	2700K/3000K	3x12W	1050mA	3x400lm
②	SP	CRI90+	2700K/3000K	4x2W	700mA	4x162lm
		CRI90+	2700K/3000K	4x3,2W	1050mA	4x218lm
	WDL WDL	CRI90+	2700K/3000K	4x8W	700mA	4x368lm
		CRI90+	2700K/3000K	4x12W	1050mA	4x400lm





### REMARKS

The pendant bar of esprit pendant may sag by gravity.  
Pendant cable: max. 2,5m

Gear: excl.  
⊗ IP40



# kreon esprit pendant mounting options

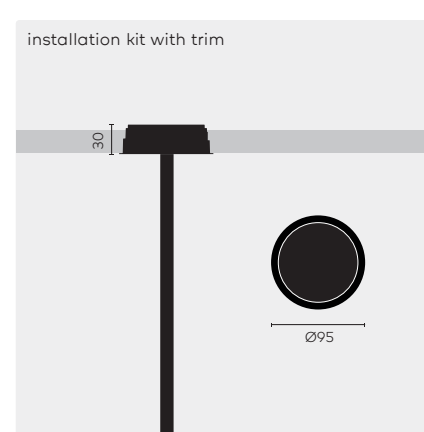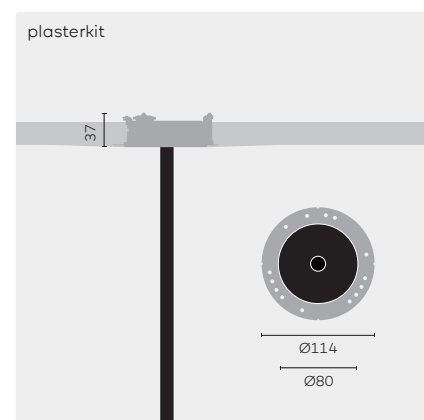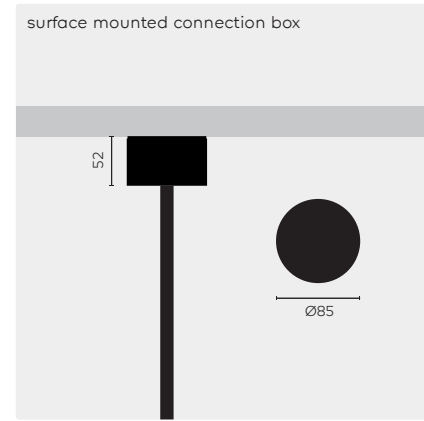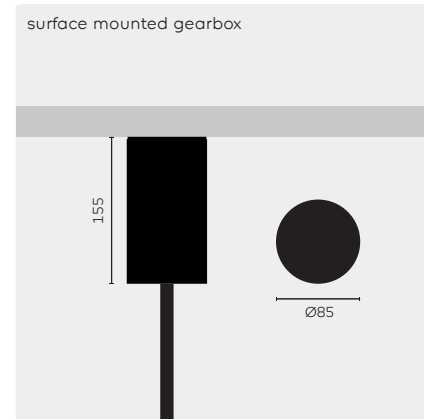

	Colour	KR-code	PD Phase dimming	DD DALI dimming 1	LV low voltage connection	Optional accessories
<b>surface mounted gearbox, 220-240Vdc, 50/60Hz</b> for SP Gear: incl., Ø85 H155	○	<a href="#">KR763591</a>	●	●		
	●	<a href="#">KR763592</a>	●	●		
<b>surface mounted gearbox, 220-240Vdc, 50/60Hz</b> for DL/WDL Gear: incl., Ø85 H155	○	<a href="#">KR763791</a>	●	●		
	●	<a href="#">KR763792</a>	●	●		
<b>surface mounted connection box</b> Gear: excl., Ø85 H52	○	<a href="#">KR763691</a>			●	■
	●	<a href="#">KR763692</a>			●	■
<b>trimless plasterkit for recessed mounting, no shadowgap</b> Gear: excl.		<a href="#">KR717104</a>				■
<b>trimless plasterkit for recessed mounting, shadowgap</b> Gear: excl.		<a href="#">KR717108</a>				■
<b>installation kit for recessed mounting , with trim</b> Gear: excl., Ø90 D110	○	<a href="#">KR717021</a>				■
	●	<a href="#">KR717022</a>				■

## Optional accessories

Driver	Code	Description
	<a href="#">KR762700</a>	LED driver, 700mA, ON/OFF, 11W 2
	<a href="#">KR752943</a>	LED driver, 700mA, phase dim, 32W 2
	<a href="#">KR772232</a>	LED driver, 700mA, 1-10V, 20W 2
	<a href="#">KR772142</a>	LED driver, 1050mA, 1-10V, 39W 2
	<a href="#">KR752733</a>	LED driver, 700mA, DALI, 20W 2
	<a href="#">KR772743</a>	LED driver, 1050mA, DALI, 38W 2
	<a href="#">KR772443</a>	LED driver, 1050mA, DALI, 60W
	<a href="#">KR772249</a>	LED driver, 1050mA, Casambi, 37W 2

## REMARKS

- 1 Internal driver is touchdim compatible.
- 2 Driver fits through the installation hole.

IP40







# kreon offices

## **kreon HQ**

Industrieweg-Noord 1152  
3660 Oudsbergen  
Belgium  
T +32 89 81 97 80  
belgium@kreon.com  
www.kreon.com

## **kreon Austria**

Eva-Maria-Mazzucco-Platz 2  
1220 Vienna  
Austria  
T +43 1 715 44 25  
austria@kreon.com

## **kreon China / The Belgian House**

Changle Road Lane 672, No. 33,  
Building No. 5,  
Jingan, Shanghai  
China  
T +86 183 1711 3541  
china@kreon.com

## **kreon France**

5, rue d'Aboukir  
75002 Paris  
France  
T +33 1 44 50 53 54  
france@kreon.com

## **kreon Germany**

Brühler Straße 11-13  
50968 Cologne  
Germany  
T +49 221 937 22 0  
germany@kreon.com

## **kreon Italy**

Via V. Forcella 5  
20144 Milano  
Italy  
T +39 02 89 42 08 46  
italy@kreon.com

## **kreon Middle East & India**

Dubai Airport Free Zone Area (DAFZA)  
West Wing 6  
Office 6 WA 634  
P.O. Box 293889  
Dubai  
United Arab Emirates  
T +971 56 705 2522  
middle.east@kreon.com

## **kreon Inc.**

### **North America & Canada**

20 Murray Hill Parkway  
Suite #180  
East Rutherford NJ 07073  
United States of America  
+1 (201) 298-44 48  
usa@kreon.com

### **kreon Scandinavia**

T +31 (0)6 52 39 16 80  
auke.bakker@kreon.com

### **kreon South East Asia**

T +65 62 22 33 93  
singapore@kreon.com

### **kreon Spain & Portugal**

Ángel Guimera 7-9 local C  
Barcelona 08017  
Spain  
T +34 600 462 551  
spain@kreon.com

### **kreon Switzerland**

Neufeldweg 6  
5103 Möriken  
Switzerland  
T +41 61 316 74 01  
switzerland@kreon.com

## **kreon The Netherlands**

Danzigerbocht 39  
1013 AM Amsterdam  
The Netherlands  
T +31 (0)6 52 391 680  
the.netherlands@kreon.com

## **kreon Turkey**

Sehit Murat Demirli Cad.  
Resadiye Yolu 76  
Alemdag-Ümraniye 34794  
Istanbul  
Turkey  
T +90 216 430 86 00  
turkey@kreon.com

## **kreon UK**

67 Maltings Place  
169 Tower Bridge Road  
London  
SE1 3LJ  
United Kingdom  
T +44 (0)20 7740 2112  
uk@kreon.com